




Catalog Number: T364811PT334MR

Amps	Volts Max.	Phase/Wires	Unprotected Fault Current Rating	Enclosure Size		
				Width*	Height	Depth
400	600V	3 Phase, 3 Wire	42,000	36"	48"	11"


*Width includes 12" wide potential transformer enclosure mounted on left side of cabinet.




INTERIOR DETAIL

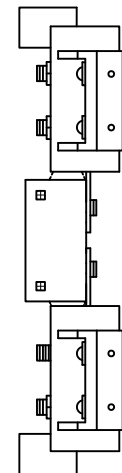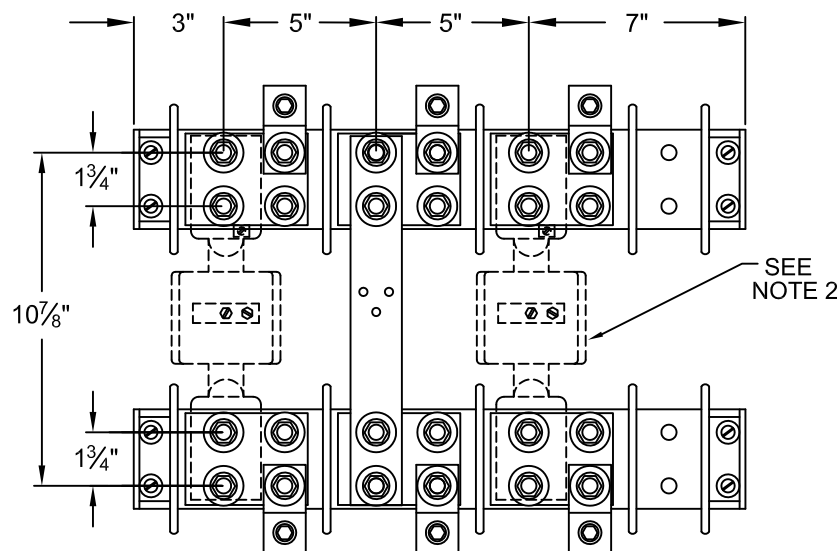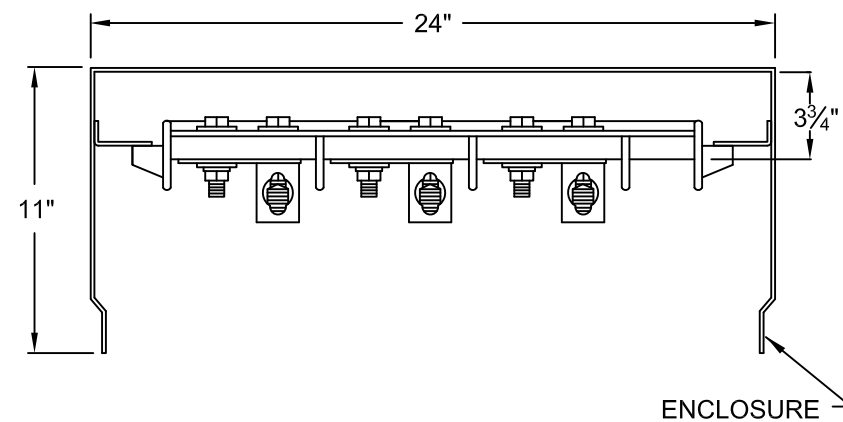

FRONT INTERIOR VIEW

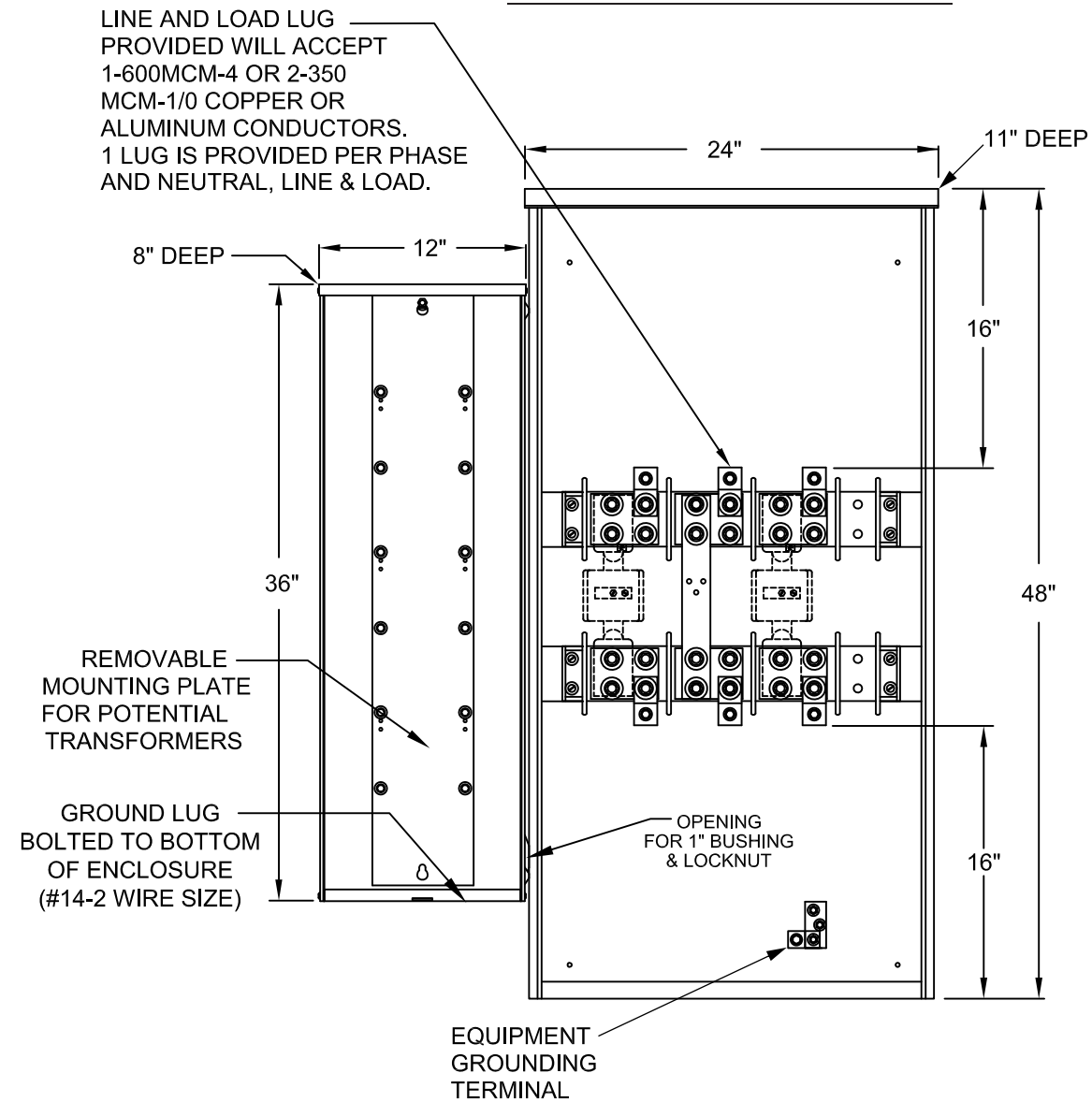

FRONT ENCLOSED VIEW

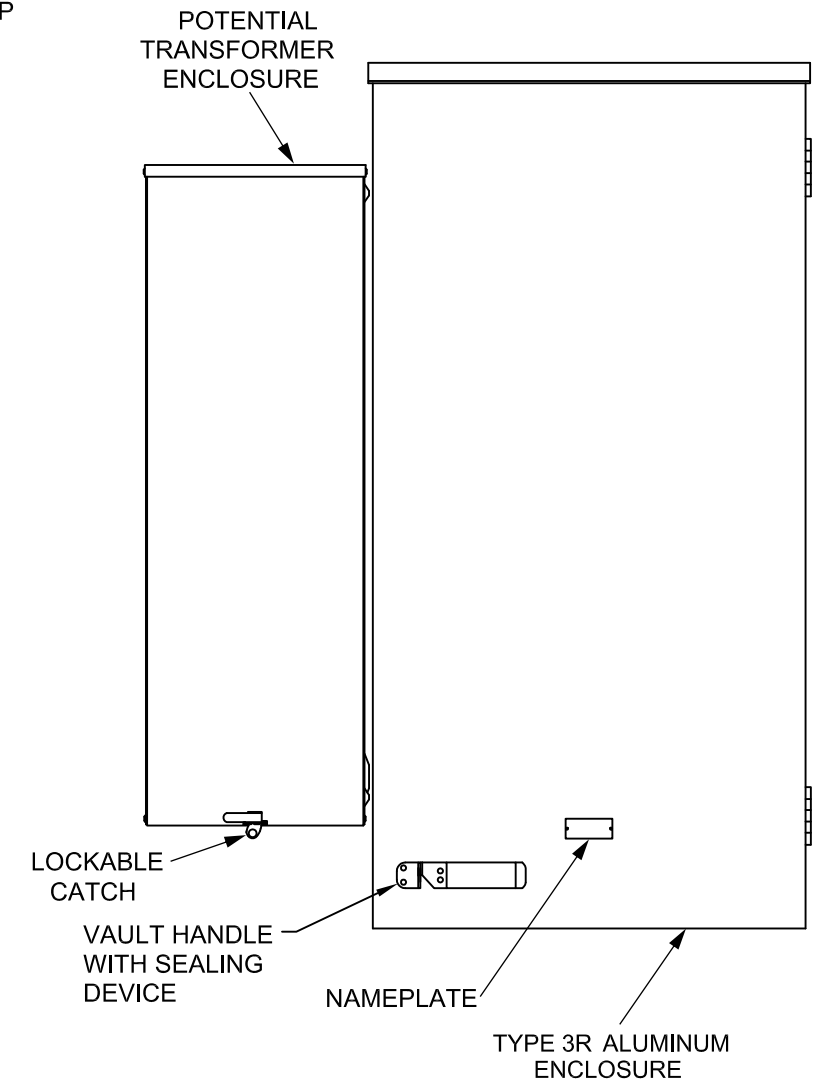

GENERAL NOTES:-

- 1 C/T AND LUG LANDING PADS AND NEUTRAL ARE RATED 400 AMPS.
- 2 CURRENT TRANSFORMERS ARE PROVIDED BY THE UTILITY CO.
- 3 LINE AND LOAD LUG PROVIDED WILL ACCEPT 1-600MCM-#4 OR 2-350MCM-1/0 COPPER OR ALUMINUM CONDUCTORS. 1 LUG IS PROVIDED PER PHASE & NEUTRAL AS SHOWN, LINE & LOAD.

TALON

Metering

Description: **400A, 600V AC Max, 3Ph 3Wire, Outdoor Current Transformer Cabinet**