
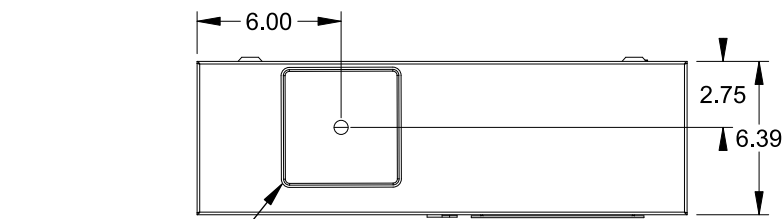



Catalog Number: 48707-82

Features and Ratings

- Ringless Type Meter Socket
- 320A Continuous, 400A Max., 600V AC
- Outdoor Enclosure (NEMA Type 3R)
- Painted G90 Steel Enclosure
- 3 Phase, 4 Wire, Commercial Socket
- 7 Jaw Meter Socket
- Meter Socket Type HQ-7DSW
- For Overhead & Underground Service
- HD Type Hub Opening w/Large Coverplate
- 7/8" Barrel Lock Provision w/Bracket
- Lever Bypass
- Side Wired


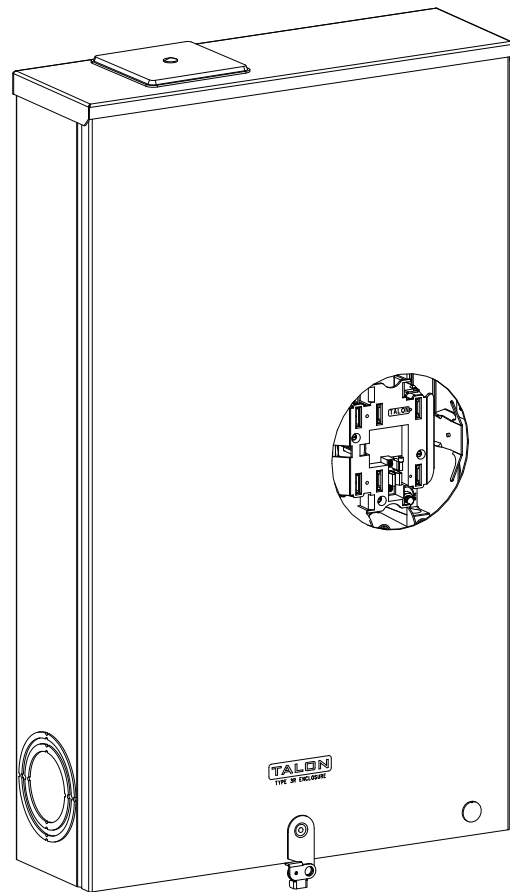


LARGE COVERPLATE

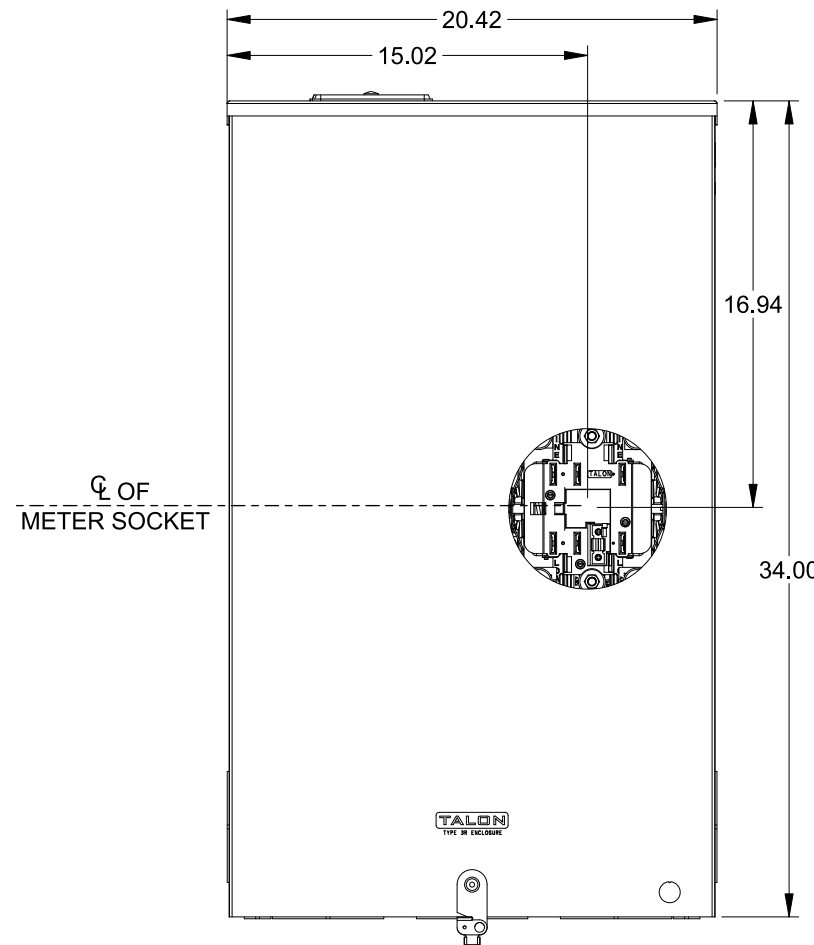


CL OF METER SOCKET

VIEW SHOWN WITH COVER REMOVED

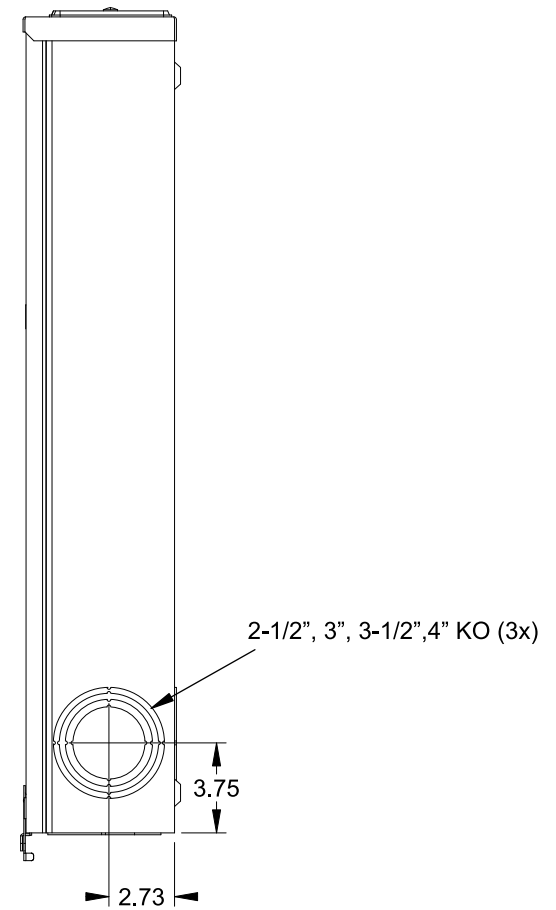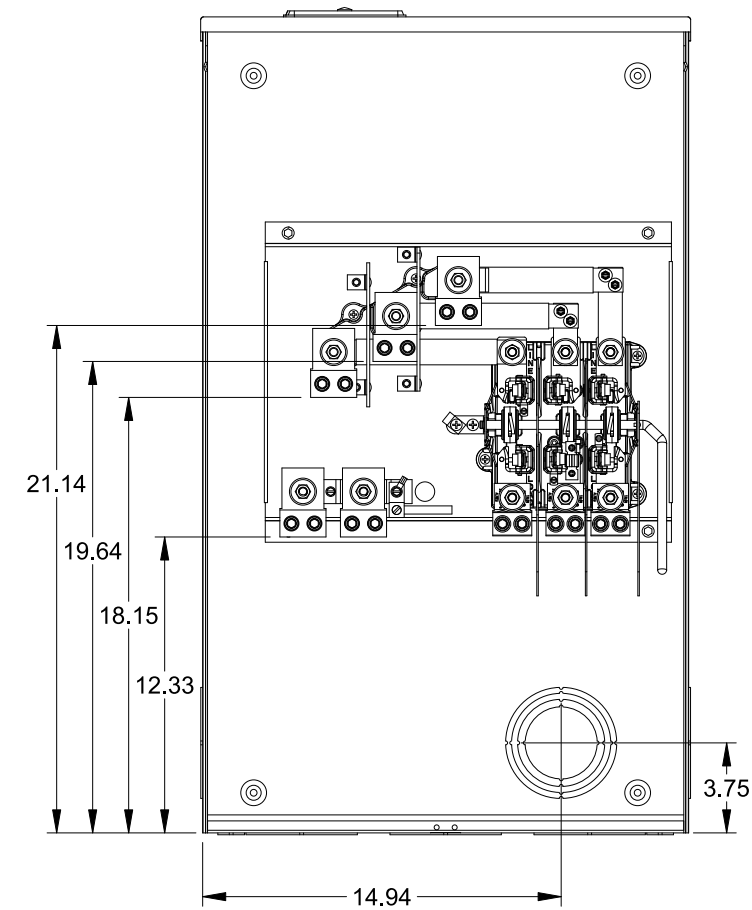

2-1/2", 3", 3-1/2", 4" KO (3x)

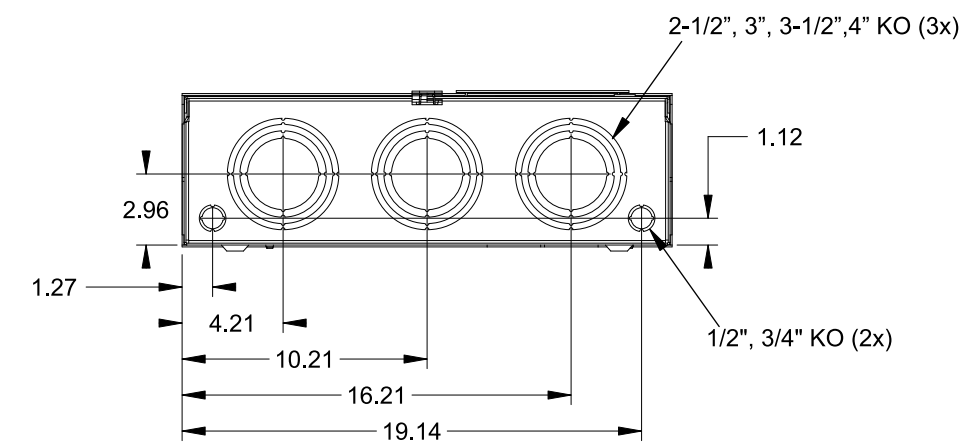

Accessories

CONDUIT HUBS (HD Type)	
TRADE SIZE	CATALOG No.
3 INCH	EC56856 or H56856-2
3-1/2 INCH	EC56857 or H56857-2
4 INCH	EC56858 or H56858-2
Hub Cover Plate	EC56933 or H56933S

Meter Opening Cover Plate
Cat No: H659-0162

Connectors, Wire Sizes and Torques

CONNECTOR	PART NO.	WIRE SIZE	HEX	TORQUE
LINE	56732-2	(2) #6 - 350 kcmil	5/16"	275 LB-IN
LOAD	56732-2	(2) #6 - 350 kcmil	5/16"	275 LB-IN
NEUTRAL	56732-2	(2) #6 - 350 kcmil	5/16"	275 LB-IN
GROUND	67554A	#14 - 2 AWG	..	50 LB-IN

© 2016 Copyright Siemens Industry, Inc.



Meter Socket

Description: 320A Cont, 7 Jaw, HQ-7DSW, 600V AC, Painted Steel Enclosure

JEL 3/18/16 DO NOT SCALE DRAWING Dwg No: 48707-82