

CATALOG NUMBER

# ECINSGB20

**electricCenter**  
ACCESSORIES

## Ground Bar Kit Insulated, 20 position, #14-4 AWG

Same As:

- INSGB20
- EINSGB20



## INSULATED GROUND BAR INSTALLATION INSTRUCTIONS



### **⚠ DANGER**

**Hazardous Voltage.**  
Will cause death, serious injury  
or substantial property damage.

Turn off power supplying this  
equipment before working inside.





### **SAFETY INSTRUCTIONS**

1. Turn off and lock off the power supplying the load center before working inside.
2. Mounting holes for insulated ground bars are provided on both sides in the back of the box as indicated in **Fig. 1**. (For indoor devices only, use hammer to flatten the lance adjacent to the upper mounting hole)
3. Referring to **Fig. 2**, bend insulation 90 degrees and position it over the mounting holes.
4. Place insulated ground bar on insulation and secure it to the box with #8-32 self threading screws provided. Tighten screws to 15 to 20 lb-ins.

**Note:** This instruction outlines the recommended installation procedure.

See wiring diagram on device for wire sizes and torques.

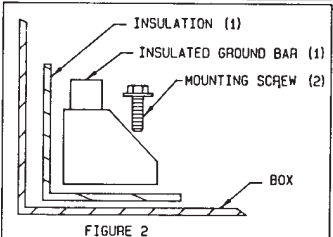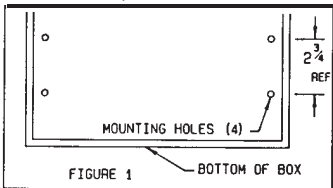

© 2010 Copyright Siemens Industry, Inc.

4810409 Rev.B

Siemens Industry, Inc.

Norcross, Georgia U.S.A.

Assembled in Mexico