


## 3VA Circuit Breakers: Compact. Global. Next Gen!

Stocking suggestion and conversion tool

### 3VA Breaker Crosses


Description	Sentron	VL	G frame	EG	3VA
15A 3P 25K @480V	ED63B015L	N/A	NGG3B015L	NEG3B015L	<a href="#">3VA5195-4EC31-0AA0</a>
20A 3P 25K @480V	ED63B020L	N/A	NGG3B020L	NEG3B020L	<a href="#">3VA5120-4EC31-0AA0</a>
50A 3P 25K @480V	ED63B050L	NDK3B050L	NGG3B050L	NEG3B050L	<a href="#">3VA5150-4EC31-0AA0</a>
100A 3P 25K @480V	ED63B100L	NDK3B100L	NGG3B100L	NEG3B100L	<a href="#">3VA5110-4EC31-0AA0</a>
125A 3P 25K @480V	ED63B125L	NDK3B125L	NGG3B125L	NEG3B125L	<a href="#">3VA5112-4EC31-0AA0</a>
150A 3P 35K @480V	FXD63B150L/FD63B150L	NDK3B150L	N/A	N/A	<a href="#">3VA5215-5EC31-0AA0</a>
200A 3P 35K @480V	FXD63B200L/FD63B200L	NFK3B200L/NFG3B200L	N/A	N/A	<a href="#">3VA5220-5EC31-0AA0</a>
225A 3P 35K @480V	FXD63B225L/FD63B225L	NFK3B225L/NFG3B225L	N/A	N/A	<a href="#">3VA5222-5EC31-0AA0</a>
250A 3P 35K @480V	FXD63B250L/FD63B250L	NFK3B250L/NFG3B250L	N/A	N/A	<a href="#">3VA5225-5EC31-0AA0</a>

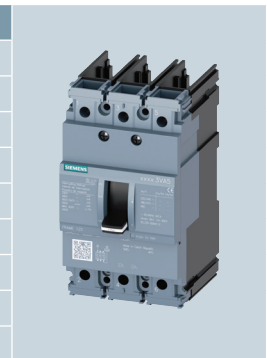

- Note: 1) 3VA breakers do not come with lugs, part numbers listed for other legacy products include lugs .  
 2) Breakers crossed have at a minimum the ratings in the description box, in some cases higher.  
 3) For a non-adjustable instantaneous version breaker sub -ED- in place of -EC- in the part number.

### 3VA Lugs

Description	3VA "Standard" lugs	Description	Cables Per Phase
125A TMTU	<a href="#">3VA9133-0JB11</a>	3-Pole #14-3/0	1
250A TMTU	<a href="#">3VA9233-0JB12</a>	3-Pole #6-350KCMIL	1
150A ETU	<a href="#">3VA9143-0JB11</a>	3-Pole #14-1/0	1
250A ETU	<a href="#">3VA9243-0JB12</a>	3-Pole #6-350KCMIL	1
400A-600A ETU	<a href="#">3VA9373-0JB13</a>	3-Pole #1 - 600KCMIL	1

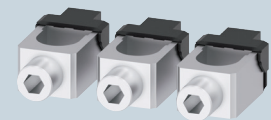


### 3VA Internal Accessories

Description	MLFB Part Number
Shunt Trip Flex 120V	<a href="#">3VA9978-0BA22</a>
Shunt Trip 24VDC	<a href="#">3VA9978-0BA20</a>
HQ Aux 1 Slot	<a href="#">3VA9978-0AA12</a>
UVR 120V	<a href="#">3VA9978-0BB24</a>
Trip Alarm Switch	<a href="#">3VA9978-0AB12</a>



### 3VA Handle Kits

Description	125A(3VA51) TMTU	250A(3VA52) TMTU
Max Flex 1/3R/12 - 36" cable	<a href="#">3VA9137-0CK12</a>	<a href="#">3VA9277-0CK12</a>
Rotary Handle 1/3R/12 - 300mm shaft	<a href="#">3VA9137-0FK31</a>	<a href="#">3VA9277-0FK31</a>
Rotary Handle 1/3R/13 Illuminated - 300mm shaft	<a href="#">3VA9137-0FK33</a>	<a href="#">3VA9277-0FK33</a>
Flange Mount 1/3R/12 - 200-400mm adj. shaft	<a href="#">3VA9138-0DK72</a>	<a href="#">3VA9278-0DK72</a>

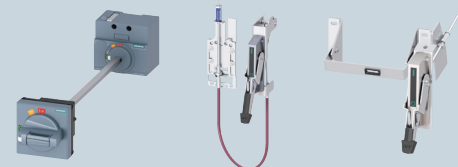

Note: The above sample of available products as well as the full catalog of over 2000 breaker and accessories currently available can be found in our catalog or via our configurator. Please visit [usa.siemens.com/3VA](http://usa.siemens.com/3VA)



**Published by  
Siemens 2020**

Siemens Industry, Inc.  
3617 Parkway Ln  
Peachtree Corners, GA 30092

Siemens Technical Support:1-800-333-7421  
info.us@siemens.com

Subject to change without prior notice  
Order No. PDFL-3VASTK-1120  
Printed in USA-CP  
All Rights Reserved  
© 2020, Siemens Industry, Inc.

The technical data presented in this document is based on an actual case or on as-designed parameters, and therefore should not be relied upon for any specific application and does not constitute a performance guarantee for any projects. Actual results are dependent on variable conditions. Accordingly, Siemens does not make representations, warranties, or assurances as to the accuracy, currency or completeness of the content contained herein. If requested, we will provide specific technical data or specifications with respect to any customer's particular applications. Our company is constantly involved in engineering and development. For that reason, we reserve the right to modify, at any time, the technology and product specifications contained herein.