





Catalog Number: 47705-82KCPL

Features and Ratings

- Ringless Type Meter Socket
- 320A Continuous, 400A Max., 600V AC
- Outdoor Enclosure (NEMA Type 3R)
- Painted G90 Steel Enclosure
- 1 Phase, 3 Wire, Commercial Socket
- 5 Jaw Meter Socket
- Meter Socket Type HQ-5DT
- For Overhead & Underground Service
- HD Type Hub Opening, Cover Plate Included
- Lever Bypass
- 7/8" Barrel Lock Provision

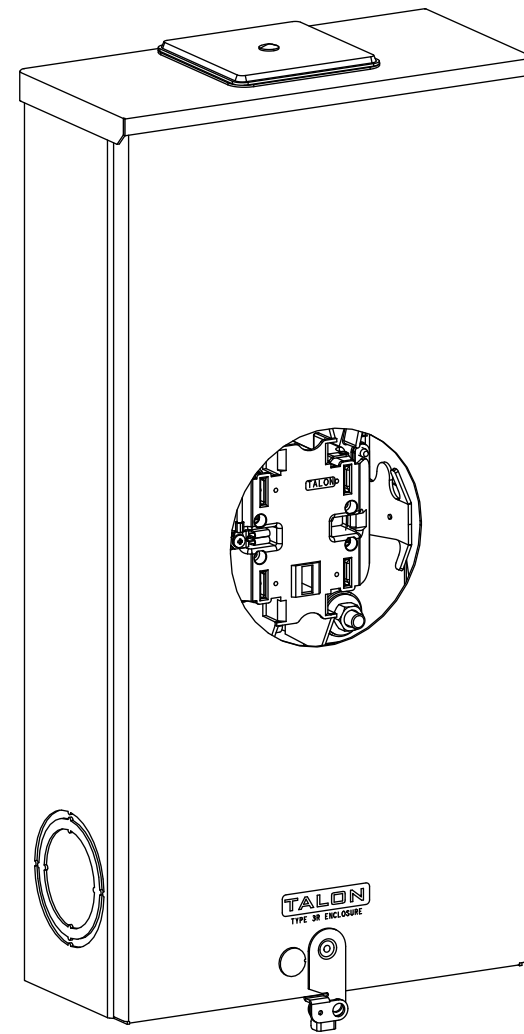

TYPE HD (LARGE) HUB OPENING WITH COVERPLATE INSTALLED

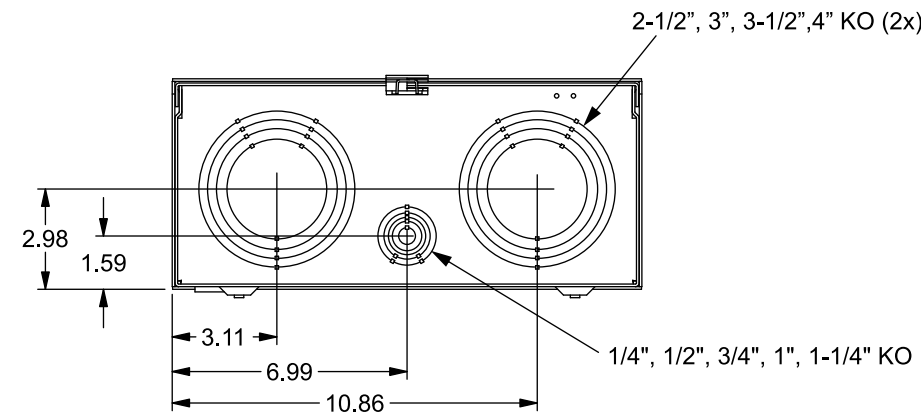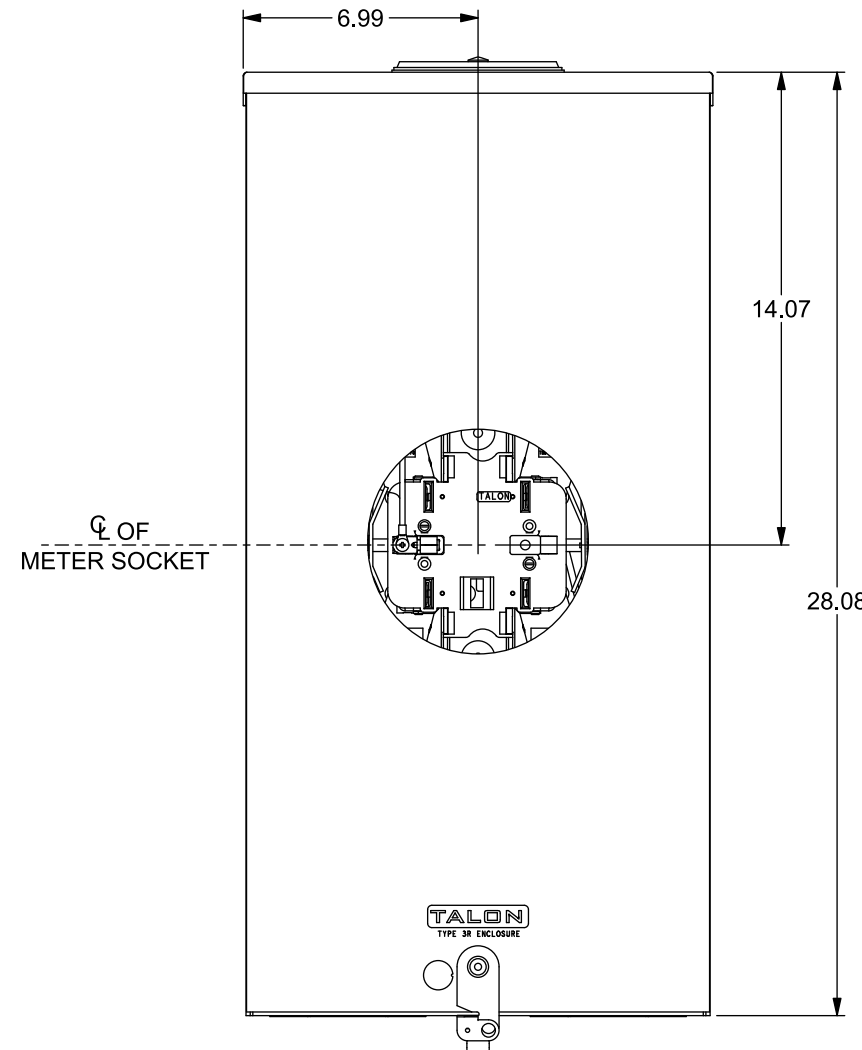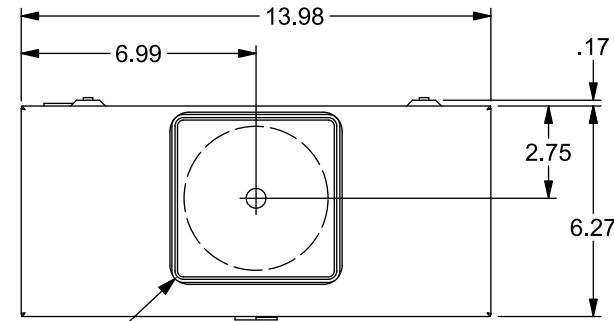

Accessories



CONDUIT HUBS (HD Type)	
TRADE SIZE	CATALOG No.
3 INCH	EC56856 or H56856-2
3-1/2 INCH	EC56857 or H56857-2
4 INCH	EC56858 or H56858-2
Hub Cover Plate	EC56933 or H56933S

Meter Opening Cover Plate
Cat No: H659-0162

Connectors, Wire Sizes and Torques

CONNECTOR	PART No.	WIRE SIZE	TORQUE
LINE	60162	#4-600 (2) 1/0-250 MCM	500 IN-LBS.
LOAD/NEUTRAL	56732	(2)#4-350 MCM	275 IN-LBS.
GROUND	67754	#14 - 2/0 AWG	50 IN-LBS.

VIEW SHOWN WITH COVER REMOVED

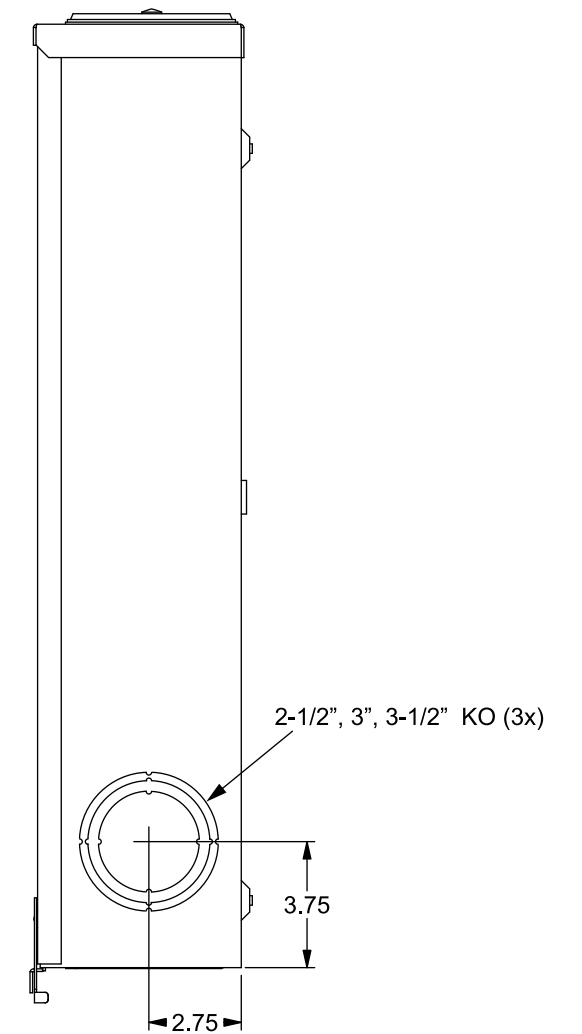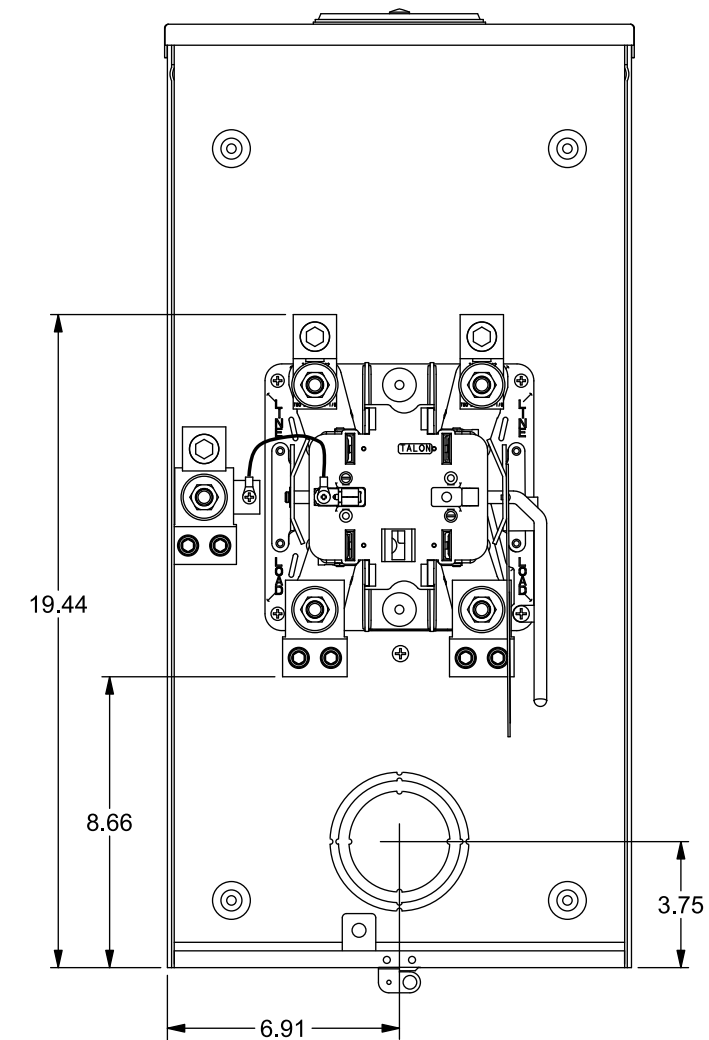

© 2018 Copyright Siemens Industry, Inc.

TALON

Meter Socket

Description: **320A Cont, 7 Jaw, HQ-5DT, 7/8 BL, 600V AC, Painted Steel Enclosure**

KAM 1/22/18 DO NOT SCALE DRAWING Dwg No: **47705-82KCPL**