

Catalog Number: UA3717-ZB

Features and Ratings

- Ringless Type Meter Socket
- 200A Continuous, 3 Position, 270A Overall
- Outdoor Enclosure (NEMA Type 3R)
- Painted G90 Steel
- 1 Phase, 3 Wire, 600V AC
- 5 Jaw
- Horn Bypass
- For Overhead or Underground Service
- HD Hub Opening, with Cover Plate Factory Installed

Accessories

Meter Opening Cover Plate
Cat No: H659-0162



5th Jaw Kit
Cat. No: 659-0121

| CONDUIT HUBS (HD Type) | |
|------------------------|---------------------|
| TRADE SIZE | CATALOG No. |
| 3 INCH | EC56856 or H56856-2 |
| 3-1/2 INCH | EC56857 or H56857-2 |
| 4 INCH | EC56858 or H56858-2 |
| Hub Cover Plate | EC56933 or H56933S |

Connectors, Wire Sizes and Torques




| CONNECTOR | WIRE SIZE | TORQUE |
|----------------|-----------------|--------------|
| LINE, NEUTRAL* | 1/0 - 600 kcmil | 375 IN.-LBS. |
| LOAD, NEUTRAL | #6 - 350 kcmil | 250 IN.-LBS. |
| GROUND | #14 - 2 (CU) | 50 IN.-LBS. |

* External Hex Drive 1/2"
* Internal Hex Drive 5/16"

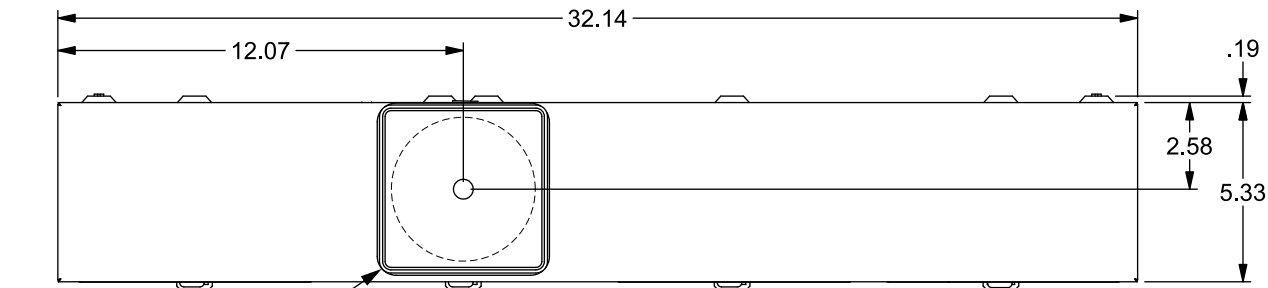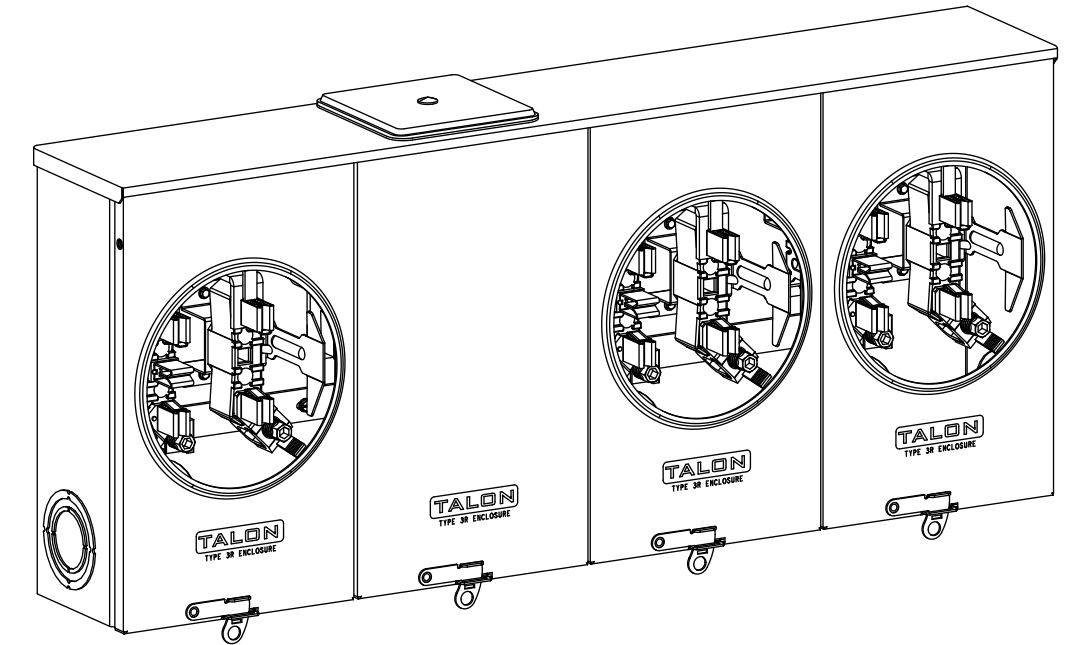

HD (Large) Hub Opening
w/Cover Plate Installed

View Shown with Covers Removed

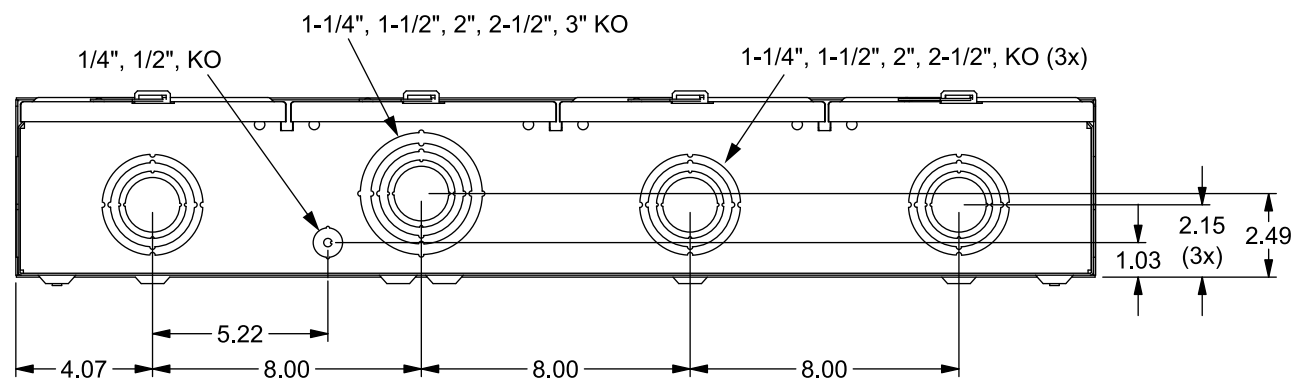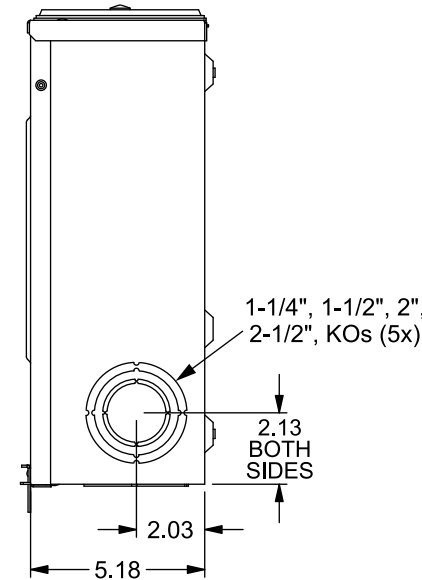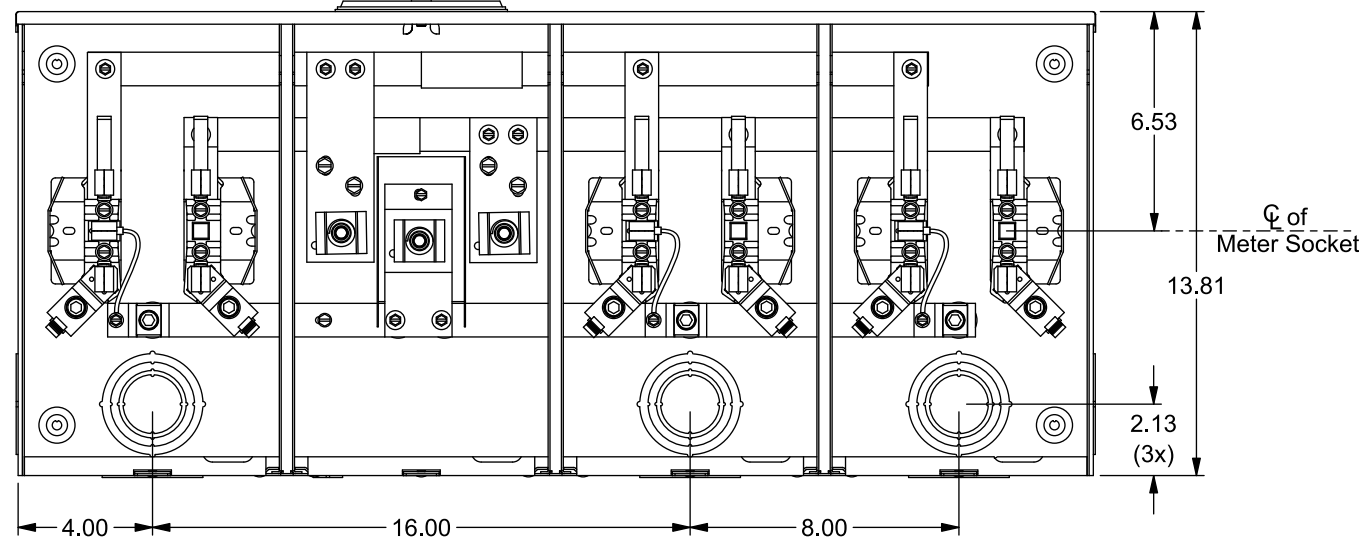

© 2018 Copyright Siemens Industry, Inc.

TALON

Multi-Position Metering

Description: **200A Cont, 5 Jaw, A14-3POS, Horn Bypass, 600VAC, Painted G90 Steel**

KAM 6/26/18 DO NOT SCALE DRAWING Dwg No: **UA3717-ZB**