






# Catalog Number: 44305-02MR

## Features and Ratings

- Ringless Type Meter Socket
- 200A Continuous, 250A Max.
- Outdoor Enclosure (NEMA Type 3R)
- Painted G90 STEEL
- 1 Phase, 3 Wire, 600V AC
- 5 Jaw, 6 O'clock 5th Jaw
- HQ Clamp Jaw Lever Bypass Meter Socket
- For Overhead or Underground Service
- HD Hub Opening With HD-RX Adapter Plate and RX Coverplate Installed
- Two Ground Lugs

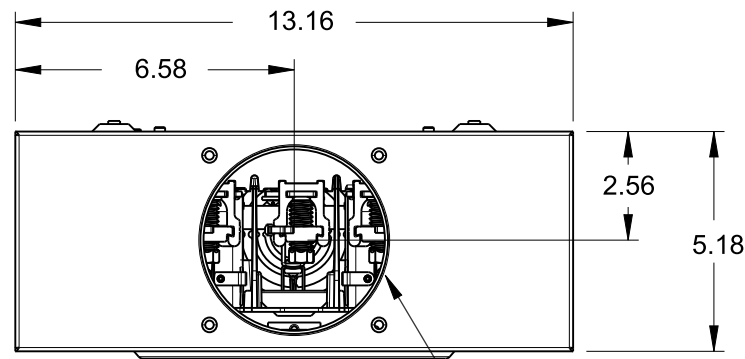

HD HUB PROVISION

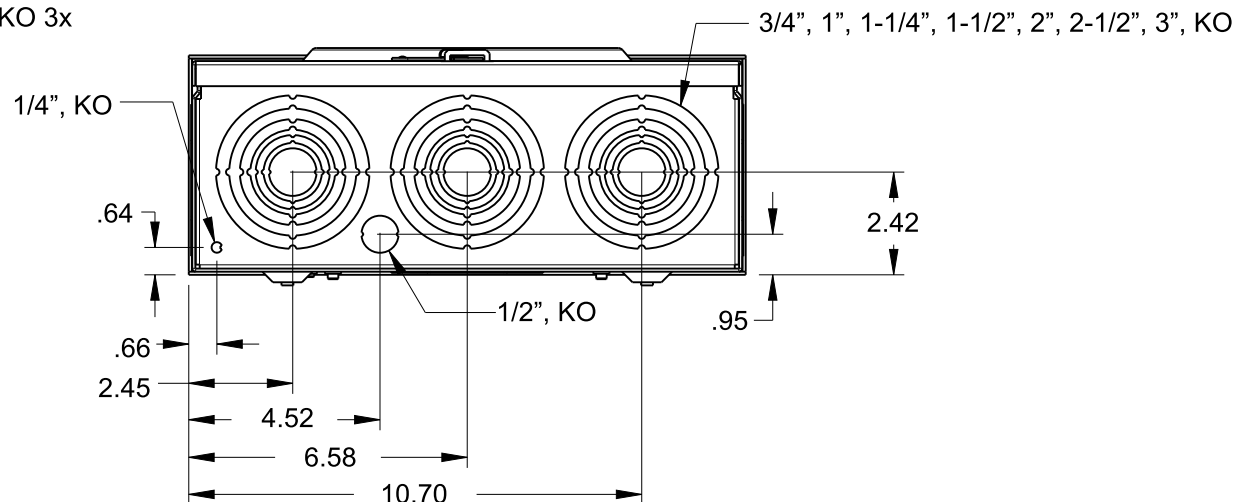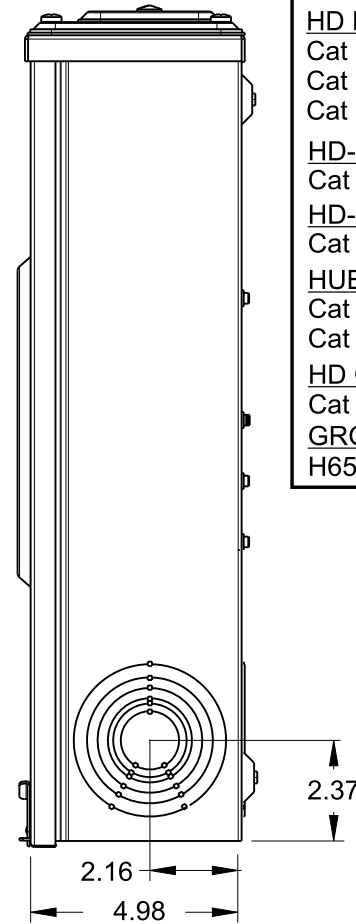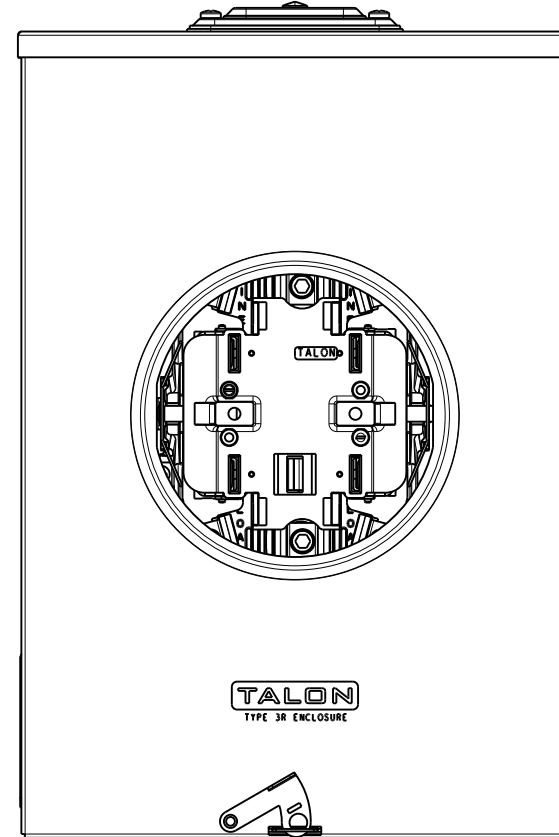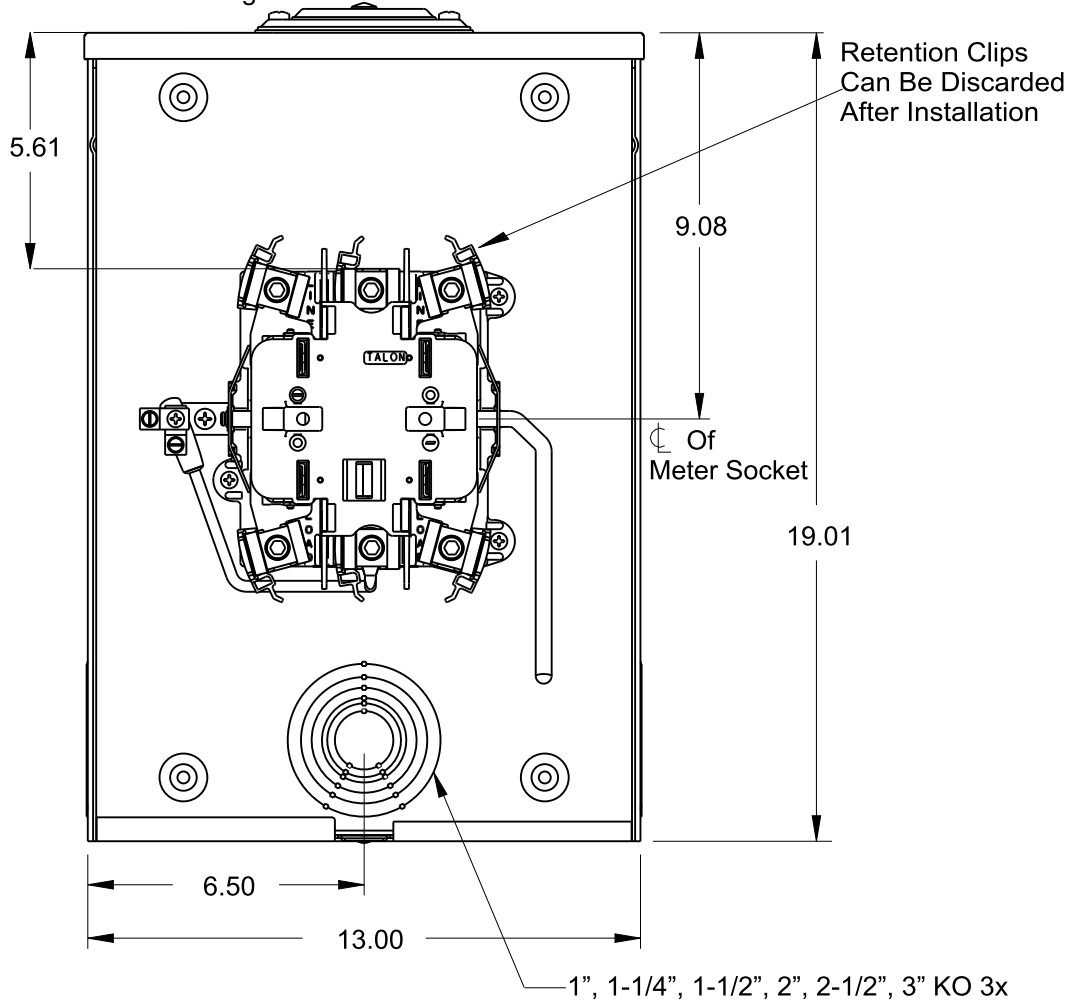

### Accessories

Meter Opening Cover Plate  
Cat No: H39968

#### RX HUB KITS

- Cat No: H38597-2 (1.25")
- Cat No: H38598-2 (1.50")
- Cat No: H38599-2 (2.00")
- Cat No: H38600-2 (2.50")

#### RX HUB KITS

- Cat No: EC38597 (1.25")
- Cat No: EC38598 (1.50")
- Cat No: EC38599 (2.00")
- Cat No: EC38600 (2.50")

#### HD HUB KITS

- Cat No: H56856-2 (3.00")
- Cat No: H56857-2 (3.50")
- Cat No: H56858-2 (4.00")

#### HD HUB KITS

- Cat No: EC56856 (3")
- Cat No: EC56857 (3.50")
- Cat No: EC56858 (4")

#### HD-RX Adapter Plate:

Cat No: H9747-1113

#### HD-RX Adapter Plate:

Cat No: EC9747-1113

#### HUB COVER PLATE

Cat No: H38595-1 (RX)

Cat No: H56933-2 (HD)

#### HD COVERPLATE

Cat No: EC56933S


#### GROUND LUG KIT

H6509991 #14-2 45 LB-IN

### Lugs, Wire Sizes and Torques

LOCATION	LUG SIZE	TORQUE
LINE*	#6-350 kcmil	275 LB-IN
LOAD*	#6-350 kcmil	275 LB-IN
NEUTRAL*	#6-350 kcmil	275 LB-IN
GROUND	#14-2	45 LB-IN

\* External Hex drive 1/2"  
\* Internal Hex drive 5/16"

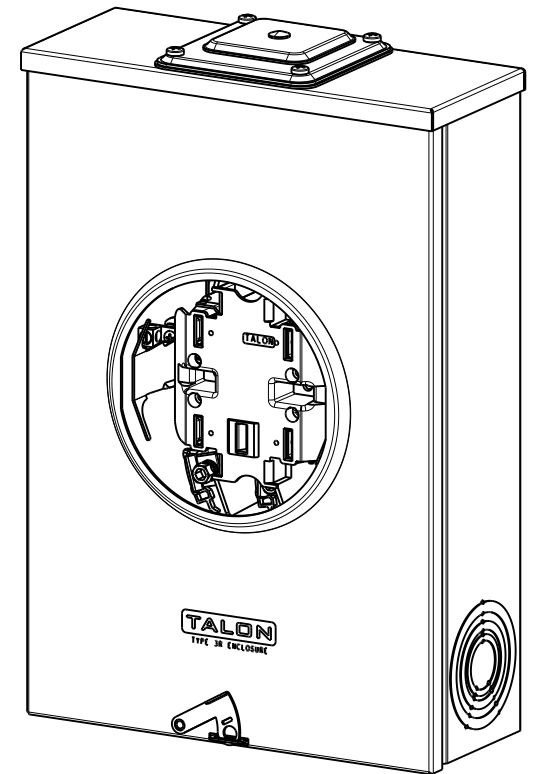

**TALON**

**Meter Socket**

Description:  
**200A Cont, 5 Jaw, HQ5U, 600V AC,  
Painted G90 Steel**