




Catalog Number: 43217-02

Features and Ratings




- Ringless Type Meter Socket
- 125A Continuous, 600V AC
- Outdoor Enclosure (NEMA Type 3R)
- Painted G90 Steel Enclosure
- 3 Phase, 4 Wire
- 7 Jaw Meter Socket
- Meter Socket Type MQ-71NB
- For Overhead Service
- Non-Clamping Lever Bypass
- 1-1/2" RX Type Hub Installed

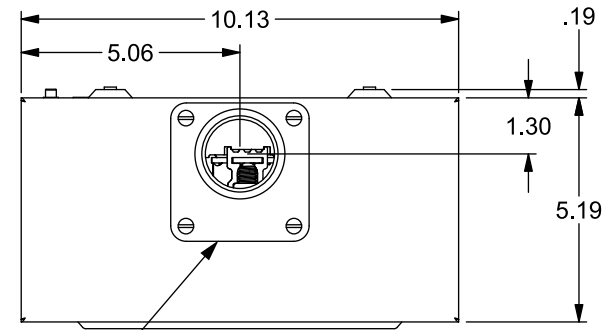

1-1/2" TYPE RX (SMALL) HUB INSTALLED

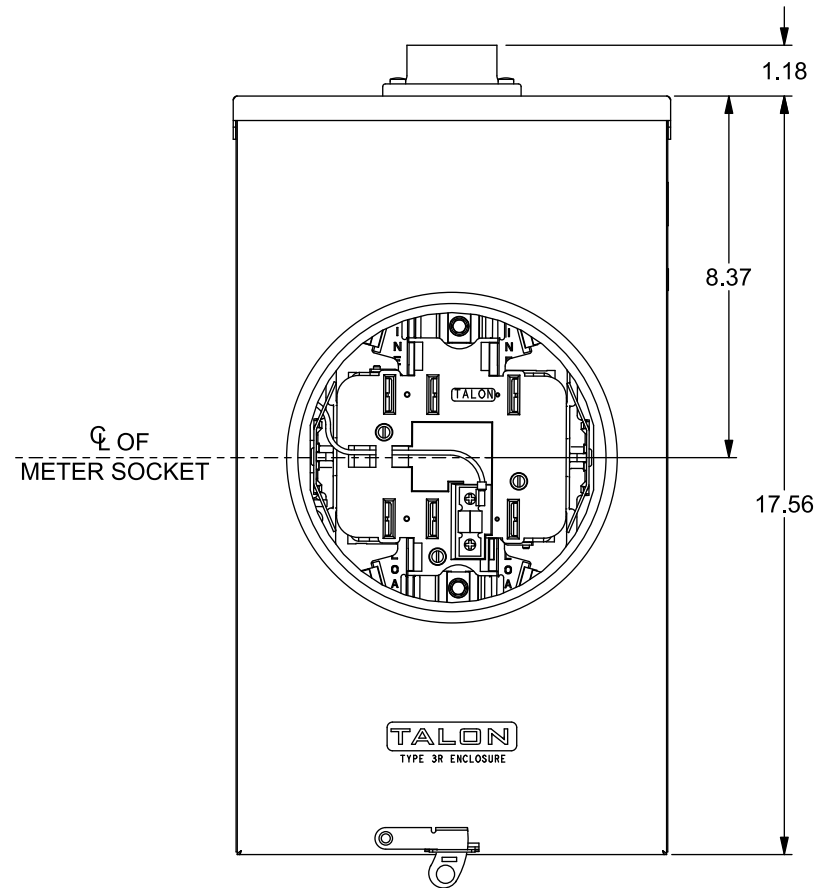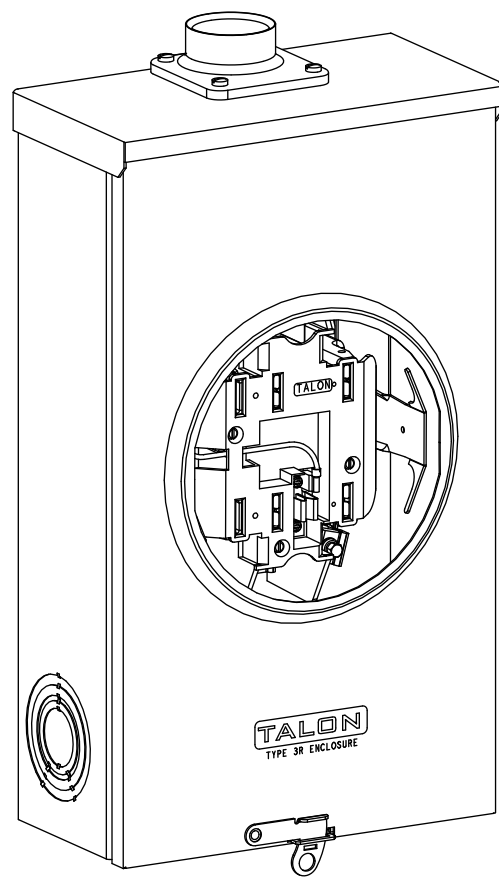

VIEW SHOWN WITH COVER AND SHIELD REMOVED

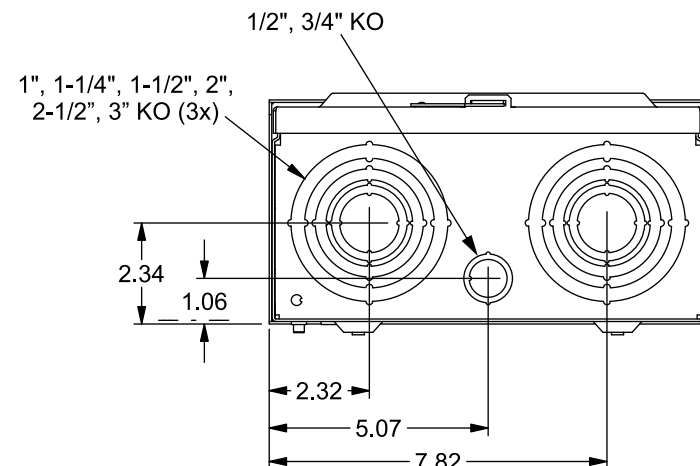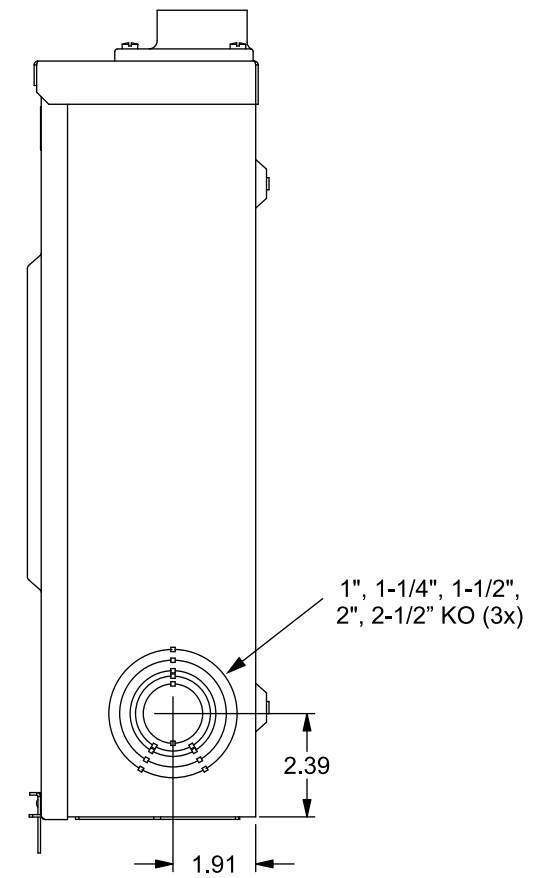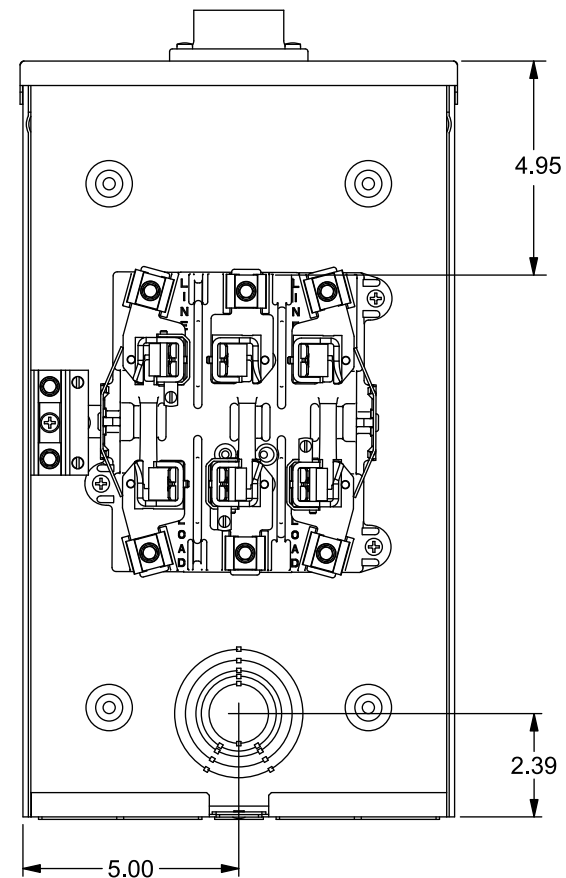

Accessories

CONDUIT HUBS (RX Type)	
TRADE SIZE	CATALOG No.
1-1/4 INCH	EC38597 or H38597-2
1-1/2 INCH	EC38598 or H38598-2
2 INCH	EC38599 or H38599-2
2-1/2 INCH	EC38600 or H38600-2
Hub Cover Plate	EC38595 or H38595-1

Meter Opening Cover Plate
Cat No: H659-0162

Connectors, Wire Sizes and Torques

CONNECTOR	WIRE SIZE	TORQUE
LINE, LOAD, NEUTRAL	#6 - 2/0	50 IN-LBS.
GROUND	#2 - 14	50 IN-LBS.

© 2017 Copyright Siemens Industry, Inc.

TALON
Meter Socket

Description: **200A Cont, 7 Jaw, MQ-7U, 1-1/2" Hub, OH, 600V AC, Painted Steel Enclosure**

KAM 12/14/17 DO NOT SCALE DRAWING Dwg No: **43217-02**