

Catalog Number: 9837-8503

**Features and Ratings**

- Ringless Type Meter Socket
- 20A Continuous, 600V AC
- Outdoor Enclosure (NEMA Type 3R)
- Painted G90 Steel
- 3 Phase, 4 Wire
- 13 Jaw Meter Socket
- Meter Socket Type PTS-13
- For Overhead or Underground Service
- RX Type Hub Opening, Cover Plate Installed

**Connectors, Wire Sizes and Torques**

CONNECTOR	WIRE SIZE	TORQUE
CURRENT, POTENTIAL, GROUND	#14 - 10 AWG	35 IN.-LBS.
CURRENT, POTENTIAL, GROUND	#8 AWG	40 IN.-LBS.
CURRENT, POTENTIAL, GROUND	#6 AWG	45 IN.-LBS.
POTENTIAL, GROUND	#4 AWG	45 IN.-LBS.
GROUND	#3 - 2 AWG	50 IN.-LBS.



**Accessories**

**CONDUIT HUBS (RX Type)**

TRADE SIZE	CATALOG No.
3/4 INCH	H38594-2
1 INCH	H38596-2
1-1/4 INCH	H38597-2
1-1/2 INCH	H38598-2
2 INCH	H38599-2
2-1/2 INCH	H38600-2

Steel Hub Cover Plate Kit  
Cat No: H38595-1

Aluminum Hub Cover Plate Kit  
Cat No: H38595-2

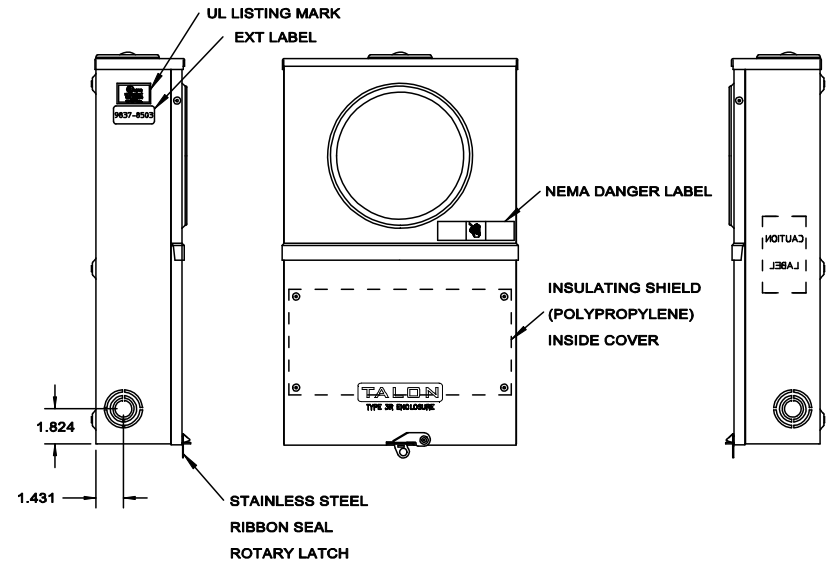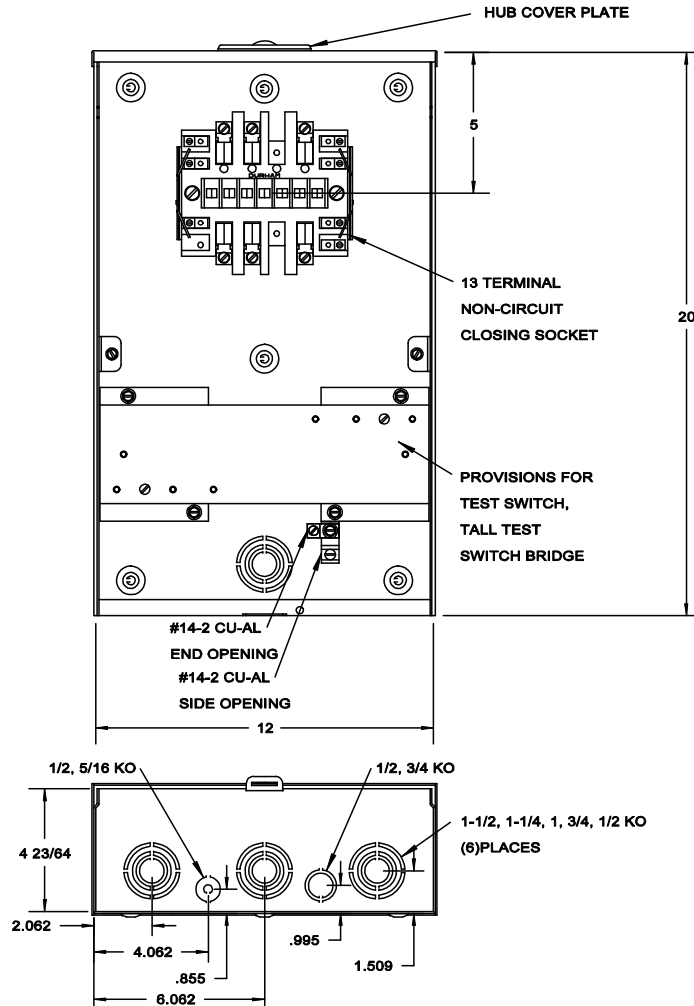

© 2017 Copyright Siemens Industry, Inc.

<b>TALON</b>	
<b>PTS13</b>	
Description: <b>SKT/SW 20A 13T HCP</b>	
CQ 08/25/2018	DO NOT SCALE DRAWING
Dwg No.	<b>9837-8503</b>