
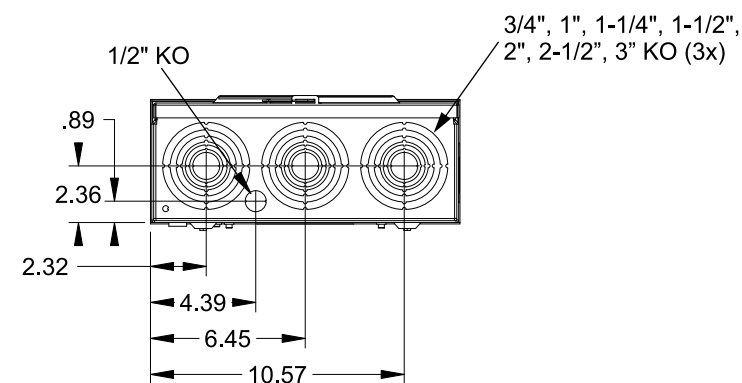
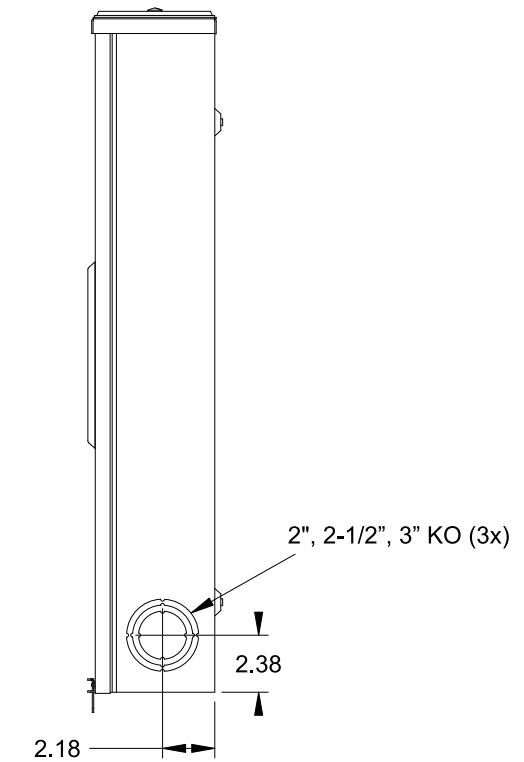
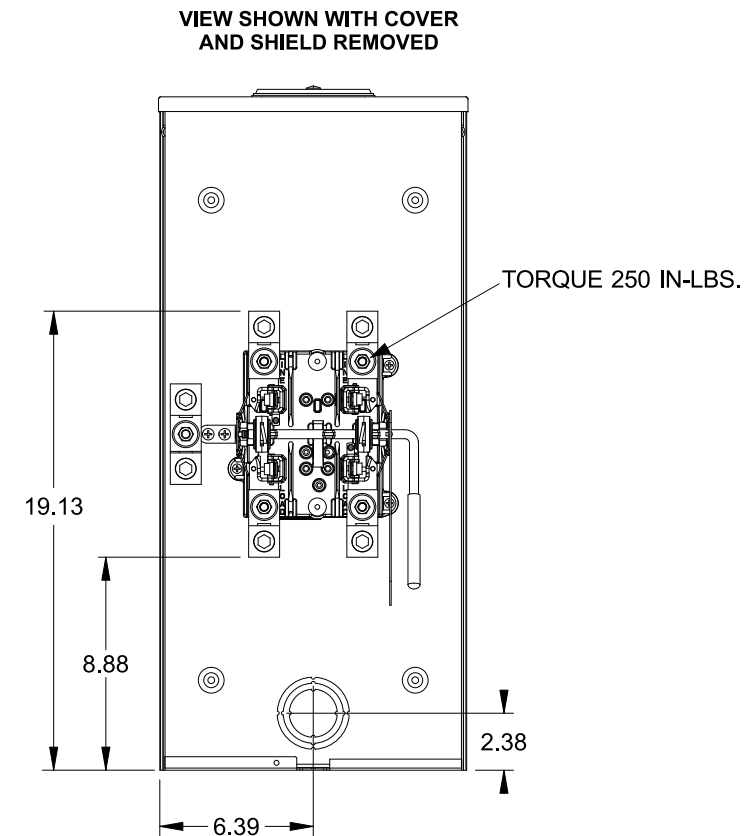
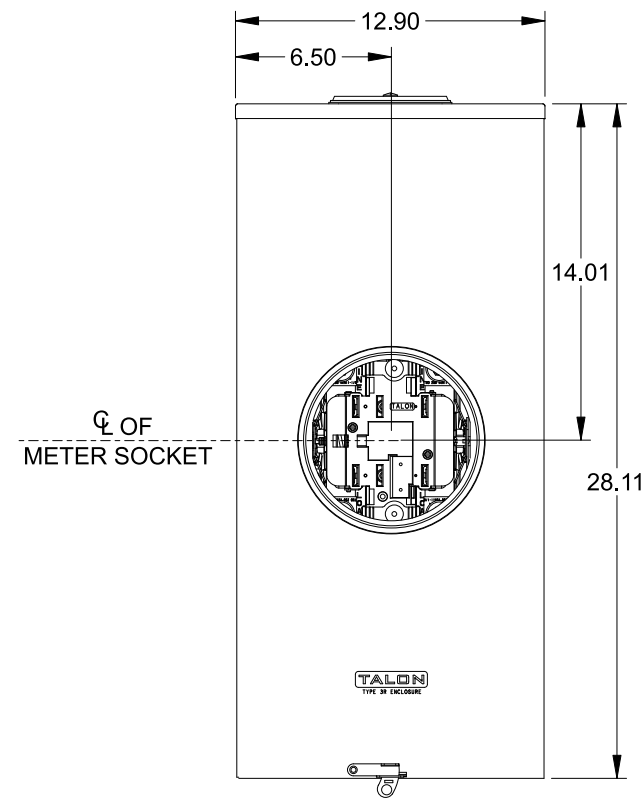
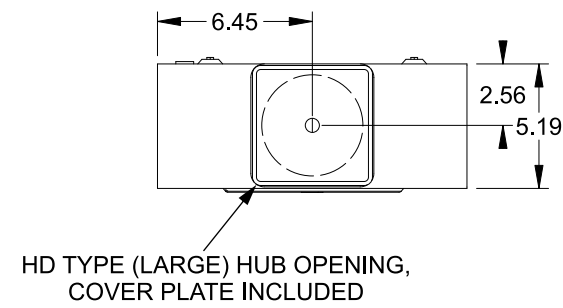


# Catalog Number: 47604-82

## Features and Ratings

- Ringless Type Meter Socket
- 320A Continuous, 400A Max., 600V AC
- Outdoor Enclosure (Type 3R)
- Painted G90 Steel Enclosure
- 1 Phase, 3-Wire, Commercial Socket
- 4 Jaw Meter Socket
- Meter Socket Type HQ-4SUT
- For Overhead & Underground Service
- HD Type Hub Opening, Cover Plate Included
- Lever Bypass

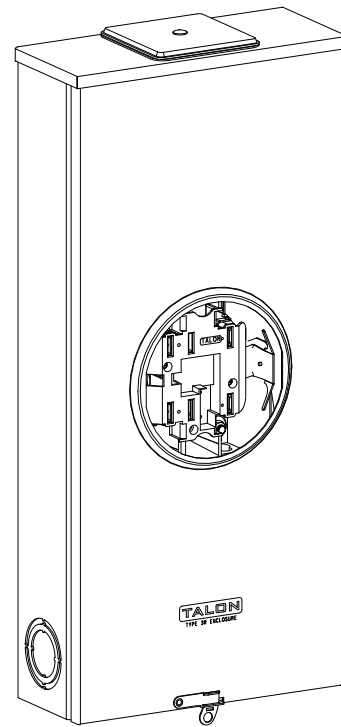

## Accessories

CONDUIT HUBS (HD Type)	
TRADE SIZE	CATALOG No.
3 INCH	EC56856 or H56856-2
3-1/2 INCH	EC56857 or H56857-2
4 INCH	EC56858 or H56858-2
Hub Cover Plate	EC56933 or H56933S

### Meter Opening Cover Plate

Cat No: H659-0162

### 5th Jaw Kit

Cat. No: EC35815-2

## Connectors, Wire Sizes and Torques

CONNECTOR	PART No.	WIRE SIZE	HEX DRIVE	TORQUE
LINE/LOAD/NEUTRAL	60300	#4-600 kcmil/ (2) 1/0-250 kcmil	3/8"	375 IN-LBS.
GROUND	67554A	#14 - 2/0 AWG	..	50 IN-LBS.

© 2019 Copyright Siemens Industry, Inc.

**TALON**  
**Meter Socket**

Description: **320A Cont, 4 Jaw, HQ-4SUT, 600V AC, Painted Steel Enclosure**

KAM 3/18/19 DO NOT SCALE DRAWING Dwg No: **47604-82**