




Catalog Number: 30407-025

Features and Ratings




- Ring Type Meter Socket
- 200A Continuous, 600V AC
- Outdoor Enclosure (NEMA Type 3R)
- Painted G90 Steel Enclosure
- 3 Phase, 4 Wire
- 7 Jaw Meter Socket
- Meter Socket Type MQ-7NBU
- For Overhead or Underground Service
- No Bypass
- RX Type Hub Opening with Coverplate Included

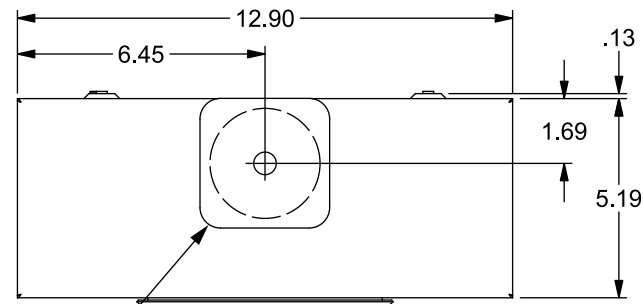

TYPE RX (SMALL) HUB OPENING WITH COVERPLATE INSTALLED

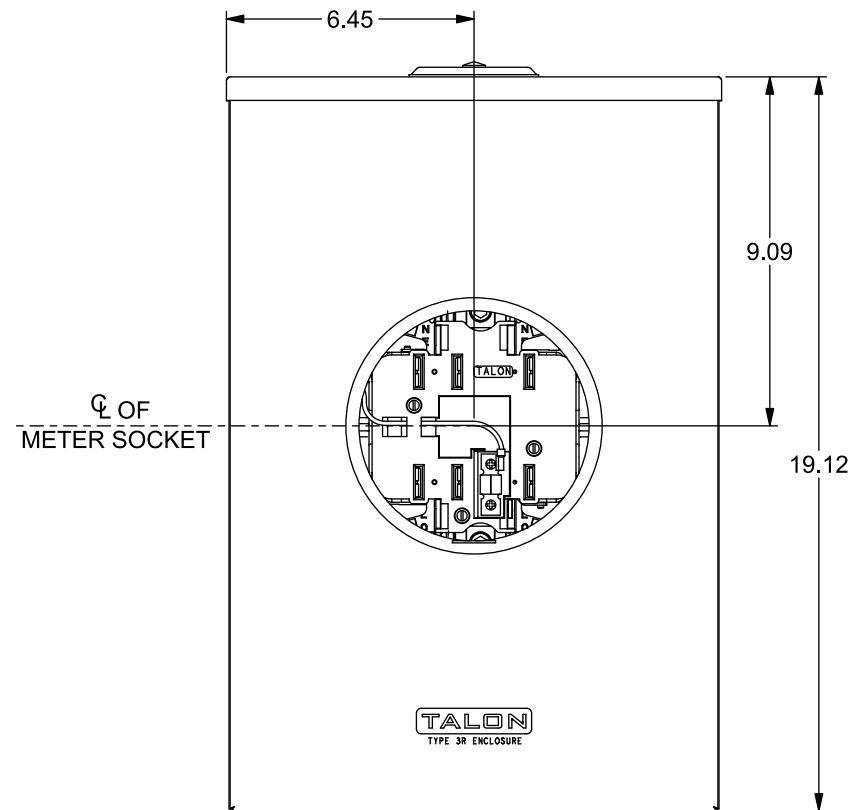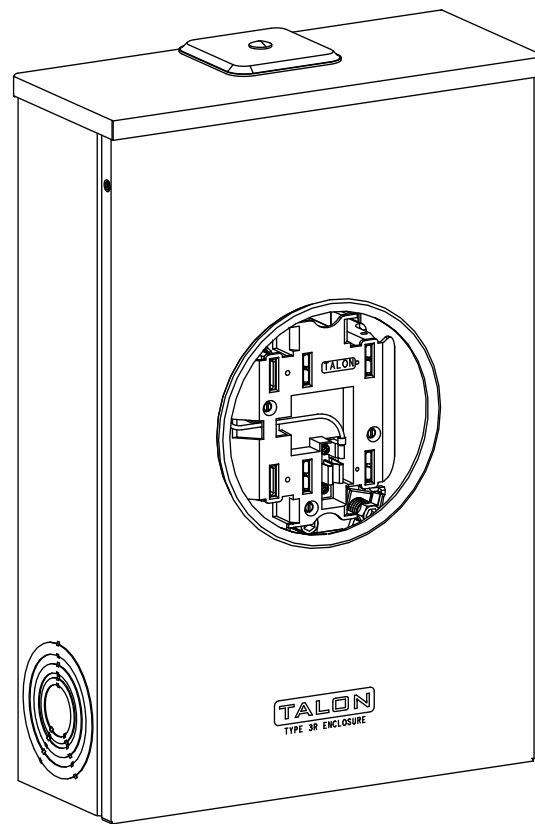

VIEW SHOWN WITH COVER AND SHIELD REMOVED

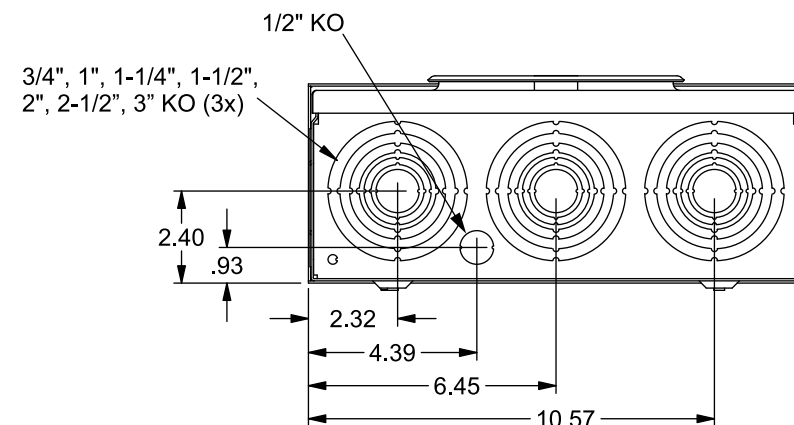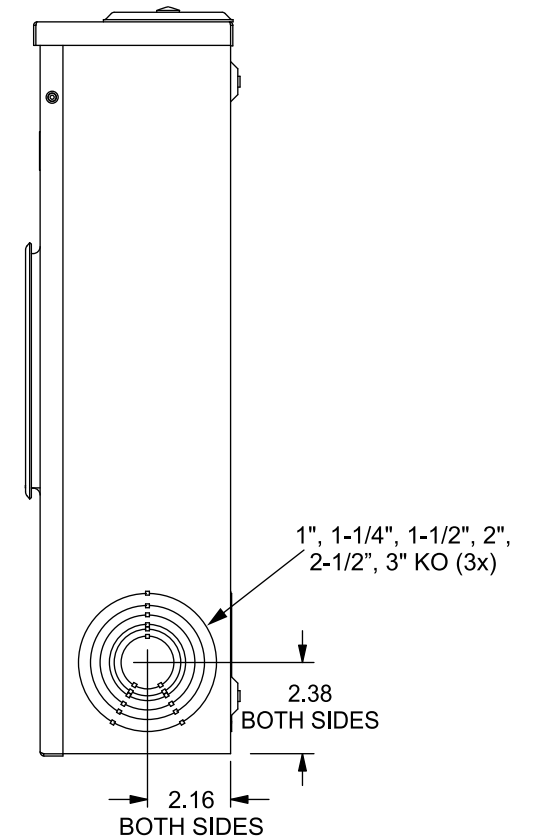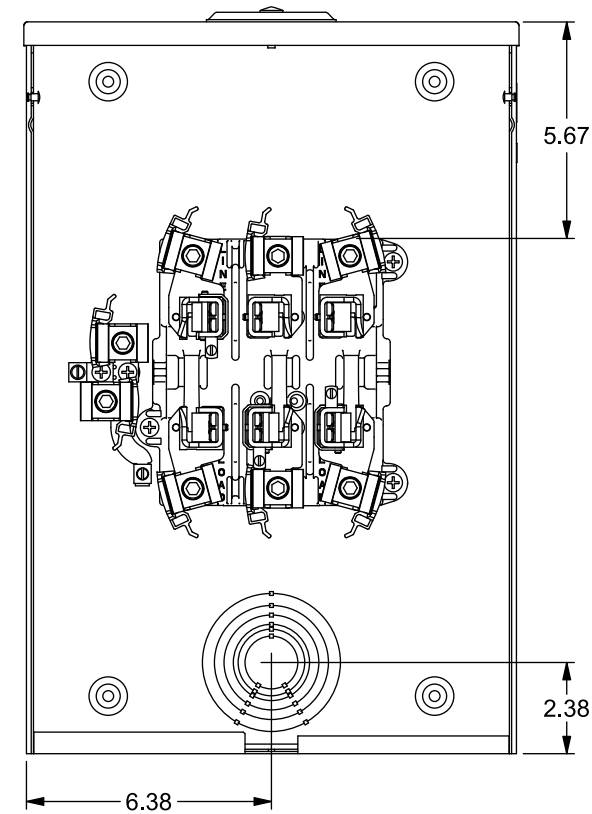

Accessories

CONDUIT HUBS (RX Type)	
TRADE SIZE	CATALOG No.
1-1/4 INCH	EC38597 or H38597-2
1-1/2 INCH	EC38598 or H38598-2
2 INCH	EC38599 or H38599-2
2-1/2 INCH	EC38600 or H38600-2
Hub Cover Plate	EC38595 or H38595-1

Meter Opening Cover Plate
Cat No: H659-0162
Insulated Neutral Kits
Cat. No: H64685-1, H64690-1

Connectors, Wire Sizes and Torques

CONNECTOR	PART No.	WIRE SIZE	TORQUE
LINE, LOAD, NEUTRAL*	..	#6-350 kcmil	275 IN-LBS.
GROUND	6509991	#14 - 2 AWG	50 IN-LBS.

*External Hex Drive 1/2", Internal Hex Drive 5/16"

© 2018 Copyright Siemens Industry, Inc.

TALON
Meter Socket

Description: **200A Cont, 7 Jaw, MQ-7NBU, 600V AC, Painted Steel Enclosure**

KAM 2/13/18 | DO NOT SCALE DRAWING | Dwg No: **30407-025**