




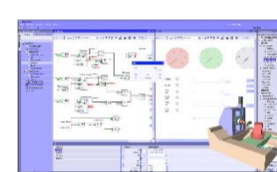






SCE Trainer Packages


Siemens Automation Cooperates with Education (SCE) | 04/2026


SIEMENS


For inquiries about SCE Trainer packages, please use SCE Support Finder: [siemens.com/sce/ssf](https://www.siemens.com/sce/ssf)


| Product | Hardware | Licenses | Delivery form | Version | Order Number | Note | |
|---|--|---|---------------|----------|--------------------|--------------------------|-------|
| Open Source Plattform | | | | | | | |
|  <p>SIMATIC IOT2050 with Quad Core Prozessor (AM6548 HS), 2 x ETHERNET Gigabit (IE/PN), 1 x RS 232/485/422, 2 x USB 2.0, RTC, incl. 6x SIMATIC IO-Shields: SIMATIC IOT2000 Input/Output Module with 5 DE, 2 DA, 2 AE, ARDUINO Shield for IOT2050 3rd Party IO-Shield: IKHDS-Powershield for IOT2050 with 10 DI, 8 DO with PWM, 2 AI, 1 AO Can only be ordered from KAFTAN media UG kaftan-media.com/iot2000</p> | 6 | | | | 6ES7647-0BA20-0SC2 | NEW | |
| | 1 | | | | 100320 | | |
| Industrial Control | | | | | | | |
|  <p>SIRIUS switchgear – Kit for infeed system feeder with IO-Link communication</p> | 1 | | | | 3TK3388-0TP00 | | |
| Engineering Software Online Software Delivery (OSD) = Software download via email address of the end user, e.g. educators/installer in educational institutions, not the distributor. | | | | | | | |
|  | SIMATIC TIA Portal Engineering Software STEP 7 Professional/WinCC | 1 | USB | V21 | 6ES7822-1AA25-4YA5 | NEW ○ | |
| | SIMATIC TIA Portal Engineering Software STEP 7 Professional/WinCC | 1 | OSD | V21 | 6ES7822-1AE25-4YA5 | NEW ○ | |
| | SIMATIC TIA Portal Engineering Software STEP 7 Professional/WinCC | 6 | USB | V21 | 6ES7822-1BA25-4YA5 | NEW ○ | |
| | SIMATIC TIA Portal Engineering Software STEP 7 Professional/WinCC | 6 | OSD | V21 | 6ES7822-1BE25-4YA5 | NEW ○ | |
| | Upgrade SIMATIC TIA Portal Engineering Software STEP 7 Professional/WinCC | 6 | USB | V21 | 6ES7822-1AA25-4YE5 | NEW ○ | |
| | Upgrade SIMATIC TIA Portal Engineering Software STEP 7 Professional/WinCC | 6 | OSD | V21 | 6ES7822-1AE25-4YE5 | NEW ○ | |
| | SIMATIC TIA Portal Engineering Software STEP 7 Professional/WinCC for Students – 365 days | 20 | USB | V21 | 6ES7822-1AC25-4YA5 | NEW ○ | |
| | SIMATIC TIA Portal Engineering Software STEP 7 Professional/WinCC for Students – 365 days | 20 | OSD | V21 | 6ES7822-1AG25-4YA5 | NEW ○ | |
| | Upgrade SIMATIC TIA Portal Engineering Software STEP 7 Basic for S7-1200 as of V10.5 | 6 | USB | V21 | 6ES7822-0AA25-4YE5 | NEW ○ | |
| | Upgrade SIMATIC TIA Portal Engineering Software STEP 7 Basic for S7-1200 as of V10.5 | 6 | OSD | V21 | 6ES7822-0AE25-4YE5 | NEW ○ | |
| | SIMATIC TIA Portal SIMOTION SCOUT - STEP 7 Professional V20 only | 6+20 | USB | V5.7 SP1 | 6AU1810-1BC57-1YA5 | NEW ○ | |
| | SIMATIC TIA Portal SIMOTION SCOUT Software for Students – exclusively for STEP 7 Professional V20 – 365 days | 20 | USB | V5.7 SP1 | 6AU1810-1BE57-1YA5 | NEW ○★ | |
| | SIMATIC CFC Software | 12 | DVD | V10 | 6ES7658-1EX78-0YS5 | NEW ○ | |
| | SIMATIC CFC Software for Students – 365 days | 20 | DVD | V10 | 6ES7658-1EX78-0YS6 | NEW ○★ | |
| SIMIT Simulation | | | | | | | |
|  <p>SIMIT Simulation Software Basic – includes SIMIT S & CTE, FLOWNET, CONTEC, Libraries Licenses – 8.000-Simulation-Tags</p> | 1 | USB | V11.3 | | 6DL8913-0AL31-0AS5 | NEW | |
| SIMATIC Universal USB Dongle License – must be ordered with every SIMIT license Link to activate the license/dongle: siemens.com/activate | 1 | | | | 6DL8900-8XX02-0XB8 | NEW | |
| SIMIT Simulation Platform, Software Media Package (SIMIT installation software) | | SIMIT Simulation Platform | 1 | | V11.3 | 6DL8913-0XL30-0XT8 | NEW |
| Demoverision SIMIT Simulation Platform, Software Media Package (SIMIT installation software) | | SIMIT Ressources | 1 | USB | V11.3 | Download | NEW |
| Process Automation SIMATIC PCS 7 | | | | | | | |
|  | SIMATIC PCS 7 Software V10.0 | | | | | | |
| | SIMATIC PCS 7 Software | 3 | DVD | V10.0 | 6ES7650-0XX78-0YS5 | NEW | |
| | SIMATIC PCS 7 Software | 6 | DVD | V10.0 | 6ES7650-0XX78-2YS5 | NEW | |
| | Upgrade SIMATIC PCS 7 Software V9.x to V10.0 | 3 | DVD | V10.0 | 6ES7650-0XX78-0YE5 | NEW | |
| SIMATIC PCS neo Software V6.0 | | | | | | | |
| SIMATIC PCS neo license | 1 | | | V6.0 | 6DL8921-0AF01-0AB5 | NEW | |
| SIMATIC License USB Universal Dongle – must be ordered with every PCS neo license Link to activate the license/dongle: siemens.com/activate | 1 | | | | 6DL8900-8XX02-0XB8 | NEW | |
| SIMATIC PCS neo, Software Media Package (neo installation software) | 1 | USB | V6.0 | | 6DL8900-0XF00-0XT8 | NEW | |
| SIMATIC PCS 7 Hardware for Software PCS 7 V10.0 and PCS neo V6.0 | | | | | | | |
| SIMATIC CPU 410-5H Single | 1 | | | | 6ES7654-0UE23-0XS5 | NEW | |
| SITOP PSU6200 24V/20A, regulated power supply | 1 | | | | 6EP3336-7SB00-3AX0 | | |
| SIMATIC ET 200SP HA | 1 | | | | 6ES7654-0UE23-0XS6 | NEW | |
| Process Instrumentation | | | | | | | |
|  | SITRANS FMS500 magnetic-inductive flow sensor | 1 | | | TRP:7ME6532 | NEW | |
| | SITRANS TS500 temperature sensor | 1 | | | TRP:7MC7511 | NEW | |
| | SIPART PS2 electropneumatic positioners | 1 | | | TRP:6DR5010A | NEW | |
| | SITRANS P320 pressure transmitter Differential pressure: Measuring range: 250 mbar | 1 | | | TRP:7MF034C | NEW | |
| | SITRANS P320 pressure transmitter Differential pressure: Measuring range: 600 mbar | 1 | | | TRP:7MF034B | NEW | |
| | SITRANS P320 pressure transmitter Differential pressure: Measuring range: 5 bar | 1 | | | TRP:7MF034A | NEW | |
| | SITRANS LR110 radar level sensor | 1 | | | TRP:7ML531 | NEW | |
| | Basic Automation | | | | | | |
|  | LOGO! 8 12/24V ETHERNET with digital modules DM8 12/24R | 6 | 6 | DVD | | 6ED1057-3SA20-0YA1 | NEW |
| | LOGO! 8 230V ETHERNET with digital modules DM8 230R | 6 | 6 | DVD | | 6ED1057-3SA20-0YB1 | NEW |
| | LOGO! 8 12/24V ETHERNET <u>without</u> digital modules DM8 12/24R | 9 | 9 | DVD | | 6ED1057-3SA30-0YA1 | NEW |
| | Basic Controller SIMATIC S7-1200 G2, CPU 1214C, DC/DC/DC with SM 1233 Analog IO | 6 | 6 | USB | V21 | 6ES7214-1AG50-4AB1 | NEW ○ |
| | Basic Controller SIMATIC S7-1200 G2, CPU 1214C, AC/DC/RELAY with SM 1233 Analog IO | 6 | 6 | USB | V21 | 6ES7214-1BG50-4AB1 | NEW ○ |
| | Basic Controller SIMATIC S7-1200 G2, CPU 1214C, DC/DC/RELAY with SM 1233 Analog IO | 6 | 6 | USB | V21 | 6ES7214-1HG50-4AB1 | NEW ○ |
| | Upgrade SIMATIC TIA Portal Engineering Software STEP 7 Basic for S7-1200 as of V10.5 | 6 | 6 | USB | V21 | 6ES7822-0AA25-4YE5 | NEW ○ |
| | Upgrade SIMATIC TIA Portal Engineering Software STEP 7 Basic for S7-1200 as of V10.5 | 6 | 6 | OSD | V21 | 6ES7822-0AE25-4YE5 | NEW ○ |
| | SIMATIC HMI KTP400 Basic Color Panel for LOGO! 7/8 | 1 | 1 | USB | V21 | 6AV2123-2DB03-0AA1 | ○ |
| | SIMATIC HMI KTP400 Basic Color Panel for LOGO! 7/8 | 6 | 6 | USB | V21 | 6AV2123-2DB03-0AA0 | ○ |
| | SIMATIC HMI MTP400 Unified Basic Color Panel for LOGO! 8 | 1 | 1 | USB | V21 | In preparation | NEW ○ |
| | SIMATIC HMI MTP400 Unified Basic Color Panel for LOGO! 8 | 6 | 6 | USB | V21 | In preparation | NEW ○ |
| | SIMATIC HMI KTP700 Basic Color Panel for S7-1200 | 1 | | | | 6AV2123-2GB03-0AA1 | ○ |
| | SIMATIC HMI KTP700 Basic Color Panel for S7-1200 | 6 | | | | 6AV2123-2GB03-0AA0 | ○ |
| | SIMATIC HMI MTP700 Unified Basic Color Panel for S7-1200 | 1 | | | | In preparation | NEW ○ |
| | SIMATIC HMI MTP700 Unified Basic Color Panel for S7-1200 | 6 | | | | In preparation | NEW ○ |


| Product | Hardware | Licenses | Delivery form | Version | Order Number | Note |
|--|----------|----------|---------------|---------|--------------------|-------|
| Advanced Automation | | | | | | |
|  SIMATIC ET 200SP Open Controller CPU 1515SP PC2 F with WinCC RT Advanced 512 PTs | 1 | 1 | USB | V21 | 6ES7677-2SB42-4AB1 | NEW ○ |
| SIMATIC ET 200SP Open Controller CPU 1515SP PC2 TF with WinCC RT Advanced 512 PTs | 1 | 1 | USB | V21 | 6ES7677-2WB42-4AB1 | NEW ○ |
| SIMATIC ET 200SP Distributed Controller CPU 1512SP F-1 PN Safety | 1 | 1 | USB | V21 | 6ES7512-1SK00-4AB2 | NEW ○ |
| SIMATIC CPU 1512C-1 PN | 1 | 1 | USB | V21 | 6ES7512-1CK00-4AB6 | NEW ○ |
| SIMATIC CPU 1512C-1 PN with PM 1507 | 1 | 1 | USB | V21 | 6ES7512-1CK00-4AB1 | NEW ○ |
| SIMATIC CPU 1512C-1 PN with CP 1542-5 (CP PROFIBUS) | 1 | 1 | USB | V21 | 6ES7512-1CK00-4AB7 | NEW ○ |
| SIMATIC CPU 1512C-1 PN with PM 1507 and CP 1542-5 (CP PROFIBUS) | 1 | 1 | USB | V21 | 6ES7512-1CK00-4AB2 | NEW ○ |
| SIMATIC CPU 1517TF-3 PN Safety <u>without</u> IOs (must be purchased separately) | 1 | 1 | USB | V21 | 6ES7517-3UP00-4AB1 | NEW ○ |
| SIMATIC CPU 1516F-3 PN/DP Safety | 1 | 1 | USB | V21 | 6ES7516-3FN00-4AB2 | NEW ○ |
| SIMATIC CPU 1516-3 PN/DP | 1 | 1 | USB | V21 | 6ES7516-3AN00-4AB3 | NEW ○ |

| Product | Hardware | Licenses | Delivery form | Version | Order Number | Note |
|---|----------|----------|---------------|---------|--------------------|------|
| Distributed IOs | | | | | | |
|  SIMATIC ET 200SP Digital PROFINET | 1 | | | | 6ES7155-6AU00-0AB0 | |
| SIMATIC ET 200SP Digital with input module ENERGY METER PN | 1 | | | | 6ES7155-6AU00-0AB1 | |
| SIMATIC ET 200SP Digital with communication module IO-LINK MASTER V1.1 PN | 1 | | | | 6ES7155-6AU00-0AB2 | |
| SIMATIC ET 200SP Digital with communication module CM AS-i MASTER ST PN | 1 | | | | 6ES7155-6AU00-0AB3 | |
| SIMATIC ET 200SP Analogue expansion module | 1 | | | | 6ES7155-6AU00-0AB6 | |
| SIMATIC ET 200SP Safety expansion module | 1 | | | | 6ES7136-6BA00-0AB1 | |


| Product | Hardware | Licenses | Delivery form | Version | Order Number | Note |
|--|----------|----------|---------------|---------|--------------------|-------|
| Operator Control & Monitoring | | | | | | |
|  SIMATIC HMI MTP700 Unified Comfort Panel | 1 | 1 | USB | V21 | 6AV2128-3GB06-4AB1 | NEW ○ |
| SIMATIC HMI MTP1500 Unified Comfort Panel | 1 | 1 | USB | V21 | 6AV2128-3QB06-4AB1 | NEW ○ |
| SCADA system SIMATIC WinCC with options Only Window 10/11 (64 bit) Prof. and Enterprise, Windows Server 2019, 2022 Standard, Datacenter | | 6 | DVD | V8.1 | 6AV6371-1DH08-1AX5 | NEW |
| SCADA system SIMATIC WinCC with options – ASIA Only Window 10/11 (64 bit) Prof. and Enterprise, Windows Server 2019, 2022 Standard, Datacenter | | 6 | DVD | V8.1 | 6AV6371-1DH08-1AV5 | NEW |
| Upgrade SCADA system SIMATIC WinCC with options from V1.0 Only Window 10/11 (64 bit) Prof. and Enterprise, Windows Server 2019, 2022 Standard, Datacenter | | 6 | DVD | V8.1 | 6AV6381-1BP08-1AX3 | NEW |

| Product | Hardware | Licenses | Delivery form | Version | Order Number | Note |
|--|----------|----------|---------------|---------|---------------|-------|
| Industrial Communication | | | | | | |
|  FASTCONNECT Cable Set | 1 | | | | 6GK1950-0BB00 | |
| IE SCALANCE Switch XC208 | 1 | | | | 6GK1950-0BB12 | ○ |
| IE SCALANCE S615 with Software SINEMA RC Basis | 1 | 1 | DVD | | 6GK1950-0BB13 | ○ |
| IE SCALANCE S615 LAN-Router | 2 | | | | 6GK1950-0BB23 | ○ |
| SIMATIC NET SINEC NMS 100 | | 6 | OSD | V3.0 | 6GK1950-0BB16 | NEW ○ |

| Product | Hardware | Licenses | Delivery form | Version | Order Number | Note |
|---|----------|----------|---------------|---------|--------------------|------|
| Industrial Identification | | | | | | |
|  SIMATIC MV540 S optical reader PROFINET | 1 | | | | 6GF3500-1TP03 | ○ |
| SIMATIC RF200 RFID-System PROFINET | 1 | | | | 6GT2096-3AA00-0AA1 | ○ |
| SIMATIC RF200 RFID-System IO-Link | 1 | | | | 6GT2096-5AA00-0AA0 | ○ |
| SIMATIC RF300 RFID-System PROFINET | 1 | | | | 6GT2096-1AA00-0AA1 | ○ |
| SIMATIC RF600 RFID-System PROFINET | 1 | | | | 6GT2811-6CC10-0XB0 | ○ |

| Product | Hardware | Licenses | Delivery form | Version | Order Number | Note |
|---|----------|----------|---------------|---------|--------------------|-------|
| Drive Technology | | | | | | |
|  SINAMICS G120 standard drive for 230V AC single phase with PROFINET | 1 | | | | 6SL3200-3AX00-0UL3 | ○ |
| SINAMICS G120 standard drive for 400V AC three phase with PROFINET | 1 | | | | 6SL3200-3AX00-0UL4 | ○ |
| SINAMICS S210 servo drive for 200 - 240V AC single phase with PROFINET and servo motor | 1 | | | | 6SL5990-0AT30-0AB0 | NEW ○ |
| SINAMICS S210 servo drive for 380 - 480V AC three phase with PROFINET and servo motor | 1 | | | | 6SL5990-0AT30-0AE0 | NEW ○ |
| SINAMICS S120 servo drive for 230V AC single phase with PROFINET | 1 | | | | 6SL3080-8AB01-0AA0 | ○ |
| SINAMICS S120 servo drive for 400V AC three phase with PROFINET | 1 | | | | 6SL3080-8AE01-0AA0 | ○ |

SinuTrain SW - In countries with sales via Siemens, DI software only with Maintenance, Order no. MCS** → Requests for offers should be sent to: mcmts_software_plm@siemens.com**
- In countries with sales via Siemens, without Maintenance, Article number 6FC5870-1 → Requests for offers should be sent to standard Siemens Sales

| Product | Hardware | Licenses | Delivery form | Version | Order Number | Note |
|---|----------|----------|---------------|---------|----------------------------------|----------------------|
|  SinuTrain SINUMERIK Operate V4.5/V4.7/V4.8/V4.9 siemens.com/sinutrain-downloads | | | | | Basic Version | No time limit NEW |
| SinuTrain Trainer Package for SINUMERIK Operate | | 6+40 | | V4.9 | MCS5370 / 6FC5870-1TC46-0YA0 | ★ |
| SinuTrain Student licenses for SINUMERIK Operate – 300 hours | | 20 | | V4.9 | MCS5360 / 6FC5870-1SC46-0YA0 | ★ |
| SinuTrain Trainer Package for SINUMERIK Operate | | 6+40 | | V4.8 | MCS40552 / 6FC5870-1TC45-0YA0 | ★ |
| SinuTrain Student licenses for SINUMERIK Operate – 300 hours | | 20 | | V4.8 | MCS40573 / 6FC5870-1SC45-0YA0 | ★ |
| SinuTrain Trainer Package for SINUMERIK Operate | | 6+40 | | V4.7 | MCS4055 / 6FC5870-1TC43-0YA0 | ★ |
| SinuTrain Student licenses for SINUMERIK Operate – 300 hours | | 20 | | V4.7 | MCS4057 / 6FC5870-1SC43-3YA0 | ★ |
| SinuTrain Trainer Package for SINUMERIK Operate | | 6+40 | | V4.5 | MCS40551 / 6FC5870-1TC41-0YA0 | ★ |
| SinuTrain Student licenses for SINUMERIK Operate – 300 hours | | 20 | | V4.5 | MCS40571 / 6FC5870-1SC41-0YA0 | ★ |
| Run MyVirtual Machine | | 1 | | | 6FC6470-1MP00-0YA_ | ★ |


PLM Software - In DE/AT/CH, contact via SCE promoters
- In all other countries via [siemens.com/plm/gaf](https://www.siemens.com/plm/gaf)

○ Relevant Information: support.industry.siemens.com/cs/ww/en/view/65601780, Windows 11 (64 Bit) Professional und (IoT) Enterprise 24H2; (IoT) Enterprise 24H2 LTSC, Windows Server 2022, 2025 Standard (Full installation)

★ Only for schools, colleges and universities

Ordering note: All trainer packages are only available for schools, colleges, universities and/or internal vocational company training centers. A specific end-use declaration must be provided in order to purchase the packages. Siemens contact partners can find this declaration in the SCE Intranet under [Additional agreement](#).

Comprehensive support in the SCE Internet [siemens.com/sce](https://www.siemens.com/sce)

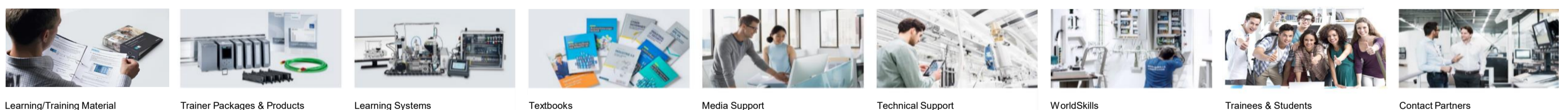

Siemens
 Digital Industries
 Factory Automation
 Postfach 4848
 90026 Nuremberg

Subject to changes and errors. The information given in this document only contains general descriptions and/or performance features which may not always specifically reflect those described, or which may undergo modification in the course of further development of the products. The requested performance features are binding only when they are expressly agreed upon in the concluded contract. All product designations, product names, etc. may contain trademarks or other rights of Siemens, its affiliated companies or third parties. Their unauthorized use may infringe the rights of the respective owner.

Unrestricted © Siemens 2026. All Rights Reserved.

[siemens.com/sce/tp](https://www.siemens.com/sce/tp)