


# Catalog Number: UAT111-0MSP

## Features and Ratings

- Ringless Type Meter Socket
- 135A Continuous, 135A Max., 600V AC
- Outdoor Enclosure (NEMA Type 3R)
- Painted Steel Enclosure
- 1 Phase, 3 Wire
- 5 Jaw Meter Socket, 5th Jaw Kit @ 9 o'clock Position
- Meter Socket Type UAT1
- For Overhead & Underground Service
- RX Type Hub Opening
- Horn Bypass
- 7/8" Barrel Lock Provision w/Bracket

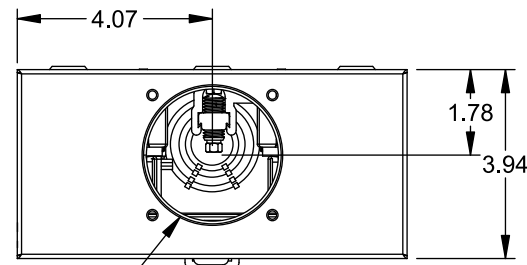

TYPE RX (SMALL) HUB OPENING

## Accessories

| CONDUIT HUBS (RX Type) |                     |
|------------------------|---------------------|
| TRADE SIZE             | CATALOG No.         |
| 1-1/4 INCH             | EC38597 or H38597-2 |
| 1-1/2 INCH             | EC38598 or H38598-2 |
| 2 INCH                 | EC38599 or H38599-2 |
| 2-1/2 INCH             | EC38600 or H38600-2 |

Hub Cover Plate EC38595 or H38595-1

Meter Opening Cover Plate

Cat No: H659-0162


5th Jaw Kit

Cat. No: EC659-0121

## Connectors, Wire Sizes and Torques

| CONNECTOR            | WIRE SIZE    | TORQUE      |
|----------------------|--------------|-------------|
| LINE, LOAD, NEUTRAL* | 2/0 - 14 AWG | 50 IN.-LBS. |
| GROUND               | #2 - 14 AWG  | 50 IN.-LBS. |

\* External Hex Drive 5/16"

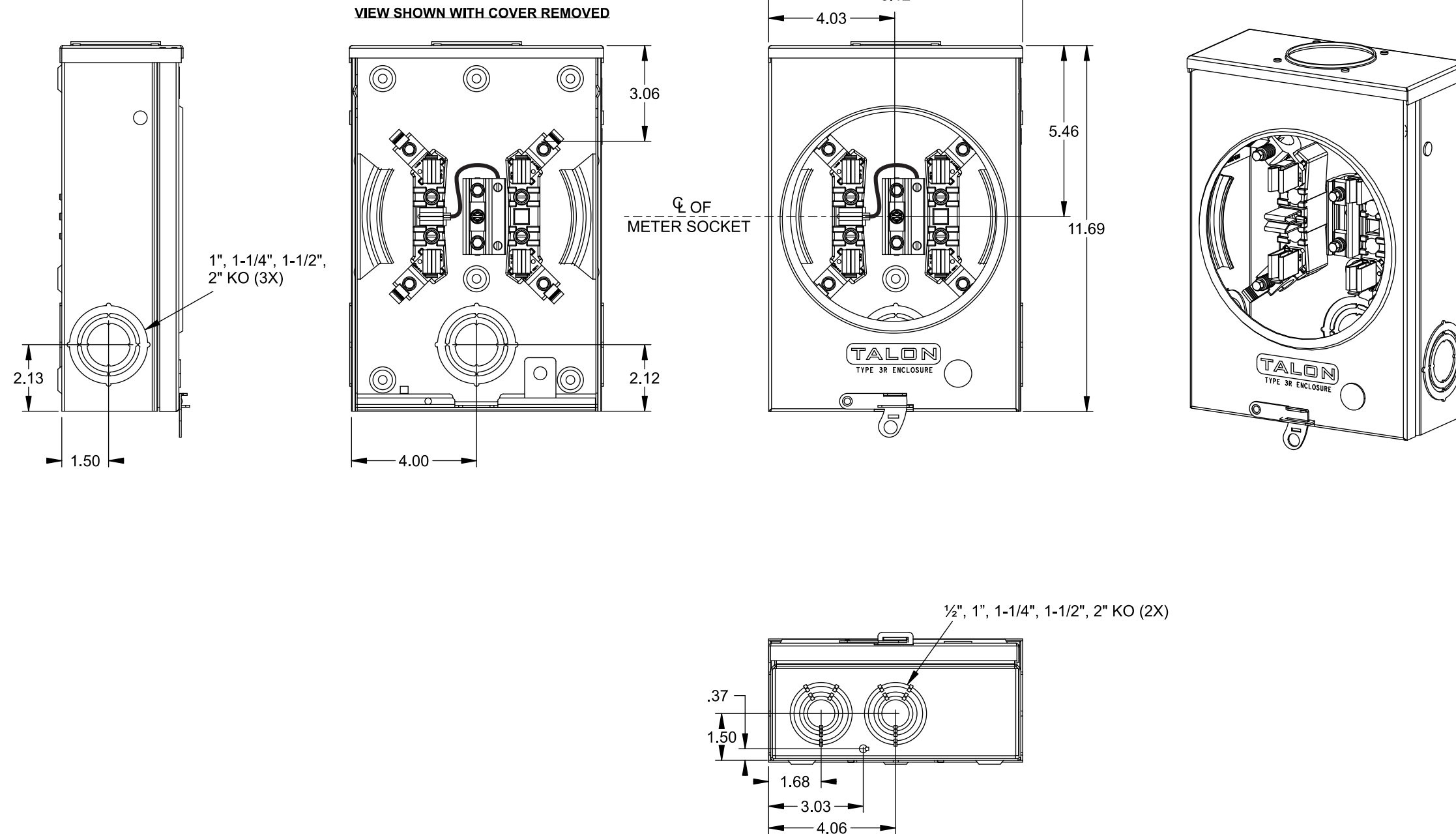

© 2015 Copyright Siemens Industry, Inc.

**TALON**

**Meter Socket**

Description: **135A Cont, 5 Jaw, UAT1, 600V AC, Painted Steel Enclosure**

JEL 8/30/15 | DO NOT SCALE DRAWING | Dwg No: **UAT111-0MSP**