

Catalog Number: UA5411-DG

Features and Ratings

- Ringless Type Meter Socket
- 100A Continuous Per Position,
- 250A Continuous (Total) Unit Rating With CU
- 205A Continuous (Total) Unit Rating With AL
- Outdoor Enclosure (NEMA Type 3R)
- Painted G90 Steel
- 1 Phase, 3 Wire, 600V AC
- 4 Jaw Meter Socket
- Meter Socket Type UA5411
- For Overhead or Underground Service
- RX Type Hub Opening, 2" Hub installed (Left)
- and Cover Plate Installed (Right)

Connectors, Wire Sizes and Torques

CONNECTOR	WIRE SIZE	TORQUE
LINE, NEUTRAL LINE	#6 - 250 kcmil	275 IN.-LBS.
LOAD, NEUTRAL LOAD	#8 - 2/0 AWG	50 IN.-LBS.
GROUND	#2 - 14 AWG	50 IN.-LBS.

* External Hex Drive 1/2"
* Internal Hex Drive 5/16"


Accessories

CONDUIT HUBS (RX Type)

TRADE SIZE	CATALOG No.
3/4 INCH	H38594-2
1 INCH	H38596-2
1-1/4 INCH	H38597-2
1-1/2 INCH	H38598-2
2 INCH	H38599-2
2-1/2 INCH	H38600-2

Hub Cover Plate Kit
Cat No: H38595-1

5th Jaw Kit
Cat No: EC5J2

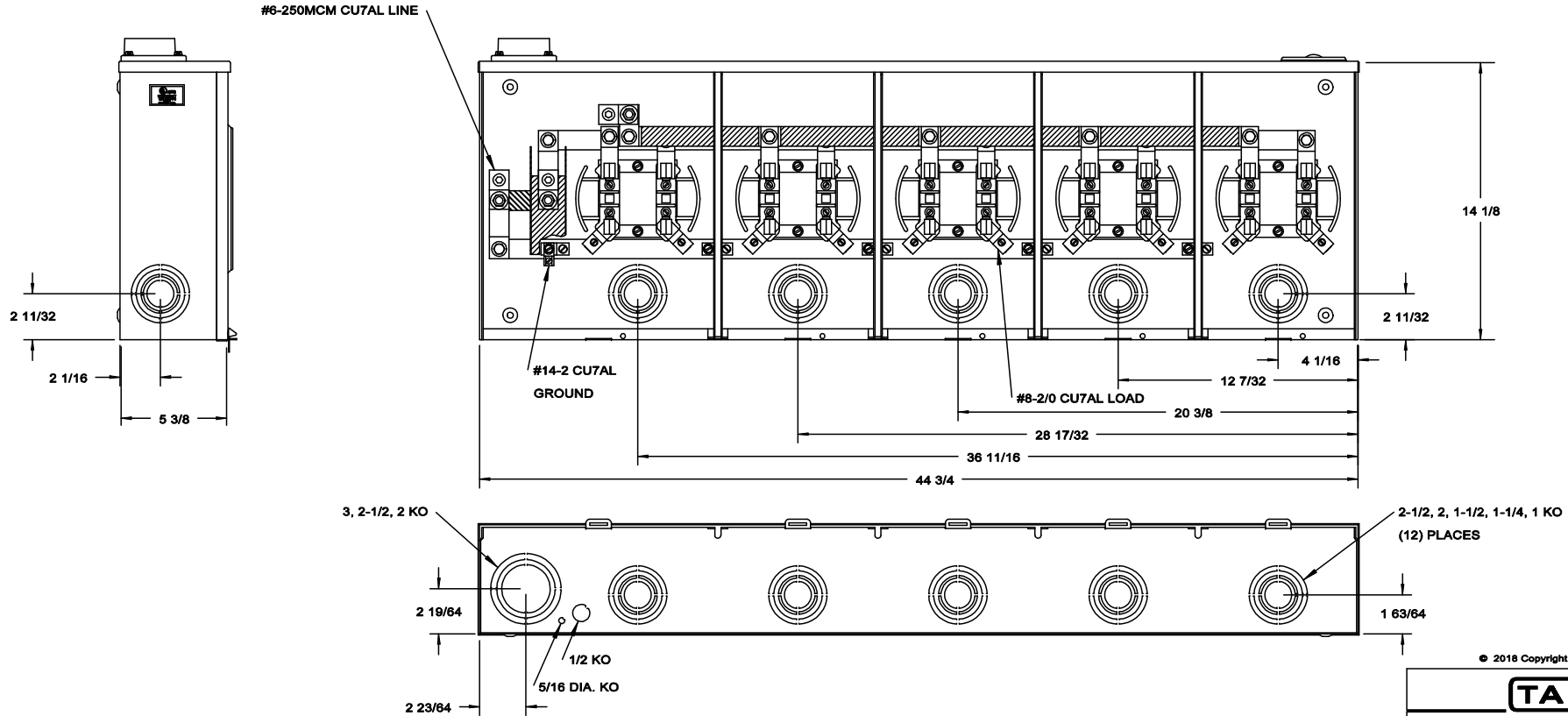

© 2018 Copyright Siemens Industry, Inc.

TALON

MULTI-POSITION METERING

Description:
RINGLESS, 100A, 4 JAW, 600V AC

GLS 7/19/2018 DO NOT SCALE DRAWING Dwg No. UA5411-DG