


Catalog Number: 49107-02FL

Features and Ratings






- Ringless Type Meter Socket
- 320A Continuous, 400A Max.
- Outdoor Enclosure (NEMA Type 3R)
- 3 Phase, 4 Wire, 600V AC
- 7 Jaw
- HQ Clamp Jaw Lever Bypass Meter Socket
- For Overhead or Underground Service
- HD Hub Opening With Coverplate Installed
- Aluminum enclosure
- Stainless steel latch and hasp

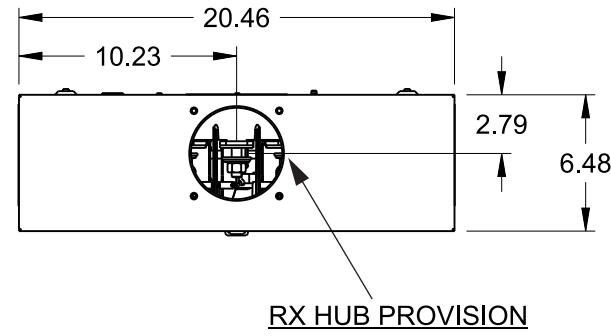

Accessories
HD HUB KITS
 Cat No: H56856-2 (3.00")
 Cat No: H56857-2 (3.50")
 Cat No: H56858-2 (4.00")
HD HUB KITS
 Cat No: EC56856 (3.00")
 Cat No: EC56857 (3.50")
 Cat No: EC56858 (4.00")
HUB COVER PLATE
 Cat No: H56833-3

**Lugs,
Wire Sizes and Torques**

LOCATION	PART NO.	HEX DRIVE SIZE	LUG SIZE	TORQUE
LINE	H60162	9/16	#4-600Kcmil	500 LB-IN
LOAD	H60162	9/16	#4-600Kcmil	500 LB-IN
NEUTRAL	H60162	9/16	#4-600Kcmil	500 LB-IN
GROUND	H67554	7/16	#14-2/0	50 LB-IN

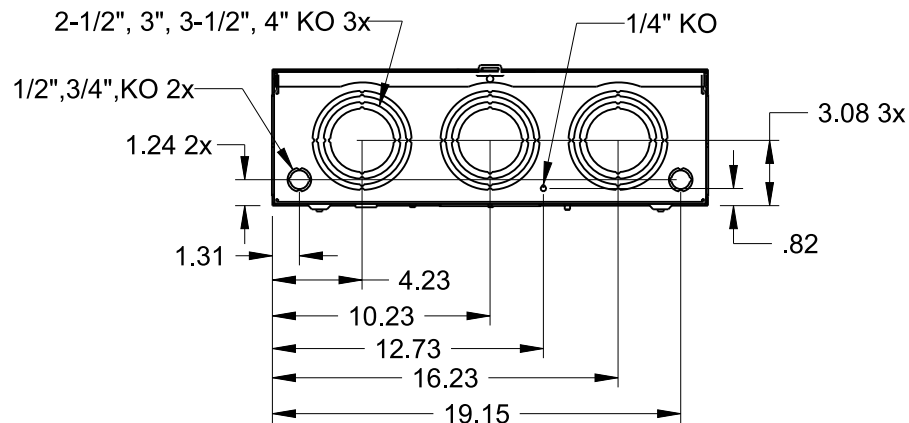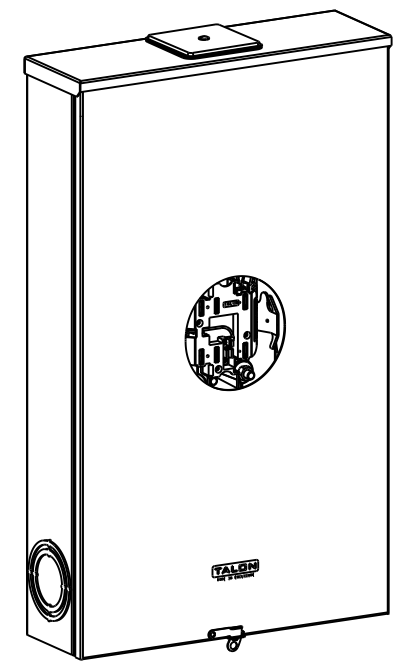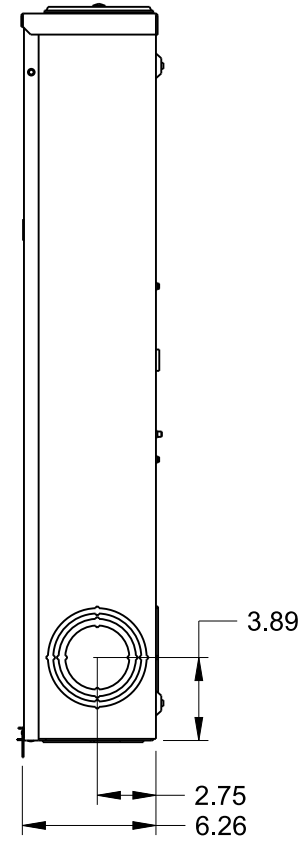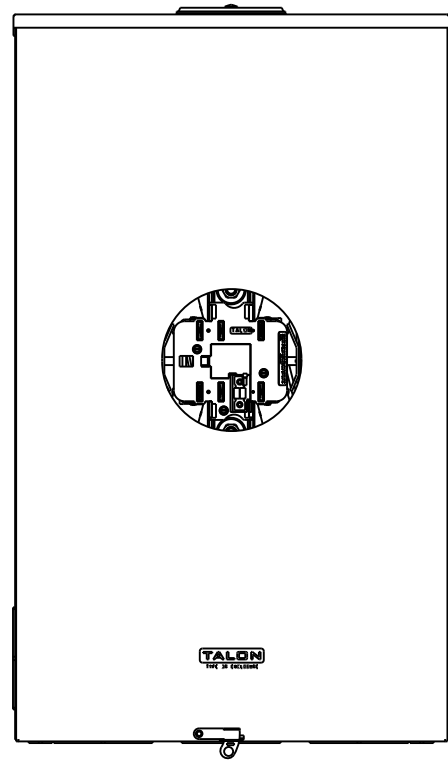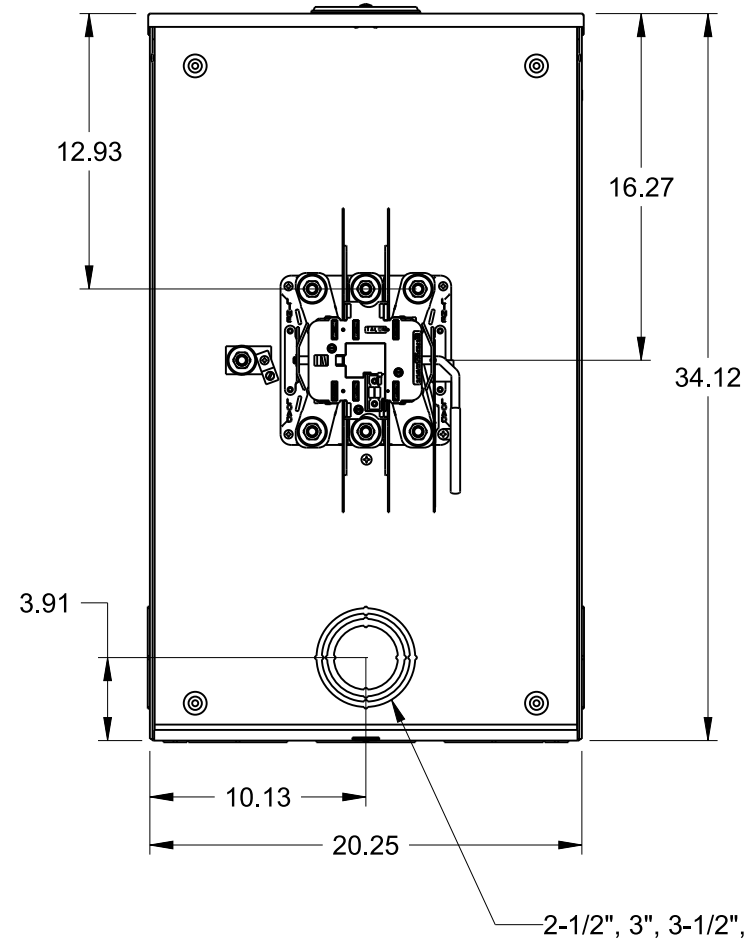

TALON
Meter Socket

Description:
320A Cont, 7 Jaw, HQ-7DB, 600V AC
Aluminum Enclosure

NH 25NOV15 DO NOT SCALE DRAWING Dwg No: 49107-02FL MEG