

Catalog Number: 9837-8403

Features and Ratings

- Ringless Type Meter Socket
- 20A Continuous, 600V AC
- Outdoor Enclosure (NEMA Type 3R)
- Painted G90 Steel
- Network, 3 Phase; 3 or 4 Wire
- 8 Jaw Meter Socket
- Meter Socket Type PTS-8
- For Overhead or Underground Service
- RX Type Hub Opening, Cover Plate Installed

Connectors, Wire Sizes and Torques

CONNECTOR	WIRE SIZE	TORQUE
CURRENT, POTENTIAL, GROUND	#14 - 10 AWG	35 IN.-LBS.
CURRENT, POTENTIAL, GROUND	#8 AWG	40 IN.-LBS.
CURRENT, POTENTIAL, GROUND	#6 AWG	45 IN.-LBS.
POTENTIAL, GROUND	#4 AWG	45 IN.-LBS.
GROUND	#3 - 2 AWG	50 IN.-LBS.



Accessories

CONDUIT HUBS (RX Type)

TRADE SIZE	CATALOG No.
3/4 INCH	H38594-2
1 INCH	H38596-2
1-1/4 INCH	H38597-2
1-1/2 INCH	H38598-2
2 INCH	H38599-2
2-1/2 INCH	H38600-2

Steel Hub Cover Plate Kit
Cat No: H38595-1

Aluminum Hub Cover Plate Kit
Cat No: H38595-2

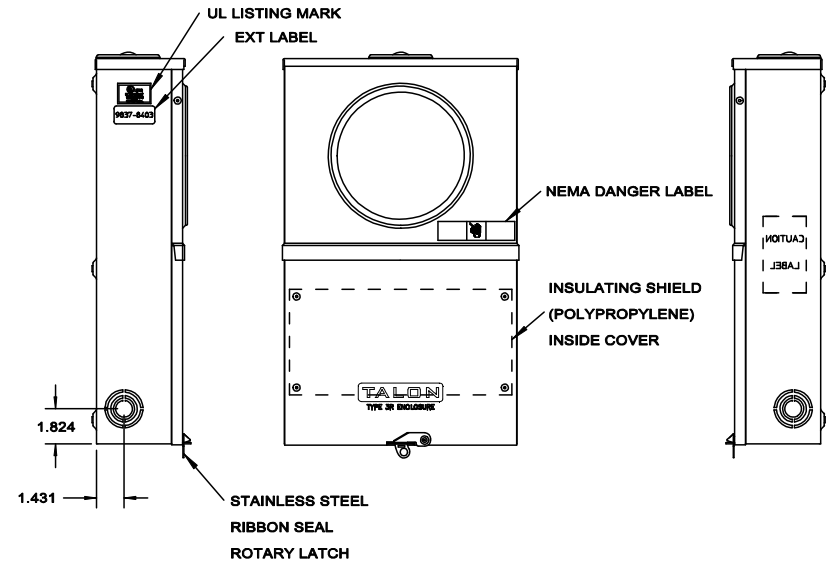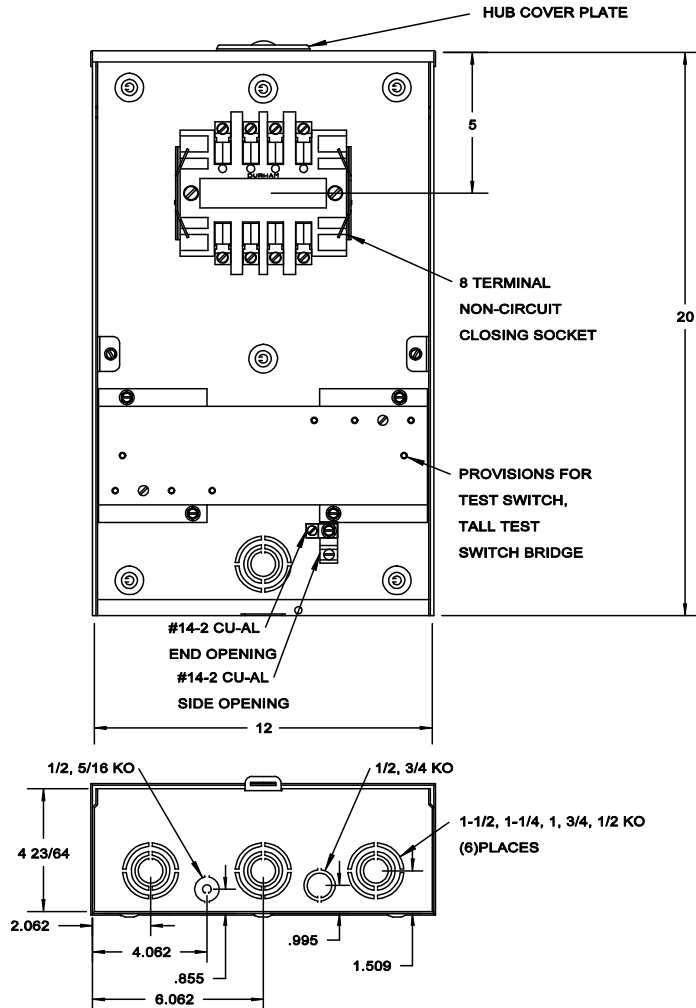

© 2017 Copyright Siemens Industry, Inc.

TALON	
PTS13	
Description: SKT/SW 20A 8T HCP	
CQ 08/25/2018	DO NOT SCALE DRAWING
Dwg No.	9837-8403