




Catalog Number: 9817-9575

Features and Ratings



- Ringless Type Meter Socket
- 480A Continuous, 600A Max., 600V AC
- Outdoor Enclosure (NEMA Type 3R)
- Painted G90 Steel Enclosure
- 3 Phase, Commercial/Industrial Socket
- Meter Socket Type K-7T
- For Overhead & Underground Service
- Two Large Hub Openings, HD Type Cover Plates Installed

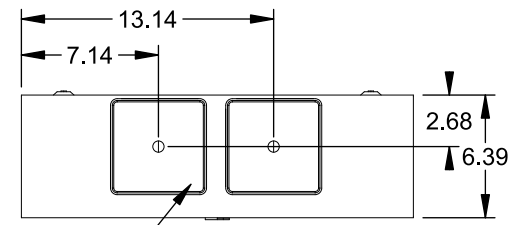

(2) TYPE HD (LARGE) HUB OPENINGS COVER PLATES INSTALLED

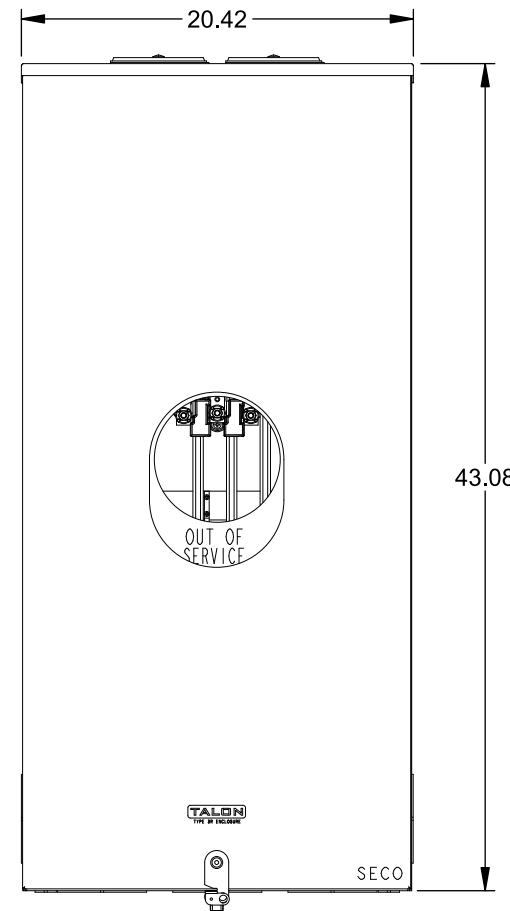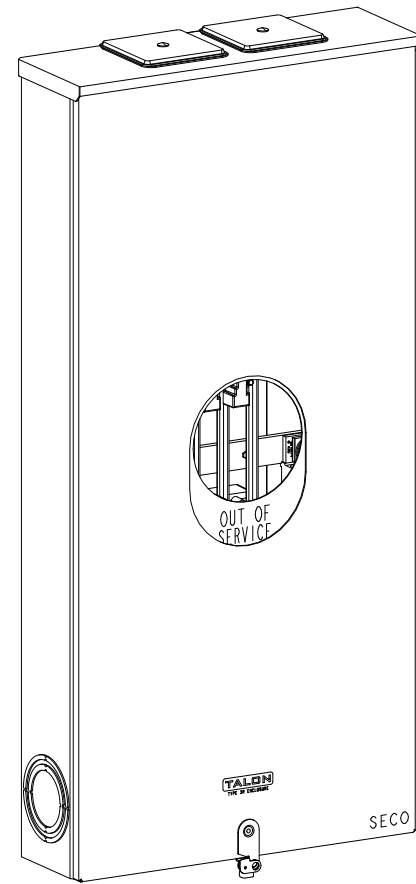

VIEW SHOWN WITH COVER REMOVED

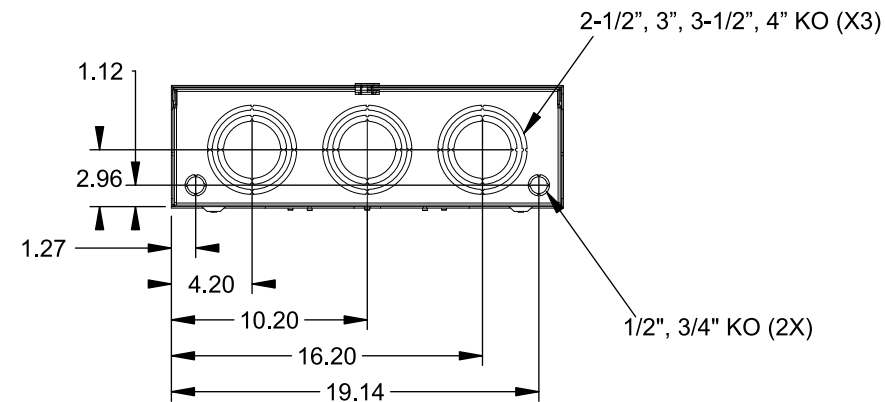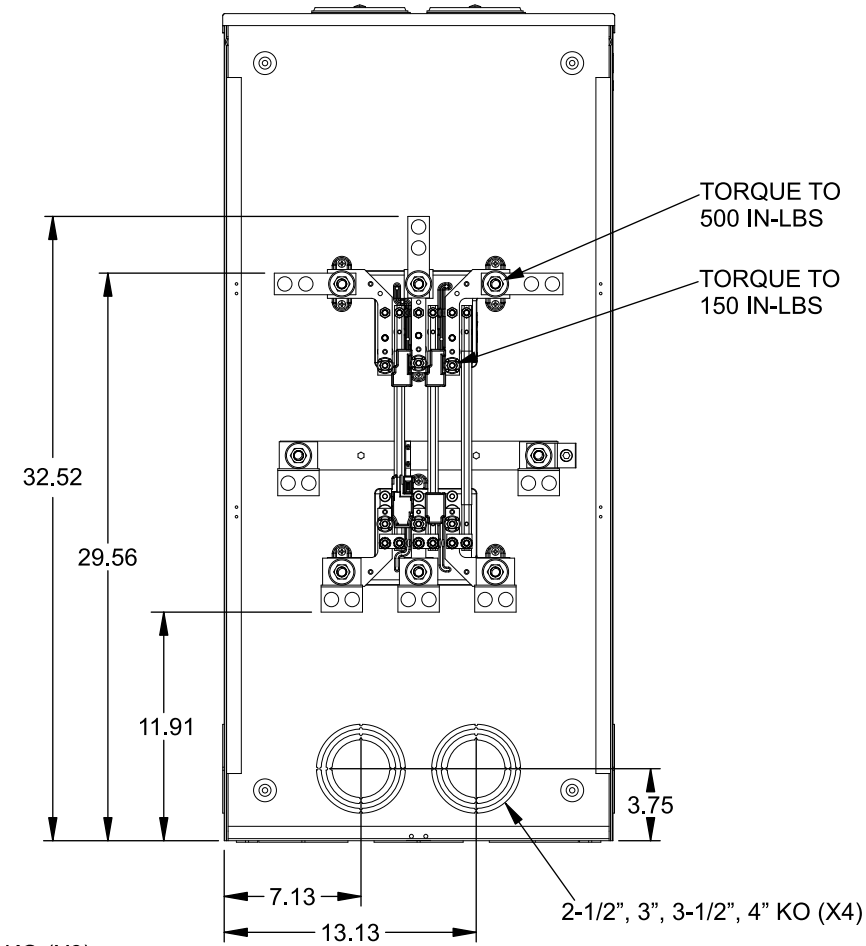

Accessories

CONDUIT HUBS (HD Type)	
TRADE SIZE	CATALOG No.
3 INCH	EC56856 or H56856-2
3-1/2 INCH	EC56857 or H56857-2
4 INCH	EC56858 or H56858-2
Hub Cover Plate	EC56933 or H56933S

CAT No.	DESCRIPTION
H69623	Bypass
H69685-1	Isolated Neutral Kit
H69546-1	Hex Magnet Socket Kit
H69232-1	Insulated T-Handle Kit
H65050	K-base Insulator Kit
H63864	K-base Ground Kit

Connectors, Wire Sizes and Torques

CONNECTOR	PART No.	HEX DRIVE	WIRE SIZE	TORQUE
LINE*	56427-M	3/8"	(2)#2 - 500 kcmil	375 IN-LBS.
LINE/LOAD*	56732-M	3/8"	(2)#4 - 500 kcmil	375 IN-LBS.
NEUTRAL*	56732-M	3/8"	(2)#4 - 500 kcmil	375 IN-LBS.
LINE/LOAD/NEUT	68752-1	5/16"	(3)#6 - 250 kcmil	275 IN-LBS.
GROUND*	56734	5/16"	#6 - 250 kcmil	275 IN-LBS.

*Factory Installed

© 2016 Copyright Siemens Industry, Inc.

TALON

Meter Socket

Description: **480A Cont, 4 Terminal, K-7T, 600V AC, Painted Steel Enclosure**

JEL 2/1/16 | DO NOT SCALE DRAWING | Dwg No: **9817-9575**