



**Catalog Number: T364811PT344MR**

Amps	Volts Max.	Phase/Wires	Unprotected Fault Current Rating	Enclosure Size		
				Width*	Height	Depth
400	600V	3 Phase, 4 Wire	42,000	36"	48"	11"

\*Width includes 12" wide potential transformer enclosure mounted on left side of cabinet.




**INTERIOR DETAIL**

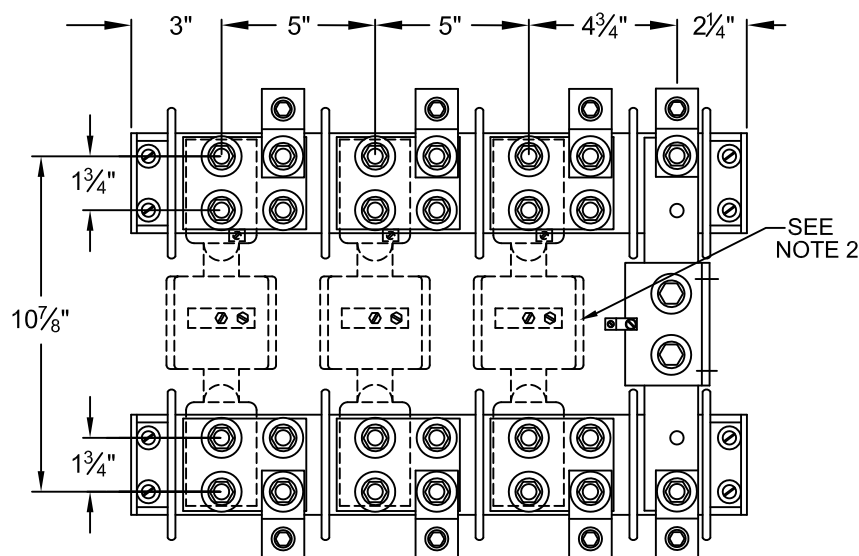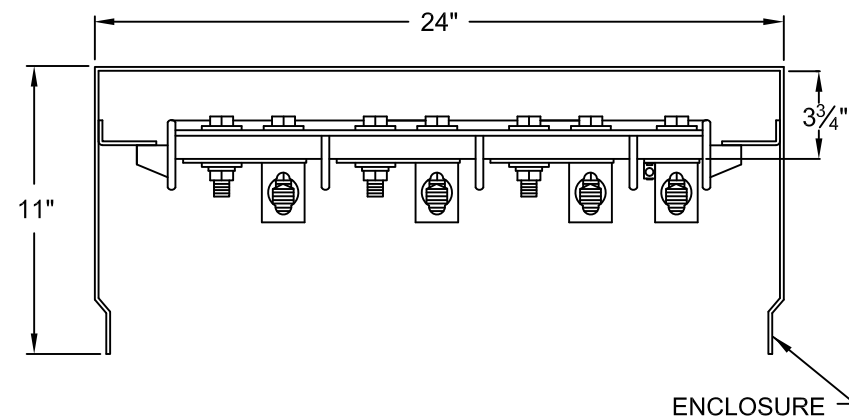


SEE NOTE 2

**FRONT INTERIOR VIEW**

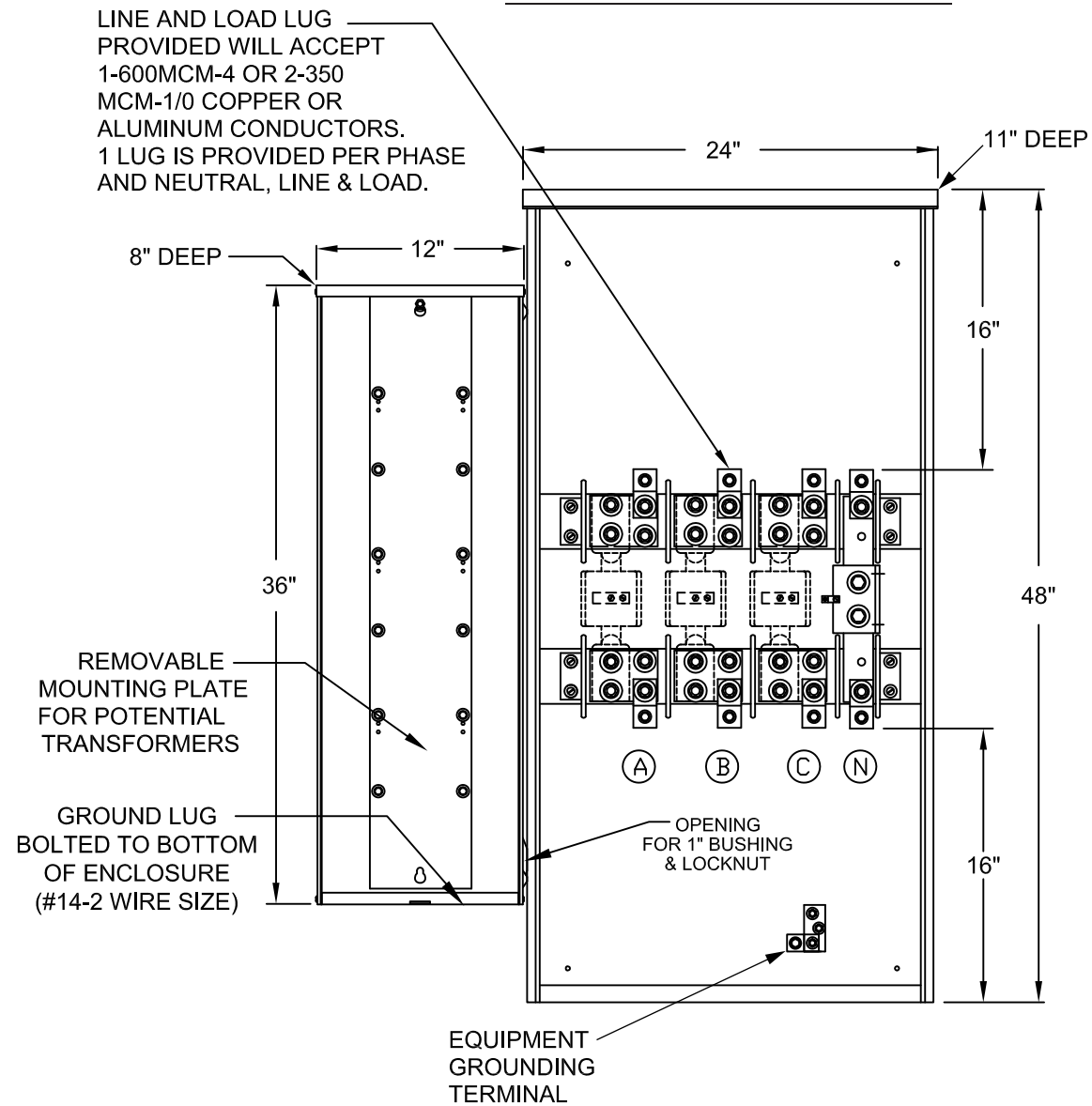

**FRONT ENCLOSED VIEW**

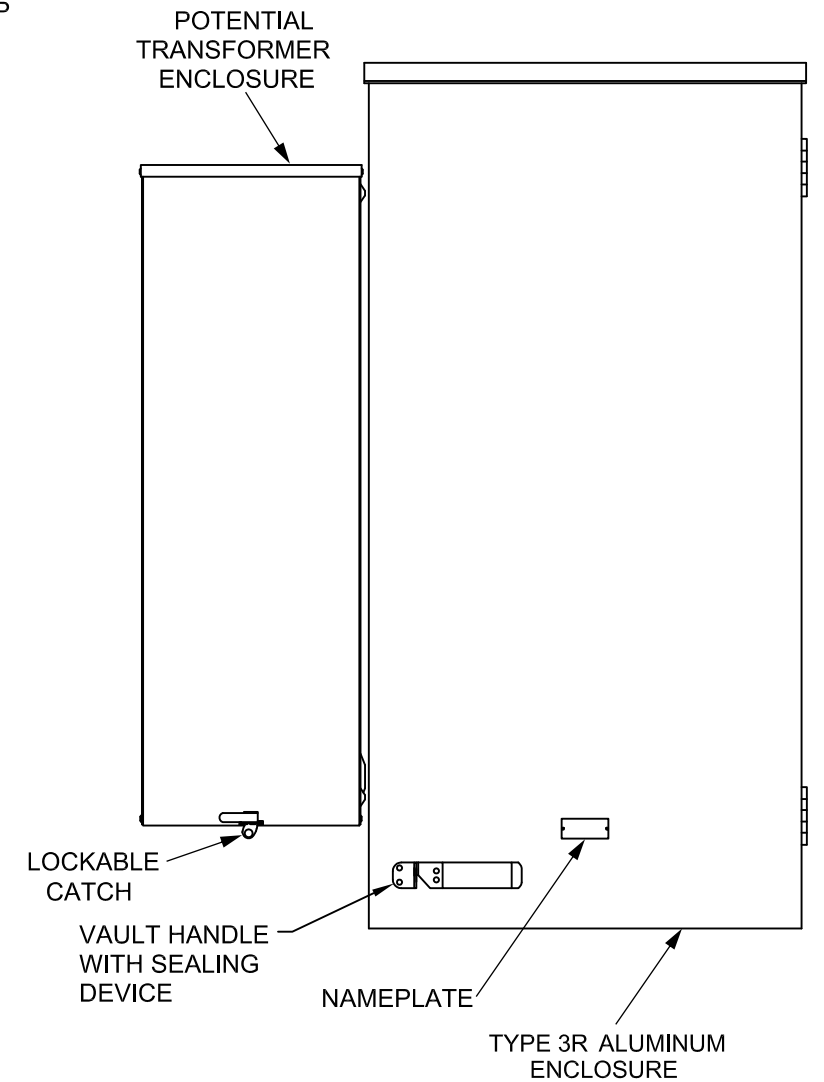

**GENERAL NOTES:**

1. C/T AND LUG LANDING PADS AND NEUTRAL ARE RATED 400 AMPS.
2. CURRENT TRANSFORMERS ARE PROVIDED BY THE UTILITY CO.
3. LINE AND LOAD LUG PROVIDED WILL ACCEPT 1-600MCM-#4 OR 2-350MCM-1/0 COPPER OR ALUMINUM CONDUCTORS. 1 LUG IS PROVIDED PER PHASE & NEUTRAL AS SHOWN, LINE & LOAD.



Description: **400A, 600V AC Max, 3Ph 4Wire, Outdoor Current Transformer Cabinet**