
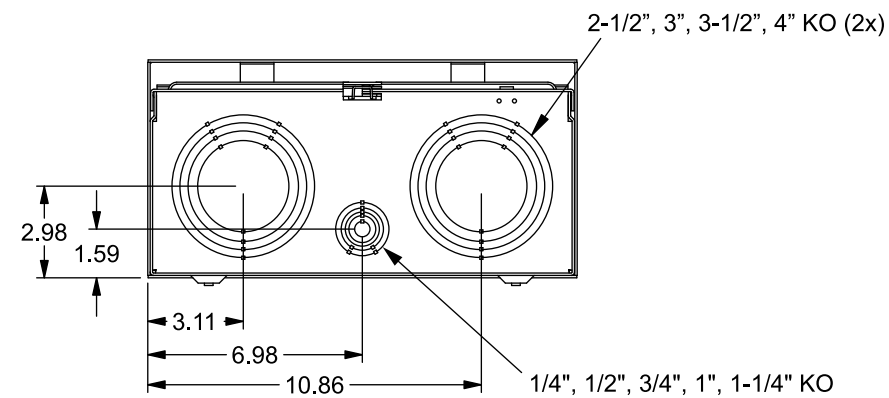
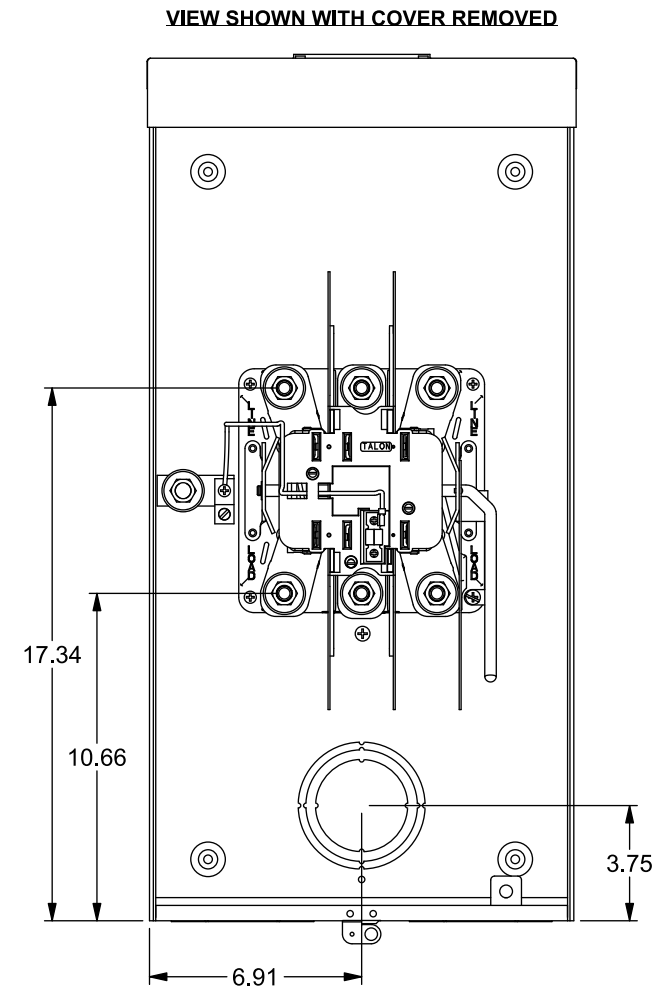
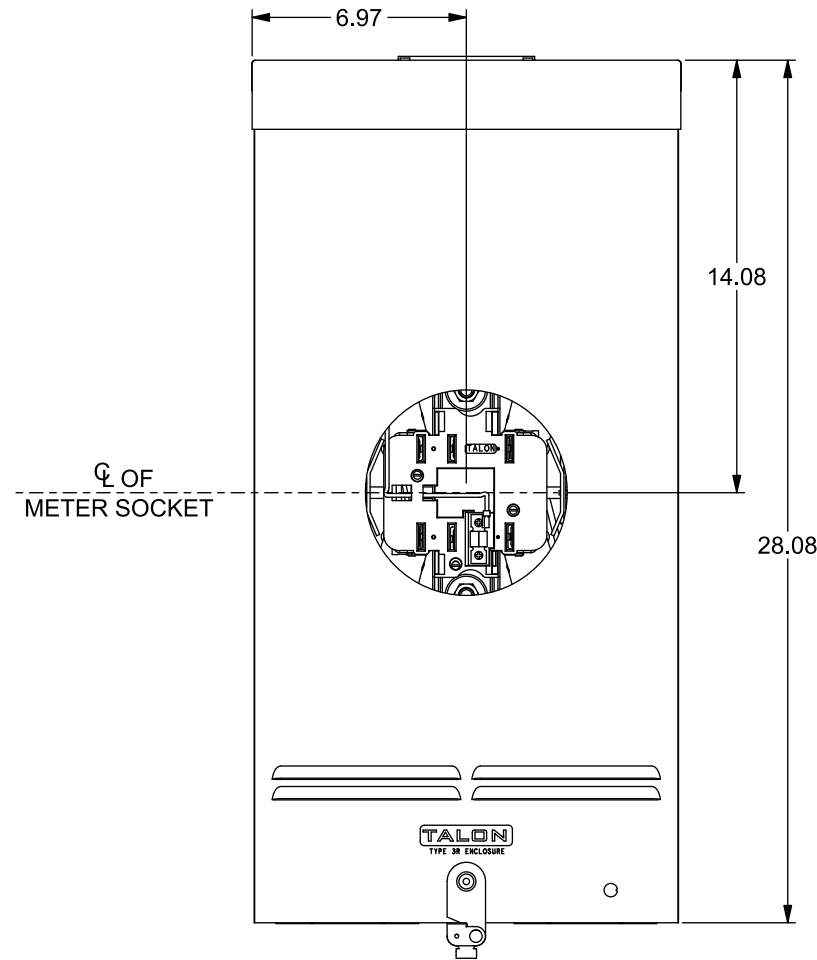
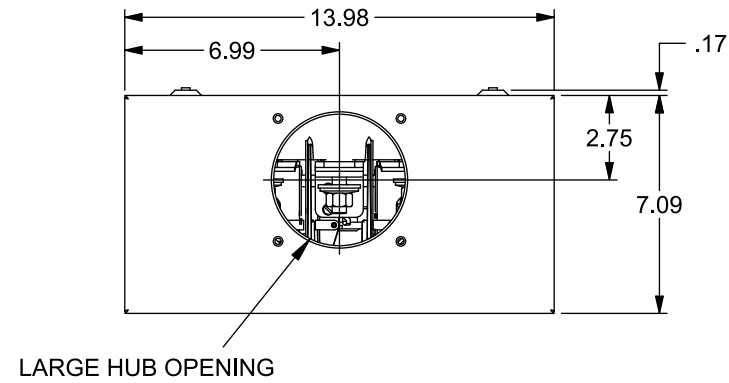


Catalog Number: 47707-01NU

Features and Ratings

- Ringless Type Meter Socket
- 320A Continuous, 400A Max., 600V AC
- Outdoor Enclosure (NEMA Type 3R)
- Painted G90 Steel Enclosure
- 3 Phase Commercial Socket
- 7 Jaw Meter Socket
- Meter Socket Type HQ-7DT
- For Overhead & Underground Service
- HD Type Hub Opening
- Lever Bypass
- 7/16" Barrel Lock Provision

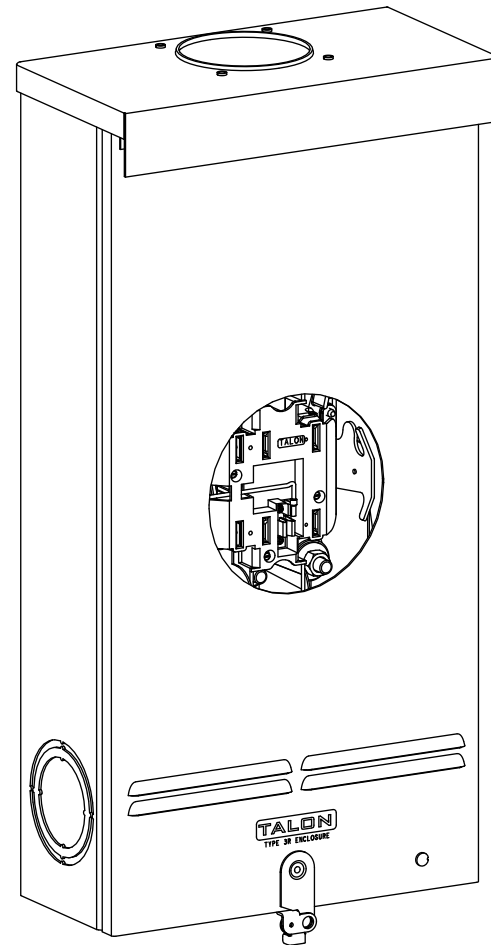


Accessories

| CONDUIT HUBS (HD Type) | |
|------------------------|---------------------|
| TRADE SIZE | CATALOG No. |
| 3 INCH | EC56856 or H56856-2 |
| 3-1/2 INCH | EC56857 or H56857-2 |
| 4 INCH | EC56858 or H56858-2 |
| Hub Cover Plate | EC56933 or H56933S |

Meter Opening Cover Plate
Cat No: H659-0162

Connectors, Wire Sizes and Torques

| CONNECTOR | PART No. | WIRE SIZE | TORQUE |
|-------------------|----------|------------------|-------------|
| LINE/LOAD/NEUTRAL | 56732 | (2) #4-350 kcmil | 275 IN-LBS. |
| GROUND | 67754A | #14 - 2/0 AWG | 50 IN-LBS. |

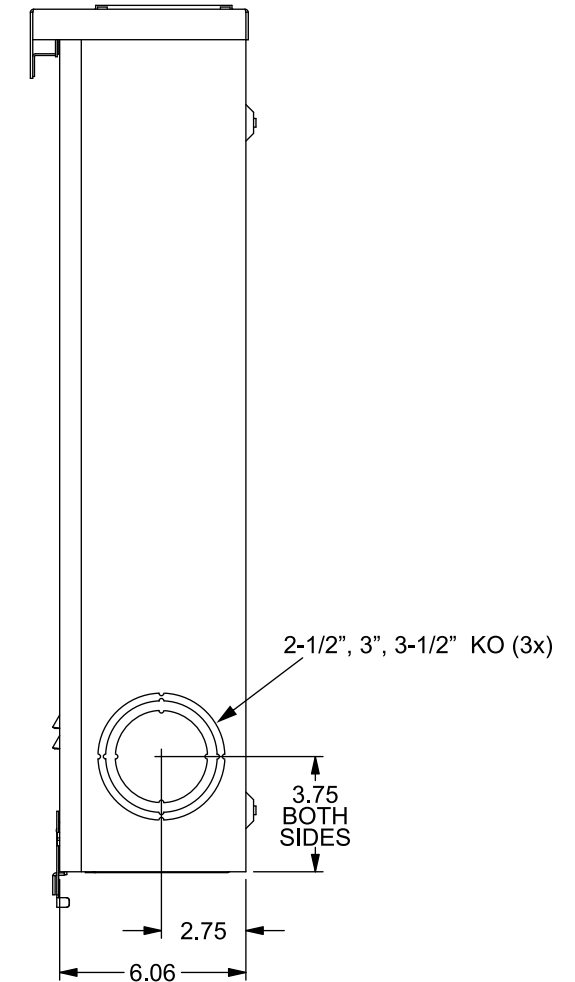

© 2019 Copyright Siemens Industry, Inc.

TALON
Meter Socket

Description:
**320A Cont, 7 Jaw, HQ-7DT, 600V AC,
w/Barrel Lock, Painted Steel Enclosure**

KAM 1/8/19 | DO NOT SCALE DRAWING | Dwg No: **47707-01NU**