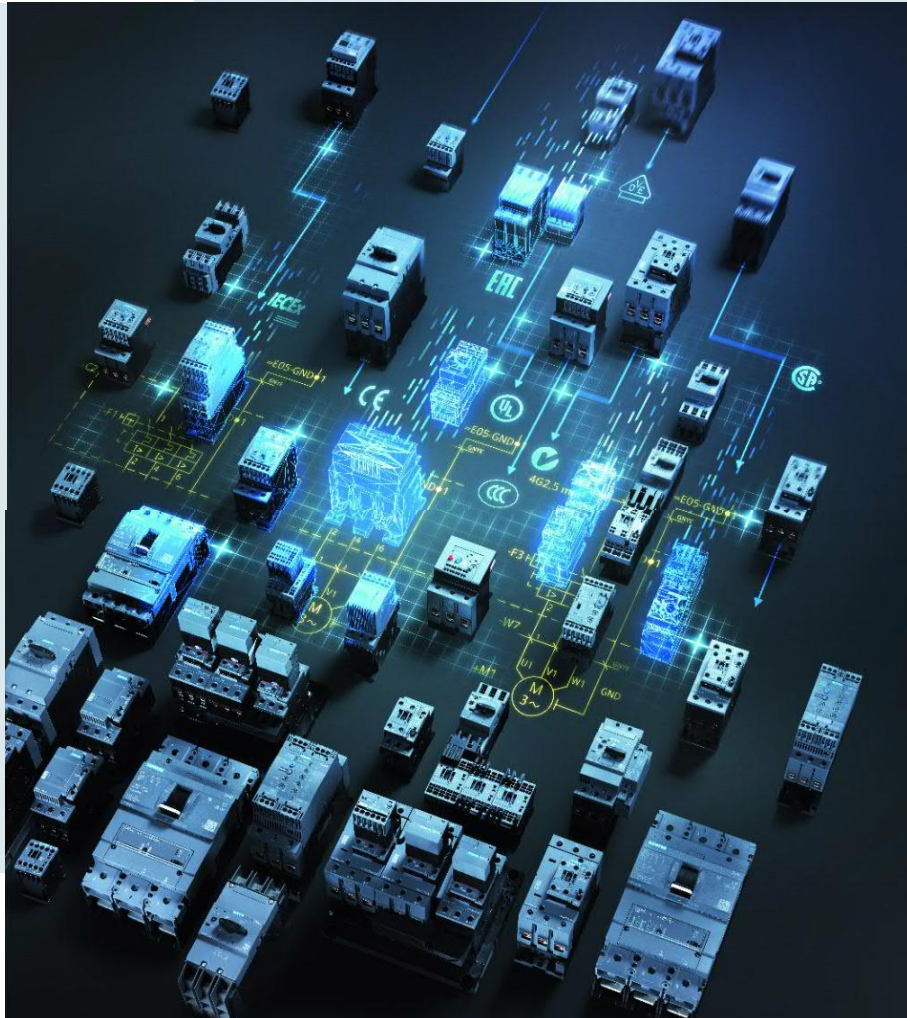


SIEMENS



Minikatalog

Kontrolprodukter

Udgave Q2/18

Kontrolprodukter

Udgave Q2/18

Udgave Q2/18

Indholdsfortegnelse

Indholdsfortegnelse	1
Introduktion til kataloget	2
Håndbetjente motorværn – Overbelastning- og kortslutningsbeskyttelse	5
Håndbetjente motorværn – Kun kortslutningsbeskyttelse	12
Håndbetjente motorværn – Transformerbeskyttelse	19
Tilbehør til håndbetjente motorværn	24
3RV29 Infeed system	31
Kontaktorer – 230V AC styrespænding	32
Kontaktorer – 24V AC styrespænding	38
Kontaktorer – 24V DC styrespænding	43
Tilbehør til kontaktorer	48
Minikontaktorer – Til M36 afdækning	57
Komplette sokkelrelæer	58
Solid-state relæer	60
Softstartere	66
SIMOCODE pro S & pro V – Intelligente motorstartere	78
SITOP strømforsyninger	87
Timere – SIRIUS serien	88
Timere - Til M36 afdækning	91
Overvågningsrelæer	92
Termistorrelæer	96
Signalkonvertere	98
Sikkerhedsrelæer	99
SIRIUS ACT – Komplette trykknapper i kunststof	100
SIRIUS ACT – Trykknaphoveder i kunststof	114
SIRIUS ACT – Komplette trykknapper i metal	123
SIRIUS ACT – Trykknaphoveder i metal	136
SIRIUS ACT – Holdere og kontaktelementer	145
SIRIUS ACT – LED moduler	147
SIRIUS ACT – Skilteholdere & skilte	153
SIRIUS ACT – Tomme trykknappbokse	155
SIRIUS ACT – Komplette trykknappbokse	158
Signaltårn	160

Introduktion

Minikataloget her er udarbejdet for at give et lettere overblik over lavspændingskomponenter til automation og kontrol applikationer. I kataloget er medtaget de mest anvendte typer, og kataloget viser derfor kun et lille uddrag af det fulde produktprogram.

Det fulde produktprogram findes i IC10 kataloget, som kan downloades her: www.siemens.com/ic10

Listepriser angivet i dette katalog er udelukkende vejledende og kan ændres uden forgående varsel. Den til enhver tid gældende listepris kan findes i Siemens Industry Mall.

Alle typenumre i dette katalog er link, som fører direkte til komponentens side på Siemens Industry Mall. Her det muligt at finde information i form af datablade, diagrammer, certifikater, manualer m.m. samt kontrollere lagerstatus på komponenten.

Nemmeste adgang til manualer, certifikater m.m. fås via Siemens Industry Mall. På enhver komponents side, findes et link til dette.

3RV2021-1AA10



Image similar

Circuit breaker size S0 for motor protection, CLASS 10 A-release 1.1...1.6 A N-release 21 A screw terminal Standard switching capacity

List Price 627,00 DKK

Customer Price 627,00 DKK [Price details](#)

Availability This product is currently available. 379 Piece
This result displays the availability situation at this moment in time. The available quantity is permanently subject to change due to new incoming orders. Therefore the shown result cannot be guaranteed.

Additional Services For this product we can offer services like Spare Part Delivery/Repair/Exchange. You have currently no rights to enter the Service Web Shop for that.
> For further information & to order this service, please contact your local Spares&Repair Partner

DataSheet in PDF [Download](#)

Service & Support (Manuals, Certificates, FAQs...) [Download](#)

CAX Product data [CAX Data](#)

> Image gallery and data for M-CAD and E-CAD (7) (7)

Håndbetjente motorværn – General information

Kortslutningsbrydeevne

I nedenstående tabel angives kortslutningsbrydeevnen for 3RV2 håndbetjente motorværn.

Motor starter protectors/ circuit breakers	Rated current I_n	Up to 240 V AC ¹⁾			Up to 400 V AC ^{1)/} 415 V AC ²⁾			Up to 440 V AC ^{1)/} 460 V AC ²⁾			Up to 500 V AC ^{1)/} 525 V AC ²⁾			Up to 690 V AC ¹⁾		
		I_{cu}	I_{cs}	Max. fuse (gG)	I_{cu}	I_{cs}	Max. fuse (gG) ³⁾	I_{cu}	I_{cs}	Max. fuse (gG) ³⁾	I_{cu}	I_{cs}	Max. fuse (gG) ³⁾	I_{cu}	I_{cs}	Max. fuse (gG) ^{3)/4)}
Type	A	kA	kA	A	kA	kA	A	kA	kA	A	kA	kA	A	kA	kA	A
Size S00																
3RV2.11	0.16 ... 1.6	100	100	--	100	100	--	100	100	--	100	100	--	100	100	--
	2; 2.5	100	100	--	100	100	--	100	100	--	100	100	--	10	10	25
	3.2	100	100	--	100	100	--	100	100	--	100	100	--	10	10	32
	4; 5	100	100	--	100	100	--	100	100	--	100	100	--	6	4	32
	6.3	100	100	--	100	100	--	100	100	--	100	100	--	6	4	50
	8	100	100	--	100	100	--	50	50	63	42	42	63	6	4	50
	10	100	100	--	100	100	--	50	50	80	42	42	63	6	4	50
	12.5	100	100	--	100	100	--	50	50	80	42	42	80	6	4	63
	16	100	100	--	55	30	100	50	12.5	80	10	5	80	4	4	63
3RV1611-0BD10	0.2	100	100	--	100	100	--	100	100	--	100	100	--	100	100	--
Size S0																
3RV2.21	0.16 ... 1.6	100	100	--	100	100	--	100	100	--	100	100	--	100	100	--
	2; 2.5	100	100	--	100	100	--	100	100	--	100	100	--	10	10	25
	3.2	100	100	--	100	100	--	100	100	--	100	100	--	10	10	32
	4; 5	100	100	--	100	100	--	100	100	--	100	100	--	6	4	32
	6.3	100	100	--	100	100	--	100	100	--	100	100	--	6	4	50
	8	100	100	--	100	100	--	50	50	63	42	42	63	6	4	50
	10	100	100	--	100	100	--	50	50	80	42	42	63	6	4	50
	12.5	100	100	--	100	100	--	50	50	80	42	42	80	6	4	63
	16	100	100	--	55	25	100	50	12.5	80	10	5	80	4	2	63
	20	100	100	--	55	25	125	50	10	80	10	5	80	4	2	63
	22; 25	100	100	--	55	25	125	50	10	100	10	5	80	4	2	63
	28; 32	100	100	--	55	25	125	30	10	125	10	5	100	4	2	100
	36; 40	100	100	--	20	10	125	12	8	125	6	3	100	3	2	100
Size S2																
3RV2.31	14; 17	100	100	--	65	30	100	50	25	100	12	6	63	5	3	63
	20	100	100	--	65	30	100	50	25	100	12	6	80	5	3	80
	25	100	100	--	65	30	100	50	15	100	12	6	80	5	3	80
	32; 36	100	100	--	65	30	125	50	15	125	10	5	100	4	2	100
	40; 45	100	100	--	65	30	160	50	15	125	10	5	100	4	2	100
	52	100	100	--	65	30	160	50	15	125	10	5	125	4	2	125
	59; 65	100	100	--	65	30	160	50	15	160	8	4	125	4	2	125
	73; 80	100	100	--	65	30	200	50	15	200	8	4	160	4	2	125
Size S2, with increased switching capacity																
3RV2.32	14; 17	100	100	--	100	50	--	65	30	100	18	10	63	8	5	63
	20; 25	100	100	--	100	50	--	65	30	100	18	10	80	8	5	80
	32 ... 45	100	100	--	100	50	--	65	30	125	15	8	100	6	4	100
	52	100	100	--	100	50	--	65	30	125	15	8	125	6	4	125
	59; 65	100	100	--	100	50	--	50	15	160	10	5	125	6	4	125
Size S3																
3RV2.41	40	100	100	--	65	30	125	65	30	125	12	6	100	6	3	63
	50	100	100	--	65	30	125	65	30	125	12	6	100	6	3	80
	63	100	100	--	65	30	160	65	30	160	12	6	100	6	3	80
	75	100	100	--	65	30	160	65	30	160	8	4	125	5	3	100
	84 ... 100	100	100	--	65	30	160	65	30	160	8	4	125	5	3	125
Size S3, with increased switching capacity																
3RV2.42	40	100	100	--	100	50	--	100	50	--	18	9	160	12	6	80
	50	100	100	--	100	50	--	100	50	--	15	7.5	160	10	5	100
	63	100	100	--	100	50	--	70	50	200	15	7.5	160	7.5	4	100
	75	100	100	--	100	50	--	70	50	200	10	5	160	6	3	125
	84 ... 100	100	100	--	100	50	--	70	50	200	10	5	160	6	3	160
3RV2742⁵⁾	up to 70 A	100	100	--	100	50	--	On request								

-- No back-up fuse required, since short-circuit resistant up to 100 kA

1) 10 % overvoltage.

2) 5 % overvoltage.

3) Back-up fuse only required if short-circuit current at the place of installation is $> I_{cu}$.

4) Alternatively, fuseless limiter combinations for 690 V AC can also be used.

5) The values for the 3RV2742 circuit breakers have been tested only up to 400 V/415 V AC.

Håndbetjente motorværn – General information

Motorstarter koordinationer

Når et håndbetjent motorværn benyttes i forbindelse med en kontaktor anses det som en koordineret løsning, hvor vi som producent angiver et maksimalt kortslutningsniveau for kombinationen.

Disse tabeller findes i et separat katalog, som kan hentes her:

<https://support.industry.siemens.com/cs/document/39714188/configuration-manual-load-feeders-configuring-the-sirius-modular-system?dti=0&lc=en-DK>

Tabellerne er opbygget med motorstørrelse i kW samt indstillingsmulighed på det håndbetjente motorværn, og angiver så præcis type på motorværn og kontaktor. Se eksempel nedenfor.

3.1 Motor starter protector + contactor

**CLASS 10, type of coordination 1,
short-circuit breaking capacity $I_k = 150$ kA**



Standard three-phase motor 4-pole at 400 V AC ¹⁾		Motor starter protector for motor protection ⁴⁾ Maximum permitted setting range overload release			Contactor ²⁾	Size
Standard output P	Motor current I	IE1 / IE2 motors	IE3 / IE4 motors			
kW	A	A	A	Article No.	Article No.	
0.04	0.16	0.11 ... 0.16	0.11 ... 0.14	3RV2011-0AA10	3RT2015-1AP01	S00/S00
0.06	0.2	0.14 ... 0.20	0.14 ... 0.18	3RV2011-0BA10	3RT2015-1AP01	S00/S00
0.06	0.2	0.18 ... 0.25	0.18 ... 0.22	3RV2011-0CA10	3RT2015-1AP01	S00/S00
0.09	0.3	0.22 ... 0.32	0.22 ... 0.28	3RV2011-0DA10	3RT2015-1AP01	S00/S00
0.09	0.3	0.28 ... 0.40	0.28 ... 0.35	3RV2011-0EA10	3RT2015-1AP01	S00/S00
0.12	0.4	0.35 ... 0.50	0.35 ... 0.45	3RV2011-0FA10	3RT2015-1AP01	S00/S00
0.18	0.6	0.45 ... 0.63	0.45 ... 0.55	3RV2011-0GA10	3RT2015-1AP01	S00/S00
0.18	0.6	0.55 ... 0.80	0.55 ... 0.7	3RV2011-0HA10	3RT2015-1AP01	S00/S00
0.25	0.85	0.70 ... 1.00	0.7 ... 0.9	3RV2011-0JA10	3RT2015-1AP01	S00/S00
0.37	1.1	0.90 ... 1.25	0.9 ... 1.1	3RV2011-0KA10	3RT2015-1AP01	S00/S00
0.55	1.5	1.1 ... 1.6	1.1 ... 1.4	3RV2011-1AA10	3RT2015-1AP01	S00/S00
0.75	1.9	1.4 ... 2.0	1.4 ... 1.8	3RV2011-1BA10	3RT2015-1AP01	S00/S00
0.75	1.9	1.8 ... 2.5	1.8 ... 2.2	3RV2011-1CA10	3RT2015-1AP01	S00/S00
1.1	2.7	2.2 ... 3.2	2.2 ... 2.8	3RV2011-1DA10	3RT2015-1AP01	S00/S00
1.5	3.6	2.8 ... 4.0	2.8 ... 3.5	3RV2011-1EA10	3RT2015-1AP01	S00/S00
1.5	3.6	3.5 ... 5.0	3.5 ... 4.5	3RV2011-1FA10	3RT2015-1AP01	S00/S00
2.2	5	4.5 ... 6.3	4.5 ... 5.5	3RV2011-1GA10	3RT2015-1AP01	S00/S00
3	6.5	5.5 ... 8.0	5.5 ... 7	3RV2011-1HA10	3RT2015-1AP01	S00/S00
4	8.5	7.0 ... 10.0	7 ... 9	3RV2011-1JA10	3RT2016-1AP01	S00/S00
5.5	11.5	9.0 ... 12.5	9 ... 10	3RV2011-1KA10	3RT2017-1AP01	S00/S00
7.5	15.5	10 ... 16	10 ... 13	3RV2011-4AA10	3RT2018-1AP01	S00/S00

Håndbetjente motorværn - Overbelastning- og kortslutningsbeskyttelse - Skrueterminaler

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3RV2011-0JA10 Håndbetjent motorværn, size S00, for motor protection, CLASS 10, Indst. 0.7...1 A, momentan udkobling 13 A, screw terminal	569,--	1	1 unit	41E
	3RV2011-1AA10 Håndbetjent motorværn, size S00, for motor protection, CLASS 10, Indst. 1.1...1.6 A, momentan udkobling 21 A screw terminal	603,--	1	1 unit	41E
	3RV2011-1CA10 Håndbetjent motorværn, size S00, for motor protection, CLASS 10, Indst. 1.8...2.5 A, momentan udkobling 33 A screw terminal	629,--	1	1 unit	41E
	3RV2011-1EA10 Håndbetjent motorværn, size S00, for motor protection, CLASS 10, Indst. 2.8...4 A, momentan udkobling 52 A screw terminal	629,--	1	1 unit	41E
	3RV2011-1GA10 Håndbetjent motorværn, size S00, for motor protection, CLASS 10, Indst. 4.5...6.3 A, momentan udkobling 82 A, screw terminal	629,--	1	1 unit	41E
	3RV2011-1HA10 Håndbetjent motorværn, size S00, for motor protection, CLASS 10, Indst. 5.5...8 A, momentan udkobling 104 A, screw terminal	629,--	1	1 unit	41E
	3RV2011-1JA10 Håndbetjent motorværn, size S00, for motor protection, CLASS 10, Indst. 7...10 A, momentan udkobling 130 A, screw terminal	705,--	1	1 unit	41E
	3RV2011-1KA10 Håndbetjent motorværn, size S00, for motor protection, CLASS 10, Indst. 9...12 A, momentan udkobling 163 A, screw terminal	705,--	1	1 unit	41E

Håndbetjente motorværn - Overbelastning- og kortslutningsbeskyttelse - Skrueterminaler

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3RV2011-4AA10 Håndbetjent motorværn, size S00, for motor protection, CLASS 10, Indst. 10...16 A, momentan udkobling 208 A, screw terminal	734,--	1	1 unit	41E
	3RV2021-0JA10 Håndbetjent motorværn, size S0, for motor protection, CLASS 10, Indst. 0.7...1 A, momentan udkobling 13 A, screw terminal	591,--	1	1 unit	41E
	3RV2021-1AA10 Håndbetjent motorværn, size S0, for motor protection, CLASS 10, Indst. 1.1...1.6 A, momentan udkobling 21 A, screw terminal	627,--	1	1 unit	41E
	3RV2021-1CA10 Håndbetjent motorværn, size S0, for motor protection, CLASS 10, Indst. 1.8...2.5 A, momentan udkobling 33 A, screw terminal	656,--	1	1 unit	41E
	3RV2021-1EA10 Håndbetjent motorværn, size S0, for motor protection, CLASS 10, Indst. 2.8...4 A, momentan udkobling 52 A, screw terminal	656,--	1	1 unit	41E
	3RV2021-1GA10 Håndbetjent motorværn, size S0, for motor protection, CLASS 10, Indst. 4.5...6.3 A, momentan udkobling 82 A, screw terminal	656,--	1	1 unit	41E
	3RV2021-1HA10 Håndbetjent motorværn, size S0, for motor protection, CLASS 10, Indst. 5.5...8 A, momentan udkobling 104 A, screw terminal	656,--	1	1 unit	41E
	3RV2021-1JA10 Håndbetjent motorværn, size S0, for motor protection, CLASS 10, Indst. 7...10 A, momentan udkobling 130 A, screw terminal	734,--	1	1 unit	41E

Håndbetjente motorværn - Overbelastning- og kortslutningsbeskyttelse - Skrueterminaler

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3RV2021-1KA10 Håndbetjent motorværn, size S0, for motor protection, CLASS 10, Indst. 9...12.5 A, momentan udkobling 163 A, screw terminal	734,--	1	1 unit	41E
	3RV2021-4AA10 Håndbetjent motorværn, size S0, for motor protection, CLASS 10, Indst. 10...16 A, momentan udkobling 208 A, screw terminal	734,--	1	1 unit	41E
	3RV2021-4CA10 Håndbetjent motorværn, size S0, for motor protection, CLASS 10, Indst. 16...22 A, momentan udkobling 286 A, screw terminal	814,--	1	1 unit	41E
	3RV2021-4NA10 Håndbetjent motorværn, size S0, for motor protection, CLASS 10, Indst. 23...28 A, momentan udkobling 364 A, screw terminal	1170,--	1	1 unit	41E
	3RV2021-4PA10 Håndbetjent motorværn, size S0, for motor protection, CLASS 10, Indst. 30...36 A, momentan udkobling 432 A, screw terminal	1410,--	1	1 unit	41E
	3RV2031-4PA10 Håndbetjent motorværn, size S2, for motor protection, CLASS 10, Indst. 28...36 A, momentan udkobling 520 A, screw terminal	1770,--	1	1 unit	41E
	3RV2031-4VA10 Håndbetjent motorværn, size S2, for motor protection, CLASS 10, Indst. 35...45 A, momentan udkobling 650 A, screw terminal	2100,--	1	1 unit	41E
	3RV2031-4XA10 Håndbetjent motorværn, size S2, for motor protection, CLASS 10, Indst. 49...59 A, momentan udkobling 845 A, screw terminal	2160,--	1	1 unit	41E

Håndbetjente motorværn - Overbelastning- og kortslutningsbeskyttelse - Skrueterminaler

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3RV2031-4KA10 Håndbetjent motorværn, size S2, for motor protection, CLASS 10, Indst. 62...73 A, momentan udkobling 949 A, screw terminal	2430,--	1	1 unit	41E
	3RV2031-4RA10 Håndbetjent motorværn, size S2, for motor protection, CLASS 10, Indst. 70...80 A, momentan udkobling 1040 A, screw terminal	2590,--	1	1 unit	41E
	3RV2041-4RA10 Håndbetjent motorværn, size S3, for motor protection, CLASS 10, Indst. 65...84 A, momentan udkobling 1170 A, screw terminal	2750,--	1	1 unit	41E
	3RV2041-4YA10 Håndbetjent motorværn, size S3, for motor protection, CLASS 10, Indst. 75...93 A, momentan udkobling 1300 A, screw terminal	2750,--	1	1 unit	41E
	3RV2041-4MA10 Håndbetjent motorværn, size S3, for motor protection, CLASS 10, Indst. 80...100 A, momentan udkobling 1300 A, screw terminal	3040,--	1	1 unit	41E

Håndbetjente motorværn - Overbelastning- og kortslutningsbeskyttelse - Fjederterminaler

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3RV2011-0JA20 Håndbetjent motorværn, size S00, for motor protection, CLASS 10, Indst. 0.7...1 A, momentan udkobling 13 A, Spring-type terminal	569,--	1	1 unit	41E
	3RV2011-1AA20 Håndbetjent motorværn, size S00, for motor protection, CLASS 10, Indst. 1.1...1.6 A, momentan udkobling 21 A, Spring-type terminal	603,--	1	1 unit	41E
	3RV2011-1CA20 Håndbetjent motorværn, size S00, for motor protection, CLASS 10, Indst. 1.8...2.5 A, momentan udkobling 33 A, Spring-type terminal	629,--	1	1 unit	41E
	3RV2011-1EA20 Håndbetjent motorværn, size S00, for motor protection, CLASS 10, Indst. 2.8...4 A, momentan udkobling 52 A, Spring-type terminal	629,--	1	1 unit	41E
	3RV2011-1GA20 Håndbetjent motorværn, size S00, for motor protection, CLASS 10, Indst. 4.5...6.3 A, momentan udkobling 82 A, Spring-type terminal	629,--	1	1 unit	41E
	3RV2011-1HA20 Håndbetjent motorværn, size S00, for motor protection, CLASS 10, Indst. 5.5...8 A, momentan udkobling 104 A, Spring-type terminal	629,--	1	1 unit	41E
	3RV2011-1JA20 Håndbetjent motorværn, size S00, for motor protection, CLASS 10, Indst. 7...10 A N release130 A, Spring-type terminal	705,--	1	1 unit	41E
	3RV2011-1KA20 Håndbetjent motorværn, size S00, for motor protection, CLASS 10, Indst. 9...12 A, momentan udkobling 163 A, Spring-type terminal	705,--	1	1 unit	41E

Håndbetjente motorværn - Overbelastning- og kortslutningsbeskyttelse - Fjederterminaler

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3RV2011-4AA20 Håndbetjent motorværn, size S00, for motor protection, CLASS 10, Indst. 10...16 A, momentan udkobling 208 A, Spring-type terminal	734,--	1	1 unit	41E
	3RV2021-0JA20 Håndbetjent motorværn, size S0, for motor protection, CLASS 10, Indst. 0.7...1 A, momentan udkobling 13 A, Spring-type terminal	591,--	1	1 unit	41E
	3RV2021-1AA20 Håndbetjent motorværn, size S0, for motor protection, CLASS 10, Indst. 1.1...1.6 A, momentan udkobling 21 A, Spring-type terminal	627,--	1	1 unit	41E
	3RV2021-1CA20 Håndbetjent motorværn, size S0, for motor protection, CLASS 10, Indst. 1.8...2.5 A, momentan udkobling 33 A, Spring-type terminal	656,--	1	1 unit	41E
	3RV2021-1EA20 Håndbetjent motorværn, size S0, for motor protection, CLASS 10, Indst. 2.8...4 A, momentan udkobling 52 A, Spring-type terminal	656,--	1	1 unit	41E
	3RV2021-1GA20 Håndbetjent motorværn, size S0, for motor protection, CLASS 10, Indst. 4.5...6.3 A, momentan udkobling 82 A, Spring-type terminal	656,--	1	1 unit	41E
	3RV2021-1HA20 Håndbetjent motorværn, size S0, for motor protection, CLASS 10, Indst. 5.5...8 A, momentan udkobling 104 A, Spring-type terminal	656,--	1	1 unit	41E
	3RV2021-1JA20 Håndbetjent motorværn, size S0, for motor protection, CLASS 10, Indst. 7...10 A N release130 A, Spring-type terminal	734,--	1	1 unit	41E

Håndbetjente motorværn - Overbelastning- og kortslutningsbeskyttelse - Fjederterminaler

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3RV2021-1KA20 Håndbetjent motorværn, size S0, for motor protection, CLASS 10, Indst. 9...12 A, momentan udkobling 163 A, Spring-type terminal	734,--	1	1 unit	41E
	3RV2021-4AA20 Håndbetjent motorværn, size S0, for motor protection, CLASS 10, Indst. 10...16 A, momentan udkobling 208 A, Spring-type terminal	734,--	1	1 unit	41E
	3RV2021-4CA20 Håndbetjent motorværn, size S0, for motor protection, CLASS 10, Indst. 16...22 A, momentan udkobling 286 A, Spring-type terminal	814,--	1	1 unit	41E
	3RV2021-4NA20 Håndbetjent motorværn, size S0, for motor protection, CLASS 10, Indst. 23...28 A, momentan udkobling 364 A, Spring-type terminal	1170,--	1	1 unit	41E

Håndbetjente motorværn - Kun kortslutningsbeskyttelse - Skrueterminaler

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3RV2311-0JC10 Håndbetjent motorværn, size S00 kun kortslutningsbeskyttelse, Mærkestrøm 1 A, momentan udkobling 13 A, screw terminal	626,--	1	1 unit	41E
	3RV2311-1AC10 Håndbetjent motorværn, size S00 kun kortslutningsbeskyttelse, Mærkestrøm 1.6 A, momentan udkobling 21 A, screw terminal	626,--	1	1 unit	41E
	3RV2311-1CC10 Håndbetjent motorværn, size S00, kun kortslutningsbeskyttelse, Mærkestrøm 2.5 A, momentan udkobling 33 A, screw terminal	639,--	1	1 unit	41E
	3RV2311-1EC10 Håndbetjent motorværn, size S00, kun kortslutningsbeskyttelse, Mærkestrøm 4 A, momentan udkobling 52 A, screw terminal	639,--	1	1 unit	41E
	3RV2311-1GC10 Håndbetjent motorværn, size S00, kun kortslutningsbeskyttelse, Mærkestrøm 6.3 A, momentan udkobling 82 A, screw terminal	639,--	1	1 unit	41E
	3RV2311-1HC10 Håndbetjent motorværn, size S00, kun kortslutningsbeskyttelse, Mærkestrøm 8 A, momentan udkobling 104 A, screw terminal	639,--	1	1 unit	41E
	3RV2311-1JC10 Håndbetjent motorværn, size S00, kun kortslutningsbeskyttelse, Mærkestrøm 10 A, momentan udkobling 130 A, screw terminal	708,--	1	1 unit	41E
	3RV2311-1KC10 Håndbetjent motorværn, size S00, kun kortslutningsbeskyttelse, Mærkestrøm 12.5 A, momentan udkobling 163 A, screw terminal	708,--	1	1 unit	41E

Håndbetjente motorværn - Kun kortslutningsbeskyttelse - Skrueterminaler

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3RV2311-4AC10 Håndbetjent motorværn, size S00, kun kortslutningsbeskyttelse, mærkestrøm 16 A, momentan udkobling 208 A, screw terminal	708,--	1	1 unit	41E
	3RV2321-1AC10 Håndbetjent motorværn, size S0, kun kortslutningsbeskyttelse, Mærkestrøm 1.6 A, momentan udkobling 21 A, screw terminal	653,--	1	1 unit	41E
	3RV2321-1CC10 Håndbetjent motorværn, size S0, kun kortslutningsbeskyttelse, Mærkestrøm 2.5 A, momentan udkobling 33 A, screw terminal	664,--	1	1 unit	41E
	3RV2321-1EC10 Håndbetjent motorværn, size S0, kun kortslutningsbeskyttelse, Mærkestrøm 4 A, momentan udkobling 52 A, screw terminal	664,--	1	1 unit	41E
	3RV2321-1GC10 Håndbetjent motorværn, size S0, kun kortslutningsbeskyttelse, Mærkestrøm 6.3 A, momentan udkobling 82 A, screw terminal	664,--	1	1 unit	41E
	3RV2321-1HC10 Håndbetjent motorværn, size S0, kun kortslutningsbeskyttelse, Mærkestrøm 8 A, momentan udkobling 104 A, screw terminal	664,--	1	1 unit	41E
	3RV2321-1JC10 Håndbetjent motorværn, size S0, kun kortslutningsbeskyttelse, Mærkestrøm 10 A, momentan udkobling 130 A, screw terminal	737,--	1	1 unit	41E
	3RV2321-1KC10 Håndbetjent motorværn, size S0, kun kortslutningsbeskyttelse, Mærkestrøm 12.5 A, momentan udkobling 163 A, screw terminal	737,--	1	1 unit	41E

Håndbetjente motorværn - Kun kortslutningsbeskyttelse - Skrueterminaler

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3RV2321-4AC10 Håndbetjent motorværn, size S0, kun kortslutningsbeskyttelse, mærkestrøm 16 A, momentan udkobling 208 A, screw terminal	708,--	1	1 unit	41E
	3RV2321-4CC10 Håndbetjent motorværn, size S0, kun kortslutningsbeskyttelse, Mærkestrøm 22 A, momentan udkobling 286 A, screw terminal	784,--	1	1 unit	41E
	3RV2321-4NC10 Håndbetjent motorværn, size S0, kun kortslutningsbeskyttelse, Mærkestrøm 28 A, momentan udkobling 364 A, screw terminal	1150,--	1	1 unit	41E
	3RV2321-4PC10 Håndbetjent motorværn, size S0, kun kortslutningsbeskyttelse, Mærkestrøm 36 A, momentan udkobling 432 A, screw terminal	1360,--	1	1 unit	41E
	3RV2331-4KC10 Håndbetjent motorværn, size S2, kun kortslutningsbeskyttelse, Mærkestrøm 73 A, momentan udkobling 949 A, screw terminal	2370,--	1	1 unit	41E
	3RV2331-4PC10 Håndbetjent motorværn, size S2, kun kortslutningsbeskyttelse, Mærkestrøm 36 A, momentan udkobling 520 A, screw terminal	1700,--	1	1 unit	41E
	3RV2331-4RC10 Håndbetjent motorværn, size S2, kun kortslutningsbeskyttelse, Mærkestrøm 80 A, momentan udkobling 1040 A, screw terminal	2520,--	1	1 unit	41E
	3RV2331-4VC10 Håndbetjent motorværn, size S2, kun kortslutningsbeskyttelse, Mærkestrøm 45 A, momentan udkobling 650 A, screw terminal	2050,--	1	1 unit	41E

Håndbetjente motorværn - Kun kortslutningsbeskyttelse - Skrueterminaler

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3RV2331-4XC10 Håndbetjent motorværn, size S2, kun kortslutningsbeskyttelse, Mærkestrøm 59 A, momentan udkobling 845 A, screw terminal	2100,--	1	1 unit	41E
	3RV2341-4MC10 Håndbetjent motorværn, size S3, kun kortslutningsbeskyttelse, Mærkestrøm 100 A, momentan udkobling 1300 A, screw terminal	2940,--	1	1 unit	41E
	3RV2341-4RC10 Håndbetjent motorværn, size S3, kun kortslutningsbeskyttelse, Mærkestrøm 84 A, momentan udkobling 1170 A, screw terminal	2650,--	1	1 unit	41E
	3RV2341-4YC10 Håndbetjent motorværn, size S3, kun kortslutningsbeskyttelse, Mærkestrøm 93 A, momentan udkobling 1300 A, screw terminal	2650,--	1	1 unit	41E

Håndbetjente motorværn - Kun kortslutningsbeskyttelse - Fjederterminaler

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3RV2311-0JC20 Håndbetjent motorværn, size S00, kun kortslutningsbeskyttelse, Mærkestrøm 1 A, momentan udkobling 13 A, Spring-type terminal	626,--	1	1 unit	41E
	3RV2311-1AC20 Håndbetjent motorværn, size S00, kun kortslutningsbeskyttelse, Mærkestrøm 1.6 A, momentan udkobling 21 A, Spring-type terminal	626,--	1	1 unit	41E
	3RV2311-1CC20 Håndbetjent motorværn, size S00, kun kortslutningsbeskyttelse, Mærkestrøm 2.5 A, momentan udkobling 33 A, Spring-type terminal	639,--	1	1 unit	41E
	3RV2311-1EC20 Håndbetjent motorværn, size S00, kun kortslutningsbeskyttelse, Mærkestrøm 4 A, momentan udkobling 52 A, Spring-type terminal	639,--	1	1 unit	41E
	3RV2311-1GC20 Håndbetjent motorværn, size S00, kun kortslutningsbeskyttelse, Mærkestrøm 6.3 A, momentan udkobling 82 A, Spring-type terminal	639,--	1	1 unit	41E
	3RV2311-1HC20 Håndbetjent motorværn, size S00, kun kortslutningsbeskyttelse, Mærkestrøm 8 A, momentan udkobling 104 A, Spring-type terminal	639,--	1	1 unit	41E
	3RV2311-1JC20 Håndbetjent motorværn, size S00, kun kortslutningsbeskyttelse, Mærkestrøm 10 A, momentan udkobling 130 A, Spring-type terminal	708,--	1	1 unit	41E
	3RV2311-1KC20 Håndbetjent motorværn, size S00, kun kortslutningsbeskyttelse, Mærkestrøm 12.5 A, momentan udkobling 163 A, Spring-type terminal	708,--	1	1 unit	41E

Håndbetjente motorværn - Kun kortslutningsbeskyttelse - Fjederterminaler

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3RV2311-4AC20 Håndbetjent motorværn, size S00, kun kortslutningsbeskyttelse, mærkestrøm 16 A, momentan udkobling 208 A, Spring-type terminal	708,--	1	1 unit	41E
	3RV2321-1AC20 Håndbetjent motorværn, size S0, kun kortslutningsbeskyttelse, Mærkestrøm 1.6 A, momentan udkobling 21 A, Spring-type terminal	653,--	1	1 unit	41E
	3RV2321-1CC20 Håndbetjent motorværn, size S0, kun kortslutningsbeskyttelse, Mærkestrøm 2.5 A, momentan udkobling 33 A, Spring-type terminal	664,--	1	1 unit	41E
	3RV2321-1EC20 Håndbetjent motorværn, size S0, kun kortslutningsbeskyttelse, Mærkestrøm 4 A, momentan udkobling 52 A, Spring-type terminal	664,--	1	1 unit	41E
	3RV2321-1GC20 Håndbetjent motorværn, size S0, kun kortslutningsbeskyttelse, Mærkestrøm 6.3 A, momentan udkobling 82 A, Spring-type terminal	664,--	1	1 unit	41E
	3RV2321-1HC20 Håndbetjent motorværn, size S0, kun kortslutningsbeskyttelse, Mærkestrøm 8 A, momentan udkobling 104 A, Spring-type terminal	664,--	1	1 unit	41E
	3RV2321-1JC20 Håndbetjent motorværn, size S0, kun kortslutningsbeskyttelse, Mærkestrøm 10 A, momentan udkobling 130 A, Spring-type terminal	737,--	1	1 unit	41E
	3RV2321-1KC20 Håndbetjent motorværn, size S0, kun kortslutningsbeskyttelse, Mærkestrøm 12.5 A, momentan udkobling 163 A, Spring-type terminal	737,--	1	1 unit	41E

Håndbetjente motorværn - Kun kortslutningsbeskyttelse - Fjederterminaler

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3RV2321-4AC20 Håndbetjent motorværn, size S0, kun kortslutningsbeskyttelse, mærkestrøm 16 A, momentan udkobling 208 A, Spring-type terminal	708,--	1	1 unit	41E
	3RV2321-4CC20 Håndbetjent motorværn, size S0, kun kortslutningsbeskyttelse, Mærkestrøm 22 A, momentan udkobling 286 A, Spring-type terminal	784,--	1	1 unit	41E
	3RV2321-4NC20 Håndbetjent motorværn, size S0, kun kortslutningsbeskyttelse, Mærkestrøm 28 A, momentan udkobling 364 A, Spring-type terminal	1150,--	1	1 unit	41E

Håndbetjente motorværn - Transformerbeskyttelse - Skrueterminaler

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3RV2411-0JA10 Håndbetjent motorværn, size S00, transformerbeskyttelse, Indst. 0.7...1 A, momentan udkobling 21 A, screw terminal	698,--	1	1 unit	41E
	3RV2411-1AA10 Håndbetjent motorværn, size S00, transformerbeskyttelse, Indst. 1.1...1.6 A, momentan udkobling 33 A, screw terminal	698,--	1	1 unit	41E
	3RV2411-1CA10 Håndbetjent motorværn, size S00, transformerbeskyttelse, Indst. 1.8...2.5 A N release52 A, screw terminal	698,--	1	1 unit	41E
	3RV2411-1EA10 Håndbetjent motorværn, size S00, transformerbeskyttelse, Indst. 2.8...4 A, momentan udkobling 82 A, screw terminal	698,--	1	1 unit	41E
	3RV2411-1GA10 Håndbetjent motorværn, size S00, transformerbeskyttelse, Indst. 4.5...6.3 A N release130 A, screw terminal	698,--	1	1 unit	41E
	3RV2411-1HA10 Håndbetjent motorværn, size S00, transformerbeskyttelse, Indst. 5.5...8 A, momentan udkobling 163 A, screw terminal	698,--	1	1 unit	41E
	3RV2411-1JA10 Håndbetjent motorværn, size S00, transformerbeskyttelse, Indst. 7...10 A, momentan udkobling 208 A, screw terminal	772,--	1	1 unit	41E
	3RV2411-1KA10 Håndbetjent motorværn, size S00, transformerbeskyttelse, Indst. 9...12.5 A, momentan udkobling 260 A, screw terminal	772,--	1	1 unit	41E

Håndbetjente motorværn - Transformerbeskyttelse - Skrueterminaler

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3RV2411-4AA10 Håndbetjent motorværn, size S00, transformerbeskyttelse, Indst. 10...16 A, momentan udkobling 286 A, screw terminal	772,--	1	1 unit	41E
	3RV2421-4BA10 Håndbetjent motorværn, size S0, transformerbeskyttelse, Indst. 13...20 A, momentan udkobling 325 A, screw terminal	809,--	1	1 unit	41E
	3RV2421-4CA10 Håndbetjent motorværn, size S0, transformerbeskyttelse, Indst. 16...22 A, momentan udkobling 364 A, screw terminal	861,--	1	1 unit	41E
	3RV2421-4DA10 Håndbetjent motorværn, size S0, transformerbeskyttelse, Indst. 18...25 A, momentan udkobling 400 A, screw terminal	991,--	1	1 unit	41E
	3RV2431-4EA10 Håndbetjent motorværn, size S2, transformerbeskyttelse, Indst. 22...32 A, momentan udkobling 640 A, screw terminal	1950,--	1	1 unit	41E
	3RV2431-4UA10 Håndbetjent motorværn, size S2, transformerbeskyttelse, Indst. 32...40 A, momentan udkobling 820 A, screw terminal	2220,--	1	1 unit	41E
	3RV2431-4VA10 Håndbetjent motorværn, size S2, transformerbeskyttelse, Indst. 35...45 A, momentan udkobling 922 A, screw terminal	2250,--	1	1 unit	41E
	3RV2431-4WA10 Håndbetjent motorværn, size S2, transformerbeskyttelse, Indst. 42...52 A, momentan udkobling 1025 A, screw terminal	2310,--	1	1 unit	41E

Håndbetjente motorværn - Transformerbeskyttelse - Skrueterminaler

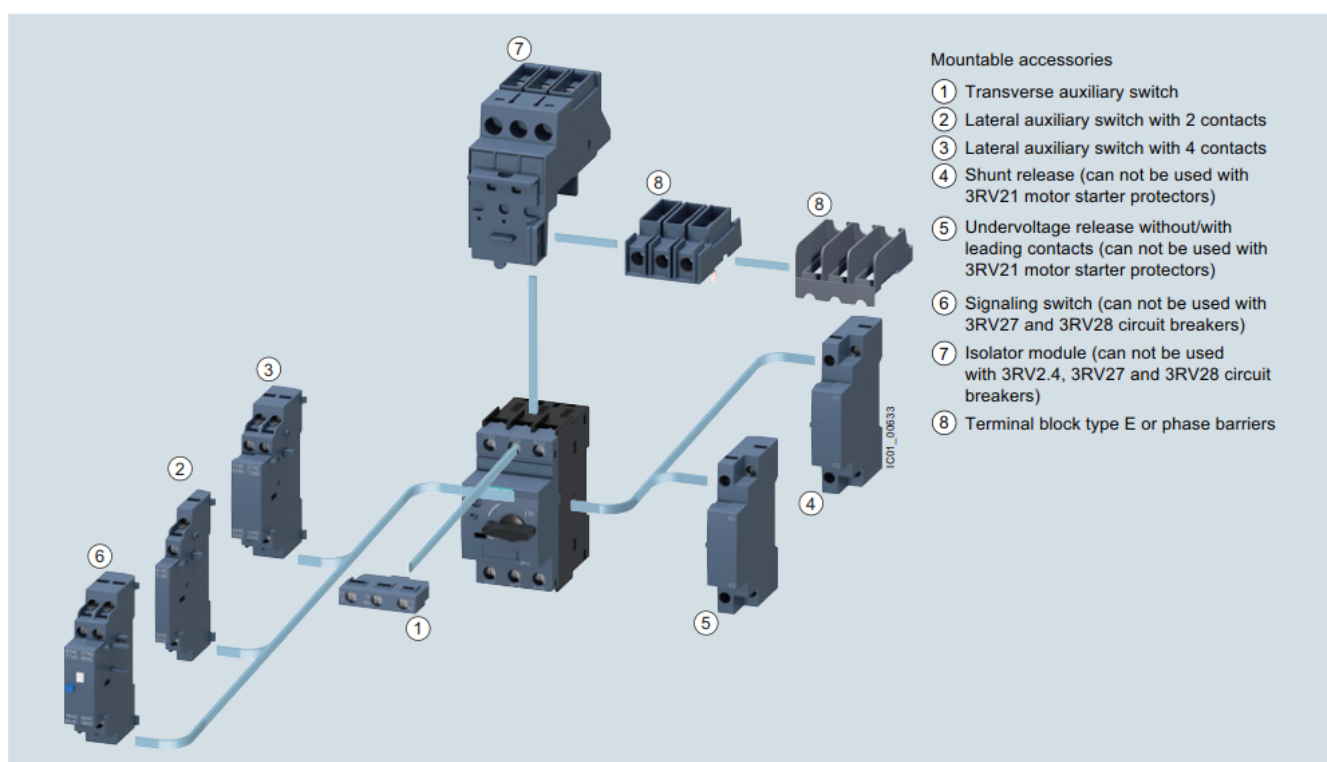
Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3RV2431-4XA10 Håndbetjent motorværn, size S2, transformerbeskyttelse, Indst. 49-59 A, momentan udkobling 1332 A, screw terminal	2320,--	1	1 unit	41E

Håndbetjente motorværn - Transformerbeskyttelse - Fjederterminaler

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3RV2411-0JA20 Håndbetjent motorværn, size S00, kun kortslutningsbeskyttelse, Indst. 0.7...1 A, momentan udkobling 21 A, Spring-type terminal	698,--	1	1 unit	41E
	3RV2411-1AA20 Håndbetjent motorværn, size S00, kun kortslutningsbeskyttelse, Indst. 1.1...1.6 A, momentan udkobling 33 A, Spring-type terminal	698,--	1	1 unit	41E
	3RV2411-1CA20 Håndbetjent motorværn, size S00, kun kortslutningsbeskyttelse, Indst. 1.8...2.5 A, momentan udkobling 52 A, Spring-type terminal	698,--	1	1 unit	41E
	3RV2411-1EA20 Håndbetjent motorværn, size S00, kun kortslutningsbeskyttelse, Indst. 2.8...4 A, momentan udkobling 82 A, Spring-type terminal	698,--	1	1 unit	41E
	3RV2411-1GA20 Håndbetjent motorværn, size S00, kun kortslutningsbeskyttelse, Indst. 4.5...6.3 A, momentan udkobling 130 A, Spring-type terminal	698,--	1	1 unit	41E
	3RV2411-1HA20 Håndbetjent motorværn, size S00, kun kortslutningsbeskyttelse, Indst. 5.5...8 A, momentan udkobling 163 A, Spring-type terminal	698,--	1	1 unit	41E
	3RV2411-1JA20 Håndbetjent motorværn, size S00, kun kortslutningsbeskyttelse, Indst. 7...10 A, momentan udkobling 208 A, Spring-type terminal	772,--	1	1 unit	41E
	3RV2411-1KA20 Håndbetjent motorværn, size S00, kun kortslutningsbeskyttelse, Indst. 9...12.5 A, momentan udkobling 260 A, Spring-type terminal	772,--	1	1 unit	41E

Håndbetjente motorværn - Transformerbeskyttelse - Fjederterminaler

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3RV2411-4AA20 Håndbetjent motorværn, size S00, kun kortslutningsbeskyttelse, Indst. 10...16 A, momentan udkobling 286 A, Spring-type terminal	772,--	1	1 unit	41E
	3RV2421-4BA20 Håndbetjent motorværn, size S0, kun kortslutningsbeskyttelse, Indst. 13...20 A, momentan udkobling 325 A, Spring-type terminal	809,--	1	1 unit	41E
	3RV2421-4CA20 Håndbetjent motorværn, size S0, kun kortslutningsbeskyttelse, Indst. 16...22 A, momentan udkobling 364 A, Spring-type terminal	861,--	1	1 unit	41E
	3RV2421-4DA20 Håndbetjent motorværn, size S0, kun kortslutningsbeskyttelse, Indst. 18...25 A, momentan udkobling 400 A, Spring-type terminal	991,--	1	1 unit	41E



Hjælpekontakter til 3RV2 håndbetjente motorværn

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3RV2901-1D Auxiliary switch transverse 1CO , screw terminal, for circuit breaker 3RV2	79,70	1	1 unit	41E
	3RV2901-1E Auxiliary switch transverse 1NO+1 NC , screw terminal, for circuit breaker 3RV2	96,40	1	1 unit	41E
	3RV2901-1F Auxiliary switch transverse 2NO , screw terminal, for circuit breaker 3RV2	96,40	1	1 unit	41E
	3RV2901-2E Auxiliary switch transverse 1NO+1 NC , spring-type terminal, for circuit breaker 3RV2	96,40	1	1 unit	41E
	3RV2901-2F Auxiliary switch transverse 2NO , spring-type terminal, for circuit breaker 3RV2	96,40	1	1 unit	41E
	3RV2901-1A Auxiliary switch can be mounted on the side, 1 NO+1 NC , screw terminal, for circuit breaker 3RV2	96,40	1	1 unit	41E
	3RV2901-1B Auxiliary switch can be mounted on the side, 2 NO , screw terminal for circuit breaker 3RV2	96,40	1	1 unit	41E
	3RV2901-2A Auxiliary switch can be mounted on the side, 1 NO+1 NC , spring-type terminal, for circuit breaker 3RV2	96,40	1	1 unit	41E
	3RV2901-2B Auxiliary switch can be mounted on the side, 2 NO , spring-type terminal, for circuit breaker 3RV2	96,40	1	1 unit	41E
	3RV2921-1M Signaling switch for circuit breaker 3RV2 with screw terminal	186,--	1	1 unit	41E

Hjælpekontakter til 3RV2 håndbetjente motorværn

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3RV2921-2M Signaling switch for circuit breaker 3RV2 with spring-type terminal	186,--	1	1 unit	41E

Tripsspoler til 3RV2 håndbetjente motorværn

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3RV2902-1AB0 Undervoltage release 24 V AC,50/60 Hz, with screw terminal, for circuit breaker 3RV2	289,--	1	1 unit	41E
	3RV2902-1AB4 Undervoltage release 24 V DC, with screw terminal, for circuit breaker 3RV2	835,--	1	1 unit	41E
	3RV2902-1AP0 Undervoltage release 230 VAC/50 Hz, 240 V AC/60 Hz, with screw terminal, for circuit breaker 3RV2	289,--	1	1 unit	41E
	3RV2902-1DB0 Shunt release 20...24 V AC,50/60 Hz, 100% ON period 20-70V AC, 50/60 Hz, 5 s ON period 20-70 V DC, 5 s ON period, with screw terminal, for circuit breaker 3RV2	289,--	1	1 unit	41E
	3RV2902-1DP0 Shunt release 210-240 V AC,50/60 Hz, 100% ON period 190-330 V AC, 50/60 Hz, 5 s ON period 190-330 V AC, 5 s ON period, with screw terminal, for circuit breaker 3RV2	289,--	1	1 unit	41E
	3RV2902-2AP0 Undervoltage release 230 VAC/50 Hz, 240 V AC/60 Hz with, spring-type terminal, for circuit breaker 3RV2	289,--	1	1 unit	41E
	3RV2902-2DB0 Shunt release 20...24 V AC,50/60 Hz, 100% ON period 20-70V AC, 50/60 Hz, 5 s ON period 20-70 V DC, 5 s ON period, with spring-type terminal, for circuit breaker 3RV2	289,--	1	1 unit	41E
	3RV2902-2DP0 Shunt release 210-240 V AC,50/60 Hz, 100% ON period 190-330 V AC, 50/60 Hz, 5 s ON period 190-330 V AC, 5 s ON period, with spring-type terminal, for circuit breaker 3RV2	289,--	1	1 unit	41E

Sløjfeskinner til 3RV2 håndbetjente motorværn

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3RV1915-1AB 3-phase busbars, Modular spacing 45 mm for 2 switches, Fork shape connections, Size S00/S0	96,40	1	1 unit	41E
	3RV1915-1BB 3-phase busbars, Modular spacing 45 mm for 3 switches, Fork shape connections, Size S00/S0	118,--	1	1 unit	41E
	3RV1915-1CB 3-phase busbars, Modular spacing 45 mm for 4 switches, Fork shape connections, Size S00/S0	130,--	1	1 unit	41E
	3RV1915-2AB 3-phase busbars, Modular spacing 55 mm for 2 switches and accessories, Fork shape connections, Size S00/S0	94,50	1	1 unit	41E
	3RV1915-2BB 3-phase busbars, Modular spacing 55 mm for 3 switches and accessories, Fork shape connections, Size S00/S0	114,--	1	1 unit	41E
	3RV1915-2CB 3-phase busbars, Modular spacing 55 mm for 4 switches and accessories, Fork shape connections, Size S00/S0	129,--	1	1 unit	41E
	3RV1915-2DB 3-phase busbars, Modular spacing 55 mm for 5 switches and accessories, Fork shape connections, Size S00/S0	142,--	1	1 unit	41E
	3RV1935-1A 3-phase busbar for 2 circuit breakers Size S2, Modular spacing: 55 mm	183,--	1	1 unit	41E
	3RV1935-1B 3-phase busbar for 3 circuit breakers Size S2, Modular spacing: 55 mm	225,--	1	1 unit	41E
	3RV1935-1C 3-phase busbar for 4 circuit breakers Size S2, Modular spacing: 55 mm	265,--	1	1 unit	41E
	3RV2925-5AB 3-phase supply terminal, for 3-phase busbar connection from top, Size S00/S0	100,--	1	1 unit	41E

 
Sløjfeskinner til 3RV2 håndbetjente motorværn

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3RV2935-5A 3-phase supply terminal, Size S2 for 3-phase busbar connection from top	181,--	1	1 unit	41E

Drejegreb til 3RV2 håndbetjente motorværn

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3RV2926-0B Door-coupling rotary operating mechanism, IP64, for circuit breaker Size S00...S3, 130 mm shaft, black	427,--	1	1 unit	41E
	3RV2926-0C Door-coupling rotary operating mechanism, IP64, Emergency switching-off, Size S00...S3, 130 mm shaft	495,--	1	1 unit	41E
	3RV2926-0K Door-coupling rotary operating mechanism, IP64, for circuit breaker Size S00...S3, black, 330 mm shaft with support	503,--	1	1 unit	41E
	3RV2926-0L Door-coupling rotary operating mechanism, IP64, Emergency switching-off, Size S00...S3, 330 mm shaft with support	574,--	1	1 unit	41E

Forbindelsesmoduler til 3RV2 håndbetjente motorværn

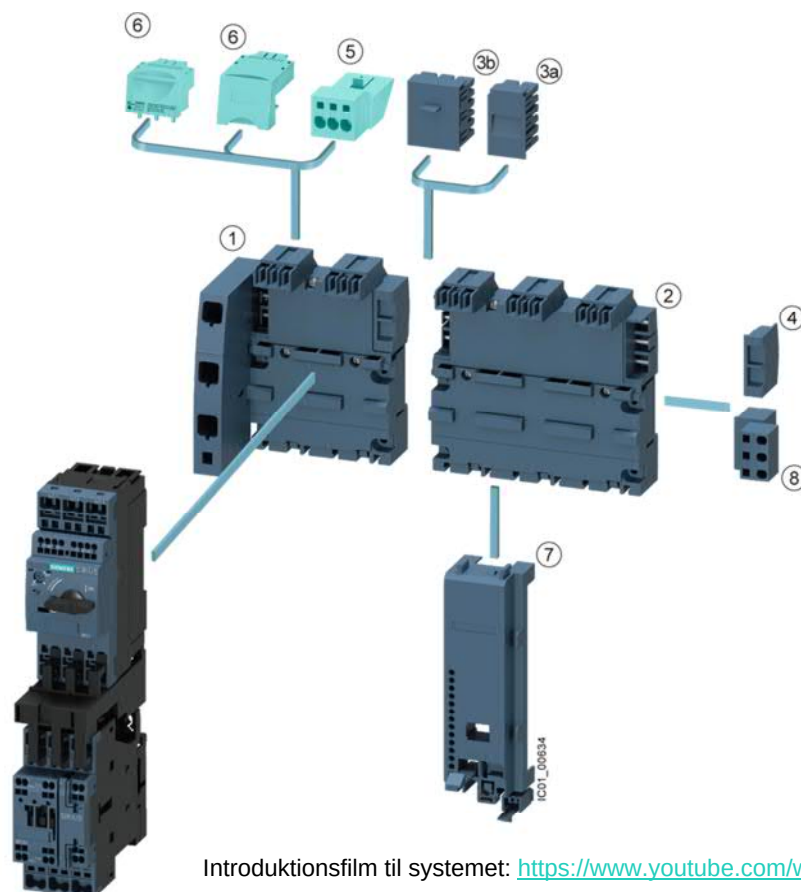
Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3RA1921-1DA00 Link module, electrical and mechanical, for 3RV2.1/3RV2.2 (S00 & S0) and 3RT2.1 (S00) AC and DC operation , (individual unit packaging), for screw terminals	61,30	1	1 unit	41B
	3RA2921-1BA00 Link module, for screw terminal , electrical and mechanical, for 3RV2.1/3RV2.2 (S00 & S0) and 3RT2.2 (S0) DC operation or soft starter 3RW3 or sold-state contactor 3RF34	64,90	1	1 unit	41B
	3RA2921-1AA00 Link module, for screw terminal , electrical and mechanical, for 3RV2.1/3RV2.2 (S00 & S0) , and 3RT2.2. (S0) AC operation	64,90	1	1 unit	41B
	3RA2931-1AA00 Link module, electrical and mechanical, for 3RV2.3 (S2) and 3RT2.3. (S2) or soft starter 3RW303/3RW403 , (individual unit packaging), for screw terminals	151,--	1	1 unit	41B
	3RA2911-2AA00 Link module, Electrical and mechanical, for 3RV2011 (S00) and 3RT201. (S00) Spring-type terminal	61,30	1	1 unit	41B
	3RA2921-2AA00 Link module, spring-type terminal , electrical and mechanical, for 3RV2.21 (S0) and 3RT2.2. (S0)	64,90	1	1 unit	41B
	3RA2911-2GA00 Link module, Electrical and mechanical, for 3RV2011 (S00) and 3RW3.1 Spring-type terminal	145,--	1	1 unit	41B
	3RA2921-2GA00 Link module, electrical and mechanical, for 3RV2021 (S0) and 3RW3.2, 3RW402, Spring-type terminal	153,--	1	1 unit	41B

3RV29 Infeed system

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3RV2917-1A Startmodul med forsyning i venstre side, for 2 circuit breakers Size S00 and S0, mærkestrøm 63A, figure 1	205,--	1	1 unit	41E
	3RV2917-1E Startmodul med forsyning i højre side, for 2 circuit breakers Size S00 and S0, mærkestrøm 63A, figure 1	205,--	1	1 unit	41E
	3RV2917-4A Udvidelsesmodul, for 2 circuit breakers Size S00 and S0, incl. connector, figure 2	125,--	1	1 unit	41E
	3RV2917-4B Udvidelsesmodul for 3 circuit breakers Size S00 and S0, incl. connector, figure 2	165,--	1	1 unit	41E
	3RV2917-5AA00 Forbindelsesblok, size S00, spring-type terminal, figure 6	35,80	1	1 unit	41E
	3RV2927-5AA00 Forbindelsesblok, size S0, spring-type terminal, figure 6	35,80	1	1 unit	41E
	3RV2917-5CA00 Forbindelsesblok, size S00, screw terminal, figure 6	35,80	1	1 unit	41E
	3RV1927-5AA00 Forbindelsesblok, Size S0, screw terminal, figure 6	35,80	1	1 unit	41E

3RV29 Infeed system

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3RV2917-5D Terminal block, 6 mm ² for current outfeed and also for connection of 3-phase busbars, figure 8	146,--	1	1 unit	41E
	3RV2917-5FA00 Terminal block, Device for infeed, figure 5	80,--	1	1 unit	41E
	3RV2917-7AA00 Contactor base, for contactor size S00, with screw/spring-type terminal, figure 7	30,30	1	1 unit	41E
	3RV2927-7AA00 Contactor base size S00/S0, with screw/spring-type terminal, figure 7	28,20	1	1 unit	41E



Introduktionsfilm til systemet: <https://www.youtube.com/watch?v=rkfKjchBPfA>

Kontaktorer - 230V AC styrespænding - Skrueterminaler

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3RT2015-1AP01 Kontaktor, AC-3 7 A, 3 kW/ 400 V, 1 NO, 230 V AC, 50 / 60Hz 3-pole, Size S00, screw terminal	287,--	1	1 unit	41B
	3RT2015-1AP02 Kontaktor, AC-3 7 A, 3 kW/ 400 V, 1 NC, 230 V AC, 50 / 60Hz 3-pole, Size S00, screw terminal	287,--	1	1 unit	41B
	3RT2016-1AP01 Kontaktor, AC-3 9 A, 4 kW/ 400 V, 1 NO, 230 V AC, 50 / 60Hz 3-pole, Size S00, screw terminal	308,--	1	1 unit	41B
	3RT2016-1AP02 Kontaktor, AC-3 9 A, 4 kW/ 400 V, 1 NC, 230 V AC, 50 / 60Hz 3-pole, Size S00, screw terminal	308,--	1	1 unit	41B
	3RT2017-1AP01 Kontaktor, AC-3 12 A, 5.5kW / 400 V, 1 NO, 230 V AC, 50 /60 Hz 3-pole, Size S00, screw terminal	379,--	1	1 unit	41B
	3RT2017-1AP02 Kontaktor, AC-3 12 A, 5.5kW / 400 V, 1 NC, 230 V AC, 50 /60 Hz 3-pole, Size S00, screw terminal	379,--	1	1 unit	41B
	3RT2018-1AP01 Kontaktor, AC-3 16 A, 7.5kW / 400 V, 1 NO, 230 V AC,50/60 Hz 3-pole, Size S00, screw terminal	482,--	1	1 unit	41B
	3RT2018-1AP02 Kontaktor, AC-3 16 A, 7.5kW / 400 V, 1 NC, 230 V AC,50/60 Hz 3-pole, Size S00, screw terminal	482,--	1	1 unit	41B

Kontaktorer - 230V AC styrespænding - Skrueterminaler

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3RT2023-1AP00 Kontaktor, AC-3 9 A, 4 kW/ 400 V, 1 NO + 1 NC, 230 V AC,50 Hz 3-pole, Size S0, screw terminal	339,--	1	1 unit	41B
	3RT2024-1AP00 Kontaktor, AC-3 12 A, 5.5kW / 400 V, 1 NO + 1 NC, 230 VAC, 50 Hz 3-pole, Size S0, screw terminal	401,--	1	1 unit	41B
	3RT2025-1AP00 Kontaktor, AC-3 17 A, 7.5kW / 400 V, 1 NO + 1 NC, 230 VAC, 50 Hz, 3-pole, Size S0, screw terminal	532,--	1	1 unit	41B
	3RT2026-1AP00 Kontaktor, AC-3 25 A, 11kW / 400 V, 1 NO + 1 NC, 230 VAC, 50 Hz, 3-pole, Size S0, screw terminal	707,--	1	1 unit	41B
	3RT2027-1AP00 Kontaktor, AC-3 32 A, 15kW / 400 V, 1 NO + 1 NC, 230 VAC, 50 Hz 3-pole, size S0, screw terminal	1030,--	1	1 unit	41B
	3RT2028-1AP00 Kontaktor, AC-3 38 A,18.5 kW / 400 V, 1 NO + 1 NC,230 V AC 50 Hz, 3-pole, size S0, screw terminal	1150,--	1	1 unit	41B
	3RT2035-1AP00 Kontaktor, AC-3 40 A,18.5 kW / 400 V, 1 NO + 1 NC,230 V AC 50 Hz, 3-pole, Size S2, screw terminal	1200,--	1	1 unit	41B
	3RT2036-1AP00 Kontaktor, AC-3 50 A, 22kW / 400 V, 1 NO + 1 NC, 230 VAC, 50 Hz, 3-pole, Size S2, screw terminal	1530,--	1	1 unit	41B

Kontaktorer - 230V AC styrespænding - Skrueterminaler

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3RT2037-1AP00 Kontaktor, AC-3 65 A, 30kW / 400 V, 1 NO + 1 NC, 230 VAC, 50 Hz 3-pole, size S2, screw terminal	2150,--	1	1 unit	41B
	3RT2038-1AP00 Kontaktor, AC-3 80 A, 37kW / 400 V, 1 NO + 1 NC, 230 VAC, 50 Hz 3-pole, size S2, screw terminal	2400,--	1	1 unit	41B
	3RT2045-1AP00 Kontaktor, AC-3 80 A, 37kW / 400 V, 1 NO + 1 NC, 230 VAC/50 Hz 3-pole, 3 NO, Size S3, screw terminal	2590,--	1	1 unit	41B
	3RT2046-1AP00 Kontaktor, AC-3 95 A, 45kW / 400 V, 1 NO + 1 NC, 230 VAC, 50 Hz 3-pole, 3 NO, Size S3, screw terminal	3250,--	1	1 unit	41B
	3RT2047-1AP00 Kontaktor, AC-3 115 A, 55kW / 400 V, 1 NO + 1 NC, 230 VAC, 50 Hz 3-pole, 3 NO, Size S3, screw terminal	3760,--	1	1 unit	41B

Kontaktorer - 230V AC styrespænding - Fjederterminaler

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3RT2015-2AP01 Kontaktor, AC-3 7 A, 3 kW/ 400 V, 1 NO, 230 V AC, 50 / 60Hz 3-pole, Size S00, Spring-type terminal	287,--	1	1 unit	41B
	3RT2015-2AP02 Kontaktor, AC-3 7 A, 3 kW/ 400 V, 1 NC, 220 V AC, 50 / 60Hz 3-pole, Size S00, Spring-type terminal	287,--	1	1 unit	41B
	3RT2016-2AP01 Kontaktor, AC-3 9 A, 4 kW/ 400 V, 1 NO, 230 V AC, 50 / 60Hz, 3-pole, Size S00, Spring-type terminal	308,--	1	1 unit	41B
	3RT2016-2AP02 Kontaktor, AC-3 9 A, 4 kW/ 400 V, 1 NC, 230 V AC, 50 / 60Hz 3-pole, Size S00, Spring-type terminal	308,--	1	1 unit	41B
	3RT2017-2AP01 Kontaktor, AC-3 12 A, 5.5kW / 400 V, 1 NO, 230 V AC, 50 /60 Hz 3-pole, Size S00, Spring-type terminal	379,--	1	1 unit	41B
	3RT2017-2AP02 Kontaktor, AC-3 12 A, 5.5kW / 400 V, 1 NC, 230 V AC, 50 /60 Hz 3-pole, Size S00, Spring-type terminal	379,--	1	1 unit	41B
	3RT2018-2AP01 Kontaktor, AC-3 16 A, 7.5kW / 400 V, 1 NO, 230 V AC, 50 /60 Hz 3-pole, Size S00, Spring-type terminal	482,--	1	1 unit	41B
	3RT2018-2AP02 Kontaktor, AC-3 16 A, 7.5kW / 400 V, 1 NC, 230 V AC,50/60 Hz 3-pole, Size S00, Spring-type terminal	482,--	1	1 unit	41B

Kontaktorer - 230V AC styrespænding - Fjederterminaler

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3RT2023-2AP00 Kontaktor, AC-3 9 A, 4 kW/ 400 V, 1 NO + 1 NC, 230 V AC,50 Hz 3-pole, Size S0, Spring-type terminal	339,--	1	1 unit	41B
	3RT2024-2AP00 Kontaktor, AC-3 12 A, 5.5kW / 400 V, 1 NO + 1 NC, 230 VAC, 50 Hz 3-pole, Size S0, Spring-type terminal	401,--	1	1 unit	41B
	3RT2025-2AP00 Kontaktor, AC-3 17 A, 7.5kW / 400 V, 1 NO + 1 NC, 230 VAC, 50 Hz, 3-pole, Size S0, Spring-type terminal	532,--	1	1 unit	41B
	3RT2026-2AP00 Kontaktor, AC-3 25 A, 11kW / 400 V, 1 NO + 1 NC, 230 VAC, 50 Hz 3-pole, Size S0, Spring-type terminal	707,--	1	1 unit	41B
	3RT2027-2AP00 Kontaktor, AC-3 32 A, 15kW / 400 V, 1 NO + 1 NC, 230 VAC, 50 Hz 3-pole, Size S0, Spring-type terminal	1030,--	1	1 unit	41B
	3RT2028-2AP00 Kontaktor, AC-3 38 A,18.5 kW / 400 V, 1 NO + 1 NC,230 V AC 50 Hz, 3-pole, Size S0, Spring-type terminal	1150,--	1	1 unit	41B

Kontaktorer - 24V AC styrespænding - Skrueterminaler

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3RT2015-1AB01 Kontaktor, AC-3 7 A, 3 kW/ 400 V, 1 NO, 24 V AC, 50 / 60Hz 3-pole, Size S00, screw terminal	287,--	1	1 unit	41B
	3RT2015-1AB02 Kontaktor, AC-3 7 A, 3 kW/ 400 V, 1 NC, 24 V AC, 50 / 60Hz 3-pole, Size S00, screw terminal	287,--	1	1 unit	41B
	3RT2016-1AB01 Kontaktor, AC-3 9 A, 4 kW/ 400 V, 1 NO, 24 V AC, 50 / 60Hz 3-pole, Size S00, screw,terminal	308,--	1	1 unit	41B
	3RT2016-1AB02 Kontaktor, AC-3 9 A, 4 kW/ 400 V, 1 NC, 24 V AC, 50 / 60Hz 3-pole, Size S00, screw terminal	308,--	1	1 unit	41B
	3RT2017-1AB01 Kontaktor, AC-3 12 A, 5.5kW / 400 V, 1 NO, 24 V AC, 50 /60 Hz 3-pole, Size S00, screw terminal	379,--	1	1 unit	41B
	3RT2017-1AB02 Kontaktor, AC-3 12 A, 5.5kW / 400 V, 1 NC, 24 V AC, 50 /60 Hz 3-pole, Size S00, screw terminal	379,--	1	1 unit	41B
	3RT2018-1AB01 Kontaktor, AC-3 16 A, 7.5kW / 400 V, 1 NO, 24 V AC, 50/60Hz 3-pole, Size S00, screw terminal	482,--	1	1 unit	41B
	3RT2018-1AB02 Kontaktor, AC-3 16 A, 7.5kW / 400 V, 1 NC, 24 V AC, 50/60Hz 3-pole, Size S00, screw terminal	482,--	1	1 unit	41B

Kontaktorer - 24V AC styrespænding - Skrueterminaler

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3RT2023-1AB00 Kontaktor, AC-3 9 A, 4 kW/ 400 V, 1 NO + 1 NC, 24 V AC,50 Hz 3-pole, Size S0, screw terminal	339,--	1	1 unit	41B
	3RT2024-1AB00 Kontaktor, AC-3 12 A, 5.5kW / 400 V, 1 NO + 1 NC, 24 VAC, 50 Hz 3-pole, Size S0, screw terminal	401,--	1	1 unit	41B
	3RT2025-1AB00 Kontaktor, AC-3 17 A, 7.5kW / 400 V, 1 NO + 1 NC, 24 VAC, 50 Hz, 3-pole, Size S0, screw terminal	532,--	1	1 unit	41B
	3RT2026-1AB00 Kontaktor, AC-3 25 A, 11kW / 400 V, 1 NO + 1 NC, 24 VAC, 50 Hz, 3-pole, Size S0, screw terminal	707,--	1	1 unit	41B
	3RT2027-1AB00 Kontaktor, AC-3 32 A, 11kW / 400 V, 1 NO + 1 NC, 24 VAC, 50 Hz 3-pole, size S0, screw terminal	1030,--	1	1 unit	41B
	3RT2028-1AB00 Kontaktor, AC-3 38 A,18.5 kW / 400 V, 1 NO + 1 NC, 24V AC 50 Hz, 3-pole, size S0, screw terminal	1150,--	1	1 unit	41B
	3RT2035-1AB00 Kontaktor, AC-3 40 A,18.5 kW / 400 V, 1 NO + 1 NC, 24V AC 50 Hz, 3-pole, Size S2, screw terminal	1200,--	1	1 unit	41B
	3RT2036-1AB00 Kontaktor, AC-3 50 A, 22kW / 400 V, 1 NO + 1 NC, 24 VAC, 50 Hz, 3-pole, Size S2, screw terminal	1530,--	1	1 unit	41B

Kontaktorer - 24V AC styrespænding - Skrueterminaler

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3RT2037-1AB00 Kontaktor, AC-3 65 A, 30kW / 400 V, 1 NO + 1 NC, 24 VAC, 50 Hz 3-pole, size S2, screw terminal	2150,--	1	1 unit	41B
	3RT2038-1AB00 Kontaktor, AC-3 80 A, 37kW / 400 V, 1 NO + 1 NC, 24 VAC, 50 Hz 3-pole, size S2, screw terminal	2400,--	1	1 unit	41B
	3RT2045-1AB00 Kontaktor, AC-3 80 A, 37kW / 400 V, 1 NO + 1 NC, 24 VAC, 50 Hz 3-pole, 3 NO, Size S3, screw terminal	2590,--	1	1 unit	41B
	3RT2046-1AB00 Kontaktor, AC-3 95 A, 45kW / 400 V, 1 NO + 1 NC, 24 VAC, 50 Hz 3-pole, 3 NO, Size S3, screw terminal	3250,--	1	1 unit	41B
	3RT2047-1AB00 Kontaktor, AC-3 115 A, 55kW / 400 V, 1 NO + 1 NC, 24 VAC, 50 Hz 3-pole, 3 NO, Size S3, screw terminal	3760,--	1	1 unit	41B

Kontaktorer - 24V AC styrespænding - Fjederterminaler

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3RT2015-2AB01 Kontaktor, AC-3 7 A, 3 kW/ 400 V, 1 NO, 24 V AC, 50 / 60Hz 3-pole, Size S00, Spring-type terminal	287,--	1	1 unit	41B
	3RT2015-2AB02 Kontaktor, AC-3 7 A, 3 kW/ 400 V, 1 NC, 24 V AC, 50 / 60Hz 3-pole, Size S00, Spring-type terminal	287,--	1	1 unit	41B
	3RT2016-2AB01 Kontaktor, AC-3 9 A, 4 kW/ 400 V, 1 NO, 24 V AC, 50 / 60Hz, 3-pole, Size S00, Spring-type terminal	308,--	1	1 unit	41B
	3RT2016-2AB02 Kontaktor, AC-3 9 A, 4 kW/ 400 V, 1 NC, 24 V AC, 50 / 60Hz 3-pole, Size S00, Spring-type terminal	308,--	1	1 unit	41B
	3RT2017-2AB01 Kontaktor, AC-3 12 A, 5.5kW / 400 V, 1 NO, 24 V AC, 50 /60 Hz 3-pole, Size S00, Spring-type terminal	379,--	1	1 unit	41B
	3RT2017-2AB02 Kontaktor, AC-3 12 A, 5.5kW / 400 V, 1 NC, 24 V AC, 50 /60 Hz 3-pole, Size S00, Spring-type terminal	379,--	1	1 unit	41B
	3RT2018-2AB01 Kontaktor, AC-3 16 A, 7.5kW / 400 V, 1 NO, 24 V AC, 50/60Hz 3-pole, Size S00, Spring-type terminal	482,--	1	1 unit	41B
	3RT2018-2AB02 Kontaktor, AC-3 16 A, 7.5kW / 400 V 1 NC, 24 V AC, 50/60Hz 3-pole, Size S00, Spring-type terminal	482,--	1	1 unit	41B

Kontaktorer - 24V AC styrespænding - Fjederterminaler

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3RT2023-2AB00 Kontaktor, AC-3 9 A, 4 kW/ 400 V, 1 NO + 1 NC, 24 V AC,50 Hz 3-pole, Size S0, Spring-type terminal	339,--	1	1 unit	41B
	3RT2024-2AB00 Kontaktor, AC-3 12 A, 5.5kW / 400 V, 1 NO + 1 NC, 24 VAC, 50 Hz 3-pole, Size S0, Spring-type terminal	401,--	1	1 unit	41B
	3RT2025-2AB00 Kontaktor, AC-3 17 A, 7.5kW / 400 V, 1 NO + 1 NC, 24 VAC, 50 Hz, 3-pole, Size S0, Spring-type terminal	532,--	1	1 unit	41B
	3RT2026-2AB00 Kontaktor, AC-3 25 A, 11kW / 400 V, 1 NO + 1 NC, 24 VAC, 50 Hz 3-pole, Size S0, Spring-type terminal	707,--	1	1 unit	41B
	3RT2027-2AB00 Kontaktor, AC-3 32 A, 15kW / 400 V, 1 NO + 1 NC, 24 VAC, 50 Hz 3-pole, size S0, Spring-type terminal	1030,--	1	1 unit	41B
	3RT2028-2AB00 Kontaktor, AC-3 38 A,18.5 kW / 400 V, 1 NO + 1 NC, 24V AC 50 Hz, 3-pole, size S0, Spring-type terminal	1150,--	1	1 unit	41B

Kontaktorer - 24V DC styrespænding - Skrueterminaler

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3RT2015-1BB41 Kontaktor, AC-3 7 A, 3 kW/ 400 V, 1 NO, 24 V DC, 3-pole, Size S00 screw terminal	337,--	1	1 unit	41B
	3RT2015-1BB42 Kontaktor, AC-3 7 A, 3 kW/ 400 V, 1 NC, 24 V DC, 3-pole, Size S00 screw terminal	337,--	1	1 unit	41B
	3RT2016-1BB41 Kontaktor, AC-3 9 A, 4 kW/ 400 V, 1 NO, 24 V DC, 3-pole, Size S00 screw terminal	360,--	1	1 unit	41B
	3RT2016-1BB42 Kontaktor, AC-3 9 A, 4 kW/ 400 V, 1 NC, 24 V DC, 3-pole, Size S00 screw terminal	360,--	1	1 unit	41B
	3RT2017-1BB41 Kontaktor, AC-3 12 A, 5.5kW / 400 V, 1 NO, 24 V DC, 3-pole, Size S00 screw terminal	437,--	1	1 unit	41B
	3RT2017-1BB42 Kontaktor, AC-3 12 A, 5.5kW / 400 V, 1 NC, 24 V DC, 3-pole, Size S00 screw terminal	437,--	1	1 unit	41B
	3RT2018-1BB41 Kontaktor, AC-3 16 A, 7.5kW / 400 V, 1 NO, 24 V DC, 3-pole, Size S00 screw terminal	774,--	1	1 unit	41B
	3RT2018-1BB42 Kontaktor, AC-3 16 A, 7.5kW / 400 V, 1 NC, 24 V DC, 3-pole, Size S00 screw terminal	774,--	1	1 unit	41B

Kontaktorer - 24V DC styrespænding - Skrueterminaler

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3RT2023-1BB40 Kontaktor, AC-3 9 A, 4 kW/ 400 V, 1 NO + 1 NC, 24 V DC, 3-pole, Size S0, screw terminal	727,--	1	1 unit	41B
	3RT2024-1BB40 Kontaktor, AC-3 12 A, 5.5kW / 400 V, 1 NO + 1 NC, 24 V DC, 3-pole, Size S0, screw terminal	787,--	1	1 unit	41B
	3RT2025-1BB40 Kontaktor, AC-3 17 A, 7.5kW / 400 V, 1 NO + 1 NC, 24 V DC, 3-pole, Size S0, screw terminal	954,--	1	1 unit	41B
	3RT2026-1BB40 Kontaktor, AC-3 25 A, 11kW / 400 V, 1 NO + 1 NC, 24 V DC, 3-pole, Size S0, screw terminal	1130,--	1	1 unit	41B
	3RT2027-1BB40 Kontaktor, AC-3 32 A, 15kW / 400 V, 1 NO + 1 NC, 24 V DC, 3-pole, size S0, screw terminal	1540,--	1	1 unit	41B
	3RT2028-1BB40 Kontaktor, AC-3 38 A, 18.5 kW / 400 V, 1 NO + 1 NC, 24V DC, 3-pole, size S0, screw terminal	1680,--	1	1 unit	41B
	3RT2035-1KB40 Kontaktor, AC-3 40 A, 18.5 kW / 400 V, 1 NO + 1 NC, 24V DC with varistor, 3-pole, Size S2, screw terminal, suitable for 2 A PLC outputs	1840,--	1	1 unit	41B
	3RT2036-1KB40 Kontaktor, AC-3 50 A, 22kW / 400 V, 1 NO + 1 NC, 24 V DC with varistor, 3-pole, Size S2, screw terminal, suitable for 2 A PLC outputs	2380,--	1	1 unit	41B

Kontaktorer - 24V DC styrespænding - Skrueterminaler

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3RT2037-1KB40 Kontaktor, AC-3 65 A, 30kW / 400 V, 1 NO + 1 NC, 24 V DC with varistor, 3-pole, Size S2, screw terminal, suitable for 2 A PLC outputs	3250,--	1	1 unit	41B
	3RT2038-1KB40 Kontaktor, AC-3 80 A, 37kW / 400 V, 1 NO + 1 NC, 24 V DC with varistor, 3-pole, Size S2, screw terminal, suitable for 2 A PLC outputs	3430,--	1	1 unit	41B
	3RT2045-1KB40 Kontaktor, AC-3 80 A, 37kW / 400 V, 1 NO + 1 NC, 24 V DC, 3-pole, 3 NO, Size S3, screw terminal, integrated varistor, suitable for 2 A PLC outputs	3620,--	1	1 unit	41B
	3RT2046-1KB40 Kontaktor, AC-3 95 A, 45kW / 400 V, 1 NO + 1 NC, 24 V DC, 3-pole, 3 NO, Size S3, screw terminal, integrated varistor, suitable for 2 A PLC outputs	4220,--	1	1 unit	41B

Kontaktorer - 24V DC styrespænding - Fjederterminaler

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3RT2015-2BB41 Kontaktor, AC-3 7 A, 3 kW/ 400 V, 1 NO, 24 V DC 3-pole, Size S00 Spring-type terminal	337,--	1	1 unit	41B
	3RT2015-2BB42 Kontaktor, AC-3 7 A, 3 kW/ 400 V, 1 NC, 24 V DC 3-pole, Size S00 Spring-type terminal	337,--	1	1 unit	41B
	3RT2016-2BB41 Kontaktor, AC-3 9 A, 4 kW/ 400 V, 1 NO, 24 V DC 3-pole, Size S00 Spring-type terminal	360,--	1	1 unit	41B
	3RT2016-2BB42 Kontaktor, AC-3 9 A, 4 kW/ 400 V, 1 NC, 24 V DC 3-pole, Size S00 Spring-type terminal	360,--	1	1 unit	41B
	3RT2017-2BB41 Kontaktor, AC-3 12 A, 5.5kW / 400 V, 1 NO, 24 V DC3-pole, Size S00 Spring-type terminal	437,--	1	1 unit	41B
	3RT2017-2BB42 Kontaktor, AC-3 12 A, 5.5kW / 400 V, 1 NC, 24 V DC3-pole, Size S00 Spring-type terminal	437,--	1	1 unit	41B
	3RT2018-2BB41 Kontaktor, AC-3 16 A, 7.5kW / 400 V, 1 NO, 24 V DC3-pole, Size S00 Spring-type terminal	774,--	1	1 unit	41B
	3RT2018-2BB42 Kontaktor, AC-3 16 A, 7.5kW / 400 V, 1 NC, 24 V DC3-pole, Size S00 Spring-type terminal	774,--	1	1 unit	41B

Kontaktorer - 24V DC styrespænding - Fjederterminaler

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3RT2023-2BB40 Kontaktor, AC-3 9 A, 4 kW/ 400 V, 1 NO + 1 NC, 24 V DC3-pole, Size S0, Spring-type terminal	727,--	1	1 unit	41B
	3RT2024-2BB40 Kontaktor, AC-3 12 A, 5.5kW / 400 V, 1 NO + 1 NC, 24 V DC3-pole, Size S0, Spring-type terminal	787,--	1	1 unit	41B
	3RT2025-2BB40 Kontaktor, AC-3 17 A, 7.5kW / 400 V, 1 NO + 1 NC, 24 V DC3-pole, Size S0, Spring-type terminal	954,--	1	1 unit	41B
	3RT2026-2BB40 Kontaktor, AC-3 25 A, 11kW / 400 V, 1 NO + 1 NC, 24 V DC3-pole, Size S0, Spring-type terminal	1130,--	1	1 unit	41B
	3RT2027-2BB40 Kontaktor, AC-3 32 A, 15kW / 400 V, 1 NO + 1 NC, 24 V DC3-pole, Size S0, Spring-type terminal	1540,--	1	1 unit	41B
	3RT2028-2BB40 Kontaktor, AC-3 38 A, 18.5 kW / 400 V, 1 NO + 1 NC, 24V DC 3-pole, Size S0, Spring-type terminal	1680,--	1	1 unit	41B

Frontmonteret hjælpekontakter til 3RT kontakter

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3RH2911-1HA11 Auxiliary switch on the front, 1 NO + 1 NC, 3RH and 3RT, screw terminal	81,60	1	1 unit	41B
	3RH2911-1HA20 Auxiliary switch on the front, 2 NO, for 3RH and 3RT, screw terminal	81,60	1	1 unit	41B
	3RH2911-1HA02 Auxiliary switch on the front, 2 NC, for 3RH and 3RT, screw terminal	81,60	1	1 unit	41B
	3RH2911-1HA12 Auxiliary switch on the front, 1 NO + 2 NC, for 3RH and 3RT, screw terminal	111,--	1	1 unit	41B
	3RH2911-1HA21 Auxiliary switch on the front, 2 NO + 1 NC, for 3RH and 3RT, screw terminal	111,--	1	1 unit	41B
	3RH2911-1HA03 Auxiliary switch on the front, 3 NC, for 3RH and 3RT, screw terminal	111,--	1	1 unit	41B
	3RH2911-1HA30 Auxiliary switch on the front, 3 NO, for 3RH and 3RT, screw terminal	111,--	1	1 unit	41B
	3RH2911-1HA22 Auxiliary switch on the front, 2 NO + 2 NC, for 3RH and 3RT, screw terminal	137,--	1	1 unit	41B

Frontmonteret hjælpekontakter til 3RT kontakter

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3RH2911-1HA31 Auxiliary switch on the front, 3 NO + 1 NC, for 3RH and 3RT, screw terminal	137,--	1	1 unit	41B
	3RH2911-1FA40 Auxiliary switch on the front, 4 NO, for 3RH and 3RT, screw terminal	137,--	1	1 unit	41B
	3RH2911-2HA11 Auxiliary switch on the front, 1 NO + 1 NC, for 3RH and 3RT, spring-type terminal	81,60	1	1 unit	41B
	3RH2911-2HA20 Auxiliary switch on the front, 2 NO, for 3RH and 3RT, spring-type terminal	81,60	1	1 unit	41B
	3RH2911-2HA02 Auxiliary switch on the front, 2 NC, for 3RH and 3RT, spring-type terminal	81,60	1	1 unit	41B
	3RH2911-2HA12 Auxiliary switch on the front, 1 NO + 2 NC, for 3RH and 3RT, spring-type terminal	111,--	1	1 unit	41B
	3RH2911-2HA21 Auxiliary switch on the front, 2 NO + 1 NC, for 3RH and 3RT, spring-type terminal	111,--	1	1 unit	41B
	3RH2911-2HA30 Auxiliary switch on the front, 3 NO, for 3RH and 3RT, spring-type terminal	111,--	1	1 unit	41B

Frontmonteret hjælpekontakter til 3RT kontakter

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3RH2911-2HA03 Auxiliary switch on the front, 3 NC, for 3RH and 3RT, spring-type terminal	111,--	1	1 unit	41B
	3RH2911-2HA22 Auxiliary switch on the front, 2 NO + 2 NC, for 3RH and 3RT, spring-type terminal	137,--	1	1 unit	41B
	3RH2911-2HA31 Auxiliary switch on the front, 3 NO + 1 NC, for 3RH and 3RT, spring-type terminal	137,--	1	1 unit	41B
	3RH2911-2FA40 Auxiliary switch on the front, 4 NO, for 3RH and 3RT, spring-type terminal	137,--	1	1 unit	41B

Sidemonteret hjælpekontakter til 3RT kontakter

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3RH2911-1DA02 Auxiliary switch lateral, 2 NC, for 3RH and 3RT, screw terminal, for Size S00	123,--	1	1 unit	41B
	3RH2911-1DA11 Auxiliary switch lateral, 1 NO+ 1 NC, for 3RH and 3RT, screw terminal, for Size S00	123,--	1	1 unit	41B
	3RH2911-1DA20 Auxiliary switch lateral, 2 NO, for 3RH and 3RT, screw terminal, for Size S00	123,--	1	1 unit	41B
	3RH2911-2DA02 Auxiliary switch lateral, 2 NC, for 3RH and 3RT, spring-type terminal, for Size S00	123,--	1	1 unit	41B
	3RH2911-2DA11 Auxiliary switch lateral, 1 NO+ 1 NC, for 3RH and 3RT, spring-type terminal, for Size S00	123,--	1	1 unit	41B
	3RH2911-2DA20 Auxiliary switch lateral, 2 NO, for 3RH and 3RT, spring-type terminal, for Size S00	123,--	1	1 unit	41B
	3RH2921-1DA02 Auxiliary switch lateral, 2 NC, for 3RH and 3RT, screw terminal, for Size S0-3	123,--	1	1 unit	41B

Sidemonteret hjælpekontakter til 3RT kontakter



Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3RH2921-1DA11 Auxiliary switch lateral, 1 NO+ 1 NC, for 3RH and 3RT screw terminal, for Size S0-3	123,--	1	1 unit	41B
	3RH2921-1DA20 Auxiliary switch lateral, 2 NO, for 3RH and 3RT, screw terminal, for Size S0-3	123,--	1	1 unit	41B
	3RH2921-2DA02 Auxiliary switch lateral, 2 NC, for 3RH and 3RT, spring-type terminal, for Size S0-3	123,--	1	1 unit	41B
	3RH2921-2DA11 Auxiliary switch lateral, 1 NO+ 1 NC, for 3RH and 3RT, spring-type terminal, for Size S0-3	123,--	1	1 unit	41B
	3RH2921-2DA20 Auxiliary switch lateral, 2 NO, for 3RH and 3RT, spring-type terminal, for Size S0-3	123,--	1	1 unit	41B

RC-led & varistorer til 3RT kontakter

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3RT2916-1BB00 Surge suppressor, varistor, 24... 48 V AC, 24 ... 70 V DC, for contactor relays and motor contactors Size S00	81,60	1	1 unit	41B
	3RT2916-1CB00 Surge suppressor, RC element, 24 ... 48 V AC, 24 ... 70 V DC, for contactor relays and motor contactors Size S00	81,60	1	1 unit	41B
	3RT2916-1CD00 Surge suppressor, RC element, 127 ... 240 V AC, 150 ... 250 VDC, for contactor relays and motor contactors Size S00	81,60	1	1 unit	41B
	3RT2926-1BB00 Surge suppressor, varistor, 24... 48 V AC, 24 ... 70 V DC, for motor contactors Size S0	100,--	1	1 unit	41B
	3RT2926-1CB00 Surge suppressor, RC element, 24 ... 48 V AC, 24 ... 70 V DC, for motor contactors Size S0	126,--	1	1 unit	41B
	3RT2926-1CD00 Surge suppressor, RC element, 127...240 V AC, 150 ... 250 VDC, for motor contactors Size S0	126,--	1	1 unit	41B
	3RT2936-1CB00 Surge suppressor, RC element, 24 ... 48 V AC, 24 ... 70 V DC, for contactors Size S2	129,--	1	1 unit	41B
	3RT2936-1CD00 Surge suppressor, RC element, 127 ... 240 V AC 150 ... 250 VDC for contactors Size S2	140,--	1	1 unit	41B

RC-led & varistorer til 3RT kontakter



Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3RT2946-1CB00 RC element, 24-48 V AC, 24-70 VDC Surge suppressor, for attaching on contactors Size S2 & S3	126,--	1	1 unit	41B
	3RT2946-1CD00 RC element, 127...240 V AC Surge suppressor for attaching on contactors Size S2 & S3	136,--	1	1 unit	41B

Forbindelsesmoduler til 3RT kontakter

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3RA2913-2AA1 Wiring kit for screw terminal , Electrical and mechanical, Including mechanical interlocking for reversing starter , Size S00	129,--	1	1 unit	41B
	3RA2913-2AA2 Wiring kit spring-type terminal , Electrical and mechanical, Including mechanical interlocking for reversing starter , Size S00	129,--	1	1 unit	41B
	3RA2916-1A Safety main power connector for series connection of 2 contactors 3RT201, Size S00, screw terminal	130,--	1	1 unit	41B
	3RA2923-2AA1 Wiring kit for screw terminal , Electrical and mechanical, Including mechanical interlocking for reversing starter , Size S0	195,--	1	1 unit	41B
	3RA2923-2AA2 Wiring kit spring-type terminal , Electrical and mechanical, Including mechanical interlocking for reversing starter , Size S0	195,--	1	1 unit	41B
	3RA2926-1A Safety main power connector for series connection of 2 contactors 3RT202. Size S0, screw terminal	130,--	1	1 unit	41B
	3RA2933-2AA1 Wiring kit for screw terminal , Electrical and mechanical, for reversing starter S2	212,--	1	1 unit	41B
	3RA2933-2AA2 Wiring kit spring-type terminal , Electrical and mechanical, for reversing starter S2	212,--	1	1 unit	41B

Forbindelsesmoduler til 3RT kontaktorer

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3RA2936-1A Safety main power connector for series connection of 2 contactors 3RT203. Size S2, screw terminal	172,--	1	1 unit	41B
	3RA2943-2AA1 Wiring kit screw terminal , Electrical and mechanical, for reversing starter size S3	463,--	1	1 unit	41B
	3RA2943-2AA2 Wiring kit spring-type terminal , Electrical and mechanical, for reversing starter size S3	463,--	1	1 unit	41B

Minikontakter - Til M36 afdækning

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3TG1001-0AC2 Minikontaktor, AC-3 8.4 A, 4 kW /400 V, 3 NO+1 NC, 24 V AC, 3-pole, screw terminal	244,--	1	1 unit	41H
	3TG1001-0BB4 Minikontaktor, AC-3 8.4 A, 4 kW /400 V, 3 NO+1 NC, 24 V DC, 3-pole, screw terminal	284,--	1	1 unit	41H
	3TG1001-0AL2 Minikontaktor, AC-3 8.4 A, 4 kW /400 V, 3 NO+1 NC, 230 V AC, 3-pole, screw terminal	244,--	1	1 unit	41H
	3TG1010-0AC2 Minikontaktor, AC-3 8.4 A, 4 kW /400 V, 4 NO, 24 V AC, 3-pole, screw terminal	244,--	1	1 unit	41H
	3TG1010-0BB4 Minikontaktor, AC-3 8.4 A, 4 kW /400 V, 4 NO, 24 V DC 3-pole, screw terminal	284,--	1	1 unit	41H
	3TG1010-0AL2 Minikontaktor, AC-3 8.4 A, 4 kW /400 V, 4 NO, 230 V AC, 3-pole, screw terminal	244,--	1	1 unit	41H

Komplette sokkelrelæer

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	LZS:PT2D5L24 Plug-in relay complete unit, 24 V DC, LED module red, Spring-type terminal (push-in) , 2 CO	211,--	1	5 units	41H
	LZS:PT2D5T30 Plug-in relay complete unit, 230 V AC, LED module red, Spring-type terminal (push-in) , 2 CO	244,--	1	5 units	41H
	LZS:PT5D5L24 Plug-in relay complete unit, 24 V DC, LED module red, Spring-type terminal (push-in) , 4 CO	184,--	1	5 units	41H
	LZS:PT5D5R24 Plug-in relay complete unit, 24 V AC, LED module red, Spring-type terminal (push-in) , 4 CO	184,--	1	5 units	41H
	LZS:PT5D5T30 Plug-in relay complete unit, 230 V AC, LED module red, Spring-type terminal (push-in) , 4 CO	196,--	1	5 units	41H
	LZS:PT3A5L24 Plug-in relay complete unit, 24 V DC, LED module red, Standard plug-in socket, screw terminal , 3 CO	175,--	1	5 units	41H
	LZS:PT3A5R24 Plug-in relay complete unit, 24 V AC, LED module red, Standard plug-in socket, screw terminal , 3 CO	175,--	1	5 units	41H
	LZS:PT3A5T30 Plug-in relay complete unit, 230 V AC, LED module red, Standard plug-in socket, screw terminal , 3 CO	187,--	1	5 units	41H

Komplette sokkelrelæer

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	LZS:PT5A5L24 Plug-in relay complete unit, 24 V DC, LED module red, Standard plug-in socket, screw terminal , 4 CO	175,--	1	5 units	41H
	LZS:PT5A5R24 Plug-in relay complete unit, 24 V AC, LED module red, Standard plug-in socket, screw terminal , 4 CO	175,--	1	5 units	41H
	LZS:PT5A5T30 Plug-in relay complete unit, 230 V AC, LED module red, Standard plug-in socket, screw terminal, 4 CO	187,--	1	5 units	41H

Solid-state relæer - Nulpunktskobling - 1-polet

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3RF2310-1AA04 Solid-state contactor, 1-phase, 3RF2 AC 51 / 10 A / 40 °C, 48-460 V, 24 V DC, screw terminal	613,--	1	1 unit	41C
	3RF2320-1AA04 Solid-state contactor, 1-phase, 3RF2 AC 51 / 20 A / 40 °C, 48-460 V, 24 V DC, screw terminal	645,--	1	1 unit	41C
	3RF2330-1AA04 Solid-state contactor, 1-phase, 3RF2 AC 51 / 30 A / 40 °C, 48-460 V, 24 V DC, screw terminal	695,--	1	1 unit	41C
	3RF2340-1AA04 Solid-state contactor, 1-phase, 3RF2 AC 51 / 40 A / 40 °C, 48-460 V, 24 V DC, screw terminal	806,--	1	1 unit	41C
	3RF2350-1AA04 Solid-state contactor, 1-phase, 3RF2 AC 51 / 50 A / 40 °C, 48-460 V, 24 V DC, screw terminal	866,--	1	1 unit	41C
	3RF2310-1AA24 Solid-state contactor, 1-phase, 3RF2 AC 51 / 10 A / 40 °C, 48-460 V, 110-230 V AC, screw terminal	656,--	1	1 unit	41C
	3RF2320-1AA24 Solid-state contactor, 1-phase, 3RF2 AC 51 / 20 A / 40 °C, 48-460 V, 110-230 V AC, screw terminal	690,--	1	1 unit	41C
	3RF2330-1AA24 Solid-state contactor, 1-phase, 3RF2 AC 51/ 30 A / 40 °C, 48-460V, 110-230 V AC, screw terminal	740,--	1	1 unit	41C

Solid-state relæer - Nulpunktskobling - 1-polet

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3RF2340-1AA24 Solid-state contactor, 1-phase, 3RF2 AC 51 / 40 A / 40 °C, 48-460 V, 110-230 V AC, screw terminal	856,--	1	1 unit	41C
	3RF2350-1AA24 Solid-state contactor, 1-phase, 3RF2 AC 51 / 50 A / 40 °C, 48-460 V, 110-230 V AC, screw terminal	909,--	1	1 unit	41C

Solid-state relæer - Nulpunktskobling - 3-polet / kobler 2 poler

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3RF2410-1AB45 Solid-state contactor, 3-phase, 3RF2 AC 51 / 10 A / 40 °C, 48-600 V, 4-30 V DC, 2-phase controlled, screw terminal	1360,--	1	1 unit	41C
	3RF2420-1AB45 Solid-state contactor, 3-phase, 3RF2 AC 51 / 20 A / 40 °C, 48-600 V, 4-30 V DC, 2-phase controlled, screw terminal	1520,--	1	1 unit	41C
	3RF2430-1AB45 Solid-state contactor, 3-phase, 3RF2 AC 51 / 30 A / 40 °C, 48-600 V, 4-30 V DC, 2-phase controlled, screw terminal	1640,--	1	1 unit	41C
	3RF2440-1AB45 Solid-state contactor, 3-phase, 3RF2 AC 51 / 40 A / 40 °C 48-600 V, 4-30 V DC, 2-phase controlled, screw terminal	1830,--	1	1 unit	41C
	3RF2450-1AB45 Solid-state contactor, 3-phase, 3RF2 AC 51 / 50 A / 40 °C, 48-600 V, 4-30 V DC, 2-phase controlled, screw terminal	2050,--	1	1 unit	41C
	3RF2410-1AB55 Solid-state contactor, 3-phase, 3RF2 AC 51 / 10 A / 40 °C, 48-600 V, 230 V AC, 2-phase controlled, screw terminal	1400,--	1	1 unit	41C
	3RF2420-1AB55 Solid-state contactor, 3-phase, 3RF2 AC 51 / 20 A / 40 °C, 48-600 V, 230 V AC, 2-phase controlled, screw terminal	1550,--	1	1 unit	41C
	3RF2430-1AB55 Solid-state contactor, 3-phase, 3RF2 AC 51 / 30 A / 40 °C, 48-600 V, 230 V AC, 2-phase controlled, screw terminal	1670,--	1	1 unit	41C

Solid-state relæer - Nulpunktskobling - 3-polet / kobler 2 poler

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3RF2440-1AB55 Solid-state contactor, 3-phase, 3RF2 AC 51 / 40 A / 40 °C, 48-600 V, 230 V AC, 2-phase controlled, screw terminal	1850,--	1	1 unit	41C
	3RF2450-1AB55 Solid-state contactor, 3-phase, 3RF2 AC 51 / 50 A / 40 °C, 48-600 V, 230 V AC, 2-phase controlled, screw terminal	2120,--	1	1 unit	41C

Solid-state relæer - Nulpunktskobling - 3-polet / kobler 3 poler

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3RF2410-1AC45 Solid-state contactor, 3-phase, 3RF2 AC 51 / 10 A / 40 °C, 48-600 V, 4-30 V DC, 3-phase controlled, screw terminal	1650,--	1	1 unit	41C
	3RF2420-1AC45 Solid-state contactor, 3-phase, 3RF2 AC 51 / 20 A / 40 °C, 48-600 V, 4-30 V DC, 3-phase controlled, screw terminal	1840,--	1	1 unit	41C
	3RF2430-1AC45 Solid-state contactor, 3-phase, 3RF2 AC 51 / 30 A / 40 °C, 48-600 V, 4-30 V DC, 3-phase controlled, screw terminal	2050,--	1	1 unit	41C
	3RF2440-1AC45 Solid-state contactor, 3-phase, 3RF2 AC 51 / 40 A / 40 °C, 48-600 V, 4-30 V DC, 3-phase controlled, screw terminal	2270,--	1	1 unit	41C
	3RF2450-1AC45 Solid-state contactor, 3-phase, 3RF2 AC 51 / 50 A / 40 °C, 48-600 V, 4-30 V DC, 3-phase controlled, screw terminal	2580,--	1	1 unit	41C
	3RF2410-1AC55 Solid-state contactor, 3-phase, 3RF2 AC 51 / 10 A / 40 °C, 48-600 V, 230 V AC, 3-phase controlled, screw terminal	1690,--	1	1 unit	41C
	3RF2420-1AC55 Solid-state contactor, 3-phase, 3RF2 AC 51 / 20 A / 40 °C, 48-600 V, 230 V AC, 3-phase controlled, screw terminal	1860,--	1	1 unit	41C
	3RF2430-1AC55 Solid-state contactor, 3-phase, 3RF2 AC 51 / 30 A / 40 °C, 48-600 V, 230 V AC, 3-phase controlled, screw terminal	2120,--	1	1 unit	41C

Solid-state relæer - Nulpunktskobling - 3-polet / kobler 3 poler

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3RF2440-1AC55 Solid-state contactor, 3-phase, 3RF2 AC 51 / 40 A / 40 °C, 48-600 V, 230 V AC, 3-phase controlled, screw terminal	2330,--	1	1 unit	41C
	3RF2450-1AC55 Solid-state contactor, 3-phase, 3RF2 AC 51 / 50 A / 40 °C, 48-600 V, 230 V AC, 3-phase controlled, screw terminal	2610,--	1	1 unit	41C

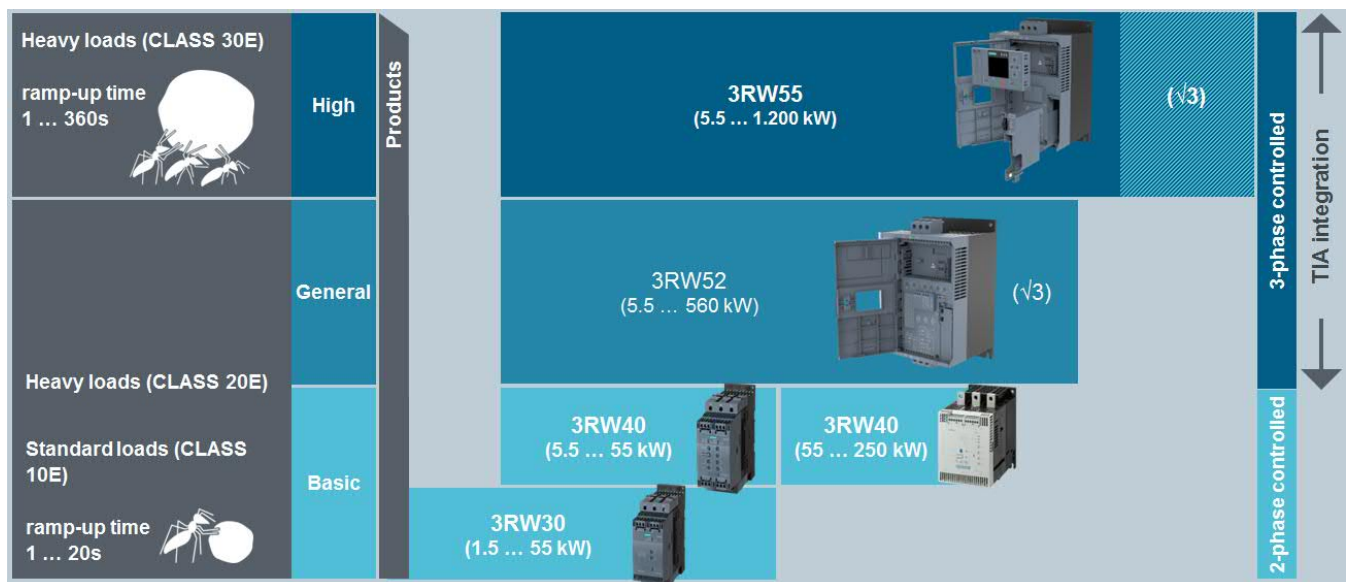
Softstartere – Oversigt

Dette minikatalog indeholder tre forskellige serier af softstartere.

- 3RW30 – Simple applikationer – 2-faset regulering
- 3RW40 – Standard applikationer – 2-faset regulering
- 3RW52 – Standard applikationer – 3-faset regulering

3RW55 serien er ved kataloget tilblivelse ikke frigivet til salg. Dette forventes at ske i 07/2018.

Nedenstående tegning giver et overblik over serierne.



Både 3RW52 og 3RW55 serien kan udstyres med kommunikationsmodul, der findes i flere forskellige protokoller. På 3RW52 serien kan der desuden tilføjes et HMI panel, som enten kan monteres i softstarteren eller i tavlefronten via et monteringskit.

Tilbehør findes i kataloget efter softstartererne.

Softstartere - Simple applikationer - Kun klasse 10 start - Skrueterminaler

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3RW3017-1BB14 SIRIUS soft starter S00, 12.5 A, 5.5 kW/400 V, 40 °C 200-480 VAC, 110-230 V AC/DC, Screw terminals	1600,--	1	1 unit	42G
	3RW3018-1BB14 SIRIUS soft starter S00, 17.6 A, 7.5 kW/400 V, 40 °C 200-480 VAC, 110-230 V AC/DC, Screw terminals	1830,--	1	1 unit	42G
	3RW3026-1BB14 SIRIUS soft starter S0, 25 A, 11kW/400 V, 40 °C 200-480 V AC,110-230 V AC/DC, Screw terminals	2140,--	1	1 unit	42G
	3RW3027-1BB14 SIRIUS soft starter S0, 32 A, 15kW/400 V, 40 °C 200-480 V AC,110-230 V AC/DC, Screw terminals	2480,--	1	1 unit	42G
	3RW3028-1BB14 SIRIUS soft starter S0, 38 A, 18.5 kW/400 V, 40 °C 200-480 VAC, 110-230 V AC/DC, Screw terminals	3070,--	1	1 unit	42G
	3RW3036-1BB14 SIRIUS soft starter S2, 45 A, 22kW/400 V, 40 °C 200-480 V AC,110-230 V AC/DC, Screw terminals	3780,--	1	1 unit	42G
	3RW3037-1BB14 SIRIUS soft starter S2, 63 A, 30kW/400 V, 40 °C 200-480 V AC,110-230 V AC/DC, Screw terminals	4600,--	1	1 unit	42G
	3RW3038-1BB14 SIRIUS soft starter S2, 72 A, 37kW/400 V, 40 °C 200-480 V AC,110-230 V AC/DC, Screw terminals	5440,--	1	1 unit	42G

Softstartere - Simple applikationer - Kun klasse 10 start - Fjederterminaler

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3RW3017-2BB14 SIRIUS soft starter S00, 12.5 A, 5.5 kW/400 V, 40 °C 200-480 VAC, 110-230 V AC/DC, spring-type terminals	1600,--	1	1 unit	42G
	3RW3018-2BB14 SIRIUS soft starter S00, 17.6 A, 7.5 kW/400 V, 40 °C 200-480 VAC, 110-230 V AC/DC, spring-type terminals	1830,--	1	1 unit	42G
	3RW3026-2BB14 SIRIUS soft starter S0, 25 A, 11kW/400 V, 40 °C 200-480 V AC,110-230 V AC/DC, spring-type terminals	2140,--	1	1 unit	42G
	3RW3027-2BB14 SIRIUS soft starter S0, 32 A, 15kW/400 V, 40 °C 200-480 V AC,110-230 V AC/DC, spring-type terminals	2480,--	1	1 unit	42G
	3RW3028-2BB14 SIRIUS soft starter S0, 38 A, 18.5 kW/400 V, 40 °C 200-480 VAC, 110-230 V AC/DC, spring-type terminals	3070,--	1	1 unit	42G
	3RW3036-2BB14 SIRIUS soft starter S2, 45 A, 22kW/400 V, 40 °C 200-480 V AC,110-230 V AC/DC, spring-type terminals	3780,--	1	1 unit	42G
	3RW3037-2BB14 SIRIUS soft starter S2, 63 A, 30kW/400 V, 40 °C 200-480 V AC,110-230 V AC/DC, spring-type terminals	4600,--	1	1 unit	42G
	3RW3038-2BB14 SIRIUS soft starter S2, 72 A, 37kW/400 V, 40 °C 200-480 V AC,110-230 V AC/DC, spring-type terminals	5440,--	1	1 unit	42G

Softstartere - Standard applikationer - 2-faset regulering - Skrueterminaler

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3RW4024-1BB14 SIRIUS soft starter S0, 12.5 A, 5.5 kW/400 V, 40 °C 200-480 VAC, 110-230 V AC/DC, Screw terminals	2930,--	1	1 unit	42G
	3RW4026-1BB14 SIRIUS soft starter S0, 25 A, 11kW/400 V, 40 °C 200-480 V AC,110-230 V AC/DC, Screw terminals	3450,--	1	1 unit	42G
	3RW4027-1BB14 SIRIUS soft starter S0, 32 A, 15kW/400 V, 40 °C 200-480 V AC,110-230 V AC/DC, Screw terminals	4100,--	1	1 unit	42G
	3RW4028-1BB14 SIRIUS soft starter S0, 38 A,18.5 kW/400 V, 40 °C 200-480 VAC, 110-230 V AC/DC, Screw terminals	4920,--	1	1 unit	42G
	3RW4036-1BB14 SIRIUS soft starter S2, 45 A, 22kW/400 V, 40 °C 200-480 V AC,110-230 V AC/DC, Screw terminals	5850,--	1	1 unit	42G
	3RW4037-1BB14 SIRIUS soft starter S2, 63 A, 30kW/400 V, 40 °C 200-480 V AC,110-230 V AC/DC, Screw terminals	6940,--	1	1 unit	42G
	3RW4038-1BB14 SIRIUS soft starter S2, 72 A, 37kW/400 V, 40 °C 200-480 V AC,110-230 V AC/DC, Screw terminals	8060,--	1	1 unit	42G
	3RW4046-1BB14 SIRIUS soft starter S3, 80 A, 45kW/400 V, 40 °C 200-480 V AC,110-230 V AC/DC, Screw terminals	9070,--	1	1 unit	42G

Softstartere - Standard applikationer - 2-faset regulering - Skrueterminaler

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3RW4047-1BB14 SIRIUS soft starter S3, 106 A, 55 kW/400 V, 40 °C 200-480 VAC, 110-230 V AC/DC, Screw terminals	9890,--	1	1 unit	42G
	3RW4055-6BB44 SIRIUS soft starter S6, 134 A, 75 kW/400 V, 40 °C 200-460 VAC, 230 V AC, Screw terminals	10500,--	1	1 unit	42G
	3RW4056-6BB44 SIRIUS soft starter S6, 162 A, 90 kW/400 V, 40 °C 200-460 VAC, 230 V AC, Screw terminals	13100,--	1	1 unit	42G
	3RW4073-6BB44 SIRIUS soft starter S12, 230 A, 132 kW/400 V, 40 °C 200-460 VAC, 230 V AC, Screw terminals	14500,--	1	1 unit	42G
	3RW4074-6BB44 SIRIUS soft starter S12, 280 A, 160 kW/400 V, 40 °C 200-460 VAC, 230 V AC, Screw terminals	16400,--	1	1 unit	42G
	3RW4075-6BB44 SIRIUS soft starter S12, 356 A, 200 kW/400 V, 40 °C 200-460 VAC, 230 V AC, Screw terminals	19200,--	1	1 unit	42G
	3RW4076-6BB44 SIRIUS soft starter S12, 432 A, 250 kW/400 V, 40 °C 200-460 VAC, 230 V AC, Screw terminals	25400,--	1	1 unit	42G

Softstartere - Standard applikationer - 2-faset regulering - Fjederterminaler

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3RW4024-2BB14 SIRIUS soft starter S0, 12.5 A, 5.5 kW/400 V, 40 °C 200-480 VAC, 110-230 V AC/DC, spring-type terminals	2930,--	1	1 unit	42G
	3RW4026-2BB14 SIRIUS soft starter S0, 25 A, 11kW/400 V, 40 °C 200-480 V AC,110-230 V AC/DC, spring-type terminals	3450,--	1	1 unit	42G
	3RW4027-2BB14 SIRIUS soft starter S0, 32 A, 15kW/400 V, 40 °C 200-480 V AC,110-230 V AC/DC, spring-type terminals	4100,--	1	1 unit	42G
	3RW4028-2BB14 SIRIUS soft starter S0, 38 A, 18.5 kW/400 V, 40 °C 200-480 VAC, 110-230 V AC/DC, spring-type terminals	4920,--	1	1 unit	42G
	3RW4036-2BB14 SIRIUS soft starter S2, 45 A, 22kW/400 V, 40 °C 200-480 V AC,110-230 V AC/DC, spring-type terminals	5850,--	1	1 unit	42G
	3RW4037-2BB14 SIRIUS soft starter S2, 63 A, 30kW/400 V, 40 °C 200-480 V AC,110-230 V AC/DC, spring-type terminals	6940,--	1	1 unit	42G
	3RW4038-2BB14 SIRIUS soft starter S2, 72 A, 37kW/400 V, 40 °C 200-480 V AC,110-230 V AC/DC, spring-type terminals	8060,--	1	1 unit	42G
	3RW4046-2BB14 SIRIUS soft starter S3, 80 A, 45kW/400 V, 40 °C 200-480 V AC,110-230 V AC/DC, spring-type terminals	9070,--	1	1 unit	42G

Softstartere - Standard applikationer - 2-faset regulering - Fjederterminaler

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3RW4047-2BB14 SIRIUS soft starter S3, 106 A, 55 kW/400 V, 40 °C 200-480 VAC, 110-230 V AC/DC, spring-type terminals	9890,--	1	1 unit	42G
	3RW4055-2BB44 SIRIUS soft starter S6, 134 A, 75 kW/400 V, 40 °C 200-460 VAC, 230 V AC, spring-type terminals	10500,--	1	1 unit	42G
	3RW4056-2BB44 SIRIUS soft starter S6, 162 A, 90 kW/400 V, 40 °C 200-460 VAC, 230 V AC, spring-type terminals	13100,--	1	1 unit	42G
	3RW4073-2BB44 SIRIUS soft starter S12, 230 A, 132 kW/400 V, 40 °C 200-460 VAC, 230 V AC, spring-type terminals	14500,--	1	1 unit	42G
	3RW4074-2BB44 SIRIUS soft starter S12, 280 A, 160 kW/400 V, 40 °C 200-460 VAC, 230 V AC, spring-type terminals	16400,--	1	1 unit	42G
	3RW4075-2BB44 SIRIUS soft starter S12, 356 A, 200 kW/400 V, 40 °C 200-460 VAC, 230 V AC, spring-type terminals	19200,--	1	1 unit	42G
	3RW4076-2BB44 SIRIUS soft starter S12, 432 A, 250 kW/400 V, 40 °C 200-460 VAC, 230 V AC, spring-type terminals	25400,--	1	1 unit	42G

Softstartere - Standard applikationer - 3-faset regulering

Selection and ordering data

Product Photo	Article Number/ Description	Price kr per PE	PU (UNIT, SET,M)	PS*/ P.UNIT	PG
	3RW5213-1TC14 SIRIUS soft starter 200-480V, 13 A, 110-250 V AC, screw terminals , Thermistor input	5270,--	1	1 unit	42S
	3RW5213-3TC14 SIRIUS soft starter 200-480V, 13 A, 110-250 V AC, spring-type terminals , Thermistor input	5270,--	1	1 unit	42S
	3RW5214-1TC14 SIRIUS soft starter 200-480V, 18 A, 110-250 V AC, screw terminals , Thermistor input	--	1	1 unit	42S
	3RW5214-3TC14 SIRIUS soft starter 200-480V, 18 A, 110-250 V AC, spring-type terminals , Thermistor input	--	1	1 unit	42S
	3RW5215-1TC14 SIRIUS soft starter 200-480V, 25 A, 110-250 V AC, screw terminals , Thermistor input	--	1	1 unit	42S
	3RW5215-3TC14 SIRIUS soft starter 200-480V, 25 A, 110-250 V AC, spring-type terminals , Thermistor input	--	1	1 unit	42S
	3RW5216-1TC14 SIRIUS soft starter 200-480V, 32 A, 110-250 V AC, screw terminals , Thermistor input	--	1	1 unit	42S
	3RW5216-3TC14 SIRIUS soft starter 200-480V, 32 A, 110-250 V AC, spring-type terminals , Thermistor input	--	1	1 unit	42S

Softstartere - Standard applikationer - 3-faset regulering

Selection and ordering data

Product Photo	Article Number/ Description	Price kr per PE	PU (UNIT, SET,M)	PS*/ P.UNIT	PG
	3RW5217-1TC14 SIRIUS soft starter 200-480V, 38 A, 110-250 V AC, screw terminals , Thermistor input	--	1	1 unit	42S
	3RW5217-3TC14 SIRIUS soft starter 200-480 V, 38 A, 110-250 V AC, spring-type terminals , Thermistor input	--	1	1 unit	42S
	3RW5224-1TC14 SIRIUS soft starter 200-480 V, 47 A, 110-250 V AC, screw terminals , Thermistor input	--	1	1 unit	42S
	3RW5224-3TC14 SIRIUS soft starter 200-480 V, 47 A, 110-250 V AC, spring-type terminals , Thermistor input	--	1	1 unit	42S
	3RW5225-1TC14 SIRIUS soft starter 200-480 V, 63 A, 110-250 V AC, screw terminals , Thermistor input	--	1	1 unit	42S
	3RW5225-3TC14 SIRIUS soft starter 200-480 V, 63 A, 110-250 V AC, spring-type terminals , Thermistor input	--	1	1 unit	42S
	3RW5226-1TC14 SIRIUS soft starter 200-480 V, 77 A, 110-250 V AC, screw terminals , Thermistor input	--	1	1 unit	42S
	3RW5226-3TC14 SIRIUS soft starter 200-480 V, 77 A, 110-250 V AC, spring-type terminals , Thermistor input	--	1	1 unit	42S

Softstartere - Standard applikationer - 3-faset regulering

Selection and ordering data

Product Photo	Article Number/ Description	Price kr per PE	PU (UNIT, SET,M)	PS*/ P.UNIT	PG
	3RW5227-1TC14 SIRIUS soft starter 200-480 V, 93 A, 110-250 V AC, screw terminals , Thermistor input	--	1	1 unit	42S
	3RW5227-3TC14 SIRIUS soft starter 200-480 V, 93 A, 110-250 V AC, spring-type terminals , Thermistor input	12300,--	1	1 unit	42S
	3RW5234-2TC14 SIRIUS soft starter 200-480 V, 113 A, 110-250 V AC, spring-type terminals , Thermistor input	--	1	1 unit	42S
	3RW5234-6TC14 SIRIUS soft starter 200-480 V, 113 A, 110-250 V AC, screw terminals , Thermistor input	--	1	1 unit	42S
	3RW5235-2TC14 SIRIUS soft starter 200-480 V, 143 A, 110-250 V AC, spring-type terminals , Thermistor input	16500,--	1	1 unit	42S
	3RW5235-6TC14 SIRIUS soft starter 200-480 V, 143 A, 110-250 V AC, screw terminals , Thermistor input	16500,--	1	1 unit	42S
	3RW5236-2TC14 SIRIUS soft starter 200-480 V, 171 A, 110-250 V AC, spring-type terminals , Thermistor input	--	1	1 unit	42S
	3RW5236-6TC14 SIRIUS soft starter 200-480 V, 171 A, 110-250 V AC, screw terminals , Thermistor input	19200,--	1	1 unit	42S

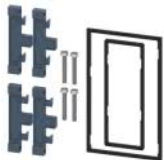
Softstartere - Standard applikationer - 3-faset regulering

Selection and ordering data

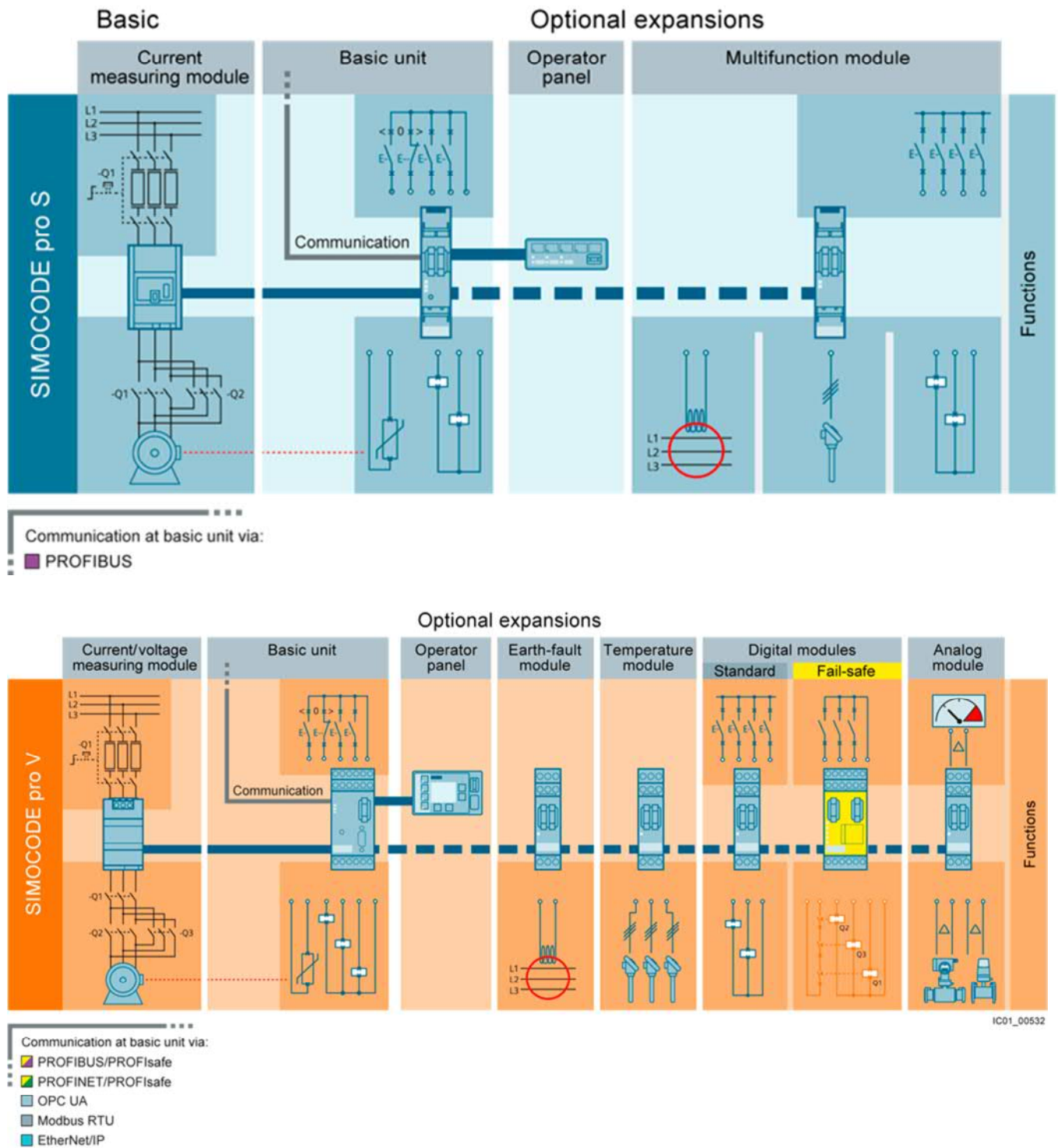
Product Photo	Article Number/ Description	Price kr per PE	PU (UNIT, SET,M)	PS*/ P.UNIT	PG
	3RW5243-2TC14 SIRIUS soft starter 200-480 V, 210 A, 110-250 V AC, spring-type terminals , Thermistor input	--	1	1 unit	42S
	3RW5243-6TC14 SIRIUS soft starter 200-480 V, 210 A, 110-250 V AC, screw terminals , Thermistor input	--	1	1 unit	42S
	3RW5245-2TC14 SIRIUS soft starter 200-480 V, 315 A, 110-250 V AC, spring-type terminals , Thermistor input	--	1	1 unit	42S
	3RW5245-6TC14 SIRIUS soft starter 200-480 V, 315 A, 110-250 V AC, screw terminals , Thermistor input	30900,--	1	1 unit	42S
	3RW5246-2TC14 SIRIUS soft starter 200-480 V, 370 A, 110-250 V AC, spring-type terminals , Thermistor input	36200,--	1	1 unit	42S
	3RW5246-6TC14 SIRIUS soft starter 200-480 V, 370 A, 110-250 V AC, screw terminals , Thermistor input	36200,--	1	1 unit	42S
	3RW5247-2TC14 SIRIUS soft starter 200-480 V, 470 A, 110-250 V AC, spring-type terminals , Thermistor input	42500,--	1	1 unit	42S
	3RW5247-6TC14 SIRIUS soft starter 200-480 V, 470 A, 110-250 V AC, screw terminals , Thermistor input	42500,--	1	1 unit	42S

Softstartere - Tilbehør til 3RW52/55

Selection and ordering data

Product Photo	Article Number/ Description	Price kr per PE	PU (UNIT, SET,M)	PS*/ P.UNIT	PG
	3RW5980-0CP00 Communication module PROFIBUS, for 3RW52/55	2340,--	1	1 unit	42S
	3RW5980-0CS00 Communication module PROFINET standard, for 3RW52/55	2340,--	1	1 unit	42S
	3RW5980-0CT00 Communication module Modbus TCP, for 3RW52/55	2340,--	1	1 unit	42S
	3RW5980-0HC60 HMI connecting cable, 5 m, for door mounting	436,--	1	1 unit	42S
	3RW5980-0HD00 Door mounting kit, IP65 for HMI module	273,--	1	1 unit	42S
	3RW5980-0HF00 HMI module High-Feature, standard on 3RW55, optionally on 3RW52	2360,--	1	1 unit	42S
	3RW5980-0HS00 HMI module Standard, optionally on 3RW52	818,--	1	1 unit	42S

SIMOCODE pro S & pro V – System oversight



SIMOCODE pro S - Intelligent motorstarter

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3UF7020-1AB01-0 Basic unit SIMOCODE pro S, PROFIBUS DP interface 1.5Mbit/s, 4I/2O freely parameterizable, Us: 24 V DC , input for thermistor connection, Monostable relay outputs, expandable by a multifunctional module	2660,--	1	1 unit	42J
	3UF7020-1AU01-0 Basic unit SIMOCODE pro S, PROFIBUS DP interface 1.5Mbit/s, 4I/2O freely parameterizable, Us: 110...240V AC/DC , input for thermistor connection, Monostable relay outputs, expandable by a multifunctional module	2190,--	1	1 unit	42J
	3UF7600-1AB01-0 Multifunctional module, 4 inputs and 2 relay outputs, input voltage 24 V DC , relay outputs monostable, residual current detection with residual-current transformer 3UL23, Connection temperature sensor Pt100/Pt1000/KTY/NTC, max. 1 multifunctional module per basic unit SIMOCODE pro S	1580,--	1	1 unit	42J
	3UF7600-1AU01-0 Multifunctional module, 4 inputs and 2 relay outputs, input voltage 110-240 V AC/DC , relay outputs monostable, residual current detection with residual-current transformer 3UL23, Connection temperature sensor Pt100/Pt1000/KTY/NTC, max. 1 multifunctional module per basic unit SIMOCODE pro S	1580,--	1	1 unit	42J

SIMOCODE pro V - Intelligent motorstarter

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3UF7010-1AB00-0 Basic unit SIMOCODE pro V PBPROFIBUS DP interface 12Mbit/s, RS 485, 4I/3O freely parameterizable, Us: 24 V DC , input for thermistor connection, Monostable relay outputs, expandable by extension modules	4220,--	1	1 unit	42J
	3UF7010-1AU00-0 Basic unit SIMOCODE pro V PBPROFIBUS DP interface 12Mbit/s, RS 485, 4I/3O freely parameterizable, Us: 110...240V AC/DC , input for thermistor connection, Monostable relay outputs, expandable by extension modules	3730,--	1	1 unit	42J
	3UF7011-1AB00-0 Basic unit SIMOCODE pro V PN, Ethernet/PROFINET IO, PN system redundancy, OPC UA server, Webserver, transmission rate 100Mbps, 2 x bus connection via RJ45, 4I/3O freely parameterizable, Us: 24 V DC , input for thermistor connection, Monostable relay outputs, expandable by extension modules	4630,--	1	1 unit	42J
	3UF7011-1AU00-0 Basic unit SIMOCODE pro V PN, Ethernet/PROFINET IO, PN system redundancy, OPC UA server, Webserver, transmission rate 100Mbps, 2 x bus connection via RJ45, 4I/3O freely parameterizable, Us: 110...240V AC/DC , input for thermistor connection, Monostable relay outputs, expandable by extension modules	4080,--	1	1 unit	42J
	3UF7300-1AB00-0 Digital module, 4 inputs and 2 relay outputs, input voltage 24V DC , relay outputs monostable, max. 2 digital modules, for SIMOCODE pro V basic unit	1180,--	1	1 unit	42J
	3UF7300-1AU00-0 Digital module, 4 inputs and 2 relay outputs, input voltage 110-240 V AC/DC , relay outputs monostable, max. 2 digital modules, for SIMOCODE pro V basic unit	1180,--	1	1 unit	42J
	3UF7320-1AB00-0 Fail-safe digital module DM-Flocal, for fail-safe shutdown via hardware signal, Us: 24 V DC , 2 relay enabling circuits, 2 relay outputs, safety function can be set via DIP switch, maximum achievable SIL IEC61508: 3, maximum achievable PLISO 13849-1: E	2330,--	1	1 unit	42J
	3UF7320-1AU00-0 Fail-safe digital module DM-Flocal, for fail-safe shutdown via hardware signal, Us: 110...240 V AC/DC , 2 relay enabling circuits, 2 relay outputs, safety function can be set via DIP switch, maximum achievable SIL IEC 61508: 3, maximum achievable PL ISO13849-1: E	2330,--	1	1 unit	42J

SIMOCODE pro V - Intelligent motorstarter

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3UF7330-1AB00-0 Fail-safe digital module DM-FPROFIsafe, for fail-safe shutdown via bus/PROFIsafe, Us: 24 V DC , 2 relay enabling circuits, 2 relay outputs, 3 inputs, maximum achievable SIL IEC 61508: 3, maximum achievable PL ISO 13849-1: E	3110,--	1	1 unit	42J
	3UF7330-1AU00-0 Fail-safe digital module DM-FPROFIsafe, for fail-safe shutdown via bus/PROFIsafe, Us: 110...240 V AC/DC , 2 relay enabling circuits, 2 relay outputs, 3 inputs, maximum achievable SIL IEC 61508: 3, maximum achievable PL ISO13849-1: E	3110,--	1	1 unit	42J
	3UF7400-1AA00-0 Analog module, 2 inputs(passive) and 1 output, for analog signals, 0/4...20 mA, for SIMOCODE pro V basic unit	1980,--	1	1 unit	42J
	3UF7510-1AA00-0 Ground fault module with analog residual current detection, for connection of a residual-current transformer 3UL23, max. 1 ground fault module per, for SIMOCODE pro V basic unit	1250,--	1	1 unit	42J
	3UF7700-1AA00-0 Temperature module, 3 inputs for connection of up to 3 temperature sensors, for SIMOCODE pro V basic unit	1670,--	1	1 unit	42J

Måletransformer til SIMOCODE - Kun strømmåling

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3UF7100-1AA00-0 Current measuring module, Set current 0.3...3 A, Overall width 45 mm, straight-through transformer, for pro S & pro V	776,--	1	1 unit	42J
	3UF7101-1AA00-0 Current measuring module, Set current 2.4...25 A, Overall width 45 mm, straight-through transformer, for pro S & pro V	816,--	1	1 unit	42J
	3UF7102-1AA00-0 Current measuring module, Set current 10...100 A, Overall width 55 mm, straight-through transformer, for pro S & pro V	895,--	1	1 unit	42J
	3UF7103-1AA00-0 Current measuring module, Set current 20...200 A, overall width 120 mm, straight-through transformer, for pro S & pro V	1740,--	1	1 unit	42J
	3UF7103-1BA00-0 Current measuring module, Set current 20...200 A, overall width 120 mm, busbar connection, for pro S & pro V	1740,--	1	1 unit	42J
	3UF7104-1BA00-0 Current measuring module, Set current 63...630 A, Overall width 145 mm, busbar connection, for pro S & pro V	1990,--	1	1 unit	42J

Måletransformer til SIMOCODE Pro V - Strøm- og spændingsmåling

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3UF7110-1AA01-0 Current/voltage measuring module V2; set current 0.3 ...4 A, voltage measurement up to 690 V, overall width 45 mm, straight-through transformer, for pro V	1530,--	1	1 unit	42J
	3UF7111-1AA01-0 Current/voltage measuring module V2; Set current 3...40A, voltage measurement up to 690 V, overall width 45 mm, straight-through transformer, for pro V	1550,--	1	1 unit	42J
	3UF7112-1AA01-0 Current/voltage measuring module V2; Set current 10...115A, voltage measurement up to 690 V, Overall width 55 mm, straight-through transformer, for pro V	1580,--	1	1 unit	42J
	3UF7113-1AA01-0 Current/voltage measuring module V2; Set current 20...200A, voltage measurement up to 690V, overall width 120 mm, straight-through transformer, for pro V	2410,--	1	1 unit	42J
	3UF7113-1BA01-0 Current/voltage measuring module V2; Set current 20...200A, voltage measurement up to 690V, overall width 120 mm, busbar connection, , for pro V	2410,--	1	1 unit	42J
	3UF7114-1BA01-0 Current/voltage measuring module V2; Set current 63...630A, voltage measurement up to 690V, Overall width 145 mm, busbar connection, , for pro V	2670,--	1	1 unit	42J

Tilbehør til SIMCODE pro S & pro V

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3UF7200-1AA01-0 Operator panel titanium gray, installation in control cabinet door or front plate, can be plugged onto basic unit or extension modules, 10 LEDs for status display and 5 freely assignable keys for manual control, for pro S & pro V	1550,--	1	1 unit	42J
	3UF7210-1AA01-0 Operator panel with display titanium gray, installation in control cabinet door or front plate, can be plugged onto basic unit or extension modules, 7 LEDs for status display and 4 freely assignable keys for manual control, only for pro V	2560,--	1	1 unit	42J
	3UF7901-0AA01-0 Memory module for the parameterization of SIMOCODE pro S & V without PC	224,--	1	1 unit	42J
	3UF7930-0AA00-0 Connecting cable Length 0.025m, flat, for connection of basic unit with extension modules via the system interface	75,40	1	1 unit	42J
	3UF7935-0AA00-0 Connecting cable Length 0.3 m, flat, for connection of basic unit, current measuring module, current/voltage measuring module, operator panel or extension modules via the system interface	100,--	1	1 unit	42J
	3UF7932-0AA00-0 Connecting cable Length 0.5 m, flat, for connection of basic unit, current measuring module, current/voltage measuring module, operator panel or extension modules via the system interface	116,--	1	1 unit	42J
	3UF7937-0BA00-0 Connecting cable Length 1.0 m, round, for connection of basic unit, current measuring module, current/voltage measuring module, operator panel or extension modules via the system interface	250,--	1	1 unit	42J
	3UF7933-0BA00-0 Connecting cable Length 2.5 m, round, for connection of basic unit, current measuring module, current/voltage measuring module, operator panel or extension modules via the system interface	277,--	1	1 unit	42J

Tilbehør til SIMCODE pro S & pro V

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3UF7941-0AA00-0 USB PC cable for connection to the USB interface of a PC, for communication with SIMOCODE pro s & pro V via the system interface	826,--	1	1 unit	42J

SIMOCODE - Spoler til jordfejlsmodulet 3UF7510-1AA00-0

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3UL2302-1A Residual-current transformer for residual current monitoring, opening 35 mm, residual current 30 mA...40 A	1380,--	1	1 unit	41H
	3UL2303-1A Residual-current transformer for residual current monitoring, opening 55 mm, residual current 30 mA...40 A	1470,--	1	1 unit	41H
	3UL2304-1A Residual-current transformer for residual current monitoring, opening 80 mm, residual current 30 mA...40 A	1580,--	1	1 unit	41H
	3UL2305-1A Residual-current transformer for residual current monitoring, opening 105 mm, residual current 30 mA...40 A	2110,--	1	1 unit	41H
	3UL2306-1A Residual-current transformer for residual current monitoring, opening 140 mm, residual current 30 mA...40 A	2910,--	1	1 unit	41H
	3UL2307-1A Residual-current transformer for residual current monitoring, opening 210 mm, residual current 30 mA...40 A	4230,--	1	1 unit	41H

SITOP Strømforsyninger

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	6EP3321-6SB00-0AY0 LOGO!POWER 12 V / 1.9 A, Stabilized power supply input: 100-240 V AC , output: 12 V DC/1.9 A	559,--	1	1 unit	583
	6EP3322-6SB00-0AY0 LOGO!POWER 12 V / 4.5 A, Regulated power supply input:100-240 V AC , output: 12 V DC/4.5 A	745,--	1	1 unit	583
	6EP3332-6SB00-0AY0 LOGO!POWER 24 V / 2.5 A, Stabilized power supply input: 100-240 V AC , output: DC 24 V /2.5 A	527,--	1	1 unit	583
	6EP3333-6SB00-0AY0 LOGO!POWER 24 V / 4 A, Stabilized power supply input: 100-240 V AC , output: DC 24 V /4 A	721,--	1	1 unit	583
	6EP1332-1LB00 SITOP PSU100L 24 V/2.5 A, Stabilized power supply input: 120/230 V AC , output: DC 24V/2,5 A	397,--	1	1 unit	593
	6EP1333-1LB00 SITOP PSU100L 24 V/5 A, Stabilized power supply input:120/230 V AC , output: 24 V DC/5A	527,--	1	1 unit	593
	6EP1334-1LB00 SITOP PSU100L 24 V/10 A, Stabilized power supply input: 120/230 V AC , output: DC 24V/10 A	802,--	1	1 unit	593
	6EP1333-2BA20 SITOP PSU100S 24 V/5 A, Stabilized power supply input: 120/230 V AC , output: 24 V DC/5A	802,--	1	1 unit	582

SITOP Strømforsyninger

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	6EP1334-2BA20 SITOP PSU100S 24 V/10 A, Stabilized power supply input: 120/230 V AC , output: DC 24V/10 A	1170,--	1	1 unit	582
	6EP1336-2BA10 SITOP PSU100S 20 A, Stabilized power supply input: 120/230 V AC , output: 24 V DC/20 A	1530,--	1	1 unit	582
	6EP1433-2BA20 SITOP PSU300S 24 V/5 A, Stabilized power supply input: 3 AC 400-500 V , output: 24 VDC/5 A	988,--	1	1 unit	582
	6EP1434-2BA20 SITOP PSU300S 24 V/10 A, Stabilized power supply input: 3 AC 400-500 V , output: DC 24V/10 A	1280,--	1	1 unit	582
	6EP1436-2BA10 SITOP PSU300S 20 A, Stabilized power supply input: 3 AC 400-500V , output: 24 V DC/20 A	1490,--	1	1 unit	582

SITOP Strømforsyninger - Tilbehør

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	6EP1964-2BA00 SITOP PSE202U, 10A Redundancy module Input/output: 24 V DC, suitable for decoupling two SITOP power supplies, with maximal per 5 A output current	356,--	1	1 unit	588
	6EP1961-3BA21 SITOP PSE202U, 40A Redundancy module Input/output: 24 V DC/40 A, suitable for decoupling two SITOP power supplies, with maximal per 20 A output current	713,--	1	1 unit	588
	6EP1961-3BA01 SITOP PSE201U, buffer module, Buffer time 100 ms to 10 s depending on load current	1230,--	1	1 unit	588
	6EP1961-2BA11 SITOP PSE200U, 3 A selectivity module 4-channel input: DC 24V/12 A output: 24 V DC/4x 3 A, level adjustable 0.5-3 A, with common signaling contact	745,--	1	1 unit	586
	6EP1961-2BA21 SITOP PSE200U, 10 A selectivity module 4-channel input: 24 VDC/40 A output: 24 V DC/4x 10 A, level adjustable 3-10 A, with common signaling contact	826,--	1	1 unit	586

Timere - SIRIUS serien

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3RP2505-1AW30 Timing relay, Multifunction, 1 change-over contact, 13 functions, 7 time ranges (0.05s...100 h), 12...240 V AC/DC at 50/60 Hz AC with LED, screw terminal	1170,--	1	1 unit	41H
	3RP2505-2AW30 Timing relay, Multifunction, 1 change-over contact, 13 functions, 7 time ranges (0.05s...100 h), 12-240 V AC/DC at 50/60 Hz AC with LED, spring-type terminal (push-in)	1170,--	1	1 unit	41H
	3RP2505-1BW30 Timing relay, Multifunction, 2 change-over contacts, 27 functions, 7 time ranges (0.05s...100 h), 12-240 V AC/DC at 50/60 Hz AC with LED, screw terminal	1450,--	1	1 unit	41H
	3RP2505-2BW30 Timing relay, Multifunction, 2 change-over contacts, 27 functions, 7 time ranges (0.05s...100 h), 12-240 V AC/DC at 50/60 Hz AC with LED, spring-type terminal (push-in)	1450,--	1	1 unit	41H
	3RP2574-1NW30 Timing relay, electronic with star-delta (wye-delta) function, 1 NO delayed, 1 NO instantaneous, 1 time range 1...20 s, 12-240 VAC/DC at 50/60 Hz AC, screw terminal	726,--	1	1 unit	41H
	3RP2574-2NW30 Timing relay, electronic with star-delta (wye-delta) function, 1 NO delayed, 1 NO instantaneous, 1 time range, 1...20 s, 12-240 VAC/DC at 50/60 Hz AC with LED, spring-type terminal (push-in)	726,--	1	1 unit	41H

Timere - Til M36 DIN-afdækning

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	7PV1508-1AW30 Timing relay, electronic, Multifunction, 1 change-over contact, 7 functions, 7 time ranges 0.05 s ... 100 h, 12-240V AC/DC with LED, Screw terminal	584,--	1	1 unit	41H
	7PV1518-1AW30 Timing relay, electronic, ON delay, 1 change-over contact, 7 time ranges 0.05 s...100 h, 12-240 V AC/DC, Screw terminal	396,--	1	1 unit	41H
	7PV1538-1AW30 Timing relay, electronic, OFF delay with control signal, 1 change-over contact, 7 time ranges, 0.05 s...100 h, 12-240 VAC/DC with LED, Screw terminal	528,--	1	1 unit	41H
	7PV1558-1AW30 Timing relay, electronic, clock generator, 1 change-over contact, 7 time ranges 0.05s...100 h, 12...240 V AC/DC with LED, Screw terminal	675,--	1	1 unit	41H
	7PV1578-1BW30 Timing relay, electronic, star-delta (wye-delta) function, 2 NO, 7 time ranges 0.05 s...100h, 12-240 V AC/DC, Screw terminal	455,--	1	1 unit	41H

Overvågningsrelæer – Faserækkefølge & fasebrud

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3UG4511-1AP20 Analog monitoring relay, Phase sequence monitoring, 3 x320...500 V 50...60 Hz AC, 1change-over contact, screw terminal	851,--	1	1 unit	41H
	3UG4511-2AP20 Analog monitoring relay, Phase sequence monitoring, 3 x320...500 V 50...60 Hz AC, 1change-over contact, spring-type connection	893,--	1	1 unit	41H
	3UG4511-1BP20 Analog monitoring relay, Phase sequence monitoring, 3 x320...500 V 50...60 Hz AC, 2 change-over contacts, screw terminal	982,--	1	1 unit	41H
	3UG4511-2BP20 Analog monitoring relay, Phase sequence monitoring, 3 x320...500 V 50...60 Hz AC, 2 change-over contacts, spring-type connection	1030,--	1	1 unit	41H
	3UG4512-1AR20 Analog monitoring relay, Phase failure and sequence, 3 x160...690 V 50...60 Hz AC, 1 change-over contact, screw terminal	936,--	1	1 unit	41H
	3UG4512-2AR20 Analog monitoring relay, Phase failure and sequence, 3 x160...690 V 50...60 Hz AC, 1 change-over contact, spring-type connection	991,--	1	1 unit	41H
	3UG4513-1BR20 Analog monitoring relay, Phase failure and sequence, Adjustable undervoltage, Asymmetry 20% fixed 3 x 160 to 690 V 50 to 60Hz AC, Hysteresis 5% fixed, Delay time 0-20 s, 2 change-over contacts, screw terminal	1250,--	1	1 unit	41H
	3UG4513-2BR20 Analog monitoring relay, Phase failure and sequence, Adjustable undervoltage, Asymmetry 20% fixed, 3 x 160 to 690 V 50 to 60Hz AC, Hysteresis 5% fixed, Delay time 0-20 s, 2 change-over contacts, spring-type connection	1310,--	1	1 unit	41H

Overvågningsrelæer - Spænding og strøm

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3UG4633-1AL30 Digital monitoring relay, Voltage monitoring , 17-275 V AC/DC Overshoot and undershoot, self-supplied , Noise pulses delay 0.1 to 20 s, Hysteresis 0.1 to 150 V, 1 change-over contact, screw terminal	1360,--	1	1 unit	41H
	3UG4633-2AL30 Digital monitoring relay, Voltage monitoring , 17-275 V AC/DC Overshoot and undershoot, self-supplied , Noise pulses delay 0.1 to 20 s, Hysteresis 0.1 to 150 V, 1 change-over contact, spring-type connection	1420,--	1	1 unit	41H
	3UG4632-1AW30 Digital monitoring relay, Voltage monitoring , 10 to 600 V AC/DC, Overshoot and undershoot, 24 to 240 V AC/DC , Noise pulses delay 0.1 to 20s, Hysteresis 0.1 to 300 V, 1 change-over contact, screw terminal	1420,--	1	1 unit	41H
	3UG4632-2AW30 Digital monitoring relay, Voltage monitoring , 10 to 600 V AC/DC, Overshoot and undershoot, 24 to 240 V AC/DC , Noise pulses delay 0.1 to 20s, Hysteresis 0.1 to 300 V, 1 change-over, spring-type connection	1500,--	1	1 unit	41H
	3UG4621-1AW30 Digital monitoring relay, Current monitoring , 2-500 mA AC/DC, Overshoot and undershoot, 24 to 240 VAC/DC , ON delay and noise pulses delay 0.1 to 20 s, Hysteresis 0.1 to 250 mA, 1 change-over contact, screw terminal	1420,--	1	1 unit	41H
	3UG4621-2AW30 Digital monitoring relay, Current monitoring , 2-500 mA AC/DC, Overshoot and undershoot, 24 to 240 VAC/DC , ON delay and noise pulses delay 0.1 to 20 s, Hysteresis 0.1 to 250 mA, 1 change-over contact, spring-type connection	1500,--	1	1 unit	41H
	3UG4622-1AW30 Digital monitoring relay, Current monitoring , 0.05-10 A AC/DC, Overshoot and undershoot, 24 to 240 VAC/DC , ON delay and noise pulses delay 0.1 to 20 s, Hysteresis 0.01 to 5 A, 1 change-over contact, screw terminal	1420,--	1	1 unit	41H
	3UG4622-2AW30 Digital monitoring relay, Current monitoring , 0.05-10 A AC/DC, Overshoot and undershoot, 24 to 240 VAC/DC , ON delay and noise pulses delay 0.1 to 20 s, Hysteresis 0.01 to 5 A, 1 change-over contact, spring-type connection	1500,--	1	1 unit	41H

Overvågningsrelæer - Temperatur uden display

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3RS1000-1CD10 Temperature monitoring relay, PT100, Overshoot, 1 threshold value, Width 22.5 mm, 0 °C to 100 °C, 24 V AC/DC , 1 NO + 1 NC, quiescent current principle, screw terminal	1410,--	1	1 unit	41H
	3RS1000-2CD10 Temperature monitoring relay, PT100, Overshoot, 1 threshold value, Width 22.5 mm, 0 °C to 100 °C, 24 V AC/DC , 1 NO + 1 NC, quiescent current principle, spring-type terminal	1440,--	1	1 unit	41H
	3RS1000-1CK10 Temperature monitoring relay, PT100, Overshoot, 1 threshold value, Width 22.5 mm, 0 °C to 100 °C, 110-120/220-240 V AC , 1NO + 1 NC, quiescent current principle, screw terminal	1410,--	1	1 unit	41H
	3RS1000-2CK10 Temperature monitoring relay, PT100, Overshoot, 1 threshold value, Width 22.5 mm, 0 °C to 100 °C, 110-120/220-240 V AC , 1NO + 1 NC, quiescent current principle, spring-type terminal	1440,--	1	1 unit	41H
	3RS1010-1CD10 Temperature monitoring relay, PT100, Undershoot, 1 threshold value, Width 22.5 mm, 0 °C to 100 °C, 24 V AC/DC , 1 NO + 1 NC, quiescent current principle, screw terminal	1410,--	1	1 unit	41H
	3RS1020-1DD10 Temperature monitoring relay, PT100, Overshoot, 2 threshold values, Width 22.5 mm, 0 °C to 100 °C, 24 V AC/DC , 1 NO + 1 CO, Load and quiescent current, screw terminal	2150,--	1	1 unit	41H
	3RS1020-1DW10 Temperature monitoring relay, PT100, Overshoot, 2 threshold values, Width 22.5 mm, 0 °C to 100 °C, 24 - 240 V AC/DC , 1 NO +1 CO, Load and quiescent current, screw terminal	2360,--	1	1 unit	41H

Overvågningsrelæer - Temperatur med display

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3RS1040-1GD50 Temperature monitoring relay, PT100/1000, KTY83/84, NTC, 2 threshold values, digitally adjustable, -50 °C to 500 °C, 24V AC/DC , 2 x 1 CO + 1 NO, Width 45 mm, screw terminal	2840,--	1	1 unit	41H
	3RS1040-2GD50 Temperature monitoring relay, PT100/1000, KTY83/84, NTC, 2 threshold values, digitally adjustable, -50 °C to 500 °C, 24V AC/DC , 2 x 1 CO + 1 NO, Width 45 mm, spring-type terminal	2870,--	1	1 unit	41H
	3RS1040-1GW50 Temperature monitoring relay, PT100/1000, KTY83/84, NTC, 2 threshold values, digitally adjustable, -50 °C to 500 °C, 24- 240 V AC/DC , 2 x 1 CO + 1 NO, Width 45 mm, screw terminal	3040,--	1	1 unit	41H
	3RS1040-2GW50 Temperature monitoring relay, PT100/1000, KTY83/84, NTC, 2 threshold values, digitally adjustable, -50 °C to 500 °C, 24- 240 V AC/DC , 2 x 1 CO + 1 NO, Width 45 mm, spring-type terminal	3100,--	1	1 unit	41H

Termistorrelæ til motorbeskyttelse

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3RN2000-1AA30 Thermistor motor protection relay, 17.5 mm enclosure, screw terminal , 1 change-over contact, 24 V AC/DC , Auto-reset, suitable for bimetallic switch	561,--	1	1 unit	41H
	3RN2000-1AW30 Thermistor motor protection relay, 17.5 mm enclosure, screw terminal , 1 change-over contact, 24 V-240 V AC/DC , Auto-reset, suitable for bimetallic switch	615,--	1	1 unit	41H
	3RN2010-1CA30 Thermistor motor protection relay, 17.5 mm enclosure, screw terminal , 1 NO contact, 1 NC contact, 24 V AC/DC , Auto RESET, suitable for bimetallic switch	713,--	1	1 unit	41H
	3RN2010-1CW30 Thermistor motor protection relay, 17.5 mm enclosure, screw terminal , 1 NO contact, 1 NC contact, 24 V-240 V AC/DC , Auto RESET, suitable for bimetallic switch	807,--	1	1 unit	41H
	3RN2011-1BA30 Thermistor motor protection relay, 22.5 mm enclosure, screw terminal , 2 change-over contacts, 24 V AC/DC , Manual/Remote-Reset, with ATEX approval , galvanic isolation, Test/Reset button, wire break monitoring, short circuit monitoring	950,--	1	1 unit	41H
	3RN2011-1BW30 Thermistor motor protection relay, 22.5 mm enclosure, screw terminal , 2 change-over contacts, 24 V-240 V AC/DC , Manual/Remote-Reset, with ATEX approval , galvanic isolation, Test/Reset button, wire break monitoring, short circuit monitoring	1010,--	1	1 unit	41H
	3RN2000-2AA30 Thermistor motor protection relay, 17.5 mm enclosure, spring-type terminal , 1 change-over contact, 24 V AC/DC , Auto-reset, suitable for bimetallic switch	561,--	1	1 unit	41H
	3RN2000-2AW30 Thermistor motor protection relay, 17.5 mm enclosure, spring-type terminal , 1 change-over contact, 24 V-240 V AC/DC , Auto-reset, suitable for bimetallic switch	615,--	1	1 unit	41H

Termistorrelæ til motorbeskyttelse

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3RN2010-2CA30 Thermistor motor protection relay, 17.5 mm enclosure, spring-type terminal , 1 NO contact, 1 NC contact, 24 V AC/DC , Auto RESET, suitable for bimetallic switch	713,--	1	1 unit	41H
	3RN2010-2CW30 Thermistor motor protection relay, 17.5 mm enclosure, spring-type terminal , 1 NO contact, 1 NC contact, 24 V-240 V AC/DC , Auto RESET, suitable for bimetallic switch	807,--	1	1 unit	41H
	3RN2011-2BA30 Thermistor motor protection relay, 22.5 mm enclosure, spring-type terminal , 2 change-over contacts, 24 V AC/DC , Manual/Remote-Reset, with ATEX approval , galvanic isolation Test/Reset button, wire break monitoring, short circuit monitoring	950,--	1	1 unit	41H
	3RN2011-2BW30 Thermistor motor protection relay, 22.5 mm enclosure, spring-type terminal , 2 change-over contacts, 24 V-240 V AC/DC , Manual/Remote-Reset, with ATEX approval , galvanic isolation, Test/Reset button, wire break monitoring, short circuit monitoring	1010,--	1	1 unit	41H

Signalkonvertere

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3RS7000-1DE00 Separation amplifier, 24 VAC/DC, 3-way separation, input: 0-10 V, output: 4-20 mA, screw terminal	1430,--	1	1 unit	41H
	3RS7000-2DE00 Separation amplifier, 24 VAC/DC, 3-way separation, input: 0-10 V, output: 4-20 mA, spring-type terminal (push-in)	1430,--	1	1 unit	41H
	3RS7002-1DE00 Separation amplifier, 24 VAC/DC, 3-way separation, input: 0-20 mA, output: 4-20 mA, screw terminal	1430,--	1	1 unit	41H
	3RS7002-2DE00 Separation amplifier, 24 VAC/DC, 3-way separation, input: 0-20 mA, output: 4-20 mA, spring-type terminal (push-in)	1430,--	1	1 unit	41H
	3RS7005-1FE00 Separation amplifier, 24 VAC/DC, 3-way separation, input: 0-10 V, 0/4-20 mA, output: 0-10V, 0/4-20 mA, screw terminal	1870,--	1	1 unit	41H
	3RS7005-2FE00 Separation amplifier, 24 VAC/DC, 3-way separation, input: 0-10 V, 0/4-20 mA; output: 0 -10 V, 0/4 - 20mA, spring-type terminal (push-in)	1870,--	1	1 unit	41H
	3RS7006-1FE00 Separation amplifier, 24 VAC/DC, 3-way separation, input: 0-60 mV, 0-100 mV, 0-300 mV, 0-500 mV, 0-1 V, 0-2 V, 0-5 V, 0-10 V, 0-20 V, 2-10 V, 0-5 mA, 0-10 mA, 0-20 mA, 4-20 mA, +5 mA, +20 mA, output: 0 - 10V, 0/4 - 20 mA, screw terminal	2730,--	1	1 unit	41H
	3RS7006-2FE00 Separation amplifier, 24 VAC/DC, 3-way separation, input: 0-60 mV, 0-100 mV, 0-300 mV, 0-500 mV, 0-1 V, 0-2 V, 0-5 V, 0-10 V, 0-20 V, 2-10 V, 0-5 mA, 0-10 mA, 0-20 mA, 4-20 mA, +5 mA, +20 mA, output: 0 - 10V, 0/4 - 20 mA, spring-type terminal (push-in)	2730,--	1	1 unit	41H

Sikkerhedsrelæer

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3SK1111-1AB30 SIRIUS safety relay, Basic unit, Standard series, Relay enabling circuits, 3 NO contacts, signaling circuit 1 NC contact, 24 V AC/DC, screw terminal	2150,--	1	1 unit	41L
	3SK1111-2AB30 SIRIUS safety relay, Basic unit, Standard series, Relay enabling circuits, 3 NO contacts, signaling circuit 1 NC contact, 24 V AC/DC, Spring-type terminal (push-in)	2150,--	1	1 unit	41L
	3SK1121-1AB40 SIRIUS safety relay, Basic unit, Advanced series, Relay enabling circuits, 3 NO contacts, signaling circuit 1 NC contact, 24 V DC, screw terminal	2730,--	1	1 unit	41L
	3SK1121-2AB40 SIRIUS safety relay, Basic unit, Advanced series, Relay enabling circuits, 3 NO contacts, signaling circuit 1 NC contact, 24 V DC, Spring-type terminal (push-in)	2730,--	1	1 unit	41L
	3SK1121-1CB42 SIRIUS safety relay, Basic unit, Advanced series, with time delay 0.5-30 s, Relay enabling circuits, 2 NO instantaneous, 2 NO delayed, 24 V DC, screw terminal	3410,--	1	1 unit	41L
	3SK1121-2CB42 SIRIUS safety relay, Basic unit, Advanced series, with time delay 0.5-30 s, Relay enabling circuits, 2 NO instantaneous, 2 NO delayed, 24 V DC, Spring-type terminal (push-in)	3410,--	1	1 unit	41L
	3SK1122-1CB42 SIRIUS safety relay, Basic unit, Advanced series, with time delay 0.5-30 s, electronic enabling circuits, 2 NO instantaneous, 2 NO delayed, screw terminal	2050,--	1	1 unit	41L
	3SK1122-2CB42 SIRIUS safety relay, Basic unit, Advanced series, with time delay 0.5-30 s, electronic enabling circuits, 2 NO instantaneous, 2 NO delayed, Spring-type terminal (push-in)	2050,--	1	1 unit	41L

SIRIUS ACT - Komplette trykknapper - Kunststof - Skrueterminaler

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3SU1100-0AB10-1BA0 Pushbutton, 22 mm, round, plastic, black, pushbutton, flat, momentary contact type, with holder, 1 NO, screw terminal, IP69K	111,--	1	1 unit	41J
	3SU1100-0AB10-1CA0 Pushbutton, 22 mm, round, plastic, black, pushbutton, flat, momentary contact type, with holder 1 NC, screw terminal, IP69K	111,--	1	1 unit	41J
	3SU1100-0AB20-1BA0 Pushbutton, 22 mm, round, plastic, red, pushbutton, flat, momentary contact type, with holder 1 NO, screw terminal, IP69K	111,--	1	1 unit	41J
	3SU1100-0AB20-1CA0 Pushbutton, 22 mm, round, plastic, red, pushbutton, flat, momentary contact type, with holder 1 NC, screw terminal, IP69K	111,--	1	1 unit	41J
	3SU1100-0AB40-1BA0 Pushbutton, 22 mm, round, plastic, green, pushbutton, flat, momentary contact type, with holder 1 NO, screw terminal, IP69K	111,--	1	1 unit	41J
	3SU1100-0AB50-1BA0 Pushbutton, 22 mm, round, plastic, blue, pushbutton, flat, momentary contact type, with holder 1 NO, screw terminal, IP69K	111,--	1	1 unit	41J
	3SU1100-0AB60-1BA0 Pushbutton, 22 mm, round, plastic, white, pushbutton, flat, momentary contact type, with holder 1 NO, screw terminal, IP69K	111,--	1	1 unit	41J
	3SU1102-0AB20-1CA0 Illuminated pushbutton, 22 mm, round, plastic, red, pushbutton, flat, momentary contact type, with holder, 1NC, LED module with integrated LED 24 V AC/DC, screw terminal, IP69K	198,--	1	1 unit	41J

SIRIUS ACT - Komplette trykknapper - Kunststof - Skrueterminaler

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3SU1102-0AB30-1BA0 Illuminated pushbutton, 22 mm, round, plastic, yellow, pushbutton, flat, momentary contact type, with holder, 1NO, LED module with integrated LED 24 V AC/DC, screw terminal, IP69K	198,--	1	1 unit	41J
	3SU1102-0AB40-1BA0 Illuminated pushbutton, 22 mm, round, plastic, green, pushbutton, flat, momentary contact type, with holder, 1NO, LED module with integrated LED 24 V AC/DC, screw terminal, IP69K	198,--	1	1 unit	41J
	3SU1102-0AB50-1BA0 Illuminated pushbutton, 22 mm, round, plastic, blue, pushbutton, flat, momentary contact type, with holder, 1NO, LED module with integrated LED 24 V AC/DC, screw terminal, IP69K	198,--	1	1 unit	41J
	3SU1102-0AB60-1BA0 Illuminated pushbutton, 22 mm, round, plastic, white, pushbutton, flat, momentary contact type, with holder, 1NO, LED module with integrated LED 24 V AC/DC, screw terminal, IP69K	198,--	1	1 unit	41J
	3SU1106-0AB20-1CA0 Illuminated pushbutton, 22 mm, round, plastic, red, pushbutton, flat, momentary contact type, with holder, 1NC, LED module with integrated LED 230 V AC, screw terminal, IP69K	254,--	1	1 unit	41J
	3SU1106-0AB30-1BA0 Illuminated pushbutton, 22 mm, round, plastic, yellow, pushbutton, flat, momentary contact type, with holder, 1NO, LED module with integrated LED 230 V AC, screw terminal, IP69K	254,--	1	1 unit	41J
	3SU1106-0AB40-1BA0 Illuminated pushbutton, 22 mm, round, plastic, green, pushbutton, flat, momentary contact type, with holder, 1NO, LED module with integrated LED 230 V AC, screw terminal, IP69K	254,--	1	1 unit	41J
	3SU1106-0AB50-1BA0 Illuminated pushbutton, 22 mm, round, plastic, blue, pushbutton, flat, momentary contact type, with holder, 1NO, LED module with integrated LED 230 V AC, screw terminal, IP69K	254,--	1	1 unit	41J

SIRIUS ACT - Komplette trykknapper - Kunststof - Skrueterminaler

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3SU1106-0AB60-1BA0 Illuminated pushbutton, 22 mm, round, plastic, white, pushbutton, flat, momentary contact type, with holder, 1NO, LED module with integrated LED 230 V AC, screw terminal, IP69K	254,--	1	1 unit	41J

SIRIUS ACT - Komplette trykknapper - Kunststof - Fjederterminaler

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3SU1100-0AB10-3BA0 Pushbutton, 22 mm, round, plastic, black, pushbutton, flat, momentary contact type, with holder 1 NO, Spring-type terminal, IP69K	116,--	1	1 unit	41J
	3SU1100-0AB10-3CA0 Pushbutton, 22 mm, round, plastic, black, pushbutton, flat, momentary contact type, with holder 1 NC, Spring-type terminal, IP69K	116,--	1	1 unit	41J
	3SU1100-0AB20-3CA0 Pushbutton, 22 mm, round, plastic, red, pushbutton, flat, momentary contact type, with holder 1 NC, Spring-type terminal, IP69K	116,--	1	1 unit	41J
	3SU1100-0AB20-3FA0 Pushbutton, 22 mm, round, plastic, red, pushbutton, flat, momentary contact type, with holder 1NO + 1 NC, Spring-type terminal, IP69K				
	3SU1100-0AB40-3BA0 Pushbutton, 22 mm, round, plastic, green, push button, flat, momentary contact type, with holder 1 NO, Spring-type terminal, IP69K	116,--	1	1 unit	41J
	3SU1100-0AB50-3BA0 Pushbutton, 22 mm, round, plastic, blue, push button, flat, momentary contact type, with holder 1 NO, Spring-type terminal, IP69K	116,--	1	1 unit	41J
	3SU1100-0AB60-3BA0 Pushbutton, 22 mm, round, plastic, white, pushbutton, flat, momentary contact type, with holder 1 NO, Spring-type terminal, IP69K	116,--	1	1 unit	41J
	3SU1102-0AB20-3CA0 Illuminated pushbutton, 22 mm, round, plastic, red ,pushbutton, flat, momentary contact type, with holder, 1NC, LED module with integrated LED 24 V AC/DC, Spring-type terminal, IP69K	213,--	1	1 unit	41J

SIRIUS ACT - Komplette trykknapper - Kunststof - Fjederterminaler

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3SU1102-0AB30-3BA0 Illuminated pushbutton, 22 mm, round, plastic, yellow, pushbutton, flat, momentary contact type, with holder, 1NO, LED module with integrated LED 24 V AC/DC, Spring-type terminal, IP69K	213,--	1	1 unit	41J
	3SU1102-0AB40-3BA0 Illuminated pushbutton, 22 mm, round, plastic, green, pushbutton, flat, momentary contact type, with holder, 1NO, LED module with integrated LED 24 V AC/DC, Spring-type terminal, IP69K	213,--	1	1 unit	41J
	3SU1102-0AB50-3BA0 Illuminated pushbutton, 22 mm, round, plastic, blue, pushbutton, flat, momentary contact type, with holder, 1NO, LED module with integrated LED 24 V AC/DC, Spring-type terminal, IP69K	213,--	1	1 unit	41J
	3SU1102-0AB60-3BA0 Illuminated pushbutton, 22 mm, round, plastic, white, pushbutton, flat, momentary contact type, with holder, 1NO, LED module with integrated LED 24 V AC/DC, Spring-type terminal, IP69K	213,--	1	1 unit	41J
	3SU1106-0AB20-3CA0 Illuminated pushbutton, 22 mm, round, plastic, red, pushbutton, flat, momentary contact type, with holder, 1NC, LED module with integrated LED 230 V AC, Spring-type terminal, IP69K	276,--	1	1 unit	41J
	3SU1106-0AB30-3FA0 Illuminated pushbutton, 22 mm, round, plastic, yellow, pushbutton, flat, momentary contact type, with holder, 1NO+1 NC, LED module with integrated LED 230 V AC, Spring-type terminal, IP69K	307,--	1	1 unit	41J
	3SU1106-0AB40-3BA0 Illuminated pushbutton, 22 mm, round, plastic, green, pushbutton, flat, momentary contact type, with holder, 1NO, LED module with integrated LED 230 V AC, Spring-type terminal, IP69K	276,--	1	1 unit	41J
	3SU1106-0AB50-3FA0 Illuminated pushbutton, 22 mm, round, plastic, blue, pushbutton, flat, momentary contact type, with holder, 1NO+1 NC, LED module with integrated LED 230 V AC, Spring-type terminal, IP69K	307,--	1	1 unit	41J

 
SIRIUS ACT - Komplette trykknapper - Kunststof - Fjederterminaler

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3SU1106-0AB60-3BA0 Illuminated pushbutton, 22 mm, round, plastic, white, pushbutton, flat, momentary contact type, with holder, 1NO, LED module with integrated LED 230 V AC, Spring-type terminal, IP69K	276,--	1	1 unit	41J

SIRIUS ACT - Komplette indikatorlamper - Kunststof - Skrueterminaler

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3SU1102-6AA20-1AA0 Indicator lights, 22 mm, round, plastic, red, lens, smooth, with holder, LED module, with integrated LED 24 V AC/DC, screw terminal, IP69K	125,--	1	1 unit	41J
	3SU1102-6AA30-1AA0 Indicator lights, 22 mm, round, plastic, yellow, lens, smooth, with holder, LED module, with integrated LED 24 V AC/DC, screw terminal, IP69K	125,--	1	1 unit	41J
	3SU1102-6AA40-1AA0 Indicator lights, 22 mm, round, plastic, green, lens, smooth, with holder, LED module, with integrated LED 24 V AC/DC, screw terminal, IP69K	125,--	1	1 unit	41J
	3SU1102-6AA50-1AA0 Indicator lights, 22 mm, round, plastic, blue, lens, smooth, with holder, LED module, with integrated LED 24 V AC/DC, screw terminal, IP69K	125,--	1	1 unit	41J
	3SU1102-6AA60-1AA0 Indicator lights, 22 mm, round, plastic, white, lens, smooth, with holder, LED module, with integrated LED 24 V AC/DC, screw terminal, IP69K	125,--	1	1 unit	41J
	3SU1106-6AA20-1AA0 Indicator lights, 22 mm, round, plastic, red, lens, smooth, with holder, LED module, with integrated LED 230 V AC, screw terminal, IP69K	181,--	1	1 unit	41J
	3SU1106-6AA30-1AA0 Indicator lights, 22 mm, round, plastic, yellow, lens, smooth, with holder, LED module, with integrated LED 230 V AC, screw terminal, IP69K	181,--	1	1 unit	41J
	3SU1106-6AA40-1AA0 Indicator lights, 22 mm, round, plastic, green, lens, smooth, with holder, LED module, with integrated LED 230 V AC, screw terminal, IP69K	181,--	1	1 unit	41J

SIRIUS ACT - Komplette indikatorlamper - Kunststof - Skrueterminaler

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3SU1106-6AA50-1AA0 Indicator lights, 22 mm, round, plastic, blue, lens, smooth, with holder, LED module, with integrated LED 230 V AC, screw terminal, IP69K	181,--	1	1 unit	41J
	3SU1106-6AA60-1AA0 Indicator lights, 22 mm, round, plastic, white, lens, smooth, with holder, LED module, with integrated LED 230 V AC, screw terminal, IP69K	181,--	1	1 unit	41J

SIRIUS ACT - Komplette indikatorlamper - Kunststof - Fjederterminaler

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3SU1102-6AA20-3AA0 Indicator lights, 22 mm, round, plastic, red, lens, smooth, with holder, LED module, with integrated LED 24 V AC/DC, Spring-type terminal, IP69K	133,--	1	1 unit	41J
	3SU1102-6AA30-3AA0 Indicator lights, 22 mm, round, plastic, yellow, lens, smooth, with holder, LED module, with integrated LED 24 V AC/DC, Spring-type terminal, IP69K	133,--	1	1 unit	41J
	3SU1102-6AA40-3AA0 Indicator lights, 22 mm, round, plastic, green, lens, smooth, with holder, LED module, with integrated LED 24 V AC/DC, Spring-type terminal, IP69K	133,--	1	1 unit	41J
	3SU1102-6AA50-3AA0 Indicator lights, 22 mm, round, plastic, blue, lens, smooth, with holder, LED module, with integrated LED 24 V AC/DC, Spring-type terminal, IP69K	133,--	1	1 unit	41J
	3SU1102-6AA60-3AA0 Indicator lights, 22 mm, round, plastic, white, lens, smooth, with holder, LED module, with integrated LED 24 V AC/DC, Spring-type terminal, IP69K	133,--	1	1 unit	41J
	3SU1106-6AA20-3AA0 Indicator lights, 22 mm, round, plastic, red, lens, smooth, with holder, LED module, with integrated LED 230 V AC, Spring-type terminal, IP69K	197,--	1	1 unit	41J
	3SU1106-6AA30-3AA0 Indicator lights, 22 mm, round, plastic, yellow, lens, smooth, with holder, LED module, with integrated LED 230 V AC, Spring-type terminal, IP69K	197,--	1	1 unit	41J
	3SU1106-6AA40-3AA0 Indicator lights, 22 mm, round, plastic, green, lens, smooth, with holder, LED module, with integrated LED 230 V AC, Spring-type terminal, IP69K	197,--	1	1 unit	41J

SIRIUS ACT - Komplette indikatorlamper - Kunststof - Fjederterminaler

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3SU1106-6AA50-3AA0 Indicator lights, 22 mm, round, plastic, blue, lens, smooth, with holder, LED module, with integrated LED 230 V AC, Spring-type terminal, IP69K	197,--	1	1 unit	41J
	3SU1106-6AA60-3AA0 Indicator lights, 22 mm, round, plastic, white, lens, smooth, with holder, LED module, with integrated LED 230 V AC, Spring-type terminal, IP69K	197,--	1	1 unit	41J

SIRIUS ACT - Komplette drejeomskifter - Kunststof - Skrueterminaler

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3SU1100-2BF60-1BA0 Selector switch, illuminable, 22 mm, round, plastic, white, selector switch, short, 2 switch positions O-I, latching,10:30h/13:30h, with holder, 1NO, screw terminal, IP69K	162,--	1	1 unit	41J
	3SU1100-2BF60-1MA0 Selector switch, illuminable,22 mm, round, plastic, white, selector switch, short, 2 switch positions O-I, latching,10:30h/13:30h, with holder, 1NO, 1 NC, screw terminal, IP69K	189,--	1	1 unit	41J
	3SU1100-2BL60-1NA0 Selector switch, illuminable, 22 mm, round, plastic, white, selector switch, short, 3 switch positions I-O-II, latching, 10:30h/12h/13:30h, with holder, 1 NO, 1 NO, screw terminal, IP69K	209,--	1	1 unit	41J
	3SU1100-2BM60-1NA0 Selector switch, illuminable, 22 mm, round, plastic, white, selector switch, short, 3 switch positions I>O<II, momentary contact type,10:30h/12h/13:30h, with holder,1 NO, 1 NO, screw terminal, IP69K	209,--	1	1 unit	41J

SIRIUS ACT - Komplette drejeomskifter - Kunststof - Fjederterminaler

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3SU1100-2BF60-3BA0 Selector switch, illuminable, 22 mm, round, plastic, white, selector switch, short, 2 switch positions O-I, latching,10:30h/13:30h, with holder, 1NO, Spring-type terminal, IP69K	167,--	1	1 unit	41J
	3SU1100-2BF60-3MA0 Selector switch, illuminable, 22 mm, round, plastic, white, selector switch, short, 2 switch positions O-I, latching,10:30h/13:30h, with holder, 1NO, 1 NC, Spring-type terminal, IP69K	194,--	1	1 unit	41J
	3SU1100-2BL60-3NA0 Selector switch, illuminable, 22 mm, round, plastic, white, selector switch, short, 3 switch positions I-O-II, latching, 10:30h/12h/13:30h, with holder, 1 NO, 1 NO, Spring-type terminal, IP69K	221,--	1	1 unit	41J
	3SU1100-2BM60-3NA0 Selector switch, illuminable,22 mm, round, plastic, white, selector switch, short, 3 switch positions I>O<II, momentary contact type,10:30h/12h/13:30h, with holder,1 NO, 1 NO, Spring-type terminal, IP69K	221,--	1	1 unit	41J

SIRIUS ACT - Potentiometre - Kunststoff

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3SU1200-2PQ10-1AA0 Potentiometer, compact, 22 mm, round, plastic, black, 1kohm, with holder, screw terminal, IP69K	400,--	1	1 unit	41J
	3SU1200-2PR10-1AA0 Potentiometer, compact, 22 mm, round, plastic, black, 4.7kohm, with holder, screw terminal, IP69K	400,--	1	1 unit	41J
	3SU1200-2PS10-1AA0 Potentiometer, compact, 22 mm, round, plastic, black, 10kohm, with holder, screw terminal, IP69K	400,--	1	1 unit	41J
	3SU1200-2PT10-1AA0 Potentiometer, compact, 22 mm, round, plastic, black, 47kohm, with holder, screw terminal, IP69K	400,--	1	1 unit	41J
	3SU1200-2PU10-1AA0 Potentiometer, compact, 22 mm, round, plastic, black, 100kohm, with holder, screw terminal, IP69K	400,--	1	1 unit	41J
	3SU1200-2PV10-1AA0 Potentiometer, compact, 22 mm, round, plastic, black, 470kohm, with holder, screw terminal, IP69K	400,--	1	1 unit	41J
	3SU1200-2PW10-1AA0 Potentiometer, compact, 22 mm, round, plastic, black, 2.2kohm, with holder, screw terminal, IP69K	400,--	1	1 unit	41J

SIRIUS ACT - Komplette nødstopstryk - Kunststof - Skrueterminaler

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3SU1100-1BA20-1CA0 Mushroom pushbutton, 22 mm, round, plastic, red, 40 mm, latching, pull-to-unlatch mechanism, with holder, 1 NC, screw terminal, IP69K	245,--	1	1 unit	41J
	3SU1100-1HB20-1CF0 EMERGENCY STOP mushroom pushbutton, 22 mm, round, plastic, red, 40 mm, latching, positive latching, Rotate-to-unlatch, with yellow backing plate, without inscription, with holder, 1 NC, screw terminal, IP69K	256,--	1	1 unit	41J
	3SU1100-1HB20-1CG0 EMERGENCY STOP mushroom pushbutton, 22 mm, round, plastic, red, 40 mm, latching, positive latching, Rotate-to-unlatch, with yellow backing plate, inscription: EMERGENCY STOP, with holder, 1NC, screw terminal, IP69K	256,--	1	1 unit	41J
	3SU1100-1HB20-1FG0 EMERGENCY STOP mushroom pushbutton, 22 mm, round, plastic, red, 40 mm, latching, positive latching, Rotate-to-unlatch, with yellow backing plate, inscription: EMERGENCY STOP, with holder, 1NO+1 NC, screw terminal, IP69K	276,--	1	1 unit	41J
	3SU1100-1HB20-1PG0 EMERGENCY STOP mushroom pushbutton, 22 mm, round, plastic, red, 40 mm, latching, positive latching, Rotate-to-unlatch, with yellow backing plate, inscription: EMERGENCY STOP, with holder, 2NC, screw terminal, IP69K	338,--	1	1 unit	41J

SIRIUS ACT - Trykknaphoveder - Kunststof

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3SU1000-0AB10-0AA0 Pushbutton, 22 mm, round, plastic, black, pushbutton, flat, momentary contact type, IP69K	45,90	1	1 unit	41J
	3SU1000-0AB20-0AA0 Pushbutton, 22 mm, round, plastic, red, pushbutton, flat, momentary contact type, IP69K	45,90	1	1 unit	41J
	3SU1000-0AB30-0AA0 Pushbutton, 22 mm, round, plastic, yellow, pushbutton, flat, momentary contact type, IP69K	45,90	1	1 unit	41J
	3SU1000-0AB40-0AA0 Pushbutton, 22 mm, round, plastic, green, pushbutton, flat, momentary contact type, IP69K	45,90	1	1 unit	41J
	3SU1000-0AB50-0AA0 Pushbutton, 22 mm, round, plastic, blue, pushbutton, flat, momentary contact type, IP69K	45,90	1	1 unit	41J
	3SU1000-0AB60-0AA0 Pushbutton, 22 mm, round, plastic, white, push button, flat, momentary contact type, IP69K	45,90	1	1 unit	41J
	3SU1000-0BB10-0AA0 Pushbutton, 22 mm, round, plastic, black, pushbutton, raised, momentary contact type, IP69K	69,20	1	1 unit	41J
	3SU1000-0BB20-0AA0 Pushbutton, 22 mm, round, plastic, red, pushbutton, raised, momentary contact type, IP69K	69,20	1	1 unit	41J

SIRIUS ACT - Trykknaphoveder - Kunststof

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3SU1000-0BB30-0AA0 Pushbutton, 22 mm, round, plastic, yellow, pushbutton, raised, momentary contact type, IP69K	69,20	1	1 unit	41J
	3SU1000-0BB40-0AA0 Pushbutton, 22 mm, round, plastic, green, pushbutton, raised, momentary contact type, IP69K	69,20	1	1 unit	41J
	3SU1000-0BB50-0AA0 Pushbutton, 22 mm, round, plastic, blue, pushbutton, raised, momentary contact type, IP69K	69,20	1	1 unit	41J
	3SU1000-0BB60-0AA0 Pushbutton, 22 mm, round, plastic, white, pushbutton, raised, momentary contact type, IP69K	69,20	1	1 unit	41J
	3SU1000-0CB10-0AA0 Pushbutton, 22 mm, round, plastic, black, Front ring raised, momentary contact type, IP69K	65,10	1	1 unit	41J
	3SU1000-0CB20-0AA0 Pushbutton, 22 mm, round, plastic, red, Front ring raised, momentary contact type, IP69K	65,10	1	1 unit	41J
	3SU1000-0CB30-0AA0 Pushbutton, 22 mm, round, plastic, yellow, Front ring raised, momentary contact type, IP69K	65,10	1	1 unit	41J
	3SU1000-0CB40-0AA0 Pushbutton, 22 mm, round, plastic, green, Front ring raised, momentary contact type, IP69K	65,10	1	1 unit	41J

SIRIUS ACT - Trykknaphoveder - Kunststof

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3SU1000-0CB50-0AA0 Pushbutton, 22 mm, round, plastic, blue, Front ring raised, momentary contact type, IP69K	65,10	1	1 unit	41J
	3SU1000-0CB60-0AA0 Pushbutton, 22 mm, round, plastic, white, Front ring raised, momentary contact type, IP69K	65,10	1	1 unit	41J

SIRIUS ACT - Belyst trykknaphoveder - Kunststof

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3SU1001-0AB20-0AA0 Illuminated pushbutton, 22 mm, round, plastic, red, pushbutton, flat momentary contact type, IP69K	63,--	1	1 unit	41J
	3SU1001-0AB30-0AA0 Illuminated pushbutton, 22 mm, round, plastic, yellow, pushbutton, flat momentary contact type, IP69K	63,--	1	1 unit	41J
	3SU1001-0AB40-0AA0 Illuminated pushbutton, 22 mm, round, plastic, green, pushbutton, flat momentary contact type, IP69K	63,--	1	1 unit	41J
	3SU1001-0AB50-0AA0 Illuminated pushbutton, 22 mm, round, plastic, blue, pushbutton, flat momentary contact type, IP69K	63,--	1	1 unit	41J
	3SU1001-0AB60-0AA0 Illuminated pushbutton, 22 mm, round, plastic, white, pushbutton, flat momentary contact type, IP69K	63,--	1	1 unit	41J

SIRIUS ACT - Drejeomskifttere - Kunststof

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3SU1002-2BF10-0AA0 Illuminable selector switch, 22mm, round, plastic, black, selector switch short, 2 switch positions O-I, latching, actuating angle 90°,10:30h/13:30h, IP69K	98,20	1	1 unit	41J
	3SU1002-2BF20-0AA0 Selector switch, illuminable, 22 mm, round, plastic, red, selector switch, short, 2 switch positions O-I, latching, actuating angle 90°,10:30h/13:30h, IP69K	98,20	1	1 unit	41J
	3SU1002-2BF40-0AA0 Selector switch, illuminable, 22 mm, round, plastic, green, selector switch, short, 2 switch positions O-I, latching, actuating angle 90°,10:30h/13:30h, IP69K	98,20	1	1 unit	41J
	3SU1002-2BF60-0AA0 Selector switch, illuminable, 22 mm, round, plastic, white, selector switch, short, 2 switch positions O-I, latching, actuating angle 90°,10:30h/13:30h, IP69K	98,20	1	1 unit	41J
	3SU1002-2BL10-0AA0 Illuminable selector switch, 22mm, round, plastic, black, selector switch short, 3 switch positions I-O-II, latching, actuating angle 2x45°,10:30h/12h/13:30h, IP69K	98,20	1	1 unit	41J
	3SU1002-2BL20-0AA0 Selector switch, illuminable, 22 mm, round, plastic, red, selector switch, short, 3 switch positions I-O-II, latching, actuating angle 2x45°, 10:30h/12h/13:30h, IP69K	98,20	1	1 unit	41J
	3SU1002-2BL40-0AA0 Selector switch, illuminable, 22 mm, round, plastic, green, selector switch, short, 3 switch positions I-O-II, latching, actuating angle 2x45°, 10:30h/12h/13:30h, IP69K	98,20	1	1 unit	41J
	3SU1002-2BL60-0AA0 Selector switch, illuminable, 22 mm, round, plastic, white, selector switch, short, 3 switch positions I-O-II, latching, actuating angle 2x45°, 10:30h/12h/13:30h, IP69K	98,20	1	1 unit	41J

SIRIUS ACT - Drejeomskiftere - Kunststoff

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3SU1002-2BM10-0AA0 Illuminable selector switch, 22mm, round, plastic, black, selector switch short, 3 switch positions I>O<II, momentary contact type, actuating angle 2x45°, 10:30h/12h/13:30h, IP69K	98,20	1	1 unit	41J
	3SU1002-2BM20-0AA0 Selector switch, illuminable, 22 mm, round, plastic, red, selector switch, short, 3 switch positions I>O<II, momentary contact type, actuating angle 2x45°, 10:30h/12h/13:30h, IP69K	98,20	1	1 unit	41J
	3SU1002-2BM40-0AA0 Selector switch, illuminable, 22 mm, round, plastic, green, selector switch, short, 3 switch positions I>O<II, momentary contact type, actuating angle 2x45°, 10:30h/12h/13:30h, IP69K	98,20	1	1 unit	41J
	3SU1002-2BM60-0AA0 Selector switch, illuminable, 22 mm, round, plastic, white, selector switch, short, 3 switch positions I>O<II, momentary contact type, actuating angle 2x45°, 10:30h/12h/13:30h, IP69K	98,20	1	1 unit	41J
	3SU1002-2BN10-0AA0 Illuminable selector switch, 22mm, round, plastic, black, selector switch short, 3 switch positions I-O<II, left latching, right momentary contact type, actuating angle 2x45°, 10:30h/12h/13:30h, IP69K	99,10	1	1 unit	41J
	3SU1002-2BN20-0AA0 Selector switch, illuminable, 22 mm, round, plastic, red, selector switch, short, 3 switch positions I-O<II, left latching, right momentary contact type, actuating angle 2x45°, 10:30h/12h/13:30h, IP69K	99,10	1	1 unit	41J
	3SU1002-2BN40-0AA0 Selector switch, illuminable, 22 mm, round, plastic, green, selector switch, short, 3 switch positions I-O<II, left latching, right momentary contact type, actuating angle 2x45°, 10:30h/12h/13:30h, IP69K	99,10	1	1 unit	41J
	3SU1002-2BN60-0AA0 Selector switch, illuminable, 22 mm, round, plastic, white, selector switch, short, 3 switch positions I-O<II, left latching, right momentary contact type, actuating angle 2x45°, 10:30h/12h/13:30h, IP69K	99,10	1	1 unit	41J

SIRIUS ACT - Drejeomskiftere - Kunststof

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3SU1002-2BP10-0AA0 Illuminable selector switch, 22mm, round, plastic, black, selector switch short, 3 switch positions I>O-II, momentary contact on the left, latching on the right, actuating angle 2x45°, 10:30h/12h/13:30h, IP69K	99,10	1	1 unit	41J
	3SU1002-2BP20-0AA0 Selector switch, illuminable, 22 mm, round, plastic, red, selector switch, short, 3 switch positions I>O-II, momentary contact on the left, latching on the right, actuating angle 2x45°, 10:30h/12h/13:30h, IP69K	99,10	1	1 unit	41J
	3SU1002-2BP40-0AA0 Selector switch, illuminable, 22 mm, round, plastic, green, selector switch, short, 3 switch positions I>O-II, momentary contact on the left, latching on the right, actuating angle 2x45°, 10:30h/12h/13:30h, IP69K	99,10	1	1 unit	41J
	3SU1002-2BP60-0AA0 Selector switch, illuminable, 22 mm, round, plastic, white, selector switch, short, 3 switch positions I>O-II, momentary contact on the left, latching on the right, actuating angle 2x45°, 10:30h/12h/13:30h, IP69K	99,10	1	1 unit	41J

SIRIUS ACT - Lampehoveder - Kunststof

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3SU1001-6AA00-0AA0 Indicator lights, 22 mm, round, plastic, amber, lens, smooth, IP69K	36,60	1	1 unit	41J
	3SU1001-6AA20-0AA0 Indicator lights, 22 mm, round, plastic, red, lens, smooth, IP69K	36,60	1	1 unit	41J
	3SU1001-6AA30-0AA0 Indicator lights, 22 mm, round, plastic, yellow, lens, smooth, IP69K	36,60	1	1 unit	41J
	3SU1001-6AA40-0AA0 Indicator lights, 22 mm, round, plastic, green, lens, smooth, IP69K	36,60	1	1 unit	41J
	3SU1001-6AA50-0AA0 Indicator lights, 22 mm, round, plastic, blue, lens, smooth, IP69K	36,60	1	1 unit	41J
	3SU1001-6AA60-0AA0 Indicator lights, 22 mm, round, plastic, white, lens, smooth, IP69K	36,60	1	1 unit	41J

SIRIUS ACT - Nødstopstryk - Kunststof

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3SU1000-1HA20-0AA0 EMERGENCY STOP mushroom pushbutton, 22 mm, round, plastic, red, 40 mm, positive latching, Pull-to-unlatch mechanism, IP69K	191,--	1	1 unit	41J
	3SU1000-1HB20-0AA0 EMERGENCY STOP mushroom pushbutton, 22 mm, round, plastic, red, 40 mm, positive latching, Rotate-to-unlatch, IP69K	191,--	1	1 unit	41J
	3SU1000-1JB20-0AA0 EMERGENCY STOP mushroom pushbutton, 22 mm, round, plastic, red, 60 mm, positive latching, Rotate-to-unlatch, IP69K	215,--	1	1 unit	41J
	3SU1001-1HB20-0AA0 EMERGENCY STOP mushroom pushbutton, illuminable, 22 mm, round, plastic, red, 40 mm, positive latching, Rotate-to-unlatch, IP69K	200,--	1	1 unit	41J

SIRIUS ACT - Komplette trykknapper - Metal - Skrueterminaler

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3SU1150-0AB10-1BA0 Pushbutton, 22 mm, round, metal, shiny, black, pushbutton, flat, momentary contact type, with holder, 1NO, screw terminal, IP69K	127,--	1	1 unit	41J
	3SU1150-0AB10-1CA0 Pushbutton, 22 mm, round, metal, shiny, black, pushbutton, flat, momentary contact type, with holder, 1NC, screw terminal, IP69K	127,--	1	1 unit	41J
	3SU1150-0AB20-1BA0 Pushbutton, 22 mm, round, metal, shiny, red, pushbutton, flat, momentary contact type, with holder, 1 NO, screw terminal, IP69K	127,--	1	1 unit	41J
	3SU1150-0AB20-1CA0 Pushbutton, 22 mm, round, metal, shiny, red, pushbutton, flat, momentary contact type, with holder, 1 NC, screw terminal, IP69K	127,--	1	1 unit	41J
	3SU1150-0AB40-1BA0 Pushbutton, 22 mm, round, metal, shiny, green, pushbutton, flat, momentary contact type, 1 NO, screw terminal, IP69K	127,--	1	1 unit	41J
	3SU1150-0AB50-1BA0 Pushbutton, 22 mm, round, metal, shiny, blue, pushbutton, flat, momentary contact type, 1NO, screw terminal, IP69K	127,--	1	1 unit	41J
	3SU1150-0AB60-1BA0 Pushbutton, 22 mm, round, metal, shiny, white, pushbutton, flat, momentary contact type, 1 NO, screw terminal, IP69K	127,--	1	1 unit	41J
	3SU1152-0AB20-1CA0 Illuminated pushbutton, 22 mm, round, metal, shiny, red, pushbutton, flat, momentary contact type, with holder, 1NC, LED module with integrated LED 24 V AC/DC, screw terminal, IP69K	210,--	1	1 unit	41J

SIRIUS ACT - Komplette trykknapper - Metal - Skrueterminaler

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3SU1152-0AB30-1BA0 Illuminated pushbutton, 22 mm, round, metal, shiny, yellow, pushbutton, flat, momentary contact type, with holder, 1NO, LED module with integrated LED 24 V AC/DC, screw terminal, IP69K	210,--	1	1 unit	41J
	3SU1152-0AB40-1BA0 Illuminated pushbutton, 22 mm, round, metal, shiny, green, pushbutton, flat, momentary contact type, with holder, 1NO, LED module with integrated LED 24 V AC/DC, screw terminal, IP69K	210,--	1	1 unit	41J
	3SU1152-0AB50-1BA0 Illuminated pushbutton, 22 mm, round, metal, shiny, blue, pushbutton, flat, momentary contact type, with holder, 1NO, LED module with integrated LED 24 V AC/DC, screw terminal, IP69K	210,--	1	1 unit	41J
	3SU1152-0AB60-1BA0 Illuminated pushbutton, 22 mm, round, metal, shiny, white, pushbutton, flat, momentary contact type, with holder, 1NO, LED module with integrated LED 24 V AC/DC, screw terminal, IP69K	210,--	1	1 unit	41J
	3SU1156-0AB20-1CA0 Illuminated pushbutton, 22 mm, round, metal, shiny, red, pushbutton, flat, momentary contact type, with holder, 1NC, LED module with integrated LED 230 V AC, screw terminal, IP69K	265,--	1	1 unit	41J
	3SU1156-0AB30-1BA0 Illuminated pushbutton, 22 mm, round, metal, shiny, yellow, pushbutton, flat, momentary contact type, with holder, 1NO, LED module with integrated LED 230 V AC, screw terminal, IP69K	265,--	1	1 unit	41J
	3SU1156-0AB40-1BA0 Illuminated pushbutton, 22 mm, round, metal, shiny, green, pushbutton, flat, momentary contact type, with holder, 1NO, LED module with integrated LED 230 V AC, screw terminal, IP69K	265,--	1	1 unit	41J
	3SU1156-0AB50-1BA0 Illuminated pushbutton, 22 mm, round, metal, shiny, blue, pushbutton, flat, momentary contact type, with holder, 1NO, LED module with integrated LED 230 V AC, screw terminal, IP69K	265,--	1	1 unit	41J

SIRIUS ACT - Komplette trykknapper - Metal - Skrueterminaler

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3SU1156-0AB60-1BA0 Illuminated pushbutton, 22 mm, round, metal, shiny, white, pushbutton, flat, momentary contact type, with holder, 1NO, LED module with integrated LED 230 V AC, screw terminal, IP69K	265,--	1	1 unit	41J

SIRIUS ACT - Komplette trykknapper - Metal - Fjederterminaler

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3SU1150-0AB10-3BA0 Pushbutton, 22 mm, round, metal, shiny, black, pushbutton, flat, momentary contact type, 1 NO, Spring-type terminal, IP69K	133,--	1	1 unit	41J
	3SU1150-0AB10-3CA0 Pushbutton, 22 mm, round, metal, shiny, black, pushbutton, flat, momentary contact type, 1 NC, Spring-type terminal, IP69K	133,--	1	1 unit	41J
	3SU1150-0AB20-3CA0 Pushbutton, 22 mm, round, metal, shiny, red, push button, flat, momentary contact type, 1 NC, Spring-type terminal, IP69K	133,--	1	1 unit	41J
	3SU1150-0AB40-3BA0 Pushbutton, 22 mm, round, metal, shiny, green, pushbutton, flat, momentary contact type, 1 NO, Spring-type terminal, IP69K	133,--	1	1 unit	41J
	3SU1150-0AB50-3BA0 Pushbutton, 22 mm, round, metal, shiny, blue, push button, flat, momentary contact type, 1NO, Spring-type terminal, IP69K	133,--	1	1 unit	41J
	3SU1150-0AB60-3BA0 Pushbutton, 22 mm, round, metal, shiny, white, pushbutton, flat, momentary contact type, 1NO, Spring-type terminal, IP69K	133,--	1	1 unit	41J
	3SU1152-0AB20-3CA0 Illuminated pushbutton, 22 mm, round, metal, shiny, red, pushbutton, flat, momentary contact type, 1NC, LED module with integrated LED 24 V AC/DC, Spring-type terminal, IP69K	224,--	1	1 unit	41J
	3SU1152-0AB30-3BA0 Illuminated pushbutton, 22 mm, round, metal, shiny, yellow, pushbutton, flat, momentary contact type, 1NO, LED module with integrated LED 24 V AC/DC, Spring-type terminal, IP69K	224,--	1	1 unit	41J

SIRIUS ACT - Komplette trykknapper - Metal - Fjederterminaler

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3SU1152-0AB40-3BA0 Illuminated pushbutton, 22 mm, round, metal, shiny, green, pushbutton, flat, momentary contact type, 1NO, LED module with integrated LED 24 V AC/DC, Spring-type terminal, IP69K	224,--	1	1 unit	41J
	3SU1152-0AB50-3BA0 Illuminated pushbutton, 22 mm, round, metal, shiny, blue, pushbutton, flat, momentary contact type, 1NO, LED module with integrated LED 24 V AC/DC, Spring-type terminal, IP69K	224,--	1	1 unit	41J
	3SU1152-0AB60-3BA0 Illuminated pushbutton, 22 mm, round, metal, shiny, white, pushbutton, flat, momentary contact type, 1NO, LED module with integrated LED 24 V AC/DC, Spring-type terminal, IP69K	224,--	1	1 unit	41J
	3SU1156-0AB20-3CA0 Illuminated pushbutton, 22 mm, round, metal, shiny, red, pushbutton, flat, momentary contact type, 1NC, LED module with integrated LED 230 V AC, Spring-type terminal, IP69K	289,--	1	1 unit	41J
	3SU1156-0AB30-3FA0 Illuminated pushbutton, 22 mm, round, metal, shiny, yellow, pushbutton, flat, momentary contact type, 1NO+1 NC, LED module with integrated LED 230 V AC, Spring-type terminal, IP69K	319,--	1	1 unit	41J
	3SU1156-0AB40-3BA0 Illuminated pushbutton, 22 mm, round, metal, shiny, green, pushbutton, flat, momentary contact type, 1NO, LED module with integrated LED 230 V AC, Spring-type terminal, IP69K	289,--	1	1 unit	41J
	3SU1156-0AB50-3FA0 Illuminated pushbutton, 22 mm, round, metal, shiny, blue, pushbutton, flat, momentary contact type, with holder, 1NO+1 NC, LED module with integrated LED 230 V AC, Spring-type terminal, IP69K	319,--	1	1 unit	41J
	3SU1156-0AB60-3BA0 Illuminated pushbutton, 22 mm, round, metal, shiny, white, pushbutton, flat, momentary contact type, with holder, 1NO, LED module with integrated LED 230 V AC, Spring-type terminal, IP69K	289,--	1	1 unit	41J

SIRUIS ACT - Komplette indikatorlamper - Metal - Skrueterminaler

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3SU1152-6AA20-1AA0 Indicator lights, 22 mm, round, metal, shiny, red, lens, smooth, with holder, LED module with integrated LED 24 V AC/DC, screw terminal, IP69K	135,--	1	1 unit	41J
	3SU1152-6AA30-1AA0 Indicator lights, 22 mm, round, metal, shiny, yellow, lens, smooth, with holder, LED module with integrated LED 24 V AC/DC, screw terminal, IP69K	135,--	1	1 unit	41J
	3SU1152-6AA40-1AA0 Indicator lights, 22 mm, round, metal, shiny, green, lens, smooth, with holder, LED module with integrated LED 24 V AC/DC, screw terminal, IP69K	135,--	1	1 unit	41J
	3SU1152-6AA50-1AA0 Indicator lights, 22 mm, round, metal, shiny, blue, lens, smooth, with holder, LED module with integrated LED 24 V AC/DC, screw terminal, IP69K	135,--	1	1 unit	41J
	3SU1152-6AA60-1AA0 Indicator lights, 22 mm, round, metal, shiny, white, lens, smooth, with holder, LED module with integrated LED 24 V AC/DC, screw terminal, IP69K	135,--	1	1 unit	41J
	3SU1156-6AA20-1AA0 Indicator lights, 22 mm, round, metal, shiny, red, lens, smooth, with holder, LED module with integrated LED 230 V AC, screw terminal, IP69K	190,--	1	1 unit	41J
	3SU1156-6AA30-1AA0 Indicator lights, 22 mm, round, metal, shiny, yellow, lens, smooth, with holder, LED module with integrated LED 230 V AC, screw terminal, IP69K	190,--	1	1 unit	41J
	3SU1156-6AA40-1AA0 Indicator lights, 22 mm, round, metal, shiny, green, lens, smooth, with holder, LED module with integrated LED 230 V AC, screw terminal, IP69K	190,--	1	1 unit	41J

SIRUIS ACT - Komplette indikatorlamper - Metal - Skrueterminaler

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3SU1156-6AA50-1AA0 Indicator lights, 22 mm, round, metal, shiny, blue, lens, smooth, with holder, LED module with integrated LED 230 V AC, screw terminal, IP69K	190,--	1	1 unit	41J
	3SU1156-6AA60-1AA0 Indicator lights, 22 mm, round, metal, shiny, white, lens, smooth, with holder, LED module with integrated LED 230 V AC, screw terminal, IP69K	190,--	1	1 unit	41J

SIRUIS ACT - Komplette indikatorlamper - Metal - Fjederterminaler

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3SU1152-6AA20-3AA0 Indicator lights, 22 mm, round, metal, shiny, red, lens, smooth, with holder, LED module with integrated LED 24 V AC/DC, Spring-type terminal, IP69K	143,--	1	1 unit	41J
	3SU1152-6AA30-3AA0 Indicator lights, 22 mm, round, metal, shiny, yellow, lens, smooth, with holder, LED module with integrated LED 24 V AC/DC, Spring-type terminal, IP69K	143,--	1	1 unit	41J
	3SU1152-6AA40-3AA0 Indicator lights, 22 mm, round, metal, shiny, green, lens, smooth, with holder, LED module with integrated LED 24 V AC/DC, Spring-type terminal, IP69K	143,--	1	1 unit	41J
	3SU1152-6AA50-3AA0 Indicator lights, 22 mm, round, metal, shiny, blue, lens, smooth, with holder, LED module with integrated LED 24 V AC/DC, Spring-type terminal, IP69K	143,--	1	1 unit	41J
	3SU1152-6AA60-3AA0 Indicator lights, 22 mm, round, metal, shiny, white, lens, smooth, with holder, LED module with integrated LED 24 V AC/DC, Spring-type terminal, IP69K	143,--	1	1 unit	41J
	3SU1156-6AA20-3AA0 Indicator lights, 22 mm, round, metal, shiny, red, lens, smooth, with holder, LED module with integrated LED 230 V AC, Spring-type terminal, IP69K	207,--	1	1 unit	41J
	3SU1156-6AA30-3AA0 Indicator lights, 22 mm, round, metal, shiny, yellow, lens, smooth, with holder, LED module with integrated LED 230 V AC, Spring-type terminal, IP69K	207,--	1	1 unit	41J
	3SU1156-6AA40-3AA0 Indicator lights, 22 mm, round, metal, shiny, green, lens, smooth, with holder, LED module with integrated LED 230 V AC, Spring-type terminal, IP69K	207,--	1	1 unit	41J

SIRUIS ACT - Komplette indikatorlamper - Metal - Fjederterminaler

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3SU1156-6AA50-3AA0 Indicator lights, 22 mm, round, metal, shiny, blue, lens, smooth, with holder, LED module with integrated LED 230 V AC, Spring-type terminal, IP69K	207,--	1	1 unit	41J
	3SU1156-6AA60-3AA0 Indicator lights, 22 mm, round, metal, shiny, white, lens, smooth, with holder, LED module with integrated LED 230 V AC, Spring-type terminal, IP69K	207,--	1	1 unit	41J

SIRUIS ACT - Komplette drejeomskiftere - Metal - Skrueterminaler

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3SU1150-2BF60-1BA0 Selector switch, illuminable, 22 mm, round, metal, shiny, white, selector switch, short, 2 switch positions O-I, latching, actuating angle 90°,10:30h/13:30h, with holder, 1NO, screw terminal, IP69K	177,--	1	1 unit	41J
	3SU1150-2BF60-1MA0 Selector switch, illuminable, 22 mm, round, metal, shiny, white, selector switch, short, 2 switch positions O-I, latching, actuating angle 90°,10:30h/13:30h, with holder, 1NO, 1 NC, screw terminal, IP69K	208,--	1	1 unit	41J
	3SU1150-2BM60-1NA0 Selector switch, illuminable, 22 mm, round, metal, shiny, white, selector switch, short, 3 switch positions I>O<II, momentary contact type, actuating angle 2x45°,10:30h/12h/13:30h, with holder, 1 NO, 1 NO, screw terminal, IP69K	224,--	1	1 unit	41J
	3SU1150-2BL60-1NA0 Selector switch, illuminable, 22 mm, round, metal, shiny, white, selector switch, short, 3 switch positions I-O-II, latching, actuating angle 2x45°, 10:30h/12h/13:30h, with holder, 1 NO, 1 NO, screw terminal, IP69K	224,--	1	1 unit	41J

SIRUIS ACT - Komplette drejeomskiftere - Metal - Fjederterminaler

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3SU1150-2BF60-3BA0 Selector switch, illuminable, 22 mm, round, metal, shiny, white, selector switch, short, 2 switch positions O-I, latching, actuating angle 90°,10:30h/13:30h, with holder, 1NO, Spring-type terminal, IP69K	184,--	1	1 unit	41J
	3SU1150-2BF60-3MA0 Selector switch, illuminable, 22 mm, round, metal, shiny, white, selector switch, short, 2 switch positions O-I, latching, actuating angle 90°,10:30h/13:30h, with holder, 1NO, 1 NC, Spring-type terminal, IP69K	204,--	1	1 unit	41J
	3SU1150-2BM60-3NA0 Selector switch, illuminable, 22 mm, round, metal, shiny, white, selector switch, short, 3 switch positions I>O<II, momentary contact type, actuating angle 2x45°,10:30h/12h/13:30h, with holder, 1 NO, 1 NO, Spring-type terminal, IP69K	235,--	1	1 unit	41J
	3SU1150-2BL60-3NA0 Selector switch, illuminable, 22 mm, round, metal, shiny, white, selector switch, short, 3 switch positions I-O-II, latching, actuating angle 2x45°, 10:30h/12h/13:30h, with holder, 1 NO, 1 NO, Spring-type terminal, IP69K	235,--	1	1 unit	41J

SIRUIS ACT - Potentiometre - Metal

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3SU1250-2PQ10-1AA0 Potentiometer, compact, 22 mm, round, metal, black, 1k ohm, with holder, screw terminal, IP69K	445,--	1	1 unit	41J
	3SU1250-2PR10-1AA0 Potentiometer, compact, 22 mm, round, metal, black, 4.7k ohm, with holder, screw terminal, IP69K	445,--	1	1 unit	41J
	3SU1250-2PS10-1AA0 Potentiometer, compact, 22 mm, round, metal, black, 10k ohm, with holder, screw terminal, IP69K	445,--	1	1 unit	41J
	3SU1250-2PT10-1AA0 Potentiometer, compact, 22 mm, round, metal, black, 47k ohm, with holder, screw terminal, IP69K	445,--	1	1 unit	41J
	3SU1250-2PU10-1AA0 Potentiometer, compact, 22 mm, round, metal, black, 100k ohm, with holder, screw terminal, IP69K	445,--	1	1 unit	41J
	3SU1250-2PV10-1AA0 Potentiometer, compact, 22 mm, round, metal, black, 470k ohm, with holder, screw terminal, IP69K	445,--	1	1 unit	41J

SIRUIS ACT - Komplette nødstopstryk - Metal - Skrueterminaler

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3SU1150-1BA20-1CA0 Mushroom pushbutton, 22 mm, round, metal, shiny, red, 40mm, latching, pull-to-unlatch mechanism, with holder, 1 NC, screw terminal, IP69K	266,--	1	1 unit	41J
	3SU1150-1HA20-1CG0 EMERGENCY STOP mushroom pushbutton, 22 mm, round, metal, shiny, red, 40 mm, latching, pull-to-unlatch mechanism, with yellow backing plate, inscription: EMERGENCYSTOP, with holder, 1 NC, screw terminal, IP69K	277,--	1	1 unit	41J
	3SU1150-1HB20-1CG0 EMERGENCY STOP mushroom pushbutton, 22 mm, round, metal, shiny, red, 40 mm, latching, Rotate-to-unlatch, with yellow backing plate, inscription: EMERGENCY STOP, with holder, 1 NC, screw terminal, IP69K	277,--	1	1 unit	41J

SIRUIS ACT - Trykknaphoveder - Metal

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3SU1050-0AB10-0AA0 Pushbutton, 22 mm, round, metal, shiny, black, pushbutton, flat momentary contact type, IP69K	59,--	1	1 unit	41J
	3SU1050-0AB20-0AA0 Pushbutton, 22 mm, round, metal, shiny, red, pushbutton, flat momentary contact type, IP69K	59,--	1	1 unit	41J
	3SU1050-0AB30-0AA0 Pushbutton, 22 mm, round, metal, shiny, yellow, pushbutton, flat momentary contact type, IP69K	59,--	1	1 unit	41J
	3SU1050-0AB40-0AA0 Pushbutton, 22 mm, round, metal, shiny, green, pushbutton, flat momentary contact type, IP69K	59,--	1	1 unit	41J
	3SU1050-0AB50-0AA0 Pushbutton, 22 mm, round, metal, shiny, blue, pushbutton, flat momentary contact type, IP69K	59,--	1	1 unit	41J
	3SU1050-0AB60-0AA0 Pushbutton, 22 mm, round, metal, shiny, white, pushbutton, flat momentary contact type, IP69K	59,--	1	1 unit	41J
	3SU1050-0BB10-0AA0 Pushbutton, 22 mm, round, metal, shiny, black, pushbutton, raised momentary contact type, IP69K	76,30	1	1 unit	41J
	3SU1050-0BB20-0AA0 Pushbutton, 22 mm, round, metal, shiny, red, pushbutton, raised momentary contact type, IP69K	76,30	1	1 unit	41J

SIRUIS ACT - Trykknaphoveder - Metal

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3SU1050-0BB30-0AA0 Pushbutton, 22 mm, round, metal, shiny, yellow, pushbutton, raised momentary contact type, IP69K	76,30	1	1 unit	41J
	3SU1050-0BB40-0AA0 Pushbutton, 22 mm, round, metal, shiny, green, pushbutton, raised momentary contact type, IP69K	76,30	1	1 unit	41J
	3SU1050-0BB50-0AA0 Pushbutton, 22 mm, round, metal, shiny, blue, pushbutton, raised momentary contact type, IP69K	76,30	1	1 unit	41J
	3SU1050-0BB60-0AA0 Pushbutton, 22 mm, round, metal, shiny, white, pushbutton, raised momentary contact type, IP69K	76,30	1	1 unit	41J
	3SU1050-0CB10-0AA0 Pushbutton, 22 mm, round, metal, shiny, black, Front ring, raised momentary contact type, IP69K	72,30	1	1 unit	41J
	3SU1050-0CB20-0AA0 Pushbutton, 22 mm, round, metal, shiny, red, Front ring, raised, momentary contact type, IP69K	72,30	1	1 unit	41J
	3SU1050-0CB30-0AA0 Pushbutton, 22 mm, round, metal, shiny, yellow, Front ring, raised, momentary contact type, IP69K	72,30	1	1 unit	41J
	3SU1050-0CB40-0AA0 Pushbutton, 22 mm, round, metal, shiny, green, Front ring, raised, momentary contact type, IP69K	72,30	1	1 unit	41J

SIRUIS ACT - Trykknaphoveder - Metal

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3SU1050-0CB50-0AA0 Pushbutton, 22 mm, round, metal, shiny, blue, Front ring, raised, momentary contact type, IP69K	72,30	1	1 unit	41J
	3SU1050-0CB60-0AA0 Pushbutton, 22 mm, round, metal, shiny, white, Front ring, raised, momentary contact type, IP69K	72,30	1	1 unit	41J

SIRUIS ACT - Belyst trykknaphoveder - Metal

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3SU1051-0AB20-0AA0 Illuminated pushbutton, 22 mm, round, metal, shiny, red, pushbutton, flat, momentary contact type, IP69K	71,20	1	1 unit	41J
	3SU1051-0AB30-0AA0 Illuminated pushbutton, 22 mm, round, metal, shiny, yellow, pushbutton, flat, momentary contact type, IP69K	71,20	1	1 unit	41J
	3SU1051-0AB40-0AA0 Illuminated pushbutton, 22 mm, round, metal, shiny, green, pushbutton, flat, momentary contact type, IP69K	71,20	1	1 unit	41J
	3SU1051-0AB50-0AA0 Illuminated pushbutton, 22 mm, round, metal, shiny, blue, pushbutton, flat, momentary contact type, IP69K	71,20	1	1 unit	41J
	3SU1051-0AB60-0AA0 Illuminated pushbutton, 22 mm, round, metal, shiny, white, pushbutton, flat, momentary contact type, IP69K	71,20	1	1 unit	41J

SIRIUS ACT - Drejeomskiftere - Metal

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3SU1052-2BF10-0AA0 Illuminable selector switch, 22 mm, round, metal, shiny, black, selector switch short, 2 switch positions O-I, latching, actuating angle 90°, 10:30h/13:30h, IP69K	109,--	1	1 unit	41J
	3SU1052-2BF20-0AA0 Selector switch, illuminable, 22 mm, round, metal, shiny, red, selector switch, short, 2 switch positions O-I, latching, actuating angle 90°, 10:30h/13:30h, IP69K	109,--	1	1 unit	41J
	3SU1052-2BF40-0AA0 Selector switch, illuminable, 22 mm, round, metal, shiny, green, selector switch, short, 2 switch positions O-I, latching, actuating angle 90°, 10:30h/13:30h, IP69K	109,--	1	1 unit	41J
	3SU1052-2BF60-0AA0 Selector switch, illuminable, 22 mm, round, metal, shiny, white, selector switch, short, 2 switch positions O-I, latching, actuating angle 90°, 10:30h/13:30h, IP69K	109,--	1	1 unit	41J
	3SU1052-2BL10-0AA0 Illuminable selector switch, 22 mm, round, metal, shiny, black, selector switch short, 3 switch positions I-O-II, latching, actuating angle 2x45°, 10:30h/12h/13:30h, IP69K	109,--	1	1 unit	41J
	3SU1052-2BL20-0AA0 Selector switch, illuminable, 22 mm, round, metal, shiny, red, selector switch, short, 3 switch positions I-O-II, latching, actuating angle 2x45°, 10:30h/12h/13:30h, IP69K	109,--	1	1 unit	41J
	3SU1052-2BL40-0AA0 Selector switch, illuminable, 22 mm, round, metal, shiny, green, selector switch, short, 3 switch positions I-O-II, latching, actuating angle 2x45°, 10:30h/12h/13:30h, IP69K	109,--	1	1 unit	41J
	3SU1052-2BL60-0AA0 Selector switch, illuminable, 22 mm, round, metal, shiny, white, selector switch, short, 3 switch positions I-O-II, latching, actuating angle 2x45°, 10:30h/12h/13:30h, IP69K	109,--	1	1 unit	41J

SIRIUS ACT - Drejeomskiftere - Metal

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3SU1052-2BP10-0AA0 Illuminable selector switch, 22 mm, round, metal shiny, black, selector switch short, 3 switch positions I>O-II, momentary contact on the left, latching on the right, actuating angle 2x45°, 10:30h/12h/13:30h, IP69K	111,--	1	1 unit	41J
	3SU1052-2BP20-0AA0 Selector switch, illuminable, 22 mm, round, metal, shiny, red, selector switch, short, 3 switch positions I>O-II, momentary contact on the left, latching on the right, actuating angle 2x45°, 10:30h/12h/13:30h, IP69K	111,--	1	1 unit	41J
	3SU1052-2BP40-0AA0 Selector switch, illuminable, 22 mm, round, metal, shiny, green, selector switch, short, 3 switch positions I>O-II, momentary contact on the left, latching on the right, actuating angle 2x45°, 10:30h/12h/13:30h, IP69K	111,--	1	1 unit	41J
	3SU1052-2BP60-0AA0 Selector switch, illuminable, 22 mm, round, metal, shiny, white, selector switch, short, 3 switch positions I>O<II, momentary contact on the left, latching on the right, actuating angle 2x45°, 10:30h/12h/13:30h, IP69K	111,--	1	1 unit	41J
	3SU1052-2BN10-0AA0 Illuminable selector switch, 22 mm, round, metal, shiny, black, selector switch short, 3 switch positions I-O<II, left latching, right momentary contact type, actuating angle 2x45°, 10:30h/12h/13:30h, IP69K	111,--	1	1 unit	41J
	3SU1052-2BN20-0AA0 Selector switch, illuminable, 22 mm, round, metal, shiny, red, selector switch, short, 3 switch positions I-O<II, left latching, right momentary contact type, actuating angle 2x45°, 10:30h/12h/13:30h, IP69K	111,--	1	1 unit	41J
	3SU1052-2BN40-0AA0 Selector switch, illuminable, 22 mm, round, metal, shiny, green, selector switch, short, 3 switch positions I-O<II, left latching, right momentary contact type, actuating angle 2x45°, 10:30h/12h/13:30h, IP69K	111,--	1	1 unit	41J
	3SU1052-2BN60-0AA0 Selector switch, illuminable, 22 mm, round, metal, shiny, white, selector switch, short, 3 switch positions I-O<II, left latching, right momentary contact type, actuating angle 2x45°, 10:30h/12h/13:30h, IP69K	111,--	1	1 unit	41J

SIRIUS ACT - Drejeomskiftere - Metal

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3SU1052-2BM10-0AA0 Illuminable selector switch, 22 mm, round, metal, shiny, black, selector switch short, 3 switch positions I>O<II, momentary contact type, actuating angle 2x45°, 10:30h/12h/13:30h, IP69K	109,--	1	1 unit	41J
	3SU1052-2BM20-0AA0 Selector switch, illuminable, 22 mm, round, metal, shiny, red, selector switch, short, 3 switch positions I>O<II, momentary contact type, actuating angle 2x45°, 10:30h/12h/13:30h, IP69K	109,--	1	1 unit	41J
	3SU1052-2BM40-0AA0 Selector switch, illuminable, 22 mm, round, metal, shiny, green, selector switch, short, 3 switch positions I>O<II, momentary contact type, actuating angle 2x45°, 10:30h/12h/13:30h, IP69K	109,--	1	1 unit	41J
	3SU1052-2BM60-0AA0 Selector switch, illuminable, 22 mm, round, metal, shiny, white, selector switch, short, 3 switch positions I>O<II, momentary contact type, actuating angle 2x45°, 10:30h/12h/13:30h, IP69K	109,--	1	1 unit	41J

SIRIUS ACT - Lampehoveder - Metal

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3SU1051-6AA00-0AA0 Indicator lights, 22 mm, round, metal, shiny, amber, lens, smooth, IP69K	42,70	1	1 unit	41J
	3SU1051-6AA20-0AA0 Indicator lights, 22 mm, round, metal, shiny, red, lens, smooth, IP69K	42,70	1	1 unit	41J
	3SU1051-6AA30-0AA0 Indicator lights, 22 mm, round, metal, shiny, yellow, lens, smooth, IP69K	42,70	1	1 unit	41J
	3SU1051-6AA40-0AA0 Indicator lights, 22 mm, round, metal, shiny, green, lens, smooth, IP69K	42,70	1	1 unit	41J
	3SU1051-6AA50-0AA0 Indicator lights, 22 mm, round, metal, shiny, blue, lens, smooth, IP69K	42,70	1	1 unit	41J
	3SU1051-6AA60-0AA0 Indicator lights, 22 mm, round, metal, shiny, white, lens, smooth, IP69K	42,70	1	1 unit	41J

SIRIUS ACT - Nødstopstryk - Metal

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3SU1050-1HA20-0AA0 EMERGENCY STOP mushroom pushbutton, 22 mm, round, metal, shiny, red, 40 mm, positive latching, Pull-to-unlatch mechanism, IP69K	210,--	1	1 unit	41J
	3SU1050-1HB20-0AA0 EMERGENCY STOP mushroom pushbutton, 22 mm, round, metal, shiny, red, 40 mm, positive latching, Rotate-to-unlatch, IP69K	210,--	1	1 unit	41J
	3SU1050-1JB20-0AA0 EMERGENCY STOP mushroom pushbutton, 22 mm, round, metal, shiny, red, 60 mm, positive latching, Rotate-to-unlatch, IP69K	233,--	1	1 unit	41J
	3SU1051-1HB20-0AA0 EMERGENCY STOP mushroom pushbutton, illuminable, 22 mm, round, metal, shiny, red, 40mm, positive latching, Rotate-to-unlatch, IP69K	233,--	1	1 unit	41J

SIRIUS ACT - Holdere og kontakteleementer

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3SU1500-0AA10-0AA0 Holder for 3 modules, kunststof	17,90	1	1 unit	41J
	3SU1550-0AA10-0AA0 Holder for 3 modules, metal	20,--	1	1 unit	41J
	3SU1400-1AA10-1BA0 Contact module with 1 contact element, 1 NO, screw terminal , for front plate mounting	46,70	1	1 unit	41J
	3SU1400-1AA10-1CA0 Contact module with 1 contact element, 1 NC, screw terminal , for front plate mounting	46,70	1	1 unit	41J
	3SU1400-1AA10-1FA0 Contact module with 2 contact elements, 1 NO+1 NC, screw terminal , for front plate mounting	76,30	1	1 unit	41J
	3SU1400-1AA10-1DA0 Contact module with 2 contact elements, 2 NO, screw terminal , for front plate mounting	105,--	1	1 unit	41J
	3SU1400-1AA10-1EA0 Contact module with 2 contact elements, 2 NC, screw terminal , for front plate mounting	105,--	1	1 unit	41J
	3SU1400-1AA10-3BA0 Contact module with 1 contact element, 1 NO, spring-type terminal , for front plate mounting	50,90	1	1 unit	41J

SIRIUS ACT - Holdere og kontakteleementer

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3SU1400-1AA10-3CA0 Contact module with 1 contact element, 1 NC, spring-type terminal , for front plate mounting	50,90	1	1 unit	41J

SIRIUS ACT - LED moduler 24V AC/DC

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3SU1401-1BB20-1AA0 LED module with integrated LED, 24 V AC/DC, red, screw terminal , for front plate mounting	71,20	1	1 unit	41J
	3SU1401-1BB30-1AA0 LED module with integrated LED, 24 V AC/DC, yellow, screw terminal , for front plate mounting	71,20	1	1 unit	41J
	3SU1401-1BB40-1AA0 LED module with integrated LED, 24 V AC/DC, green, screw terminal , for front plate mounting	71,20	1	1 unit	41J
	3SU1401-1BB50-1AA0 LED module with integrated LED, 24 V AC/DC, blue, screw terminal , for front plate mounting	71,20	1	1 unit	41J
	3SU1401-1BB60-1AA0 LED module with integrated LED, 24 V AC/DC, white, screw terminal , for front plate mounting	71,20	1	1 unit	41J
	3SU1401-1BB20-3AA0 LED module with integrated LED, 24 V AC/DC, red, spring-type terminal , for front plate mounting	78,30	1	1 unit	41J
	3SU1401-1BB30-3AA0 LED module with integrated LED, 24 V AC/DC, yellow, spring-type terminal , for front plate mounting	78,30	1	1 unit	41J
	3SU1401-1BB40-3AA0 LED module with integrated LED, 24 V AC/DC, green, spring-type terminal , for front plate mounting	78,30	1	1 unit	41J

SIRIUS ACT - LED moduler 24V AC/DC



Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3SU1401-1BB50-3AA0 LED module with integrated LED, 24 V AC/DC, blue, spring-type terminal , for front plate mounting	78,30	1	1 unit	41J
	3SU1401-1BB60-3AA0 LED module with integrated LED, 24 V AC/DC, white, spring-type terminal , for front plate mounting	78,30	1	1 unit	41J

SIRIUS ACT - LED moduler 230V AC

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3SU1401-1BF20-1AA0 LED module with integrated LED, 230 V AC, red, screw terminal , for front plate mounting	126,--	1	1 unit	41J
	3SU1401-1BF30-1AA0 LED module with integrated LED, 230 V AC, yellow, screw terminal , for front plate mounting	126,--	1	1 unit	41J
	3SU1401-1BF40-1AA0 LED module with integrated LED, 230 V AC, green, screw terminal , for front plate mounting	126,--	1	1 unit	41J
	3SU1401-1BF50-1AA0 LED module with integrated LED, 230 V AC, blue, screw terminal , for front plate mounting	126,--	1	1 unit	41J
	3SU1401-1BF60-1AA0 LED module with integrated LED, 230 V AC, white, screw terminal , for front plate mounting	126,--	1	1 unit	41J
	3SU1401-1BF20-3AA0 LED module with integrated LED, 230 V AC, red, spring-type terminal , for front plate mounting	143,--	1	1 unit	41J
	3SU1401-1BF30-3AA0 LED module with integrated LED, 230 V AC, yellow, spring-type terminal , for front plate mounting	143,--	1	1 unit	41J
	3SU1401-1BF40-3AA0 LED module with integrated LED, 230 V AC, green, spring-type terminal , for front plate mounting	143,--	1	1 unit	41J

SIRIUS ACT - LED moduler 230V AC



Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3SU1401-1BF50-3AA0 LED module with integrated LED, 230 V AC, blue, spring-type terminal , for front plate mounting	143,--	1	1 unit	41J
	3SU1401-1BF60-3AA0 LED module with integrated LED, 230 V AC, white, spring-type terminal , for front plate mounting	143,--	1	1 unit	41J

SIRIUS ACT - LED moduler 24...240V AC/DC

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3SU1401-1BH20-1AA0 LED module with integrated LED, 24-240 V AC/DC, red, screw terminal , for front plate mounting	153,--	1	1 unit	41J
	3SU1401-1BH30-1AA0 LED module with integrated LED, 24-240 V AC/DC, yellow, screw terminal , for front plate mounting	153,--	1	1 unit	41J
	3SU1401-1BH40-1AA0 LED module with integrated LED, 24-240 V AC/DC, green, screw terminal , for front plate mounting	153,--	1	1 unit	41J
	3SU1401-1BH50-1AA0 LED module with integrated LED, 24-240 V AC/DC, blue, screw terminal , for front plate mounting	153,--	1	1 unit	41J
	3SU1401-1BH60-1AA0 LED module with integrated LED, 24-240 V AC/DC, white, screw terminal , for front plate mounting	153,--	1	1 unit	41J
	3SU1401-1BH20-3AA0 LED module with integrated LED, 24-240 V AC/DC, red, spring-type terminal , for front plate mounting	166,--	1	1 unit	41J
	3SU1401-1BH30-3AA0 LED module with integrated LED, 24-240 V AC/DC, yellow, spring-type terminal , for front plate mounting	166,--	1	1 unit	41J
	3SU1401-1BH40-3AA0 LED module with integrated LED, 24-240 V AC/DC, green, spring-type terminal , for front plate mounting	166,--	1	1 unit	41J

SIRIUS ACT - LED moduler 24...240V AC/DC



Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3SU1401-1BH50-3AA0 LED module with integrated LED, 24-240 V AC/DC, blue, spring-type terminal , for front plate mounting	166,--	1	1 unit	41J
	3SU1401-1BH60-3AA0 LED module with integrated LED, 24-240 V AC/DC, white, spring-type terminal , for front plate mounting	166,--	1	1 unit	41J

SIRIUS ACT - Skilteholdere

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3SU1900-0AG10-0AA0 Label holder, 22 mm, flat, Frame rounded off at the bottom black, for labeling plate 12.5mm x 27 mm , for gluing	643,--	1	10 units	41J
	3SU1900-0AH10-0AA0 Label holder, 22 mm, flat, Frame rounded off at the bottom black, for labeling plate 17.5mm x 27 mm , for gluing	643,--	1	10 units	41J
	3SU1900-0AJ10-0AA0 Label holder, 22 mm, flat, Frame rounded off at the bottom black, for labeling plate 27mm x 27mm , for gluing	643,--	1	10 units	41J
	3SU1900-0AN10-0AA0 Label holder, 22 mm, frame rectangular at the bottom, black, for labeling plate 12.5mm x 27 mm , for gluing	643,--	1	10 units	41J
	3SU1900-0AP10-0AA0 Label holder, 22 mm, frame rectangular at the bottom, black, for labeling plate 17.5mm x 27 mm , for gluing	643,--	1	10 units	41J
	3SU1900-0AQ10-0AA0 Label holder, 22 mm, frame rectangular at the bottom, black, for labeling plate 27mm x 27mm , for gluing	643,--	1	10 units	41J

 
 
SIRIUS ACT - Skilte

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3SU1900-0AC16-0DJ0 Labeling plate for snapping on or gluing to label holder ,label size 12.5x27mm, black label, white font, with inscription: On	705,--	1	10 units	41J
	3SU1900-0AC16-0DK0 Labeling plate for snapping on or gluing to label holder, label size 12.5x27mm, black label, white font, with inscription: Off	705,--	1	10 units	41J
	3SU1900-0AC16-0DS0 Labeling plate for snapping on or gluing to label holder, label size 12.5x27mm, black label, white font, with inscription: Stop	705,--	1	10 units	41J
	3SU1900-0AC16-0DT0 Labeling plate for snapping on or gluing to label holder, label size 12.5x27mm, black label, white font, with inscription: Start	705,--	1	10 units	41J
	3SU1900-0AC16-0DU0 Labeling plate for snapping on or gluing to label holder, label size 12.5x27mm, black label, white font, with inscription: Reset	705,--	1	10 units	41J
	3SU1900-0AC16-0DV0 Labeling plate for snapping on or gluing to label holder, label size 12.5x27mm, black label, white font, with inscription: Test	705,--	1	10 units	41J
	3SU1900-0AC16-0QA0 Labeling plate for snapping on or gluing to label holder, label size 12.5x27mm, black label, white font, with graphic symbol: ○	705,--	1	10 units	41J
	3SU1900-0AC16-0QB0 Labeling plate for snapping on or gluing to label holder, label size 12.5x27mm, black label, white font, with graphic symbol: I	705,--	1	10 units	41J
	3SU1900-0AD16-0DJ0 Labeling plate for snapping on or gluing on label holder ,label size 17.5 x 27 mm, black label, white font, with inscription: On	705,--	1	10 units	41J
	3SU1900-0AD16-0DK0 Labeling plate for snapping on or gluing on label holder, label size 17.5 x 27 mm, black label, white font, with inscription: Off	705,--	1	10 units	41J
	3SU1900-0AD16-0DS0 Labeling plate for snapping on or gluing on label holder, label size 17.5 x 27 mm, black label, white font, with inscription: Stop	705,--	1	10 units	41J

 
SIRIUS ACT - Skilte

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3SU1900-0AD16-0DT0 Labeling plate for snapping on or gluing on label holder, label size 17.5 x 27 mm, black label, white font, with inscription: Start	705,--	1	10 units	41J
	3SU1900-0AD16-0QA0 Labeling plate for snapping on or gluing on label holder, label size 17.5 x 27 mm, black label, white font, with graphic symbol: ○	705,--	1	10 units	41J
	3SU1900-0AD16-0QB0 Labeling plate for snapping on or gluing on label holder, label size 17.5 x 27 mm, black label, white font, with graphic symbol: I	705,--	1	10 units	41J
	3SU1900-0BC31-0AT0 Backing plate round, for EMERGENCY STOP mushroom pushbutton, yellow, self-adhesive, Outer diameter 75 mm, inside diameter 23 mm, with inscription: NOT-HALT	35,50	1	10 units	41J
	3SU1900-0BC31-0DA0 Backing plate round, for EMERGENCY STOP mushroom pushbutton, yellow, self-adhesive, Outer diameter 75 mm, inside diameter 23 mm, with inscription: EMERGENCY STOP	35,50	1	10 units	41J
	3SU1900-0BC31-0LA0 Backing plate round, for EMERGENCY STOP mushroom pushbutton, yellow, self-adhesive, outer diameter 75 mm, inside diameter 23 mm, with inscription: Nødstop	35,50	1	10 units	41J

SIRIUS ACT - Tomme trykknappbokse

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3SU1801-0AA00-0AA2 Enclosure for command devices, 22 mm, round, Enclosure material plastic , Enclosure top part yellow, 1 control point, IP69K	112,--	1	1 unit	41J
	3SU1801-0AA00-0AC2 Enclosure for command devices, 22 mm, round, Enclosure material plastic , Enclosure top part yellow, 1 control point, with protective collar, IP69K	275,--	1	1 unit	41J
	3SU1801-0AA00-0AB1 Enclosure for command devices, 22 mm, round, Enclosure material plastic , enclosure top part gray, 1 control point, IP69K	112,--	1	1 unit	41J
	3SU1802-0AA00-0AB1 Enclosure for command devices, 22 mm, round, Enclosure material plastic , enclosure top part gray, 2 control points, IP69K	144,--	1	1 unit	41J
	3SU1803-0AA00-0AB1 Enclosure for command devices, 22 mm, round, Enclosure material plastic , enclosure top part gray, 3 control points, IP69K	159,--	1	1 unit	41J
	3SU1804-0AA00-0AB1 Enclosure for command devices, 22 mm, round, Enclosure material plastic , enclosure top part gray, 4 control points, IP69K	201,--	1	1 unit	41J
	3SU1806-0AA00-0AB1 Enclosure for command devices, 22 mm, round, Enclosure material plastic , enclosure top part gray, 6 control points, IP69K	284,--	1	1 unit	41J
	3SU1851-0AA00-0AA2 Enclosure for command devices, 22 mm, round, Enclosure material metal , Enclosure top part yellow, 1 control point, IP69K	339,--	1	1 unit	41J

SIRIUS ACT - Tomme trykknappbokse

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3SU1851-0AA00-0AC2 Enclosure for command devices, 22 mm, round, Enclosure material metal , Enclosure top part yellow, with protective collar, 1 control point, IP69K	668,--	1	1 unit	41J
	3SU1851-0AA00-0AB1 Enclosure for command devices, 22 mm, round, Enclosure material metal , enclosure top part gray, 1 control point, IP69K	295,--	1	1 unit	41J
	3SU1852-0AA00-0AB1 Enclosure for command devices, 22 mm, round, Enclosure material metal , enclosure top part gray, 2 control points, IP69K	353,--	1	1 unit	41J
	3SU1853-0AA00-0AB1 Enclosure for command devices, 22 mm, round, Enclosure material metal , enclosure top part gray, 3 control points, IP69K	468,--	1	1 unit	41J
	3SU1854-0AA00-0AB1 Enclosure for command devices, 22 mm, round, Enclosure material metal , enclosure top part gray, 4 control points, IP69K	621,--	1	1 unit	41J
	3SU1856-0AA00-0AB1 Enclosure for command devices, 22 mm, round, Enclosure material metal , enclosure top part gray, 6 control points, IP69K	806,--	1	1 unit	41J

SIRIUS ACT - Komplette trykknappbokse

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3SU1801-0NA00-2AA2 Enclosure for command devices, 22 mm, round, Enclosure material plastic , Enclosure top part yellow, 1 control point plastic , A=EMERGENCY STOP mushroom pushbutton red, 40 mm, rotate-to-unlatch, 1 NC, screw terminal, 1xM20 each on top and bottom, IP69K	378,--	1	1 unit	41J
	3SU1801-0NA00-2AC2 Enclosure for command devices, 22 mm, round, Enclosure material plastic , Enclosure top part yellow, 1 control point plastic , with protective collar, A=EMERGENCY STOP mushroom pushbutton red, 40 mm, rotate-to-unlatch, 1 NC, screw terminal, 1xM20 each on top and bottom, IP69K	531,--	1	1 unit	41J
	3SU1801-0NB00-2AC2 Enclosure for command devices, 22 mm, round, Enclosure material plastic , Enclosure top part yellow, with protective collar, 1 control point plastic , A=EMERGENCY STOP mushroom pushbutton red, 40 mm, rotate-to-unlatch, 2 NC, screw terminal, 1xM20 each on top and bottom, IP69K	589,--	1	1 unit	41J
	3SU1802-0AB00-2AB1 Enclosure for command devices, 22 mm, round, Enclosure material plastic , enclosure top part gray, 2 control points plastic , B=pushbutton green, label: "I", 1 NO, screw terminal, A=pushbutton red, label: "O", 1NC, screw terminal, 1xM20 each on top and bottom, IP69K	398,--	1	1 unit	41J
	3SU1802-0AC00-2AB1 Enclosure for command devices, 22 mm, round, Enclosure material plastic , enclosure top part gray, 2 control points plastic , B=pushbutton white, label: "I", 1NO, screw terminal, A=pushbutton black label: "O", 1NC, screw terminal, IP69K	396,--	1	1 unit	41J
	3SU1803-0AB00-2AB1 Enclosure for command devices, 22 mm, round, Enclosure material plastic , enclosure top part gray, 3 control points plastic , C=indicator light clear, LED 24 V, screw terminal, B=pushbutton green, label: "I", 1 NO, screw terminal, A=pushbutton red, label: "O", 1NC, screw terminal, 1xM20 each on top and bottom, IP69K	533,--	1	1 unit	41J
	3SU1803-0AC00-2AB1 Enclosure for command devices, 22 mm, round, Enclosure material plastic , enclosure top part gray, , IP69K, C=indicator light clear, LED 24 V, screw terminal, B=pushbutton white, label: "I", 1 NO, screw terminal, A=pushbutton black, Label: "O", 1NC, screw terminal, 1xM20 each on top and bottom, IP69K	533,--	1	1 unit	41J

SIRIUS ACT - Komplette trykknappbokse

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	3SU1851-0NA00-2AA2 Enclosure for command devices, 22 mm, round, Enclosure material metal , Enclosure top part yellow, 1 control point metal , A=EMERGENCY STOP mushroom pushbutton red, 40 mm, rotate-to-unlatch, 1 NC, screw terminal, 1xM20 each on top and bottom, IP69K	643,--	1	1 unit	41J
	3SU1851-0NA00-2AC2 Enclosure for command devices, 22 mm, round, Enclosure material metal , Enclosure top part yellow, with protective collar, 1 control point metal , A=EMERGENCY STOP mushroom pushbutton red, 40 mm, rotate-to-unlatch, 1 NC, screw terminal, 1xM20 each on top and bottom, IP69K	936,--	1	1 unit	41J
	3SU1851-0NB00-2AC2 Enclosure for command devices, 22 mm, round, Enclosure material metal , Enclosure top part yellow, with protective collar, 1 control point metal , A=EMERGENCY STOP mushroom pushbutton red, 40 mm, rotate-to-unlatch, 2 NC, screw terminal, 1xM20 each on top and bottom, IP69K	1000,--	1	1 unit	41J
	3SU1852-0AB00-2AB1 Enclosure for command devices, 22 mm, round, Enclosure material metal , enclosure top part gray, 2 control points metal , B=pushbutton green, label: "I", 1 NO, screw terminal, A=pushbutton red, label: "O", 1NC, screw terminal, 1xM20 each on top and bottom, IP69K	643,--	1	1 unit	41J
	3SU1852-0AC00-2AB1 Enclosure for command devices, 22 mm, round, Enclosure material metal , enclosure top part gray, 2 control points metal , B=pushbutton white, label: "I", 1 NO, screw terminal, A=pushbutton black, label: "O", 1NC, screw terminal, 1xM20 each on top and bottom, IP69K	643,--	1	1 unit	41J
	3SU1853-0AB00-2AB1 Enclosure for command devices, 22 mm, round, Enclosure material metal , enclosure top part gray, 3 control points metal , C=indicator light clear, LED 24 V, screw terminal, B=pushbutton green, label: "I", 1 NO, screw terminal, A=pushbutton red, label: "O", 1NC, screw terminal, 1xM20 each on top and bottom, IP69K	875,--	1	1 unit	41J

Signaltårn - 70mm

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	8WD4308-0DA Pipe with foot, length 100 mm, accessory for signaling columns, with diameter 70 mm	402,--	1	1 unit	41J
	8WD4408-0CD Bracket for base mounting, accessory for signaling columns, with diameter 70 mm	195,--	1	1 unit	41J
	8WD4408-0AA Connection element, with end cover, black, for pipe mounting, screw terminal	454,--	1	1 unit	41J
	8WD4408-0AD Connection element, with end cover, black, for pipe mounting, spring-type terminal	454,--	1	1 unit	41J
	8WD4408-0AB Connection element, with end cover, black, for floor/angle mounting, screw terminal	446,--	1	1 unit	41J
	8WD4408-0AE Connection element, with end cover, black, for floor/angle mounting, spring-type terminal	446,--	1	1 unit	41J
	8WD4420-5AB Continuous light element , with integrated LED, red, 24 VAC/DC, Diameter 70 mm	767,--	1	1 unit	41J
	8WD4420-5AC Continuous light element , with integrated LED, green, 24 VAC/DC, Diameter 70 mm	767,--	1	1 unit	41J

Signaltårn - 70mm

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	8WD4420-5AD Continuous light element , with integrated LED, yellow, 24 VAC/DC, Diameter 70 mm	767,--	1	1 unit	41J
	8WD4420-5AE Continuous light element , with integrated LED, clear, 24 VAC/DC, Diameter 70 mm	821,--	1	1 unit	41J
	8WD4420-5AF Continuous light element , with integrated LED, blue, 24 VAC/DC, Diameter 70 mm	821,--	1	1 unit	41J
	8WD4420-5BB Flashlight element , with integrated LED, red, 24 VAC/DC, Diameter 70 mm	1020,--	1	1 unit	41J
	8WD4420-5BC Flashlight element , with integrated LED, green, 24 VAC/DC, Diameter 70 mm	1020,--	1	1 unit	41J
	8WD4420-5BD Flashlight element , with integrated LED, yellow, 24 VAC/DC, Diameter 70 mm	1020,--	1	1 unit	41J
	8WD4420-5DB Rotating light element , with integrated LED, red, 24 VAC/DC, Diameter 70 mm	1050,--	1	1 unit	41J
	8WD4420-5DC Rotating light element , with integrated LED, green, 24 VAC/DC, Diameter 70 mm	1050,--	1	1 unit	41J

Signaltårn - 70mm

Product Photo	Article Number/ Description	Price kr per PE	(UNIT, SET,M)	PS*/ P.UNIT	PG
	8WD4420-5DD Rotating light element , with integrated LED, yellow, 24 VAC/DC, Diameter 70 mm	1050,--	1	1 unit	41J
	8WD4420-0EA2 Siren element , multi-tone, 100dB, 8 tones + adjustable volume, black, 24 V AC/DC, Diameter 70 mm	1110,--	1	1 unit	41J
	8WD4420-0FA Buzzer element , continuous tone or pulsating, adjustable, black, 24 V AC/DC, Diameter 70mm	762,--	1	1 unit	41J

Generelle salgs- og leveringsbetingelser

1. GYLDIGHED

Med mindre andet er skriftligt aftalt, gælder disse generelle betingelser ("Betingelser") mellem Siemens A/S ("Siemens") og Siemens' kunder ("Kunden") ved Siemens' salg af produkter ("Produkter") og Serviceydelser ("Serviceydelser") til Kunden. Produkter og Serviceydelser betegnes under ét "Leverancen".

2. LEVERANCE Leveringsbetingelser

Alle Produkter leveres *DDP (Incoterms 2010)* til den dansk-tyske grænse, hvorefter de for Kundens regning og risiko fragtes til en med Kunden aftalt lokation i Danmark. Siemens' chartering af fragtfører eller speditør på Kundens vegne ændrer hverken på overgangen af risiko eller nogen øvrige betingelser og/eller omstændigheder vedrørende leveringstiden.

Serviceydelser leveres på det tidspunkt og sted, der er aftalt mellem Siemens og Kunden.

Hvis Parterne har aftalt overtagelsesforretning, som af årsager uden for Siemens kontrol ikke er afholdt senest på den aftalte overtagelsesdag, vil levering blive anset for at have fundet sted på den aftalte overtagelsesdag. Risiko og ansvar for Leverancen overgår hermed til Kunden og reklamationsperioden, jf. pkt. 5, begynder.

Såfremt Kunden tager Leverancen i brug før overtagelsen har fundet sted, vil levering blive anset for at have fundet sted fra den dato, Leverancen blev taget i brug. Risiko og ansvar overgår herefter til Kunden og reklamationsperioden, jf. pkt. 5, begynder.

Forsinkelse

Såfremt Siemens er årsag til forsinkelse af en Leverance, kan Kunden kræve erstatning for dokumenterede tab op til et beløb svarende til 0,5 % af prisen på den forsinkede del af Leverancen for hver hele uge, som Leverancen forsinkes, dog samlet, maksimalt et beløb svarende til 7,5 % af denne pris. Kunden skal uden ophold meddele Siemens, såfremt det påtænkes at kræve erstatning. Hvis Siemens ikke modtager meddelelse uden ophold, bortfalder Kundens ret til at kræve erstatning for forsinkelsen.

Såfremt maksimumbeløbet for erstatning kommer til udbetaling, kan Kunden hæve købet af den forsinkede del af Leverancen uden at pådrage sig ansvar forudsat, levering ikke sker inden for en af Kunden fastsat rimelig periode. Ophævelse berettiger ikke Kunden til at kræve yderligere erstatning.

For så vidt angår fortløbende levering af Varer og/eller Serviceydelser har Kunden ikke ret til at ophæve ikke-forsinkede ordrer.

3. IMMATERIELLE RETTIGHEDER

Ved Siemens' salg under disse Betingelser overføres ingen immaterielle rettigheder ("IPR") mellem parterne, med mindre der er indgået en særskilt, skriftlig aftale herom. Siemens beholder alle IPR, der indgår i Leverancen. I tilfælde, hvor Leverancen omfatter software, har Kunden dog en tidsbegrænset, ikke-eksklusiv og ikke-overdragelig ret til at anvende softwaren i softwarens oprindelige form og udelukkende til den brug, der fremgår af produktspecifikationen. Kunden har ikke ret til at kopiere, videreudvikle eller ændre nogen del af softwaren. Alle tegninger, beskrivelser, modeller mv. der stilles gratis til rådighed af Siemens forbliver Siemens' ejendom.

4. PRIS OG BETALING Priser

Alle priser er eksklusive skatter og afgifter samt transport- og forsikringspræmier. Sådanne omkostninger vil fremgå separat af fakturaer. Ved køb på mindre end 1.000 kr. tillægges fakturaen et ekspositionsgebyr på 500 kr.

Ved fortløbende levering af Produkter og Serviceydelser vil prisen for hver enkelt levering, med mindre andet er aftalt, være baseret på Siemens listepriis på leveringstidspunktet.

Betalingsbetingelser

Betaling skal finde sted senest 25 dage efter fakturadato. Ved for sen betaling tillægges det udestående beløb renter på 12 % per år.

Ejendomsforbehold

SIEMENS HAR EJENDOMSFORBEHOLD I ALLE SOLGTE PRODUKTER INDTIL FULD BETALING HAR FUNDET STED.

5. MANGLER

Beføjelserne i pkt. 5 er Kundens eneste misligholdelsesbeføjelser i tilfælde af mangler i forbindelse med Leverancen.

Mangelfhjælpning

Siemens indestår for at 1) alle Produkter produceres i overensstemmelse med produktspecifikationerne og leveres fejlfri, samt 2) alle Serviceydelser udføres som aftalt mellem Kunden og Siemens med den nødvendige ekspertise og grundighed. Siemens indestår ikke for, at Leverancer er designet eller egnet til at blive anvendt til særlige, bestemte formål.

Kunden har pligt til at undersøge Leverancen for synlige mangler ved modtagelsen. Enhver mangel skal meddeles skriftligt til Siemens, så snart Kunden bliver eller burde være blevet opmærksom herpå. Såfremt Kunden ikke omgående underretter Siemens om en mangel, bortfalder Kundens ret til at påberåbe sig denne mangel.

Siemens skal iværksætte mangeludbedring uden unødigt ophold efter modtagelsen af rettidig meddelelse om en mangel. Siemens afgør selv, hvorvidt en mangeludbedring skal ske ved reparation eller udskiftning af den mangelfulde Leverance. Hvis en væsentlig mangel ikke er udbedret indenfor rimelig tid (typen og omfanget af manglen taget i betragtning) har Kunden ret til at ophæve købet af den mangelbehæftede del af Leverancen med et yderligere varsel på to (2) uger. Denne ret bortfalder, hvis manglen udbedres i løbet af de to uger.

Erstatning

I tilfælde af mangler, som Siemens er ansvarlig for, er Kunden med de begrænsninger der følger af pkt. 6, berettiget til erstatning for direkte tab, hvilket omfatter 1) direkte omkostninger afholdt som følge af manglen, og 2) person- og tingsskade forårsaget af den mangelfulde Leverance (produktsansvar).

Kunden kan ikke modregne erstatningen i udestående betalinger.

Reklamationsperiode

Ethvert krav fra Kunden vedrørende Leverancen, herunder produktansvarskrav, skal straks meddeles Siemens og under alle omstændigheder senest 1 (et) år efter levering af de fejlbehæftede Produkter/Serviceydelser. Efter udløbet af denne periode kan der ikke længere rejses krav mod Siemens.

6. ANSVARSBEGRÆNSNING

Indirekte tab og følgeskader

Siemens kan i intet tilfælde holdes ansvarlig, herunder i forhold til produktansvar, for indirekte tab og følgeskader, herunder, men ikke begrænset til drifts-, eller indtægts- og tab af data eller fortjeneste samt driftsafbrudelse, ligesom Siemens ikke kan holdes ansvarlig for forhold som skyldes normalt slid, efterbehandling, forkert brug eller fejlhåndtering af Leverancen.

Produktsansvar

Siemens kan ikke holdes ansvarlig for skader, som Leverancen måtte forvolde, når de integreres i eller udgør en del af Kundens eller tredjemands udstyr, produkter, ejendom eller fast ejendom.

Samlet Ansvar

Siemens' samlede ansvar herunder erstatningsansvar og ansvar for omkostninger relateret til mangeludbedring, kan - uanset om kravet baseres på kontrakt, garanti, skadevoldende handling, produktansvar (undtaget personskade) eller anden form for manglende opfyldelse af køb, som er omfattet af disse Betingelser - ikke overstige det laveste af følgende beløb: 1) 50% af købssummen for den del af Leverancen, som kravet udspringer af, og 2) DKK 500.000.

Regres

Kunden skal holde Siemens skadesløs for ethvert krav fra tredjemand i forbindelse med Leverancen i det omfang sådanne krav ville have været omfattet af eller begrænset under disse Betingelser.

7. FORCE MAJEURE

Siemens kan ikke holdes ansvarlig for forsinkelse eller manglende opfyldelse, når dette skyldes force majeure-begivenheder såsom brand, eksplosion, arbejdsnedlæggelse eller lockout, jordskælv, skade eller ulykke, manglende eller fejl på transportenheder, epidemi, oversvømmelse, tørke, erklæret eller ikke-erklæret krig, revolution, civile optøjer, samfundsfjendtlige handlinger, blokade eller embargo, manglende opnåelse af fornødne licenser, tilladelser eller autorisation, uventede omkostningsstigninger, som direkte eller indirekte påvirker Leverancens produktionsomkostninger eller love, bekendtgørelser, regler, forordninger, krav eller betingelser fra myndigheder. I en force majeure situation udsættes Leverancen

med et tidsrum svarende til den forsinkelse, force majeure begivenheden medfører. Såfremt den berørte Leverance forsinkes i mere end 60 (tres) dage kan Parterne hver især opsigte denne.

8. HEMMELIGHOLDELSE

I forbindelse med køb omfattet af disse Betingelser skal enhver information som Kunden modtager fra Siemens, herunder, men ikke begrænset til, information om Leverancen, processer, teknik, resultater, materialer, design, priser og alt fysisk materiale behandles og holdes fortrolig af Kunden med mindre andet er aftalt. Kunden må således ikke uden forudgående skriftligt samtykke bruge Siemens' fortrolige information til andet end, hvad der er nødvendig for kunne anvende Leverancen til de formål, der fremgår af eller klart forudsættes i den til Leverancen hørende dokumentation.

9. DATABASESKYTTELSE

I det omfang Siemens behandler persondata som databehandler for kunden, gælder følgende:

Kunden er dataansvarlig og Siemens behandler som databehandler alene persondata på vegne af kunden. Siemens må kun handle efter instruks fra kunden. Siemens må alene behandle persondata som led i opfyldelsen af kontraktuelle ydelser. Siemens skal træffe de fornødne tekniske og organisatoriske sikkerhedsforanstaltninger mod, at oplysninger hændeligt eller ulovligt tilintetgøres, fortabes eller forringes, samt mod, at de kommer til uvedkommendes kendskab, misbruges eller i øvrigt behandles i strid med databeskyttelsesloven.

Siemens kan uden yderligere godkendelse fra kunden anvende underdatabehandlere inden for Siemens-koncernen i EØS. Anvendelse af underdatabehandlere i EØS uden for Siemens-koncernen eller anvendelse af underdatabehandlere uden for EØS skal godkendes af kunden, hvilken godkendelse ikke må tilbageholdes uden saglig grund, og kunden skal indgå EU standardkontrakter for databehandlere i tredjelande, hvis det er påkrævet. Databehandlere i andre EØS-lande skal overholde de specifikke regler, der gælder for databehandlere i det pågældende land.

Siemens skal sikre, at underdatabehandlere er underlagt forpligtelser svarende til, hvad der fremgår af dette afsnit om databeskyttelse.

10. EKSPORTKONTROL

Hvis Kunden eksporterer eller reeksporterer Leverancen globalt skal Kunden opfylde alle nationale og internationale (re-)eksportkontrolbestemmelser.

Hvis Siemens skal udføre eksportkontrolljek, skal Kunden på anmodning fra Siemens omgående give Siemens alle relevante oplysninger vedrørende slutkunden, bestemmelsesstedet og den tiltænkte brug af varer, arbejde og serviceydelser leveret af Siemens.

Kunden skal holde Siemens skadesløs for ethvert krav, sagsanlæg, bøder, tab, udgifter og skader som skyldes eller har relation til Kundens manglende opfyldelse af eksportkontrolbestemmelser, og Kunden skal godtgøre Siemens alle deraf følgende tab og udgifter.

Siemens er ikke forpligtet til at opfylde denne aftale, hvis opfyldelsen forhindres som følge af nationale eller internationale handels- eller toldkrav eller andre sanktioner, herunder embargo.

11. TVISTER

Medmindre parterne specifikt aftaler andet må Siemens efter eget skøn afgøre, om tvister opstår pga. eller i forbindelse med disse Betingelser skal afgøres ved 1) Voldgift efter de af Voldgiftsinstituttet til enhver tid gældende regler eller 2) ved de danske domstole. Værneting er København, Danmark.

Alle tvister skal afgøres efter dansk ret, dog finder danske lovalvsregler og De Forenede Nationers International Købelov (CISG) ikke anvendelse.

12. FOR RETURNINGER GÆLDER FØLGENDE:

Produkter tages ikke retur for kreditering uden forudgående accept fra Siemens A/S. Alle returneringer skal mærkes med et returnnummer som udelveres af Customer Support. Customer Support angiver om pakken bliver afhentet eller hvortil den skal sendes. Produkter som fremsendes til Siemens A/S uden aftale, vil blive returneret til afsender.

Get more information

[siemens.com/lowvoltage](https://www.siemens.com/lowvoltage)

Siemens A/S
DF/PD
Borupvang 9
2750 Ballerup
Denmark

© Siemens A/S 2018
Subject to change without prior notice
Produced in Denmark

The information provided in this catalog contains merely general descriptions or characteristics of performance which in case of actual use do not always apply as described or which may change as a result of further development of the products. An obligation to provide the respective characteristics shall only exist if expressly agreed in the terms of contract. Availability and technical specifications are subject to change without notice.

All product designations may be trademarks or product names of Siemens AG or supplier companies whose use by third parties for their own purposes could violate the rights of the owners.

Security information

Siemens provides products and solutions with industrial security functions that support the secure operation of plants, systems, machines and networks.

In order to protect plants, systems, machines and networks against cyber threats, it is necessary to implement – and continuously maintain – a holistic, state-of-the-art industrial security concept. Siemens' products and solutions only form one element of such a concept.

Customer is responsible to prevent unauthorized access to its plants, systems, machines and networks. Systems, machines and components should only be connected to the enterprise network or the internet if and to the extent necessary and with appropriate security measures (e.g. use of firewalls and network segmentation) in place.

Additionally, Siemens' guidance on appropriate security measures should be taken into account. For more information about industrial security, please visit **<http://www.siemens.com/industrialsecurity>**.

Siemens' products and solutions undergo continuous development to make them more secure. Siemens strongly recommends to apply product updates as soon as available and to always use the latest product versions. Use of product versions that are no longer supported, and failure to apply latest updates may increase customer's exposure to cyber threats.

To stay informed about product updates, subscribe to the Siemens Industrial Security RSS Feed under **<http://www.siemens.com/industrialsecurity>**.