


Catalog Number: 49007-02FL

Features and Ratings






- Ringless Type Meter Socket
- 320A Continuous, 400A Max.
- Outdoor Enclosure (NEMA Type 3R)
- 3 Phase, 4 Wire, 600V AC
- 7 Jaw
- HQ Clamp Jaw Lever Bypass Meter Socket
- For Overhead or Underground Service
- HD hub Opening With Coverplate Installed
- Painted G90 Steel enclosure
- Stainless steel latch and hasp

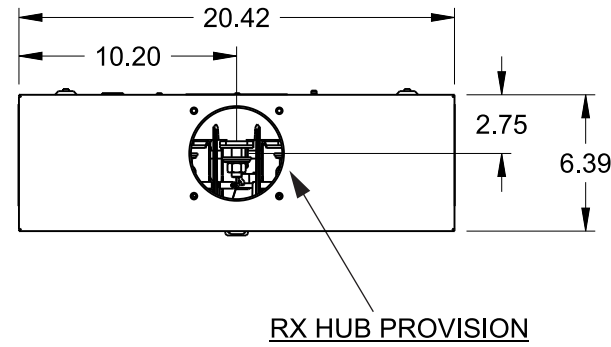

- ### Accessories
- HD HUB KITS**
 Cat No: H56856-2 (3.00")
 Cat No: H56857-2 (3.50")
 Cat No: H56858-2 (4.00")
- HD HUB KITS**
 Cat No: EC56856 (3.00")
 Cat No: EC56857 (3.50")
 Cat No: EC56858 (4.00")
- HUB COVER PLATE**
 Cat No: H56833-2

Lugs, Wire Sizes and Torques

LOCATION	PART NO.	HEX DRIVE SIZE	LUG SIZE	TORQUE
LINE	H60162	9/16	#4-600Kcmil	500 LB-IN
LOAD	H60162	9/16	#4-600Kcmil	500 LB-IN
NEUTRAL	H60162	9/16	#4-600Kcmil	500 LB-IN
GROUND	H67554	7/16	#14-2/0	50 LB-IN

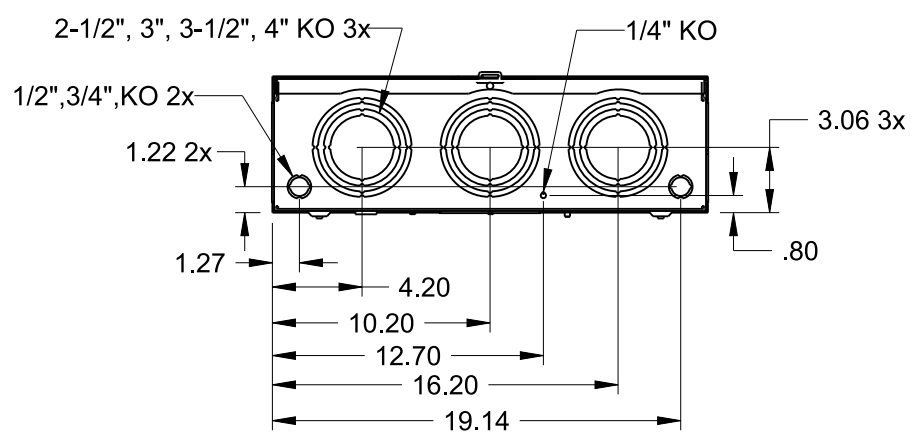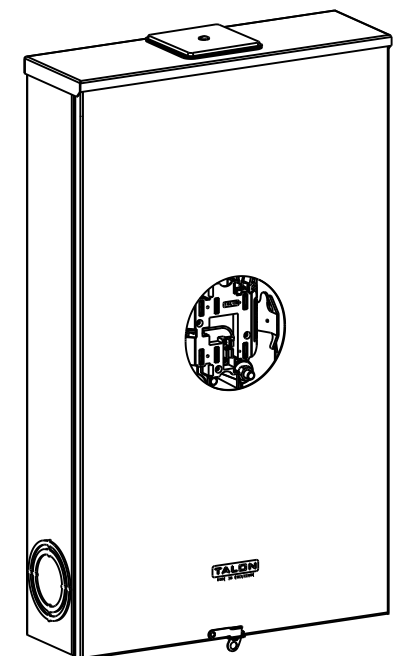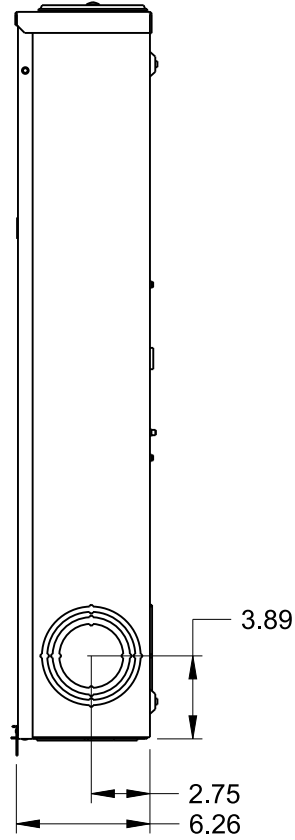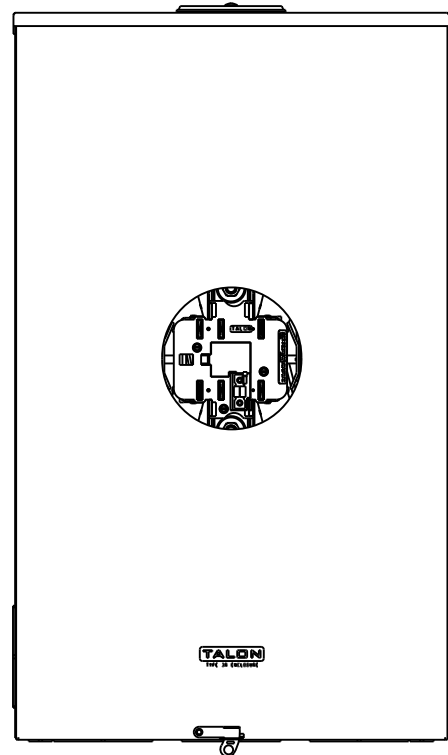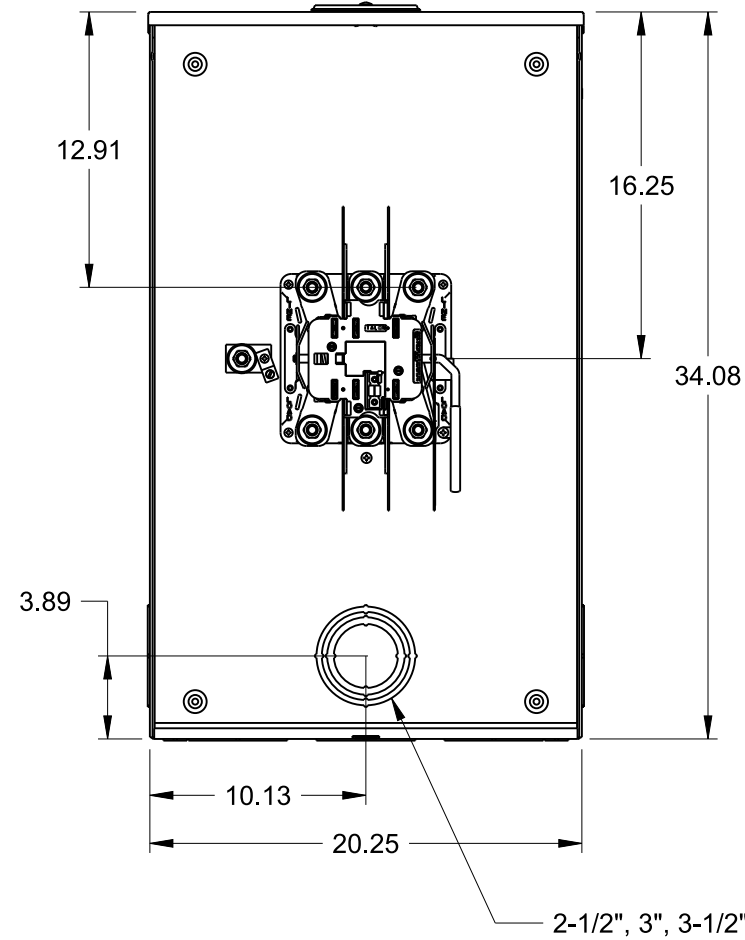

TALON

Meter Socket

Description:
320A Cont, 7 Jaw, HQ-7DB, 600V AC
Painted G90 Steel

NH 25NOV15 DO NOT SCALE DRAWING Dwg No: **49005-02FL** MEG