


**Catalog Number: 40604-015**

**Features and Ratings**

- Ringless Type Meter Socket
- 200A Continuous, 200A Max., 600V AC
- Outdoor Enclosure (NEMA Type 3R)
- Painted Steel Enclosure
- 1 Phase, 3 Wire
- 4 Jaw Meter Socket
- Meter Socket Type MQ-4U
- For Overhead or Underground Service
- RX Type (Small) Hub Opening
- Non-Clamping Lever Bypass

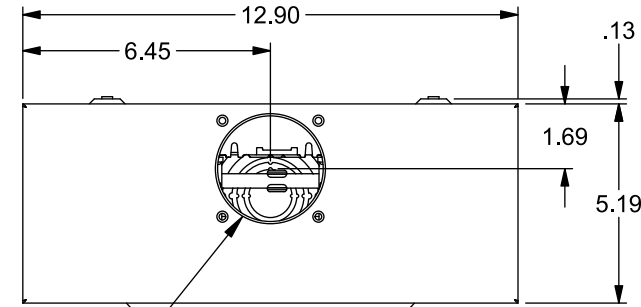

TYPE RX (SMALL) HUB OPENING

**Accessories**

CONDUIT HUBS (RX Type)	
TRADE SIZE	CATALOG No.
1-1/4 INCH	EC38597 or H38597-2
1-1/2 INCH	EC38598 or H38598-2
2 INCH	EC38599 or H38599-2
2-1/2 INCH	EC38600 or H38600-2

Hub Cover Plate EC38595 or H38595-1

Meter Opening Cover Plate  
Cat No: H659-0162

5th Jaw Kit (9 o'clock)  
Cat No: H8059864

Insulated Neutral Kit  
Cat No: H64685-1,  
H64690-1



Ground Lug Kit  
Cat No: H55303

Wire Size #4-14, Torque 50 in-lbs.




**Connectors, Wire Sizes and Torques**

CONNECTOR	WIRE SIZE	TORQUE
LINE, LOAD, NEUTRAL*	#6 - 350 kcmil	275 IN.-LBS.

\* External Hex Drive 1/2"  
\* Internal Hex Drive 5/16"

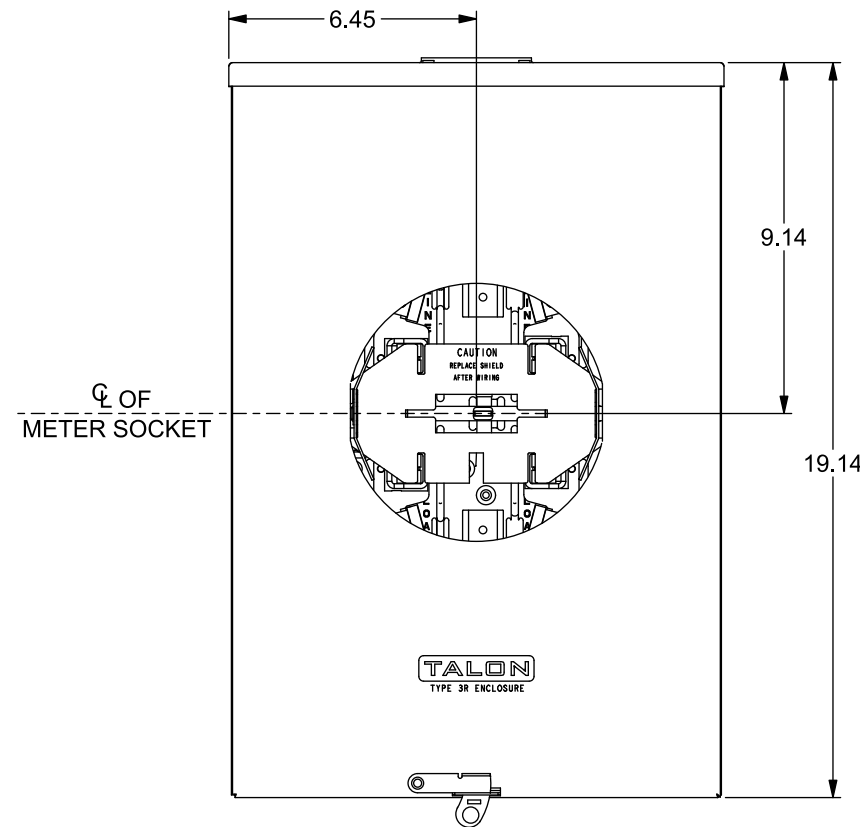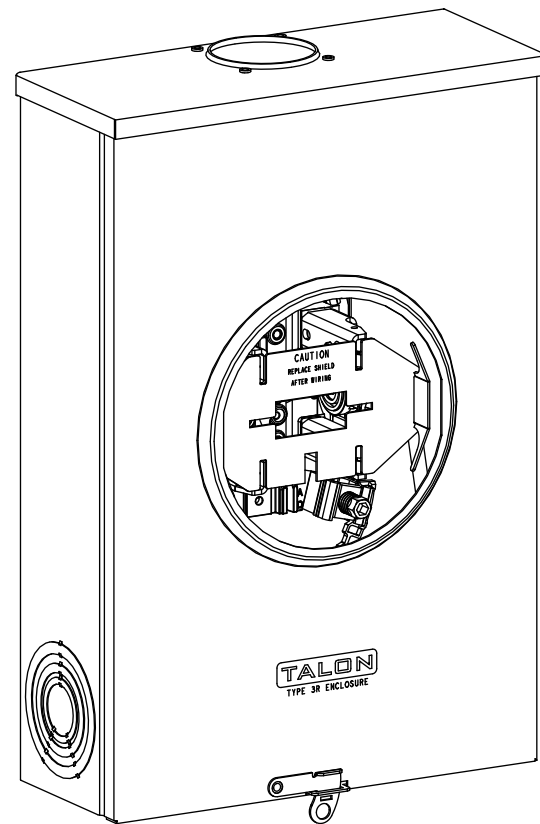

VIEW SHOWN WITH COVER AND SHIELD REMOVED

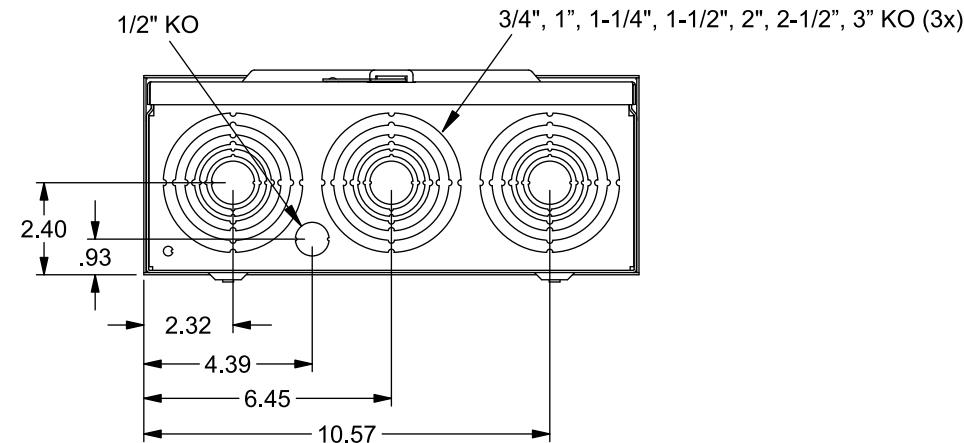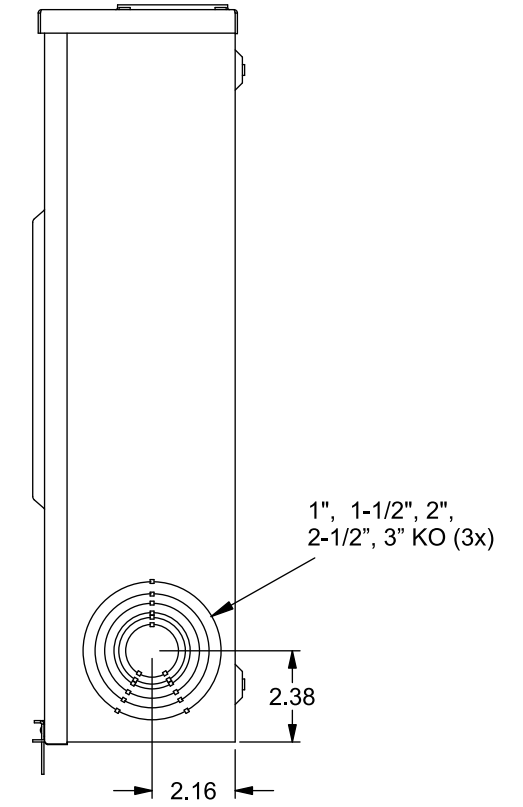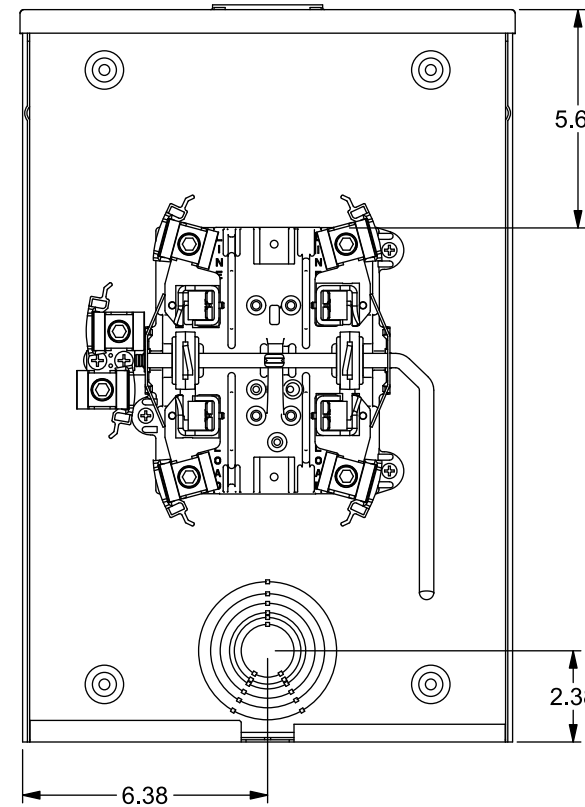

© 2019 Copyright Siemens Industry, Inc.

**TALON**

**Meter Socket**

Description: **200A Cont, 4 Jaw, MQ-4U, 600V AC, Painted Steel Enclosure**

KAM 3/4/19 | DO NOT SCALE DRAWING | Dwg No: **40604-015**