

 
 
 
Terminal Blocks

8WA2 Terminals with Cage Clamps






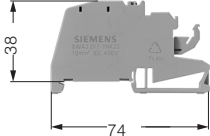

N isolating terminals

Selection and ordering data

With insulating body of moulded thermoplastic · Front connection with Cage Clamps · 1-pole with one clamping point

Dimensions ¹⁾	IEC ratings uninterrupted current	UL ratings current / voltage	Description	Color	Height H	Depth D	Order No.	Price
	IEC ratings insulation voltage				mm ¹⁾	mm ¹⁾		
	Terminal size 4 mm ² · Overall width 6.2 mm		N isolating terminal	blue	68.5	31.0	8WA2 011-1NG23	
	32 A isolating gap 400 V	20 A 600 V						
	Terminal size 6 mm ² · Overall width 8.2 mm		N isolating terminal	blue	71.0	31.0	8WA2 011-1NH23	
	41 A isolating gap 400 V	30 A 300 V						
	Terminal size 6 mm ² · Overall width 8.2 mm		N isolating terminal high Insta terminal level, for mixing standard and Insta terminals on the standard mounting rail	blue	70.0	37.0	8WA2 011-3JH10	
	41 A isolating gap 400 V	30 A 300 V						
	Terminal size 16 mm ² · Overall width 12 mm		N isolating terminal	blue	89.4	38	8WA2 011-1NK20	
	76 A isolating gap 400 V	65 A 600 V						

Accessories

8WA2 843	8WA2 848		N busbar support	blue			8WA2 843	
			Lockout	yellow			8WA2 848	
8WA2 837		135 A	N busbar end for insertion into 8WA2 808 end retainer	blue			8WA2 837	
			N busbar 10 x 3 mm; tin-coated, 1000 mm long				8WA2 842	
8WA2 842		68 A 800 V	Cover for N busbar, 500 mm long	transparent			8WA2 805	
		63 A 600 V	Supply terminal 16 mm² / 16 AWG with screw connection (the 8WA2 843 N busbar support is included in the scope of supply)	blue	Overall width 10 mm		8WA2 011-1NK23	
8WA2 805			Supply terminal for 10 x 3 mm – and 6 x 6 mm – N busbars up to 4 mm ² / 12 AWG up to 25 mm ² / 14 AWG up to 35 mm ² / 12 AWG	bare			8WA2 867 8WA2 868 8WA2 870	
								
8WA2 011-1NK23								
								
8WA2 867/868/870								
								

Linking accessories see page 15/13, other accessories see page 15/14, labelling accessories see page 15/40 - 43.

1) 25.4 mm = 1 inch