




Catalog Number: 9817-8113

Features and Ratings

- Ringless Type Meter Socket
- 400A Continuous, 400A Max., 600V AC
- Outdoor Enclosure (NEMA Type 3R)
- Painted G90 Steel Enclosure
- 1 or 3 Phase, Commercial/Industrial Socket
- Meter Socket Type K-7
- For Overhead & Underground Service
- Large Hub Opening, HD Type Cover Plate Installed

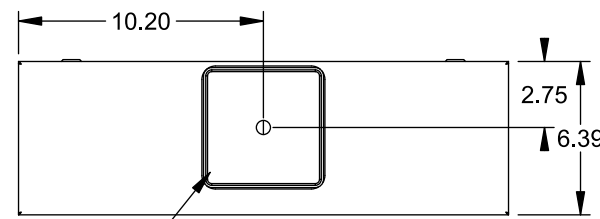

TYPE HD (LARGE) HUB OPENING
COVER PLATE INSTALLED

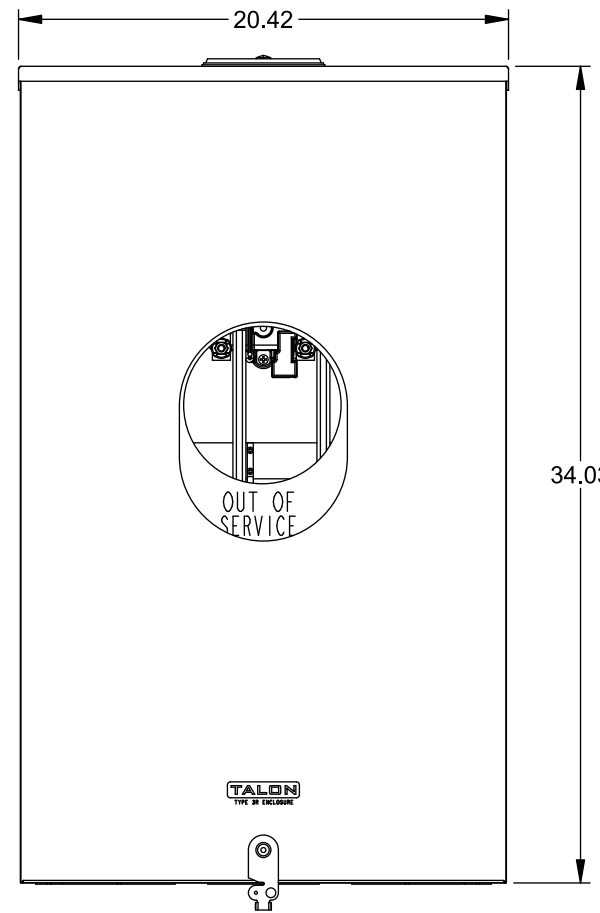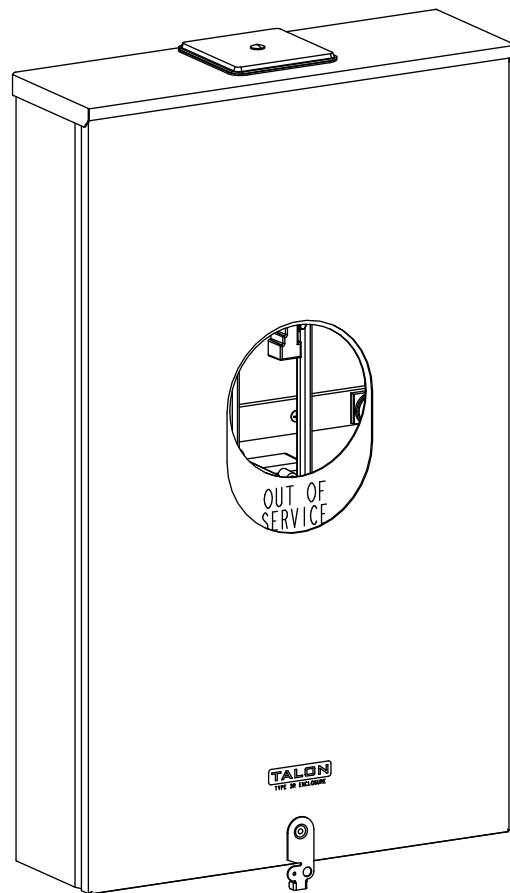

Accessories

CONDUIT HUBS (HD Type)	
TRADE SIZE	CATALOG No.
3 INCH	EC56856 or H56856-2
3-1/2 INCH	EC56857 or H56857-2
4 INCH	EC56858 or H56858-2
Hub Cover Plate	EC56933 or H56933S



CAT No.	DESCRIPTION
H69623	Bypass
H69685-1	Isolated Neutral Kit
H69546-1	Hex Magnet Socket Kit
H69232-1	Insulated T-Handle Kit
H65050	K-base Insulator Kit
H63864	K-base Ground Kit

Connectors, Wire Sizes and Torques

CONNECTOR	PART No.	HEX DRIVE	WIRE SIZE	TORQUE
LINE*	58853	5/16"	(2)#6 - 350 kcmil	275 IN-LBS.
LINE/LOAD*	56732	5/16"	(2)#6 - 350 kcmil	275 IN-LBS.
LINE/LOAD	56732-M	5/16"	(2)#4 - 500 kcmil	275 IN-LBS.
GROUND*	56734	5/16"	#6 - 250 kcmil	275 IN-LBS.

*Factory Installed

VIEW SHOWN WITH COVER REMOVED

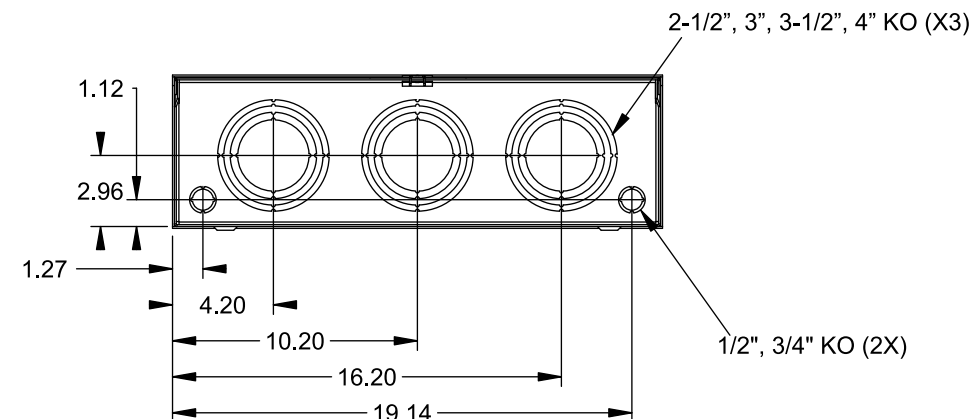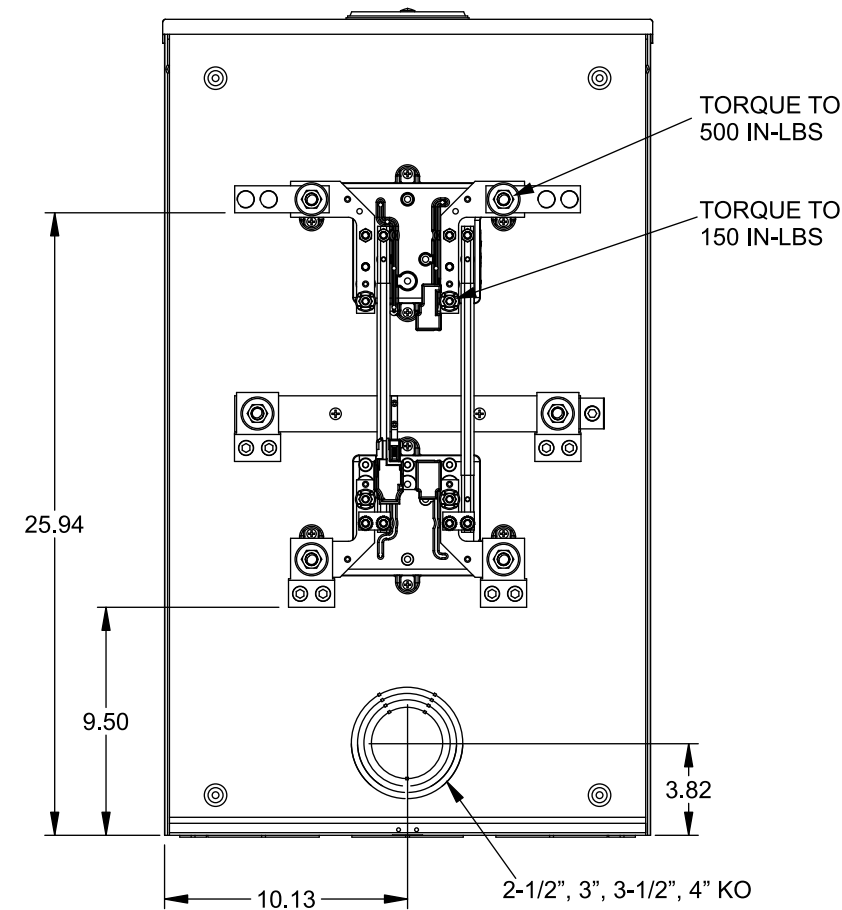

© 2015 Copyright Siemens Industry, Inc.

TALON
Meter Socket

Description: **400A Cont, 4 Terminal, K-7,
600V AC, Painted Steel Enclosure**

JEL 12/1/15 DO NOT SCALE DRAWING Dwg No: **9817-8113**