

Catalog Number: UA5411-XPCH

Features and Ratings

- Ringless Type Meter Socket
- 100A Continuous Per Position,
- 250A Continuous (Total) Unit Rating With CU
- 205A Continuous (Total) Unit Rating With AL
- Outdoor Enclosure (NEMA Type 3R)
- Painted G90 Steel
- 1 Phase, 3 Wire, 600V AC
- 4 Jaw Meter Socket
- Meter Socket Type UA5411
- Horn Bypass
- For Overhead or Underground Service
- RX Type Hub Opening, Cover Plate Installed
- CECHA Approved

Connectors, Wire Sizes and Torques

| CONNECTOR | WIRE SIZE | TORQUE |
|----------------------------|----------------|--------------|
| LINE, NEUTRAL LINE | #6 - 250 kcmil | 275 IN.-LBS. |
| LOAD, NEUTRAL LOAD | #8 - 2/0 AWG | 50 IN.-LBS. |
| GROUND | #2 - 14 AWG | 50 IN.-LBS. |
| * External Hex Drive 1/2" | | |
| * Internal Hex Drive 5/16" | | |


Accessories

CONDUIT HUBS (RX Type)

| TRADE SIZE | CATALOG No. |
|------------|-------------|
| 3/4 INCH | H38594-2 |
| 1 INCH | H38596-2 |
| 1-1/4 INCH | H38597-2 |
| 1-1/2 INCH | H38598-2 |
| 2 INCH | H38599-2 |
| 2-1/2 INCH | H38600-2 |

Hub Cover Plate Kit
Cat No: H38595-1

5th Jaw Kit
Cat No: EC5J2

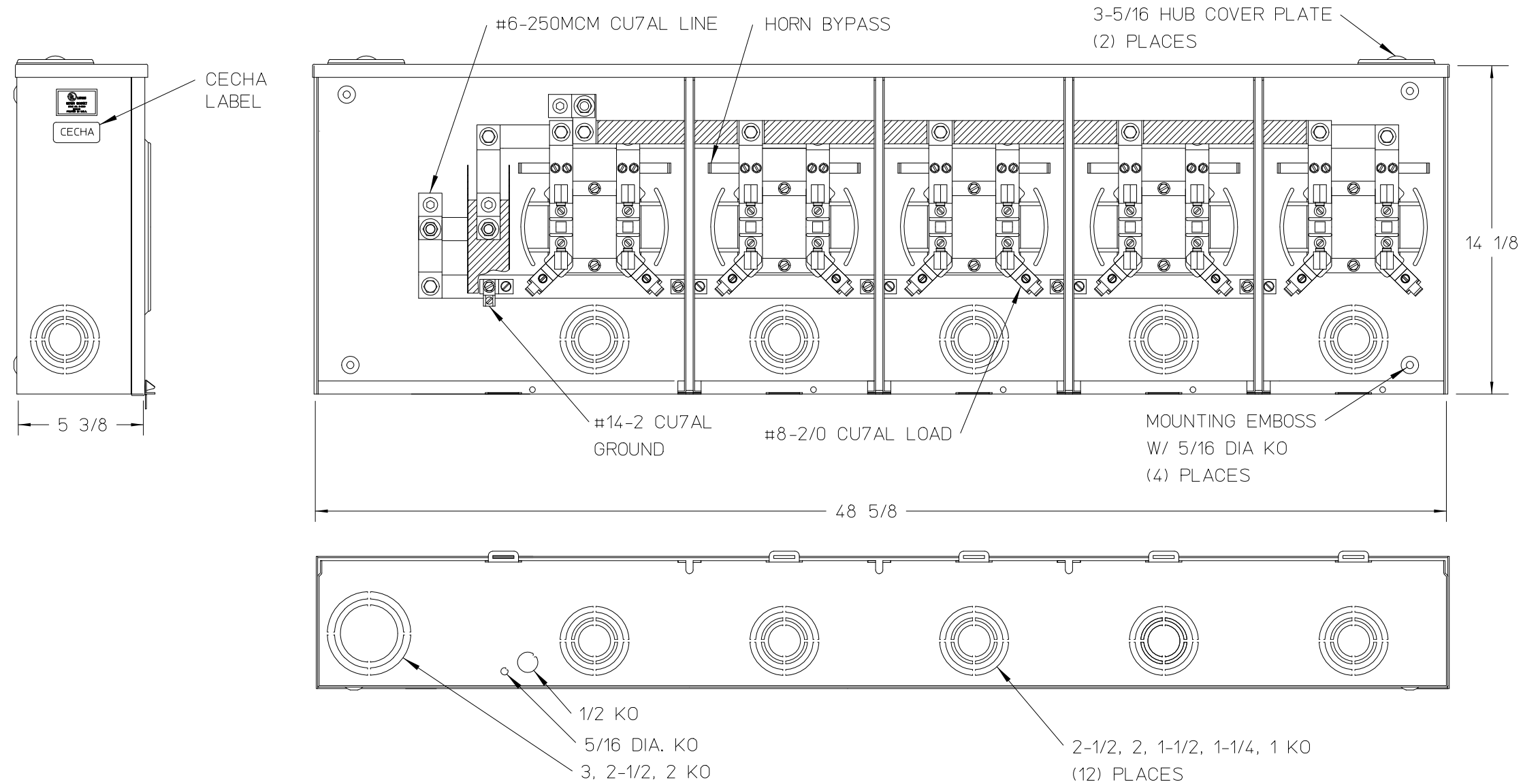

© 2016 Copyright Siemens Industry, Inc.



MULTI-POSITION METERING

Description: RINGLESS, 100A, 4 JAW, 600V AC

GLS 7/18/2016 DO NOT SCALE DRAWING Dwg No: UA5411-XPCH