




Catalog Number: 9817-9406

Features and Ratings




- Ringless Type Meter Socket
- 400A Continuous, 400A Max., 600V AC
- Outdoor Enclosure (NEMA Type 3R)
- Painted Steel Enclosure
- 2 or 3 Phase, Commercial/Industrial Socket
- Meter Socket Type K-5T
- For Overhead & Underground Service
- Two Large Hub Openings, HD Type Cover Plates Installed

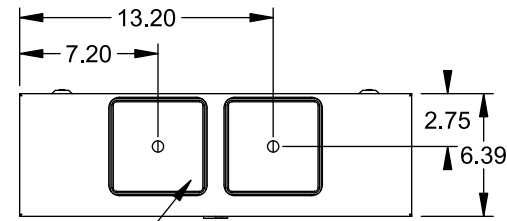

(2) TYPE HD (LARGE) HUB OPENINGS COVER PLATES INSTALLED

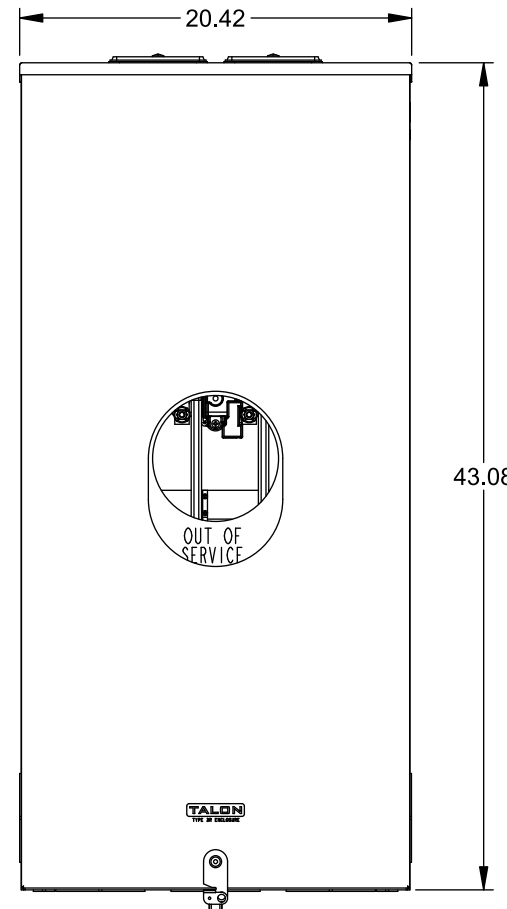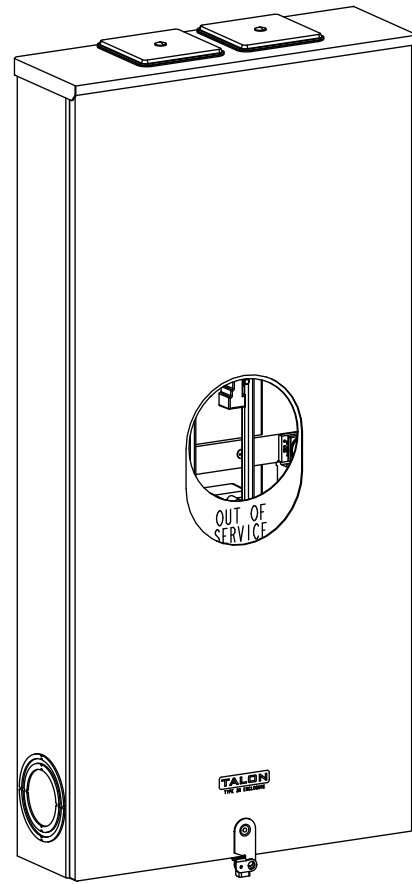

VIEW SHOWN WITH COVER REMOVED

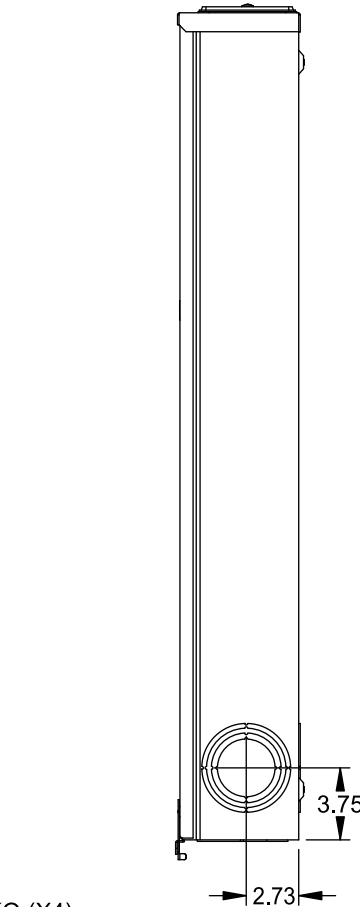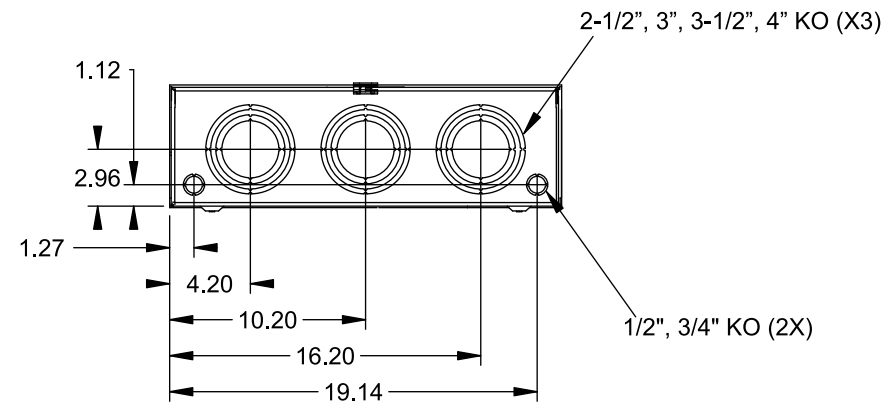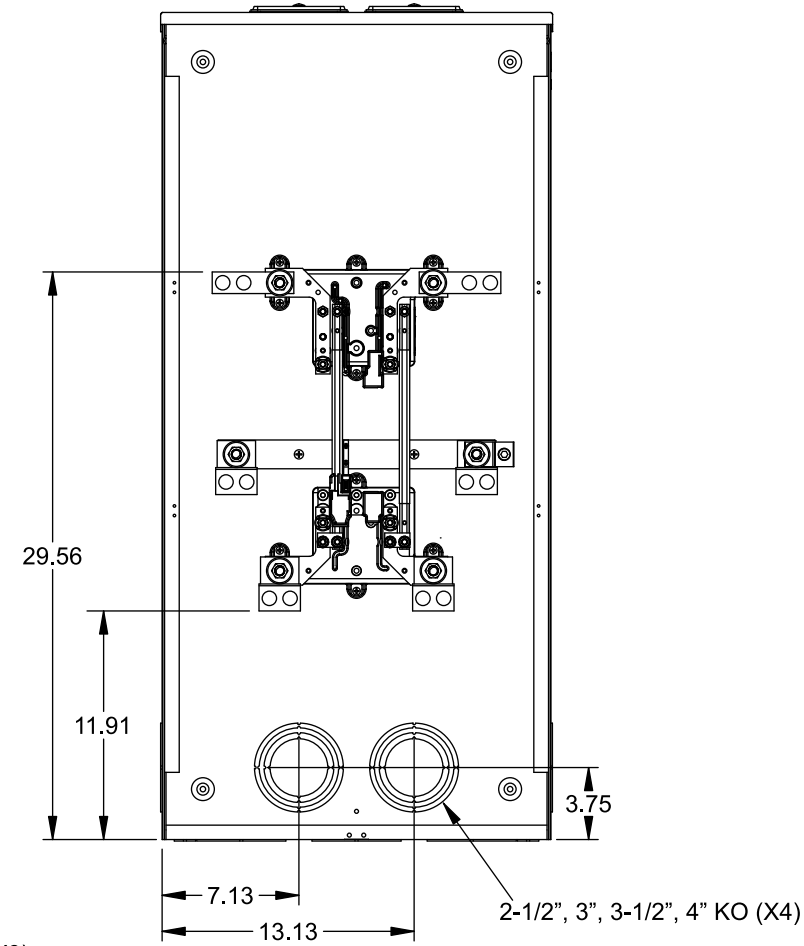

Accessories

CONDUIT HUBS (HD Type)		CAT No.	DESCRIPTION
TRADE SIZE	CATALOG No.		
3 INCH	EC56856 or H56856-2	H69685-1	Bypass Isolated Neutral Kit
3-1/2 INCH	EC56857 or H56857-2	H69546-1	Hex Magnet Socket Kit
4 INCH	EC56858 or H56858-2	H69232-1	Insulated T-Handle Kit
		H65050	K-base Insulator Kit
		H63864	K-base Ground Kit
Hub Cover Plate		EC56933 or H56933S	

Connectors, Wire Sizes and Torques

CONNECTOR	PART No.	HEX DRIVE	WIRE SIZE	TORQUE
LINE	56427-M*	1/2"	(2)#2 - 500 kcmil	375 IN-LBS.
LOAD	56732-M*	1/2"	(2)#4 - 500 kcmil	375 IN-LBS.
GROUND	56734*	5/16"	#6 - 250 kcmil	275 IN-LBS.

*Factory installed

© 2019 Copyright Siemens Industry, Inc.

TALON
Meter Socket

Description: **400A Cont, 5 Terminal, K-5T, 600V AC, Painted Steel Enclosure**

JEL 7/19/19 | DO NOT SCALE DRAWING | Dwg No: **9817-9406**