

Catalog Number: MP0406B1200RB2

Features and Ratings

- Unit Rating: 200A Max., 120/240VAC
- Meter Socket Rating: 200A Continuous
- Ringless Horn Bypass Socket
- Outdoor Enclosure (NEMA Type 3R)
- Painted G90 Steel
- 1 Phase, 3 Wire
- For Underground Service Only

Accessories

FILLER PLATE

Cat No: ECQF3

PAD MOUNT KIT


Cat No: MPFLANGE2

PEDESTAL EXTENSION

Cat No: MPEXT2



Connectors, Wire Sizes and Torques

CONNECTOR	WIRE SIZE	TORQUE
A, B, N	#6 - #1 AWG	75 LB. IN.
	1/0 - 350 KCMIL	275 LB. IN.
LARGE LOAD NEUTRAL N1	#6 - 250 KCMIL	275 LB. IN.
SMALL LOAD NEUTRAL N2	#14 - 1/0 AWG	50 LB. IN.
GROUND G1	#14 - 1/0 AWG	50 LB. IN.
EQUIP GROUND G2	#14 - 4 AWG	50 LB. IN.
EQUIP GROUND G3	#14 - 2 AWG	50 LB. IN.
BRANCH BREAKER	SEE MARKINGS ON BREAKER	

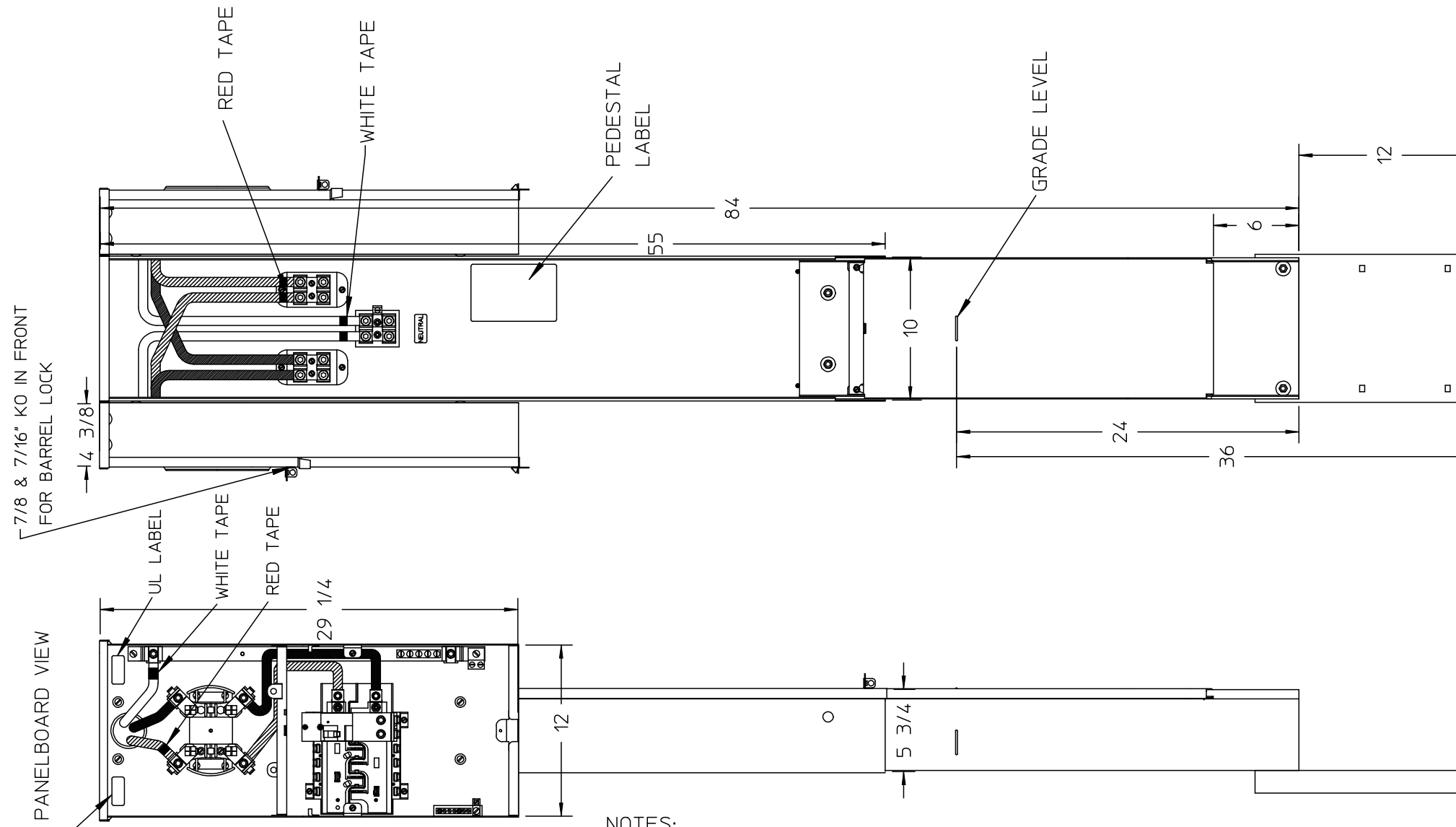

NOTES:

1. PEDESTAL IS FABRICATED FROM 14 GAUGE GALVANIZED STEEL
2. PANELBOARD ENCLOSURE IS FABRICATED FROM 16 GAUGE GALVANIZED STEEL
3. BREAKER COMPARTMENT COVER IS HINGED AT TOP AND LOCKS INTO OPEN POSITION
4. 120/240 VAC, 200 AMP, 1 PHASE, 3 WIRE. 200A BRANCH BREAKER FACTORY INSTALLED
5. LOAD TERMINALS ARE RATED FOR 60° C OR 75° C CONDUCTOR
6. SIEMENS ACCEPTABLE BREAKER TYPES:15-100A "QP" (2) 2-POLE OR UP TO (4) 1-POLE'
7. UNIT SHIPS AS ONE PIECE.

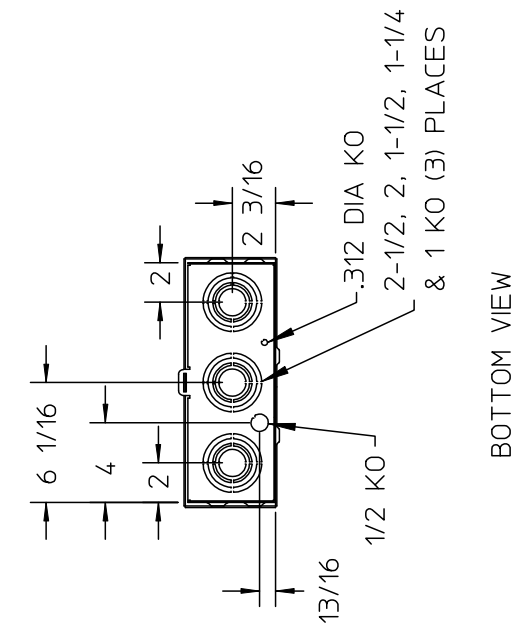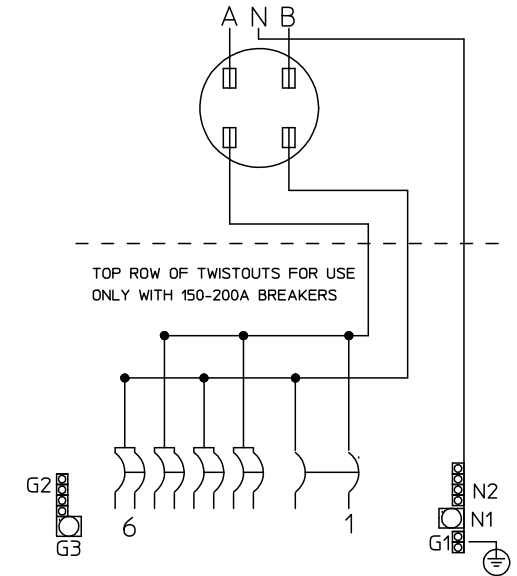

© 2015 Copyright Siemens Industry, Inc.

TALON

MOBILE HOME PEDESTAL

Description:

2 SKT/BKR/PED 200A 1P HORN

CH 6/16/15

DO NOT SCALE DRAWING

Dwg No: MP0406B1200RB2