

WIRE CONNECTOR 2 CABLES 3 PCS. ACCESSORY FOR: 3VA6  
150/250








Model	
Product brand name	SENTRON
Product designation	accessories
Design of the product	circular conductor terminal

Connections according IEC	
Connectable conductor cross-section	
<ul style="list-style-type: none"> <li>• for copper cable / finely stranded / minimum</li> </ul>	25 mm <sup>2</sup>
<ul style="list-style-type: none"> <li>• for copper cable / finely stranded / maximum</li> </ul>	150 mm <sup>2</sup>
<ul style="list-style-type: none"> <li>• for copper cable / stranded / minimum</li> </ul>	25 mm <sup>2</sup>
<ul style="list-style-type: none"> <li>• for copper cable / stranded / maximum</li> </ul>	150 mm <sup>2</sup>
<ul style="list-style-type: none"> <li>• for aluminum cable / stranded / minimum</li> </ul>	25 mm <sup>2</sup>
<ul style="list-style-type: none"> <li>• for aluminum cable / stranded / maximum</li> </ul>	150 mm <sup>2</sup>
Wire stripping length	25 / 50 mm
Tightening torque / when using copper cables	
<ul style="list-style-type: none"> <li>• stranded</li> </ul>	31
<ul style="list-style-type: none"> <li>• finely stranded</li> </ul>	31

Connections according UL	
Wire stripping length	1.0 / 2.0 in

Connectable conductor cross-section	
<ul style="list-style-type: none"> <li>• for copper cable / stranded / minimum</li> <li>• for copper cable / stranded / maximum</li> <li>• for copper cable / finely stranded / minimum</li> <li>• for copper cable / finely stranded / maximum</li> <li>• for aluminum cable / stranded / minimum</li> <li>• for aluminum cable / stranded / maximum</li> </ul>	<p>4 AWG 300 kcmil 4 AWG 300 kcmil 4 AWG 300 kcmil</p>
Tightening torque / when using copper cables	
<ul style="list-style-type: none"> <li>• stranded</li> <li>• finely stranded</li> </ul>	<p>275 lb-in 275 lb-in</p>

## Certificates

General Product Approval	EMC	Declaration of Conformity	other
 CSA	 UL		 RCM
		 EG-Konf.	<a href="#">Miscellaneous</a>

## Further information

### Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/lowvoltage/catalogs>

### Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=3VA9243-0JJ22>

### Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/3VA9243-0JJ22>

### Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)

 




[http://www.automation.siemens.com/bilddb/cax\\_en.aspx?mlfb=3VA9243-0JJ22](http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=3VA9243-0JJ22)

### CAX-Online-Generator

<http://www.siemens.com/cax>

### Tender specifications

<http://www.siemens.com/specifications>

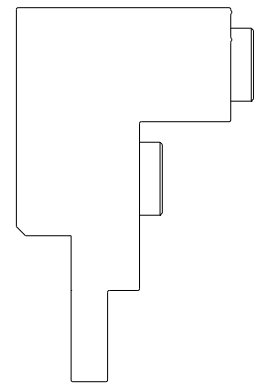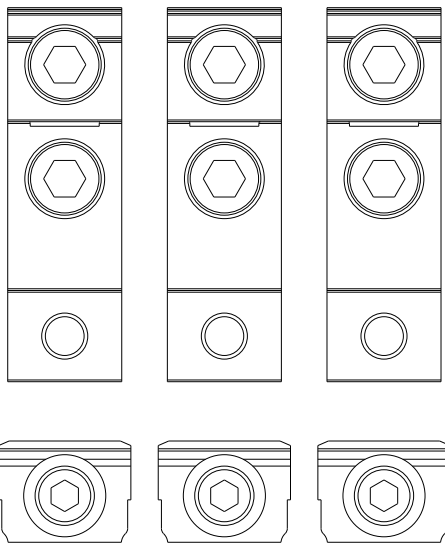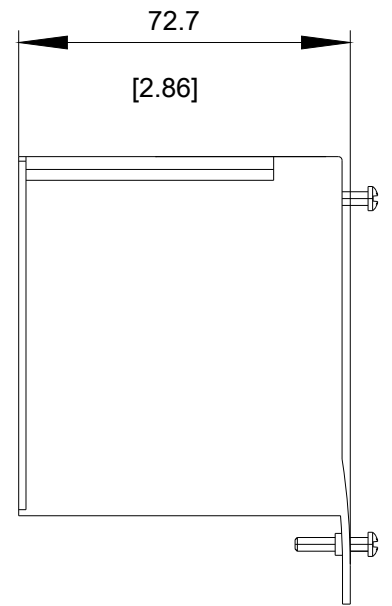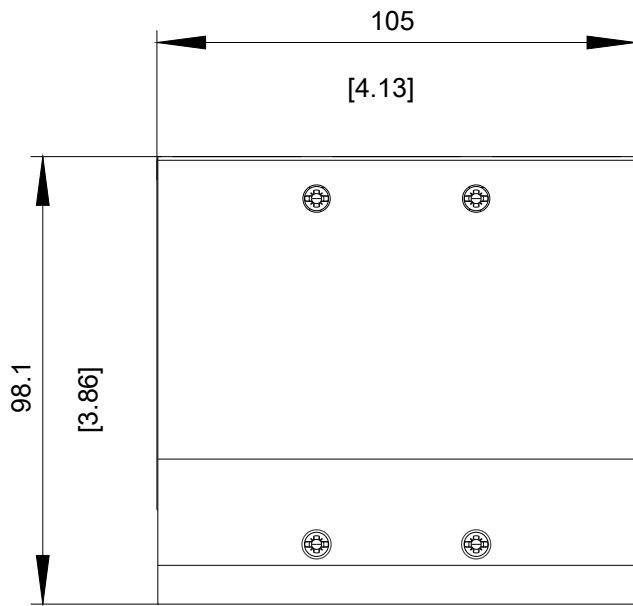

**last modified:**

11/20/2017