




Catalog Number: 9817-8012

Features and Ratings



- Ringless Type Meter Socket
- 400A Continuous, 400A Max., 600V AC
- Outdoor Enclosure (NEMA Type 3R)
- Painted G90 Steel Enclosure
- 3 Phase, Commercial/Industrial Socket
- Meter Socket Type K-7
- For Overhead & Underground Service
- Large Hub Opening, HD Type Cover Plate Installed

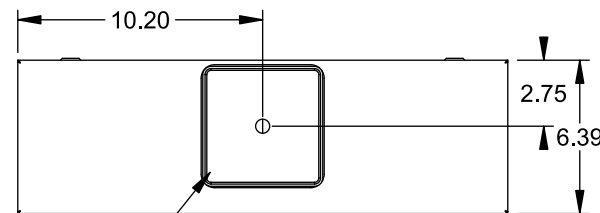

TYPE HD (LARGE) HUB OPENING
COVER PLATE INSTALLED

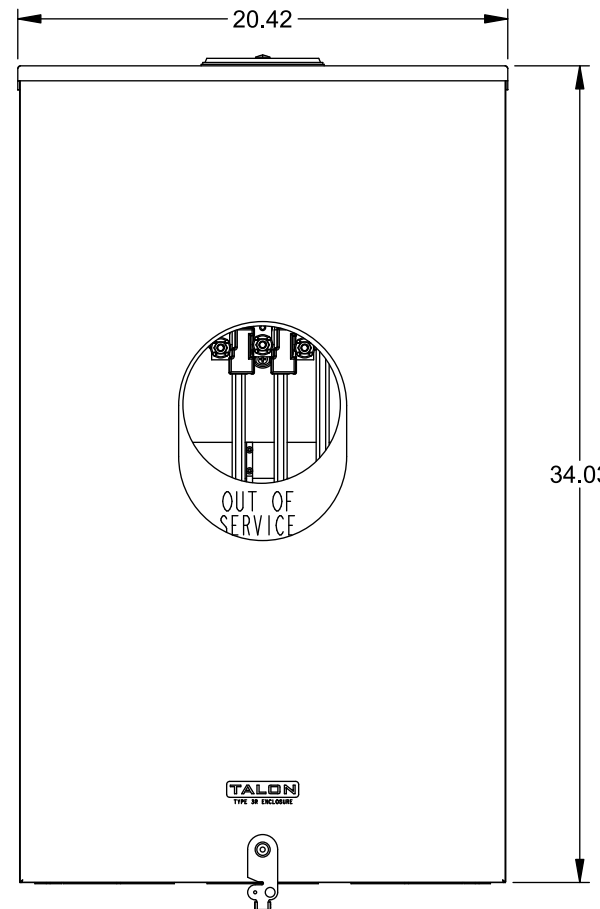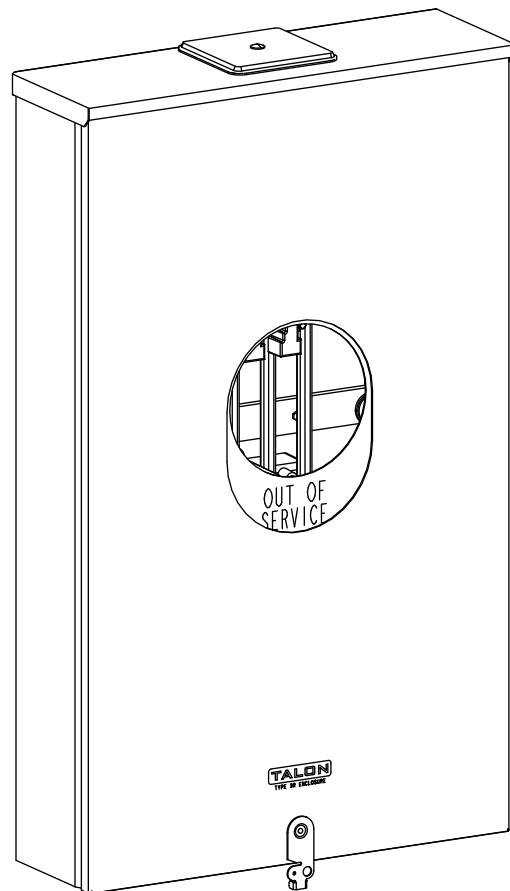

VIEW SHOWN WITH COVER REMOVED

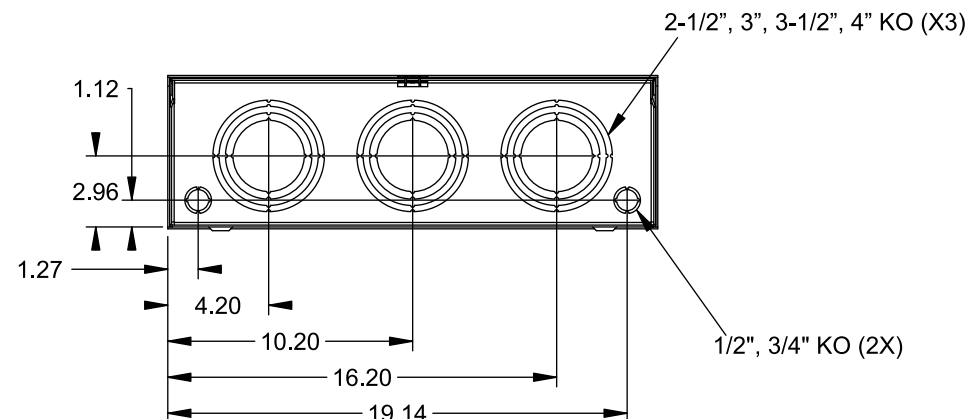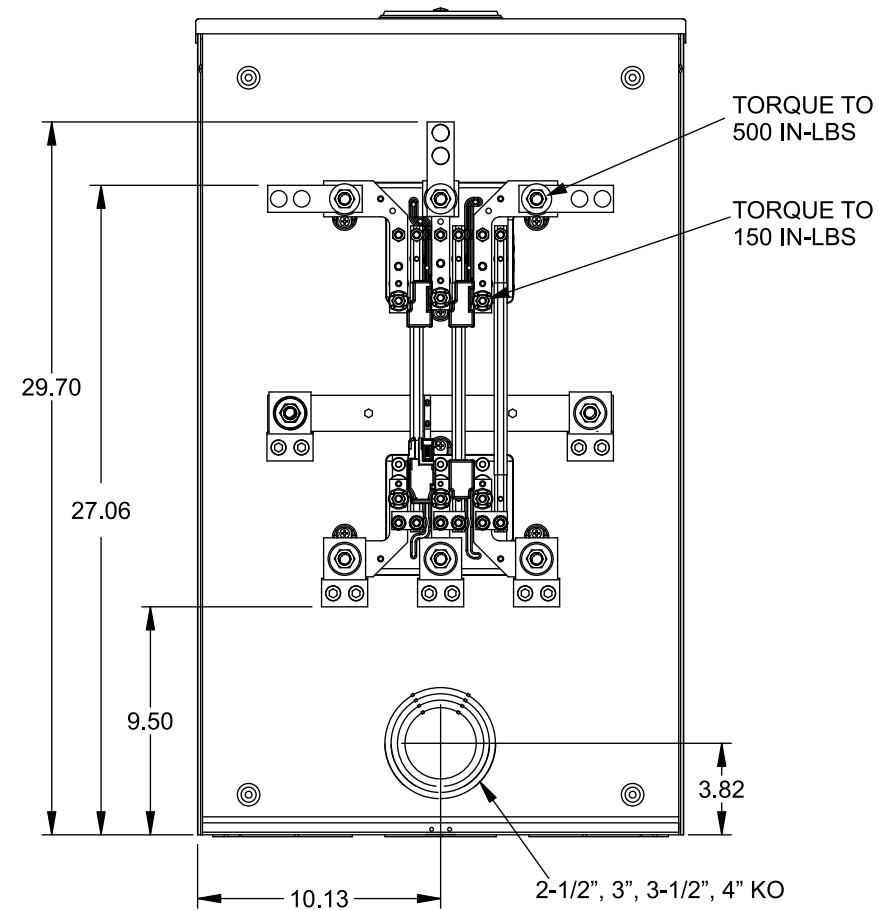

Accessories

| CONDUIT HUBS (HD Type) | | CAT No. | DESCRIPTION |
|------------------------|---------------------|----------|-----------------------------|
| TRADE SIZE | CATALOG No. | | |
| 3 INCH | EC56856 or H56856-2 | H69685-1 | Bypass Isolated Neutral Kit |
| 3-1/2 INCH | EC56857 or H56857-2 | H69546-1 | Hex Magnet Socket Kit |
| 4 INCH | EC56858 or H56858-2 | H69232-1 | Insulated T-Handle Kit |
| Hub Cover Plate | EC56933 or H56933S | H65050 | K-base Insulator Kit |
| | | H63864 | K-base Ground Kit |

Connectors, Wire Sizes and Torques

| CONNECTOR | PART No. | HEX DRIVE | WIRE SIZE | TORQUE |
|-----------|----------|-----------|-------------------|-------------|
| LINE* | 58853 | 5/16" | (2)#6 - 350 kcmil | 275 IN-LBS. |
| LOAD* | 56732 | 5/16" | (2)#4 - 350 kcmil | 275 IN-LBS. |
| NEUTRAL* | 56732 | 5/16" | (2)#4 - 350 kcmil | 275 IN-LBS. |
| GROUND | 56734 | 5/16" | (2)#6 - 250 kcmil | 275 IN-LBS. |

*Factory Installed

© 2015 Copyright Siemens Industry, Inc.

TALON
Meter Socket

Description: **400A Cont, 4 Terminal, K-7, 600V AC, Painted Steel Enclosure**

JEL 12/1/15 DO NOT SCALE DRAWING Dwg No: **9817-8012**