





Catalog Number: 43217-02

Features and Ratings



- Ringless Type Meter Socket
- 125A Continuous, 600V AC
- Outdoor Enclosure (NEMA Type 3R)
- Painted G90 Steel Enclosure
- 3 Phase, 4 Wire
- 7 Jaw Meter Socket
- Meter Socket Type MQ-71NB
- For Overhead Service
- Non-Clamping Lever Bypass
- 1-1/2" RX Type Hub Installed

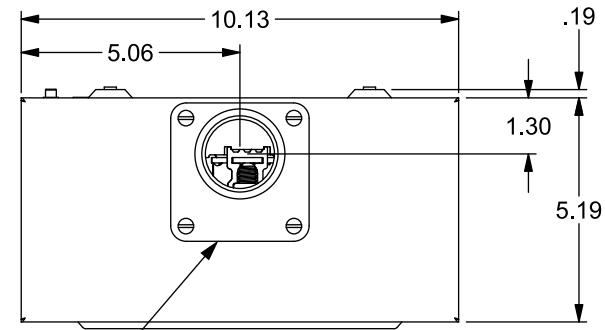

1-1/2" TYPE RX (SMALL) HUB INSTALLED

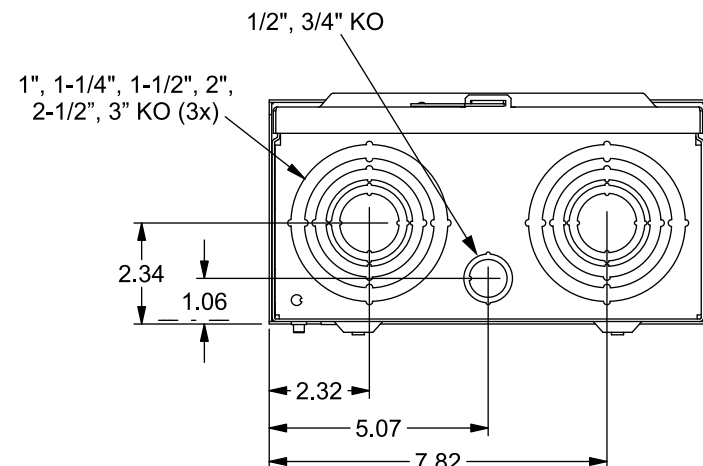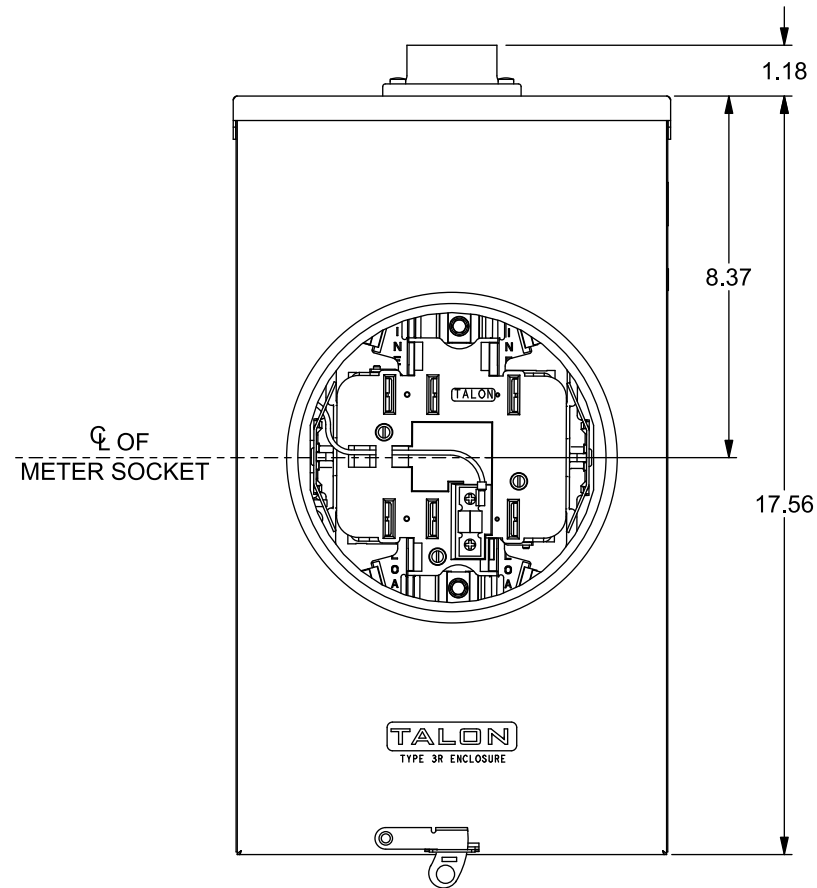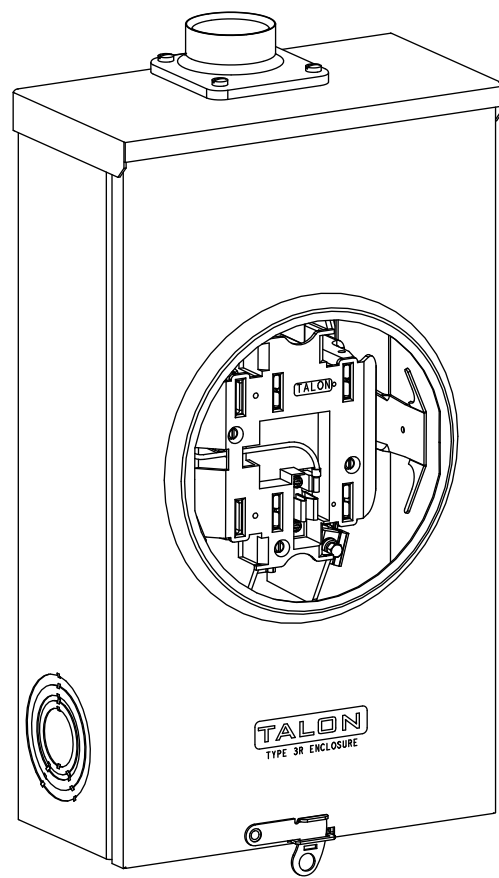

VIEW SHOWN WITH COVER AND SHIELD REMOVED

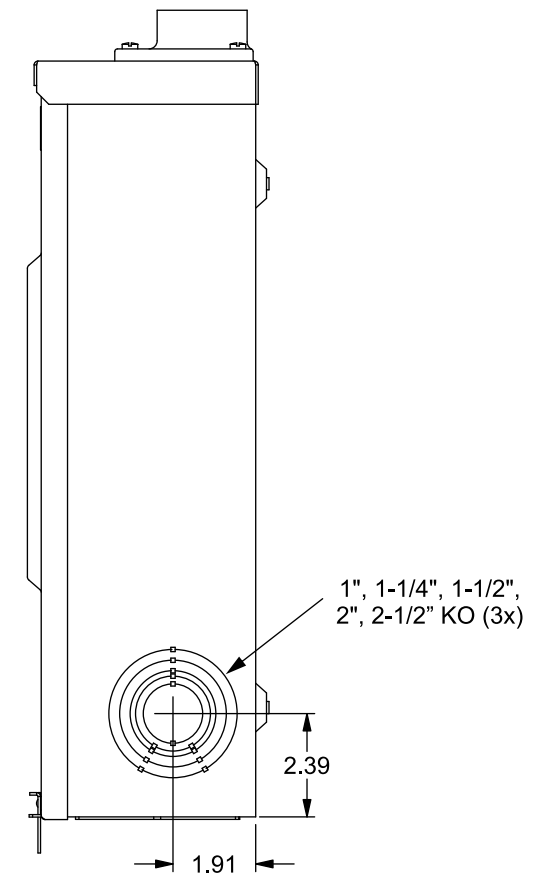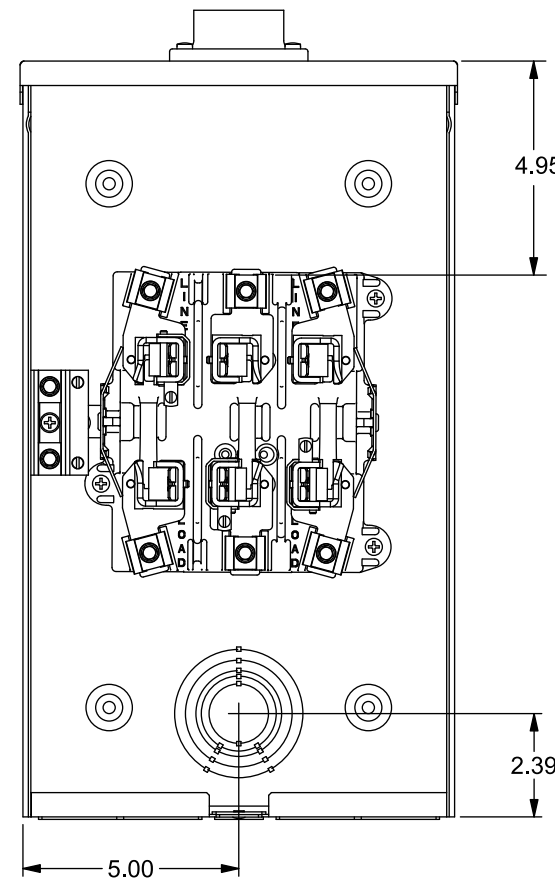

Accessories

| CONDUIT HUBS (RX Type) | |
|------------------------|---------------------|
| TRADE SIZE | CATALOG No. |
| 1-1/4 INCH | EC38597 or H38597-2 |
| 1-1/2 INCH | EC38598 or H38598-2 |
| 2 INCH | EC38599 or H38599-2 |
| 2-1/2 INCH | EC38600 or H38600-2 |
| Hub Cover Plate | EC38595 or H38595-1 |

Meter Opening Cover Plate
Cat No: H659-0162

Connectors, Wire Sizes and Torques

| CONNECTOR | WIRE SIZE | TORQUE |
|---------------------|-----------|------------|
| LINE, LOAD, NEUTRAL | #6 - 2/0 | 50 IN-LBS. |
| GROUND | #2 - 14 | 50 IN-LBS. |

© 2017 Copyright Siemens Industry, Inc.

TALON
Meter Socket

Description: **200A Cont, 7 Jaw, MQ-7U, 1-1/2" Hub, OH, 600V AC, Painted Steel Enclosure**

KAM 12/14/17 DO NOT SCALE DRAWING Dwg No: **43217-02**