



# Catalog Number: 42395-02MR

## Features and Ratings

- Ringless Type Meter Socket
- 125A Continuous, 125A Max.
- Outdoor Enclosure (NEMA Type 3R)
- Painted G90 STEEL
- 1 Phase, 3 Wire, 600V AC
- 5 Jaw, 6 O'clock 5th Jaw
- HQ Clamp Jaw Lever Bypass Meter Socket
- For Overhead or Underground Service
- RX Hub Opening with 1-1/4" HUB Installed
- Two Ground Lugs

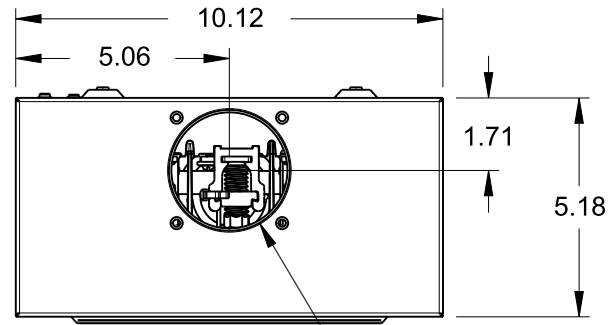




RX HUB PROVISION

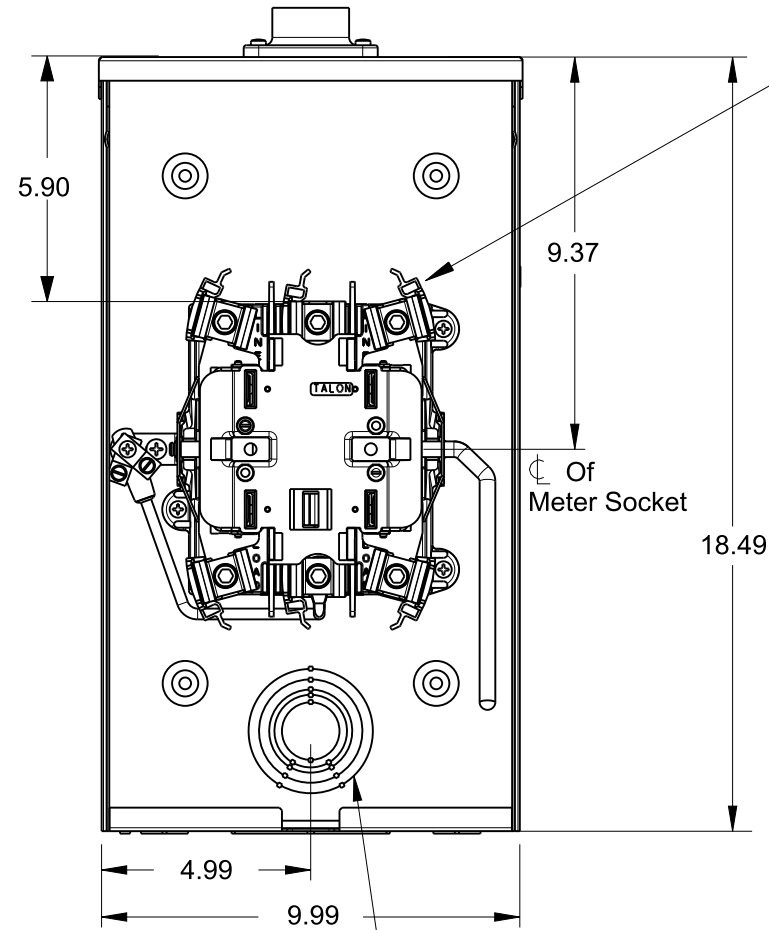

Retention Clips  
Can Be Discarded  
After Installation

Of  
Meter Socket

1", 1-1/4", 1-1/2", 2", 2-1/2", KO 3x

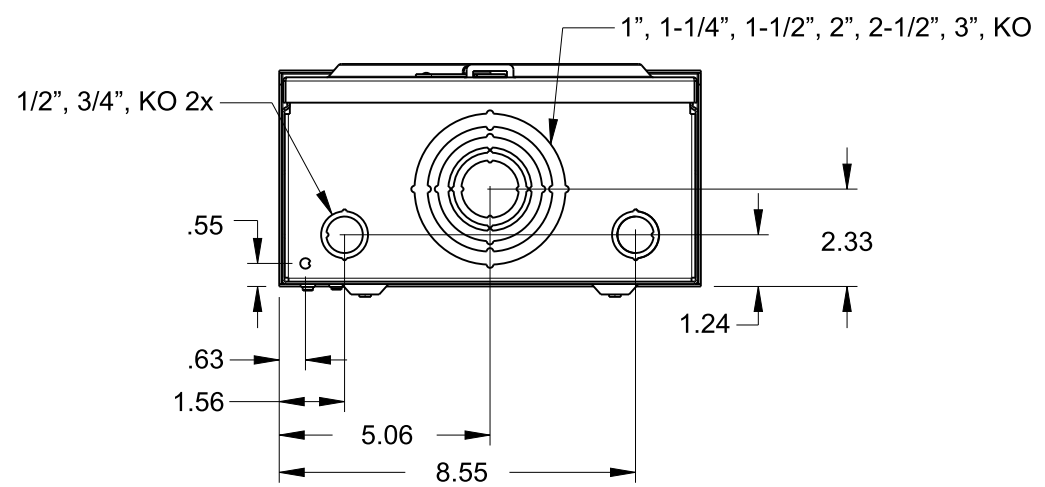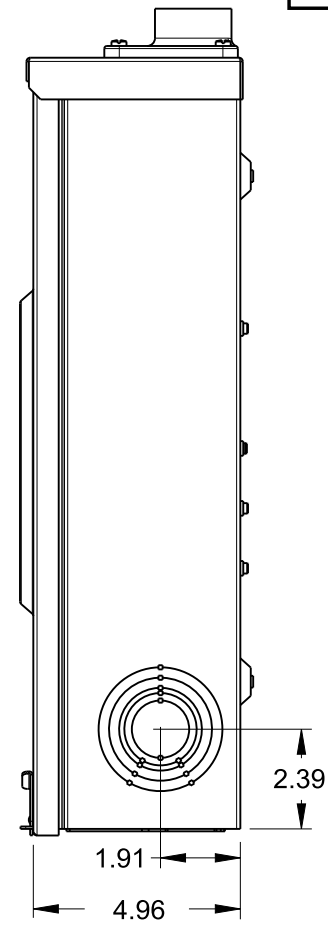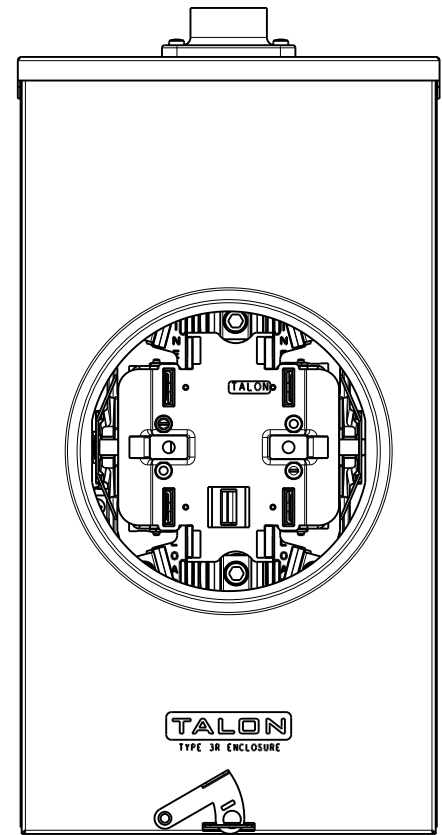


### Accessories

- Meter Opening Cover Plate  
Cat No: H39968
- RX HUB KITS  
Cat No: H38597-2 (1.25")  
Cat No: H38598-2 (1.50")  
Cat No: H38599-2 (2.00")  
Cat No: H38600-2 (2.50")
- RX HUB KITS  
Cat No: EC38597 (1.25")  
Cat No: EC38598 (1.50")  
Cat No: EC38599 (2.00")  
Cat No: EC38600 (2.50")
- HUB COVER PLATE  
Cat No: H38595-1
- GROUND LUG KIT  
H6509991 #14-2 45 LB-IN

### Lugs, Wire Sizes and Torques

LOCATION	LUG SIZE	TORQUE
LINE*	#6-350 kcmil	275 LB-IN
LOAD*	#6-350 kcmil	275 LB-IN
NEUTRAL*	#6-350 kcmil	275 LB-IN
GROUND	#14-2	45 LB-IN

\* External Hex drive 1/2"  
\* Internal Hex drive 5/16"

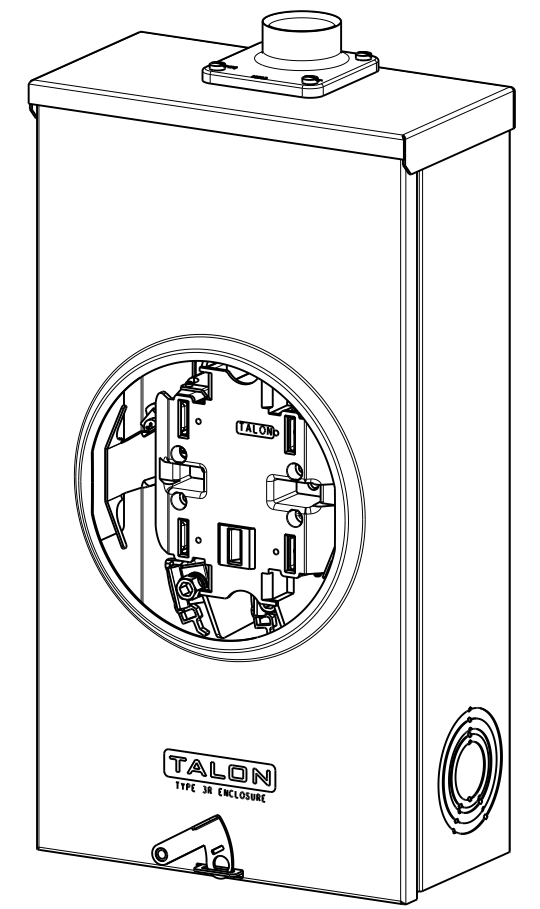

**TALON**  
Meter Socket

Description:  
**125A Cont, 5 Jaw, HQ5, 600V AC,  
Painted G90 Steel**