


1

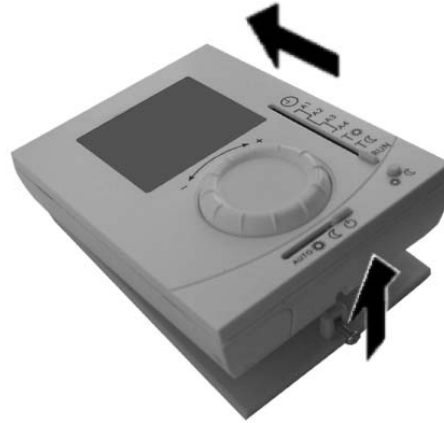

2




3



4



Wiring Diagram

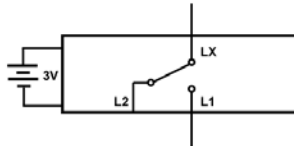

Legend

- LX = Common
- L1 = Live feed to item to be controlled
- L2 = Changeover contact

5



6



Technical Details

Power supply:	2 x 1.5V AA batteries
Temperature setting range	5°C - 30°C
Switching voltage	24...250V~
Current rating	5(2)A

Standards According To EN 60730

Automatic action	Type 1.B
Degree of pollution	2
Rated impulse voltage	4000V

Mounting Instructions

The controller can be wall mounted.

The BPS 242 should be located such that it can acquire the room temperature as accurately as possible, without being affected by direct solar radiation or other heat or refrigeration sources.

Check wiring

All electrical connections must comply with current regulations.