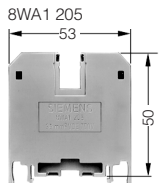



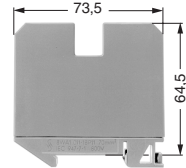


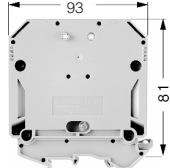


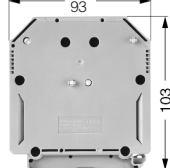


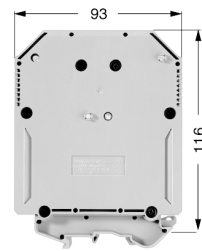




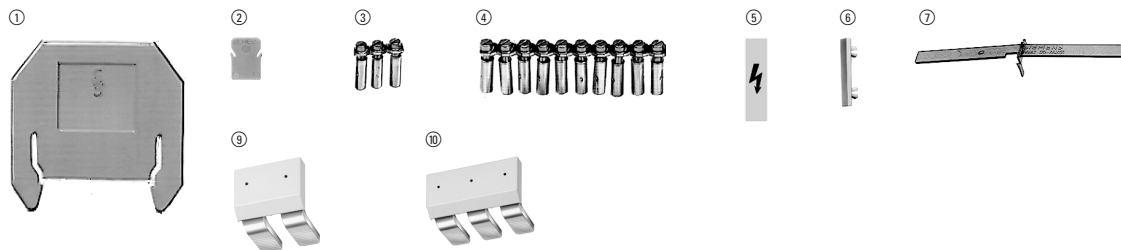
# Terminal Blocks

## 8WA1 Terminals with Screw Connection

Through-type terminals

With insulating body of molded thermoplastic · With screw connections on both sides

Dimensions <sup>3)</sup>	IEC ratings uninterrupted current	UL ratings current / voltage	Description	Design Color	Fig. No.	Order No.	Price
	IEC ratings insulation voltage						
 <p>8WA1 205</p>	Terminal size 35 · Assembly width 16 mm  AWG 10-1  AWG 12-2		<b>Single terminal</b>	beige blue		<b>8WA1 205</b> <b>8WA1 011-1BM11</b>	
	125 A 800 V	120 A 600 V	<b>Terminal block, 3-pole</b>	width 48 mm		<b>8WA1 305</b>	
			<b>Barrier</b>	width 1.5 mm	①	<b>8WA1 823</b>	
			<b>Small partition</b> for single terminal (to 500 V)		②	<b>8WA1 822-7TK00</b>	
 <p>8WA1 305</p>	125 A		<b>Link rail</b> for	2 terminals 3 terminals 10 terminals	③ ④	<b>8WA1 828</b> <b>8WA1 803</b> <b>8WA1 804</b>	
	-		<b>Cover</b>	with warning arrow white, for inscription	⑤ ⑥	<b>8WA1 813</b> <b>8WA1 893</b>	
			for link rails <sup>1)</sup> , length 100 mm	transparent white, for inscription	⑦	<b>8WA1 822-7AX02</b> <b>8WA1 822-7AX04</b>	
 <p>8WA1 206</p>	Terminal size 70 · Assembly width 25 mm  AWG 8-3/0  AWG 8-1/0		<b>Single terminal</b>	beige blue		<b>8WA1 206</b> <b>8WA1 011-1BP11</b>	
	192 A 800 V	220 A 600 V	<b>Barrier</b>	width 1.5 mm	①	<b>8WA1 824</b>	
	192 A		<b>Link rail</b>	for 2 terminals		<b>8WA1 216</b>	
	-		<b>Cover</b>	with warning arrow	⑤	<b>8WA1 814</b>	
 <p>8WA1 011-1DQ10</p>	Terminal size 95 · Assembly width 25 mm  AWG 4/0-2  AWG 4/0-2 AWG		<b>Single terminal</b> <sup>2)</sup>	beige		<b>8WA1 011-1DQ10</b>	
	232 A 1000 V	230 A 600 V	<b>Cover</b>	with warning arrow	⑤	<b>8WA1 822-7AQ00</b>	
			<b>Link</b>	for 2 terminals for 3 terminals	⑨ ⑩	<b>8WA1 822-7VQ12</b> <b>8WA1 822-7VQ13</b>	
 <p>8WA1 011-1DS10</p>	Terminal size 150 · Assembly width 31 mm  AWG 300 mcm - 2 AWG  AWG 300 mcm - 2 AWG		<b>Single terminal</b> <sup>2)</sup>	beige		<b>8WA1 011-1DS10</b>	
	309 A 1000 V	275 A 600 V	<b>Cover</b>	with warning arrow	⑤	<b>8WA1 822-7AS00</b>	
			<b>Link</b>	for 2 terminals for 3 terminals	⑨ ⑩	<b>8WA1 822-7VS12</b> <b>8WA1 822-7VS13</b>	
 <p>8WA1 011-1DU10</p>	Terminal size 240 · mounting width 36 mm  AWG 500 mcm - 2/0 AWG  AWG 500 mcm - 2/0 AWG		<b>Single terminal</b> <sup>2)</sup>	beige		<b>8WA1 011-1DU10</b>	
	380 A 1000 V	370 A 600 V					



Labelling accessories see page 15/40 - 43.

1) Only to be used for single terminals 3) 25.4 mm = 1.00 inch.  
2) Tightening torque MA = 15 Nm

Discount Code: Terminal Blocks